


**Flush light indicator**

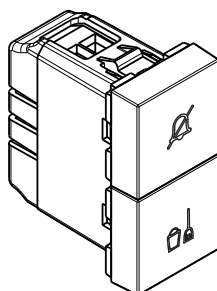

**Use** | **Connection**

Flush light indicator unit signalling “do not disturb / make up the room”, to be used with changeover switch for hotel room.

Terminal type: screw clamp  
Terminal capacity: 2 x 1.5 mm<sup>2</sup> or 1 x 2.5 mm<sup>2</sup> max  
Stripping length: 8 mm  
Compatible with flexible or rigid cables


**Range**

Designation	Item
Flush light indicator - power supply 127/230 V a.c. - 1 modules	□ R4373

**Technical characteristics**

- **Protection index**  
(considering a complete installation, including cover plate)  
Penetration by solid bodies/liquid: IP40
- **Mechanical characteristics**  
Impact test: IK 04
- **Material characteristics**  
Material:  
Case: PC (Polycarbonate)  
Key cover: PC  
UV resistant
- **Self-extinguishing:**  
850° C / 30 s for insulating parts holding live parts in place  
650° C / 30 s for other parts made of insulating materials
- **Electrical characteristics**  
Voltage: 127/230 V a.c.  
Frequency: 50-60 Hz  
Power consumption : 2x0.4W
- **Climatic characteristics**  
Storage temperature: - 10° C to + 70° C  
Use temperature: - 5° C to + 35° C

**Overall dimensions (mm)**

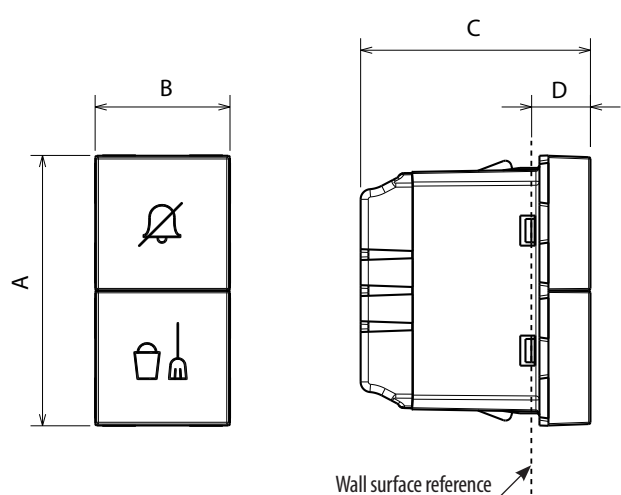

A	B	C	D
45.1	22.5	38.3	9.8

**Cleaning**

Clean the surface with a cloth.  
Do not use acetone, tar-removing cleaning agents or trichloroethylene.  
**Caution: Always test before using special cleaning products.**

**Standards and approvals**

Compliance with standards  
Refer to e.catalogue.