


**Flush light indicator**

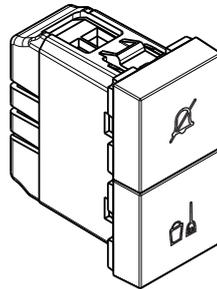

**Use** **Connection**

Flush light indicator unit signalling “do not disturb / make up the room”, to be used with changeover switch for hotel room. The LEDs are not replaceable.

Terminal type: screw clamp  
Terminal capacity: 2 x 1.5 mm<sup>2</sup> or 1 x 2.5 mm<sup>2</sup> max  
Stripping length: 8 mm  
Compatible with flexible or rigid cables

**Range**

**Technical characteristics**

**Designation** **Item**

Flush light indicator □ J4373  
- power supply 127/230 Va.c.  
- 1 module

- **Protection index:**  
(considering a complete installation, including cover plate)

- Penetration by solid bodies/liquid: IP40
- Impact test: IK04

- **Material characteristics:**

- Case / Key cover : PC
- UV resistant
- Self-extinguishing:  
850°C/30s for insulating parts holding live parts in place.  
650°C/30s for other parts made of insulating material.

**Colors:** □ Opal White


- **Electrical characteristics:**

- Voltage: 127/230 V a.c.
- Frequency: 50/60 Hz
- Power consumption : 2x0.4 W
- LED light

- **Climatic characteristics:**

- Storage temperature: -10° C a +70° C
- Use temperature: -5° C a +35° C

**Overall dimensions (mm)**

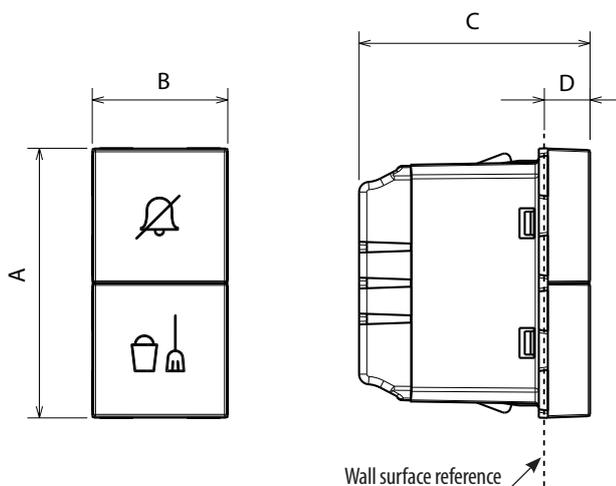

A	B	C	D
45.1	22.5	38.3	7.6

**Cleaning**

Clean the surface with a cloth.  
Do not use acetone, tar-removing cleaning agents or trichloroethylene.  
**Caution: Always test before using special cleaning products.**

**Standards and approvals**

Compliance with standards CEI/EN62094-1

Refer to e.catalogue.