


Connector for optical fiber

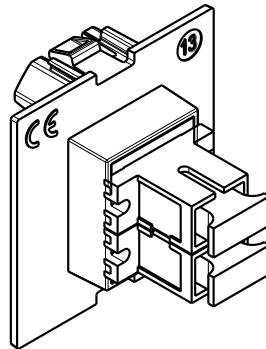

Use

SC/APC double optical fiber connector
 - For connecting fibres to the workstation
 - 2 modules

Connection

Snap coupling

Range

Designation	Cat. No.	Related Cover Codes
Connector for optical fiber	■ K4286SCA2	<input type="checkbox"/> KW13M2 <input type="checkbox"/> KM13M2 <input checked="" type="checkbox"/> KG13M2

Technical characteristics

- **Protection index**
 (considering a complete installation, including cover plate)
 Penetration by solid bodies/liquid: IP20

- Impact test: IK 04

- **Material characteristics**


Material: Cover PC/ABS
 Halogen-free
 UV resistant
 Self-extinguishing: 650°C/30 s

- **Climatic characteristics**

Storage temperature: - 10° C to + 70° C
 Use temperature: -5° C to + 35° C

Colours code: White Sand Black

Overall dimensions (mm)

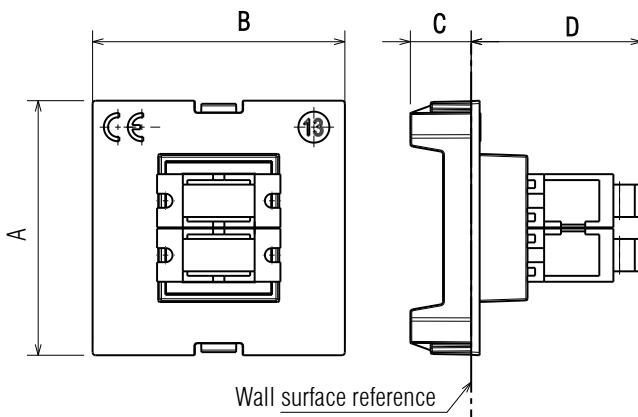

A	B	C	D
45	45	11	30.3

- **Features of the connectors**

SC/APC connector
 - Singlemode APC
 - Insertion loss: 0.2 dB
 - Endurance (500 insertions): increase of 0.2 dB maximum

Cleaning

Clean the surface with a cloth.
 Do not use acetone, tar-removing cleaning agents or trichloroethylene.
Caution: Always test before using special cleaning products.

Standards and approvals

Compliance with standards TIA-568-C-2
 Refer to e.catalogue.