


Mounting Kit for Polybox Enclosures


Mounting instructions

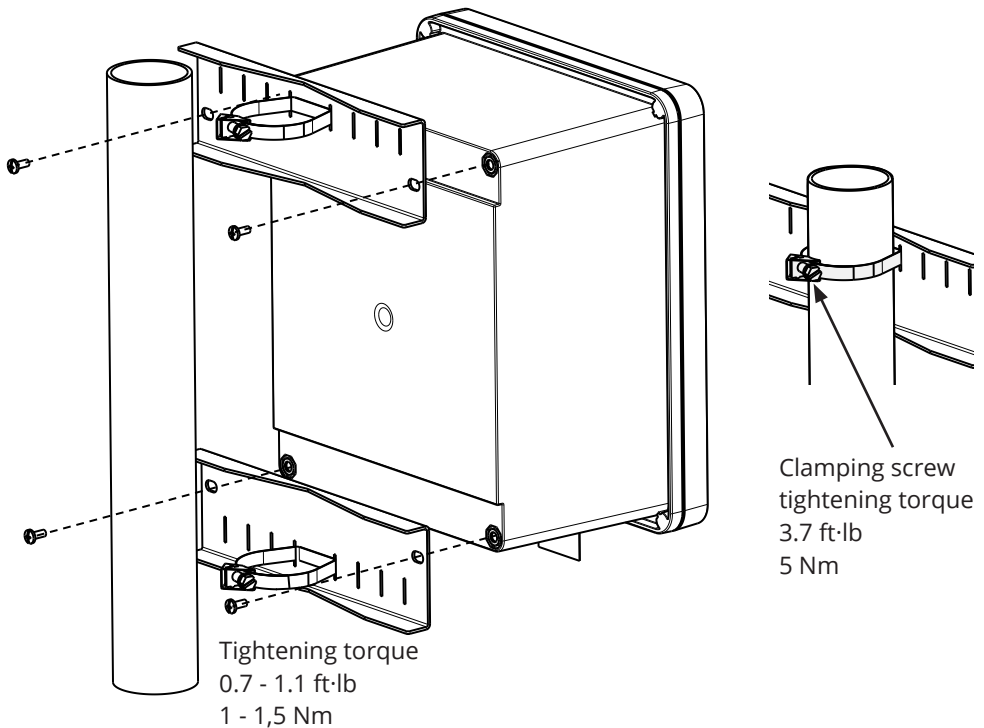

Ensto Building Systems Finland Oy
Ensio Miettisen katu 2, P.O. Box 77
FIN-06101 Porvoo, Finland
Tel. +358 204 76 21
www.ensto.com

PEM862
10.2.2022
© 2022 Ensto



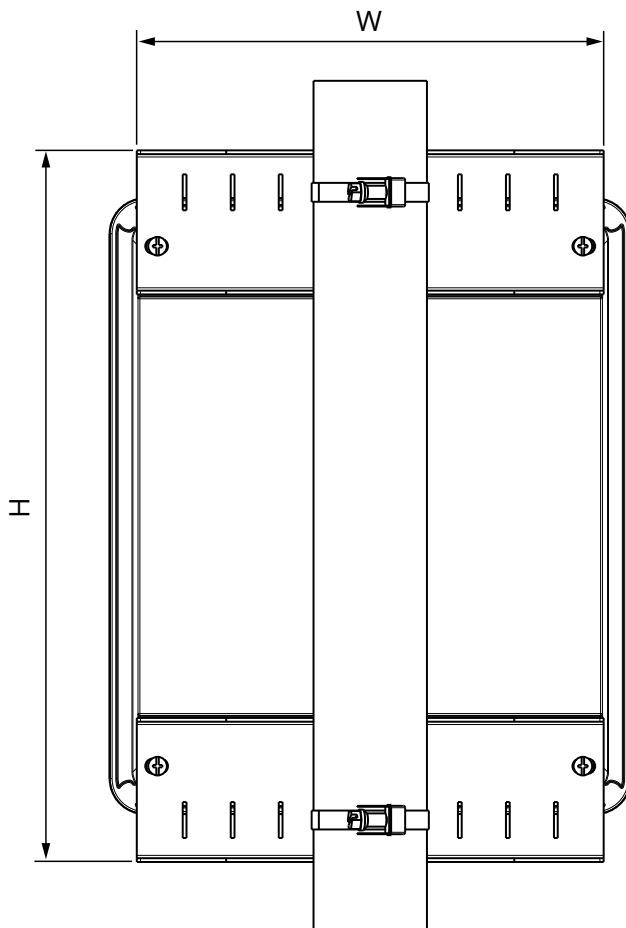

Code	W	H	Pole Ø	Load *
UPMB0806	5.79 in 147 mm	10.80 in 275 mm	2.36 - 5.51 in 60 - 140 mm	55.1 lb 25 kg
UPMB1008	7.75 in 197 mm	12.83 in 326 mm	2.36 - 5.51 in 60 - 140 mm	220.4 lb 100 kg
UPMB1210	9.72 in 247 mm	14.80 in 376 mm	2.36 - 5.51 in 60 - 140 mm	220.4 lb 100 kg
UPMB1412	11.69 in 297 mm	16.80 in 427 mm	2.36 - 5.51 in 60 - 140 mm	220.4 lb 100 kg
UPMB1612	13.66 in 347 mm	18.80 in 478 mm	2.36 - 5.51 in 60 - 140 mm	220.4 lb 100 kg
UPMB1810	16.63 in 397 mm	20.80 in 529 mm	2.36 - 5.51 in 60 - 140 mm	220.4 lb 100 kg

* The values are tested for brackets. The enclosure may have a lower tolerance.