


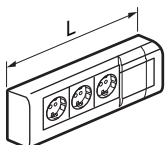



 
L x 75 x 45,5 mm

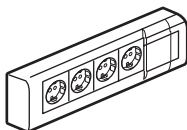

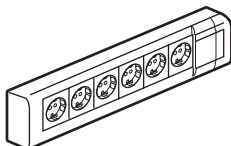

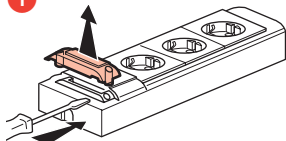


 L = 208
 3909 01

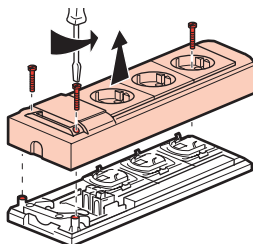 L = 253
 3909 02

 L = 343
 3909 03


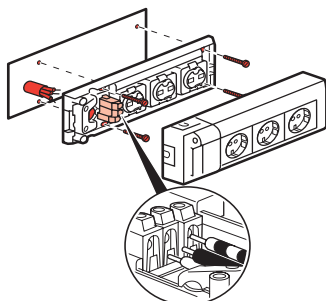
1



2

3G 2,5 mm²

	a	b	c	d
 IRO 16  IRO 20	✓	✓	✓	-
 32 x 20  32 x 16  32 x 12,5	✓	✓	✓	-
 20 x 12,5 <small>IEC 60900</small>	✓	✓	✓	-
 3G 2,5 mm ²	✓	✓	✓	✓


 3G
 1,5 mm² min.
