

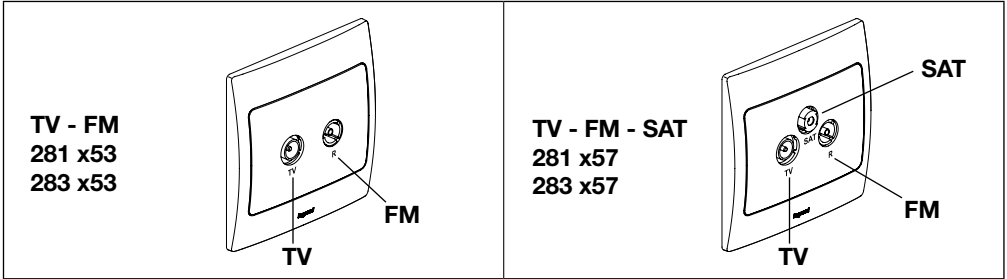


Mallia™ 281 153 283 153 283 353 283 553
 281 157 283 157 283 357 283 557



- TV - FM SOCKET
- TV - FM - SAT TYPE F SOCKET

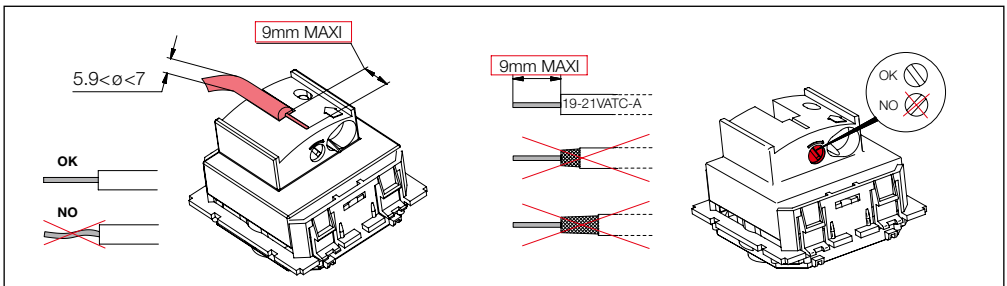


		DISEqC®	Return channel	Band 1	FM	VHF	UHF	IF1 SAT
Mallia™		22 KHz 13/18 V	4-30 MHz	47-68 MHz	87.5-108 MHz	120-470 MHz	470-862 MHz	950-2150 MHz
281 x53	TV			1.5dB			1.5dB	
283 x53	FM				1.5dB			
281 x57	TV			1.5dB			1.5dB	
283 x57	FM				1.5dB			
	SAT	500mA						2dB

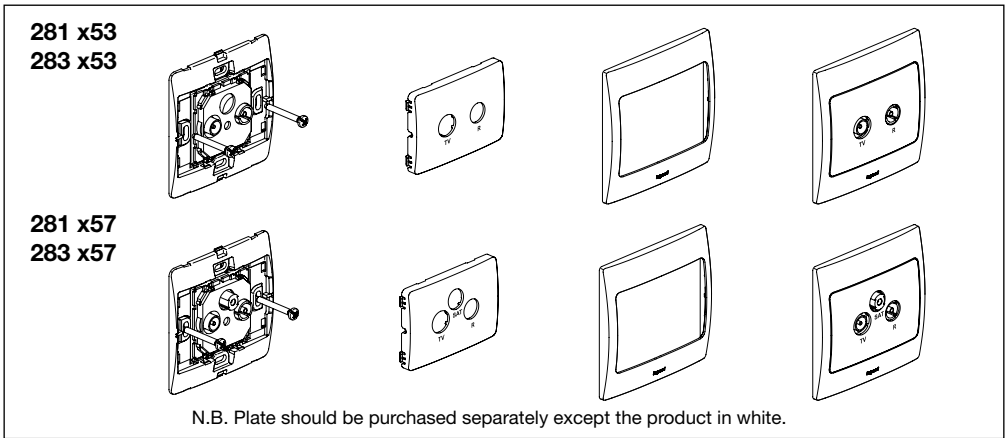


①

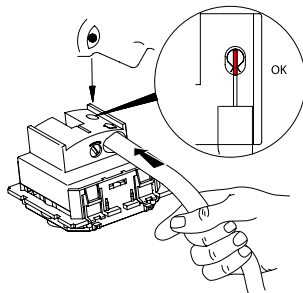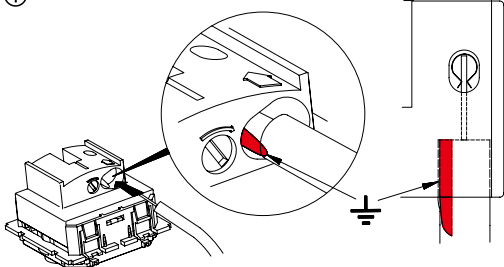


②

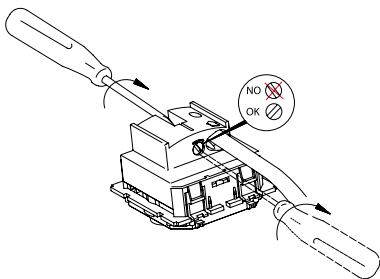


③

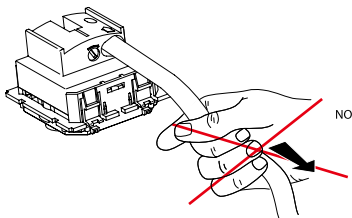

● Auxiliaries

 




TV TV + SAT

 

TV TV TV + SAT



TV TV TV TV + SAT

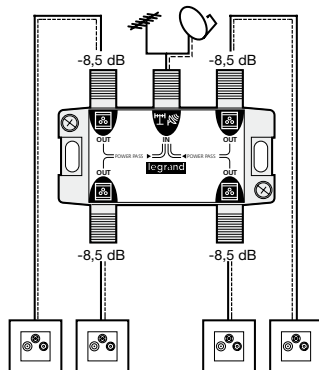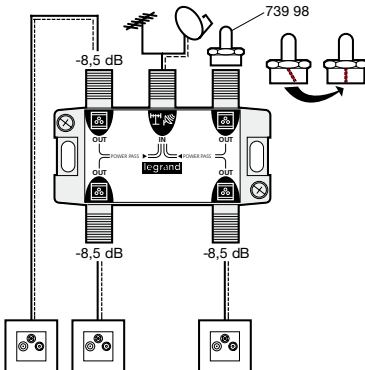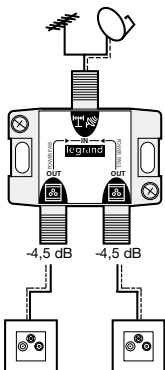

----- power pass ♡

----- power pass ♡

----- power pass ♡