




5 722 38

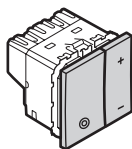

5 727 38 - 5 729 38/39

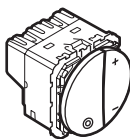

5 743 18

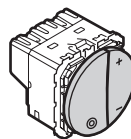

5 743 38

		0 - 10 V		
 50/60 Hz	 2 x 2,5 mm ²			
240 V	Max.	600 VA	600 VA	600 VA
	Min.	20 VA	20 VA	20 VA
100 V	Max.	300 VA	300 VA	300 VA
	Min.	20 VA	20 VA	20 VA

