


<p>Ø 38</p>	<p>Ø 25</p>	<p>20 cm mini</p>
<p>50W (halogène) max. 13W (fluo) max.</p>	<p>11W max.</p>	

NF C 15-100

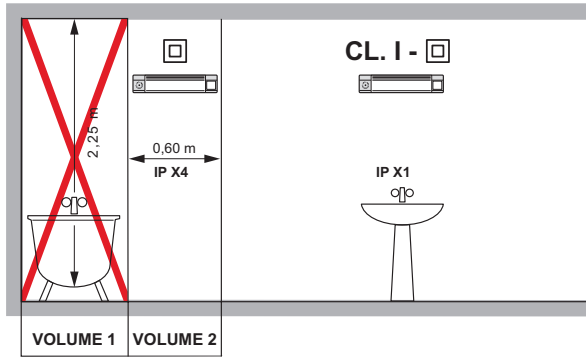

1

IP 24

CLIC

CLIC

2

202 mm

Ø 5 x 50 mm

3

