
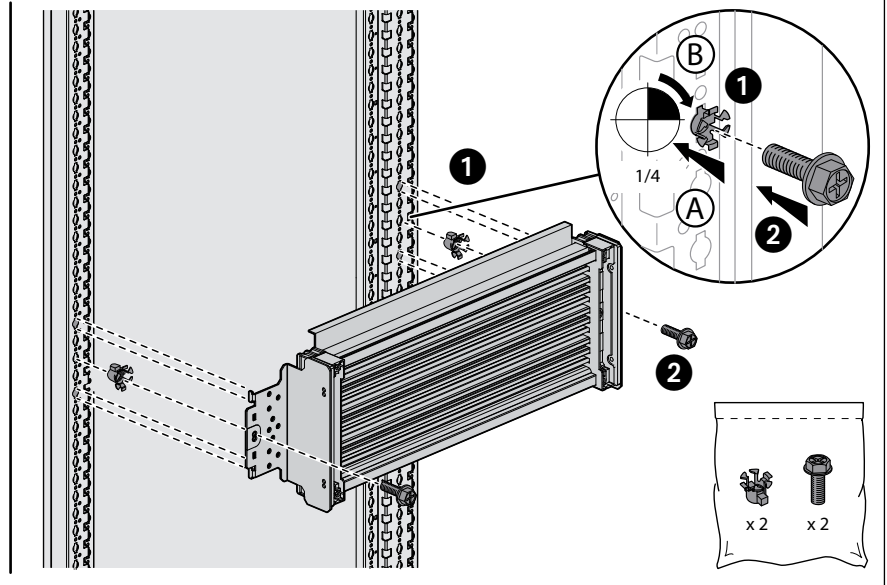




TF250M24/TF250M36/TG250M24/
TG250M36/TG400M24/TG400M36

250A	TF250...	MAS400 – XL ³ 400
	TG250...	MAS800/4000 – XL ³ 800/4000
400A	TG400...	MAS800/4000 – XL ³ 800/4000


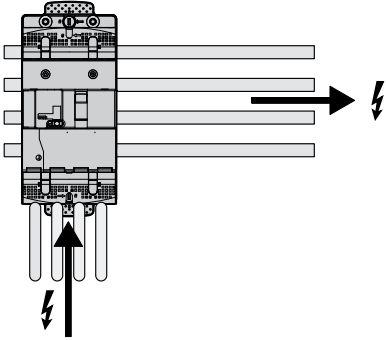



TF250AM24/TF250AM36/TG250AM24/
TG250AM36/TG400AM24/TG400AM36

250A	TF250...	MAS400 – XL ³ 400
	TG250...	MAS800/4000 – XL ³ 800/4000
400A	TG400...	MAS800/4000 – XL ³ 800/4000

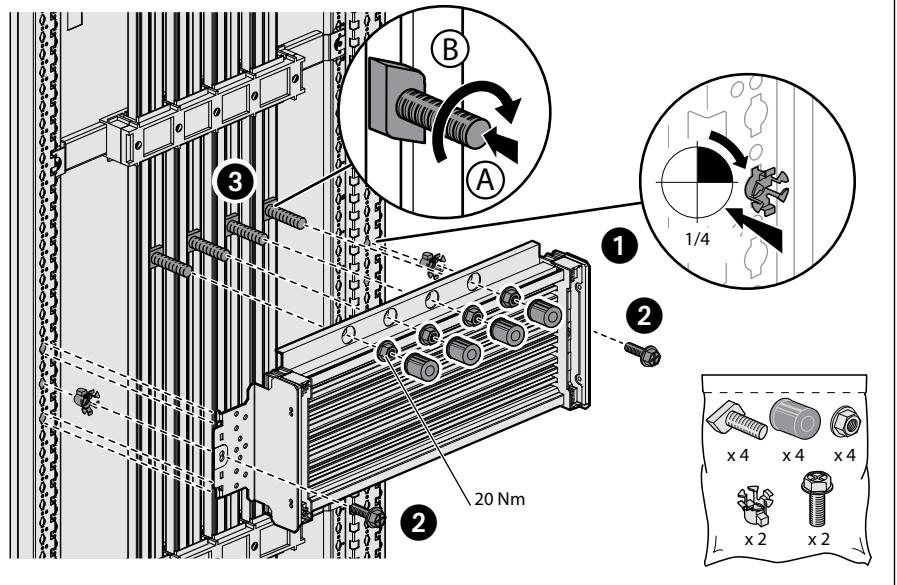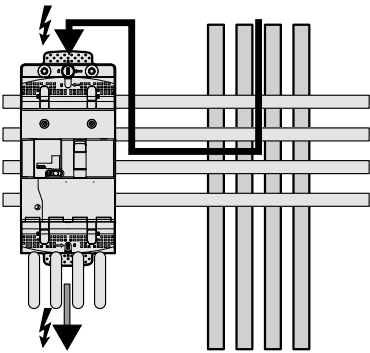












TCAL400/4 044 82

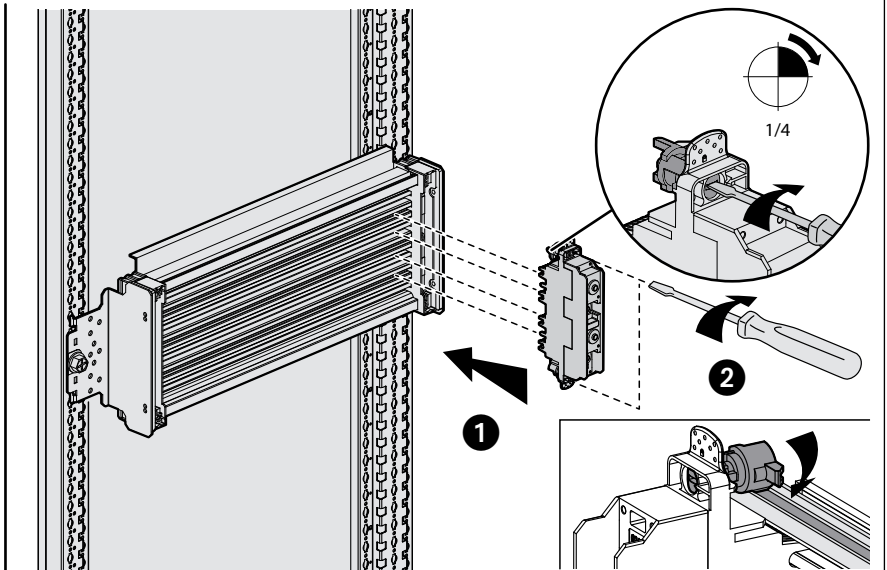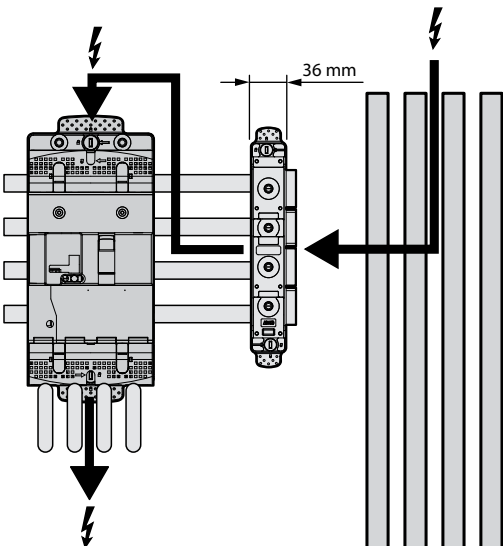

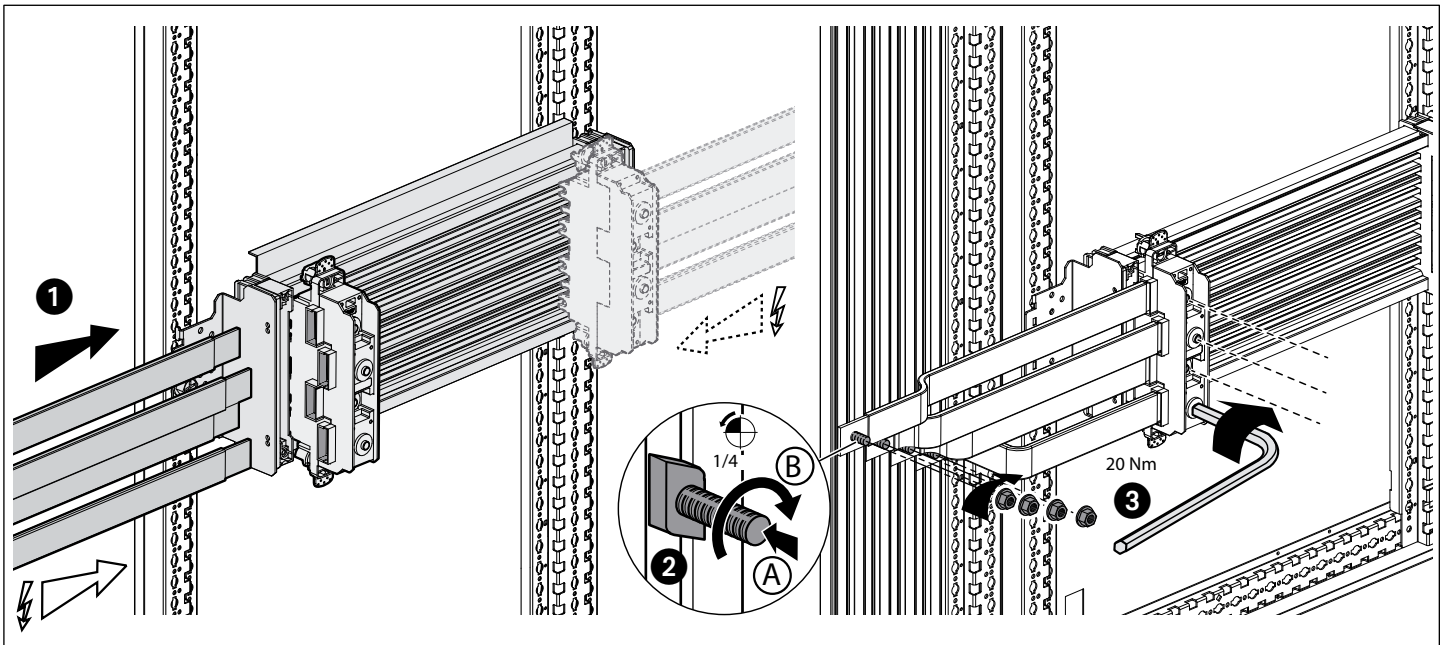


TKAL250		TKAL250E 4 044 87	
TKAL250B8E TKAL400B8E 4 044 86		TKAL400I350 4 045 53	

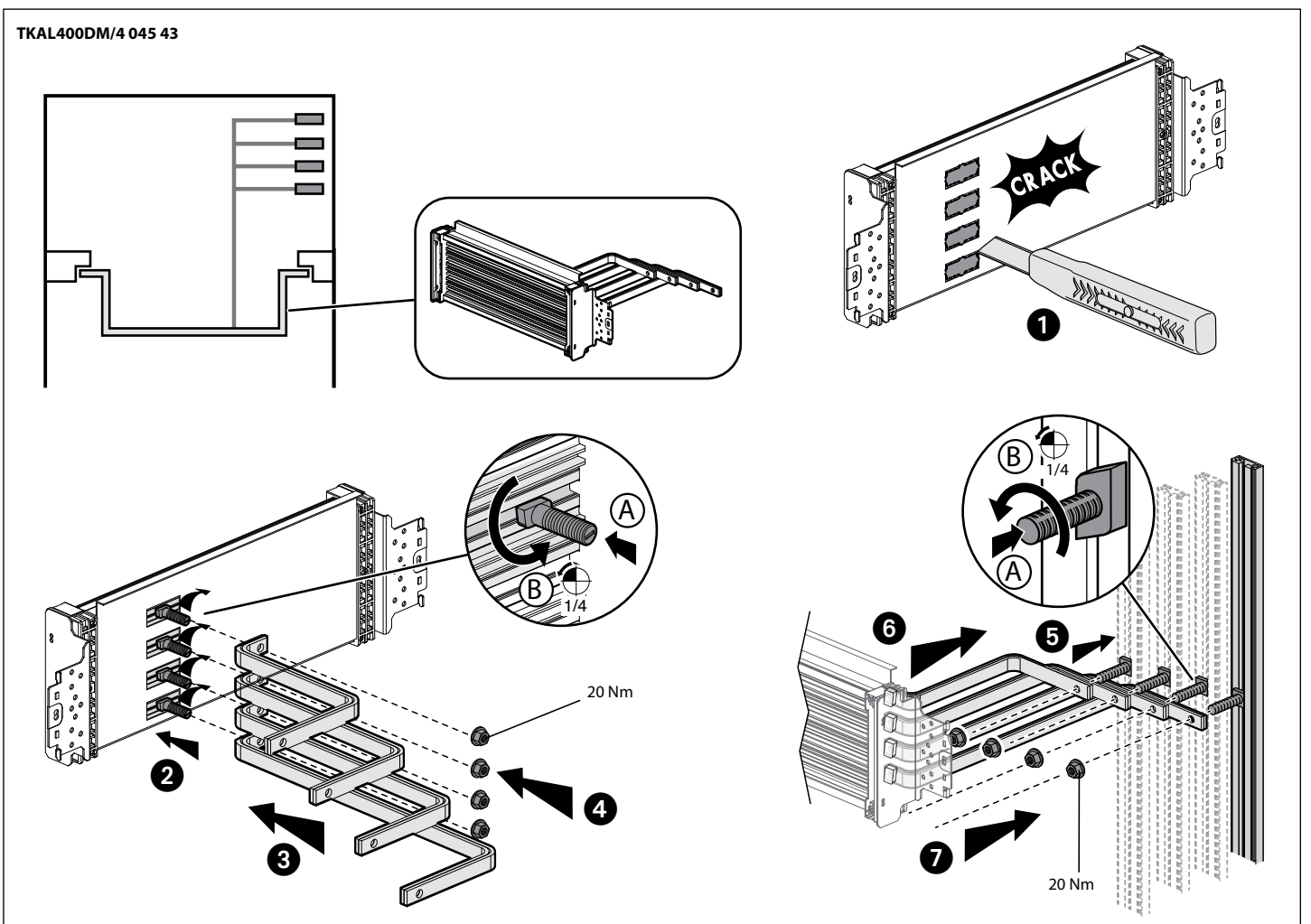

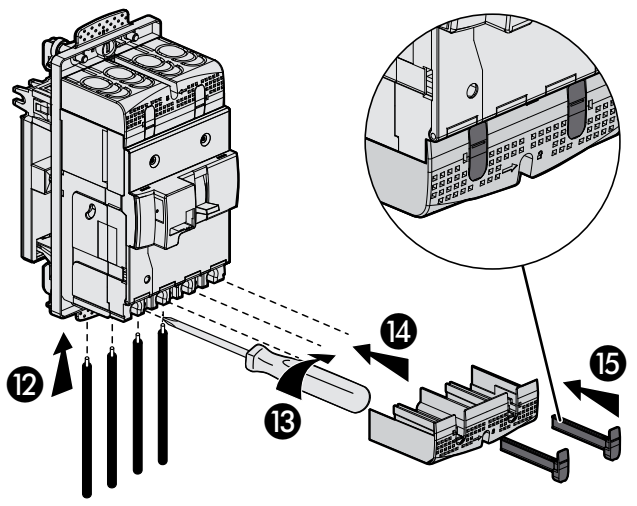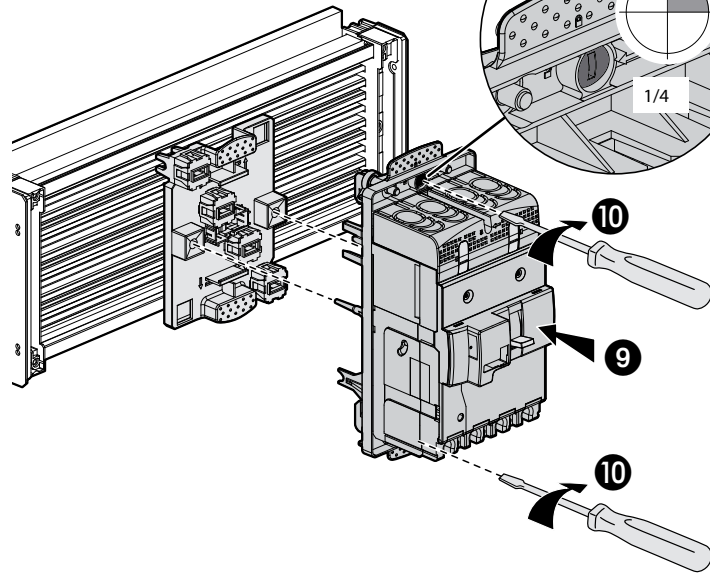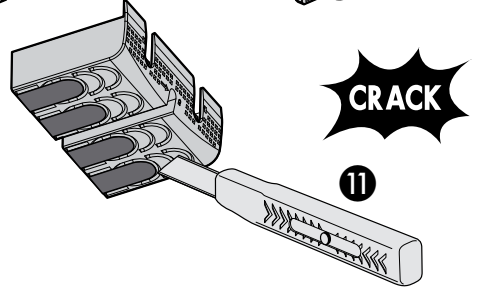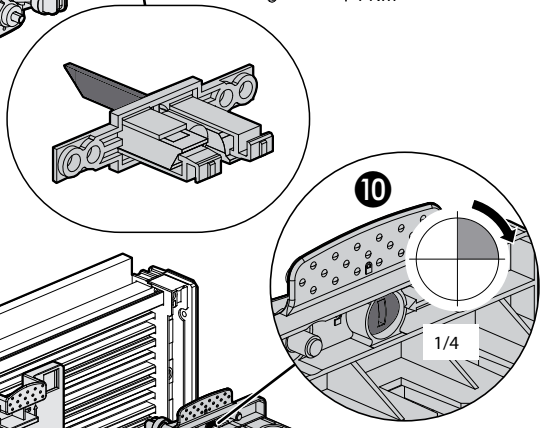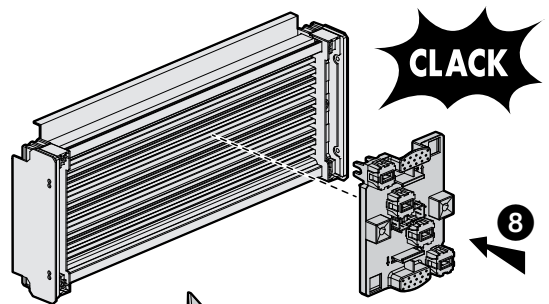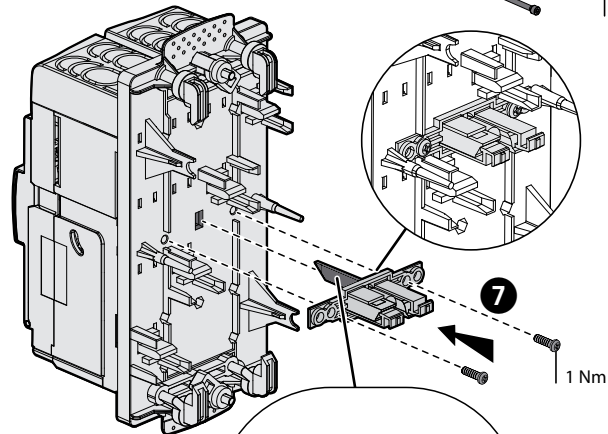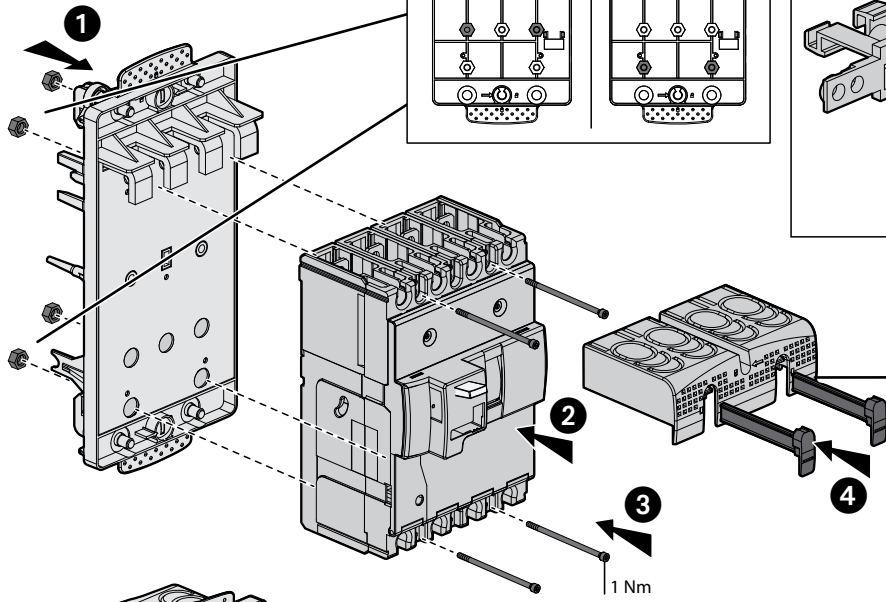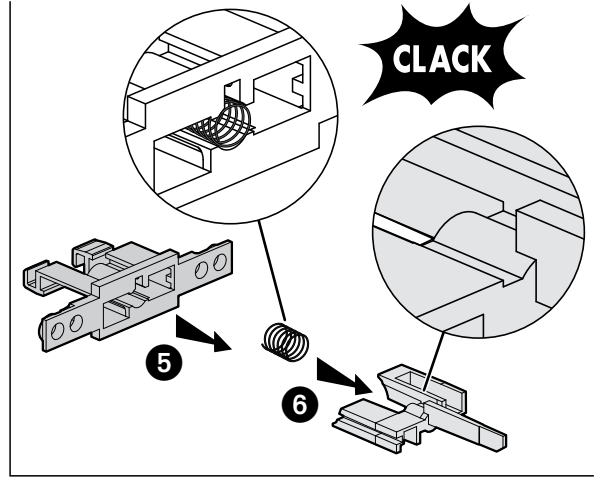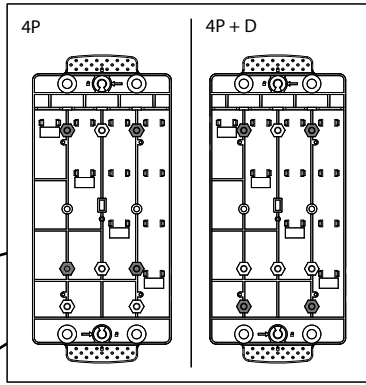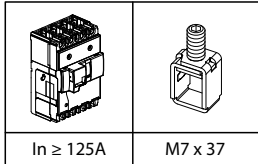

TC32L1NP/TC32L2NP/TC32L3NP/
TC80P3P/TC80P4P/TC80L1P/TC80L2P/TC80L3P/TC80NP
4 045 08/09/10/11/12/13

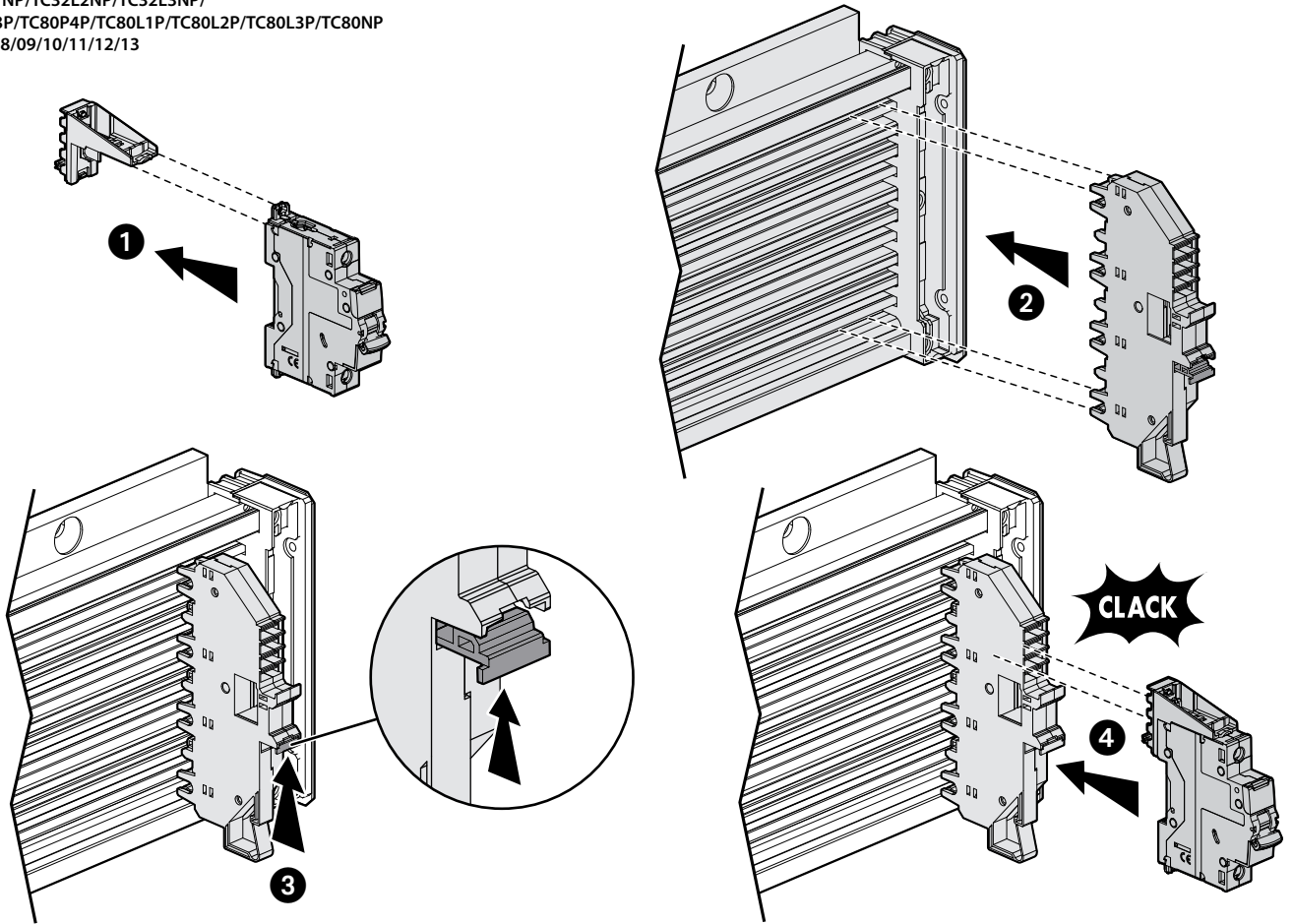

TC32L1NC/TC32L2NC/TC32L3NC/
TC63P3C/TC63P4C/TC63L1C/TC63L2C/TC63L3C/TC63NC/
TC125P3C/TC125P4C/TC125L1C/TC125L2C/TC125L3C/TC125NC
4 045 15/16/17/18/19/20/21/22/23/24/25/26

