


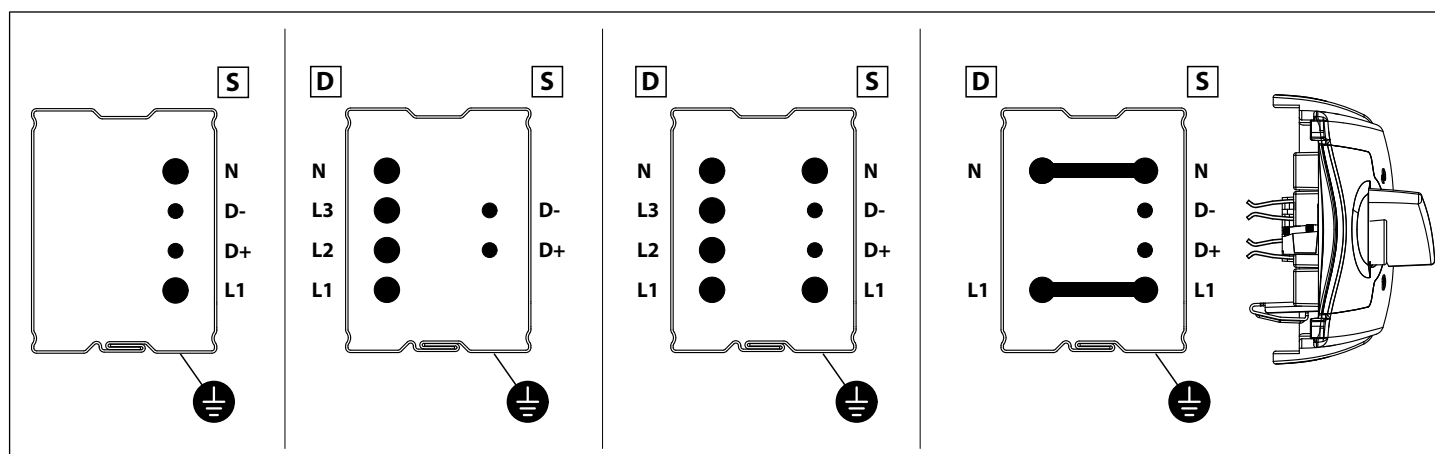
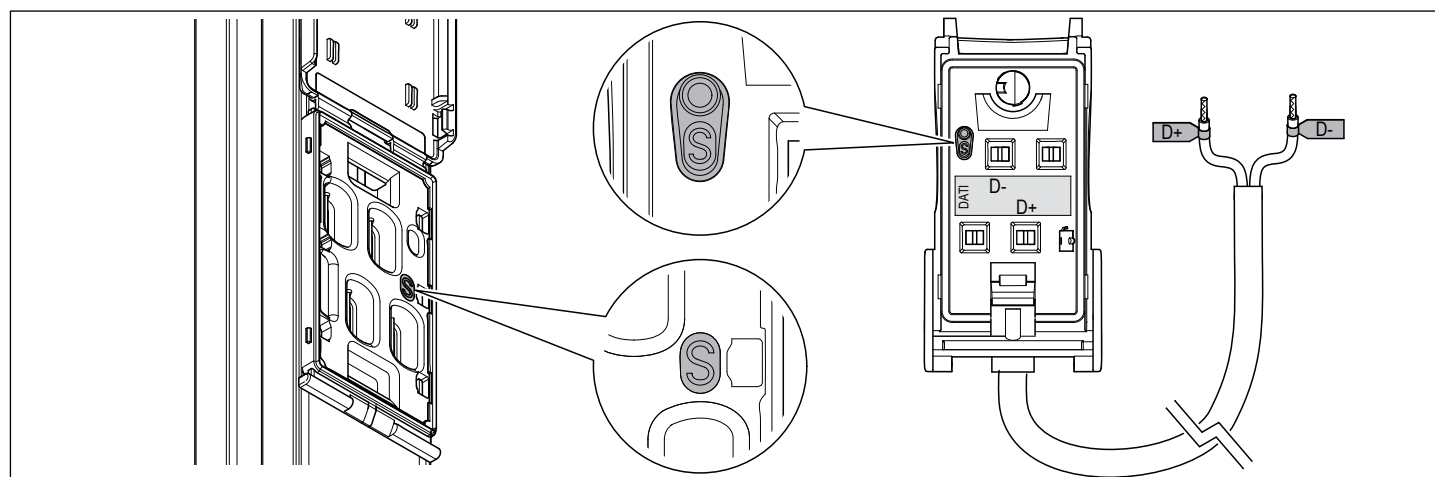
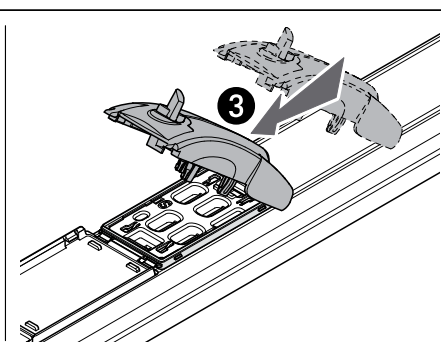
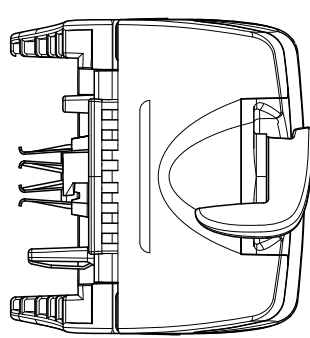
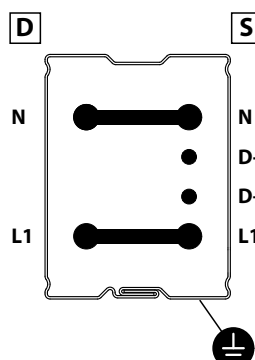
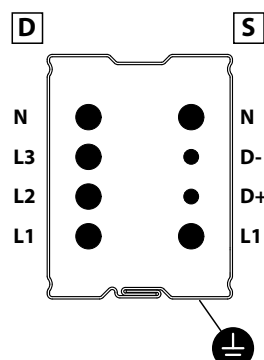
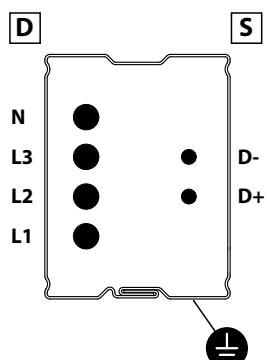
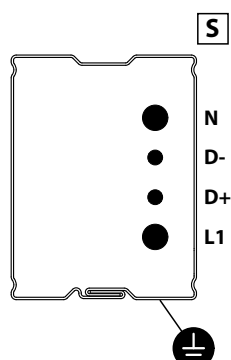
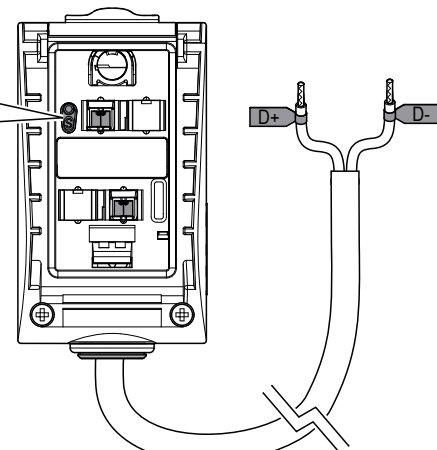
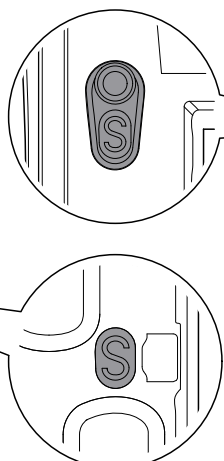
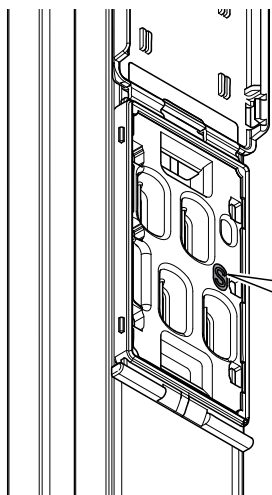
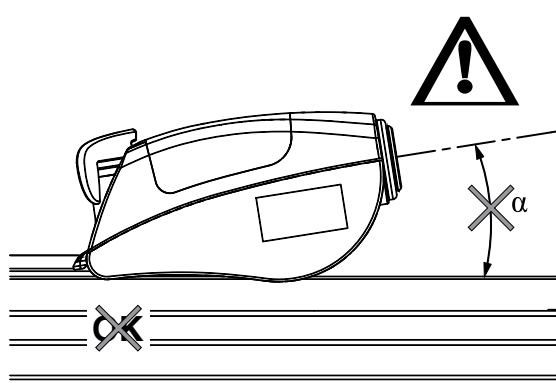
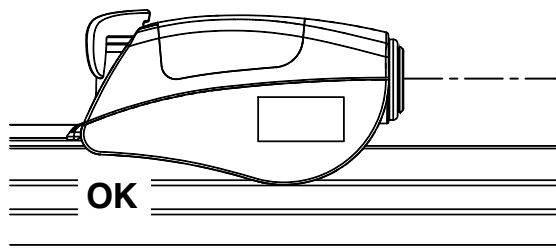
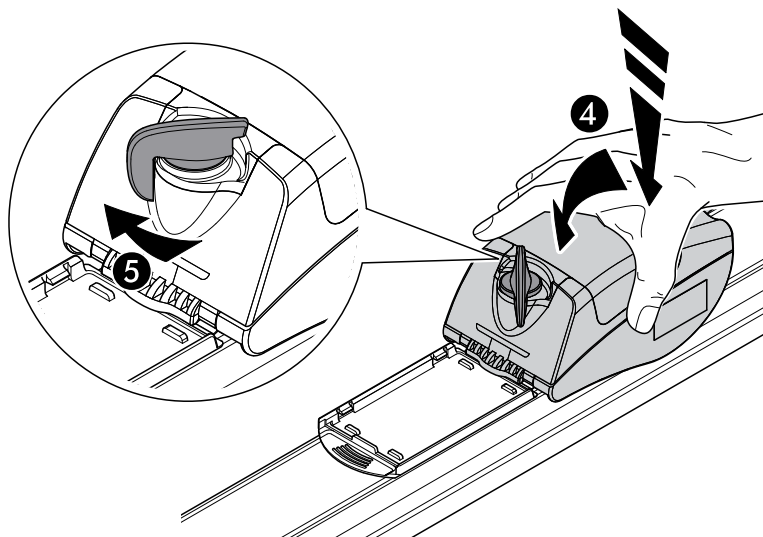
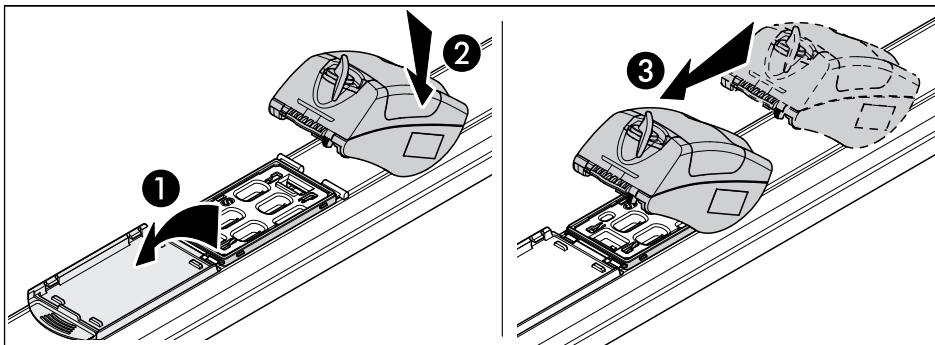
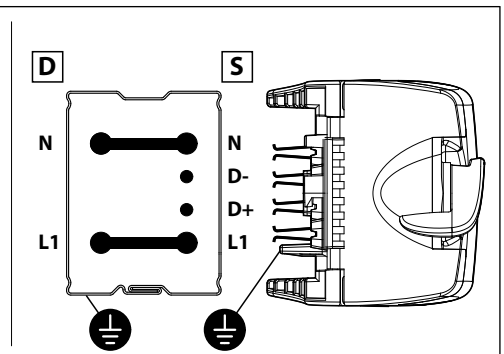
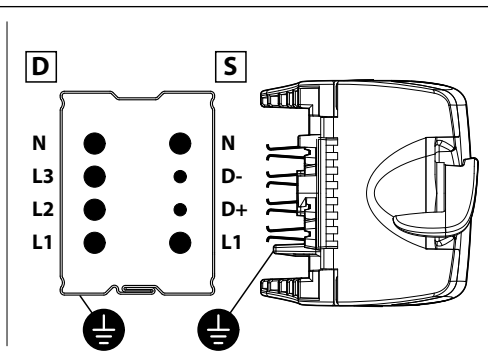
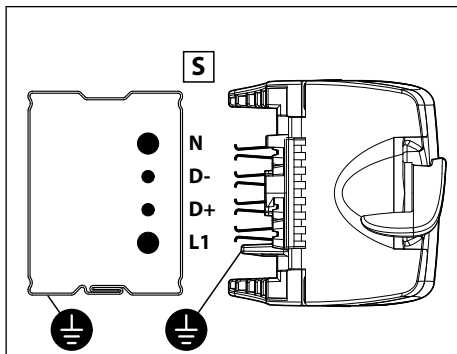
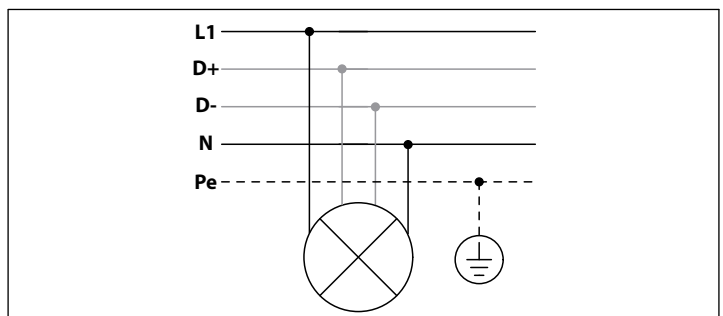
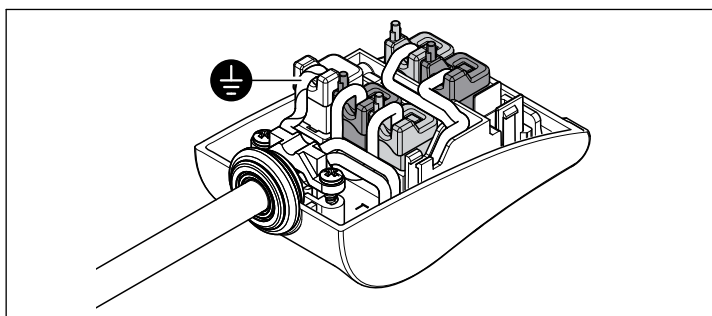
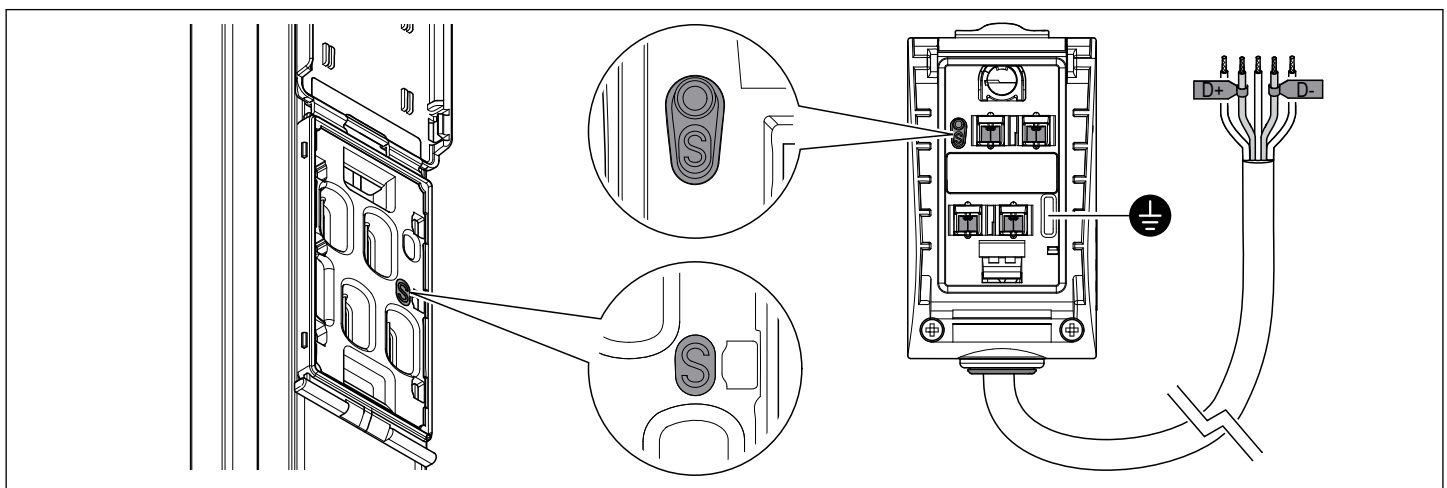


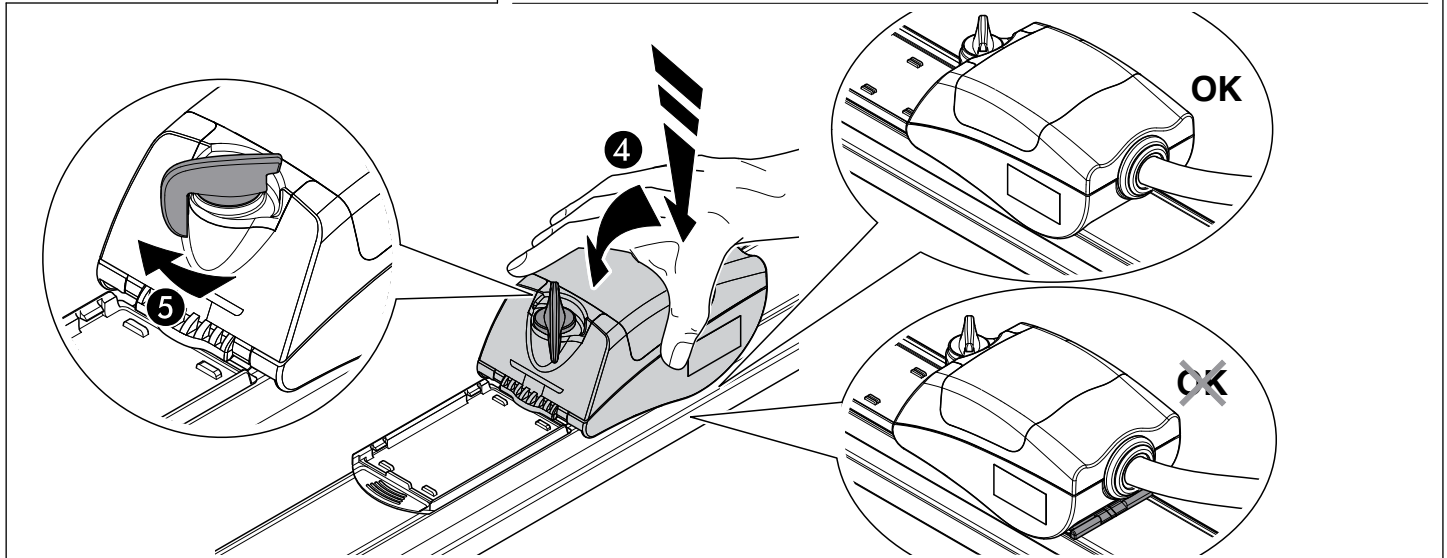


75005034D FG160M16 (1m)
75005000D (no cable)

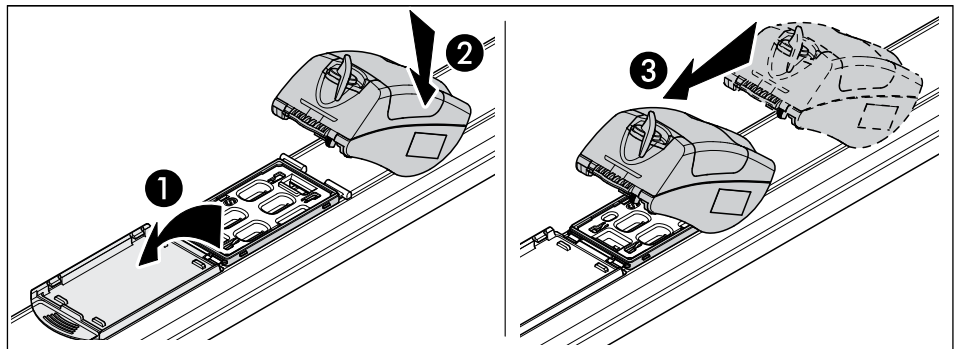

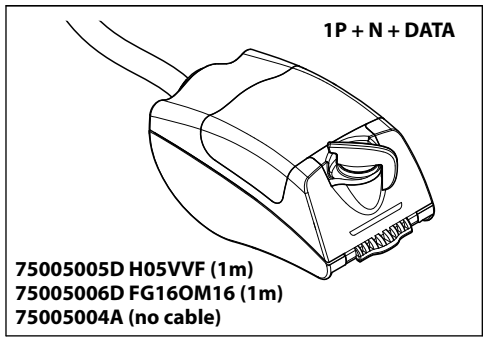


1P + N + DATA


① 1P + N

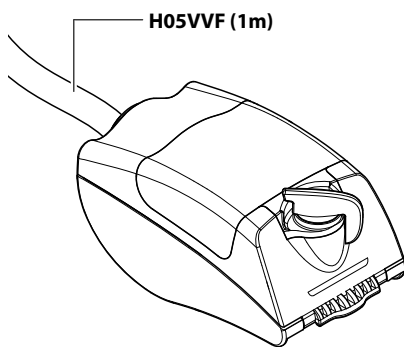






② DATA
D+ D-



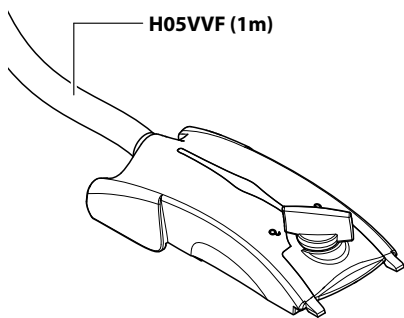


75005007D

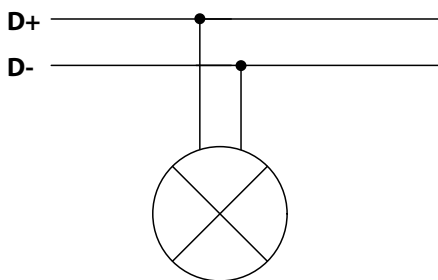


① 1P + N

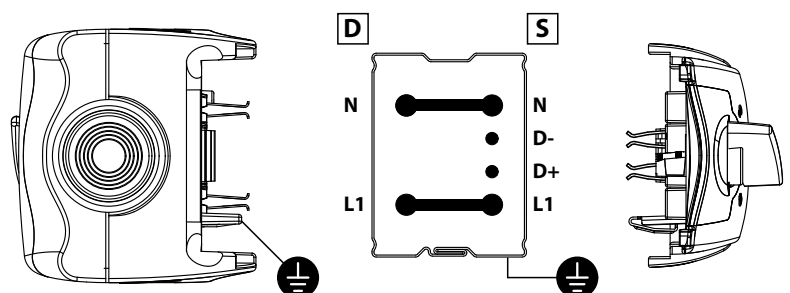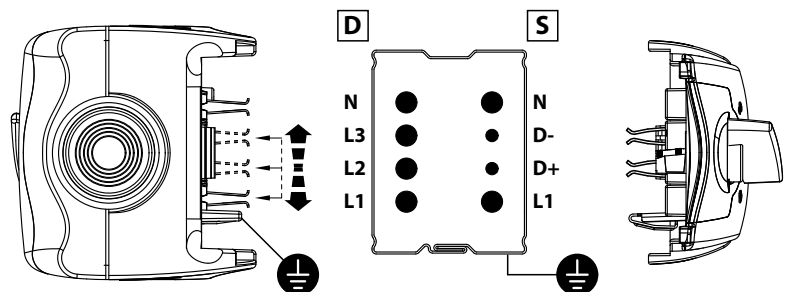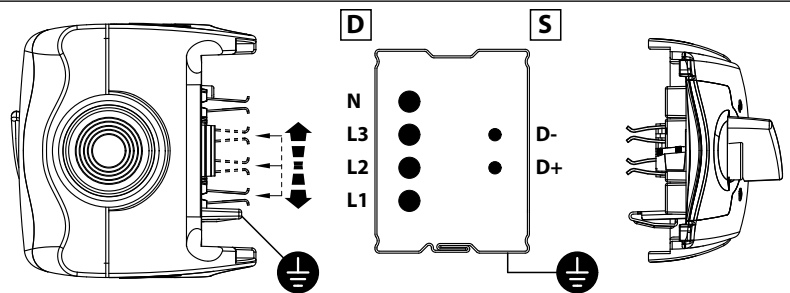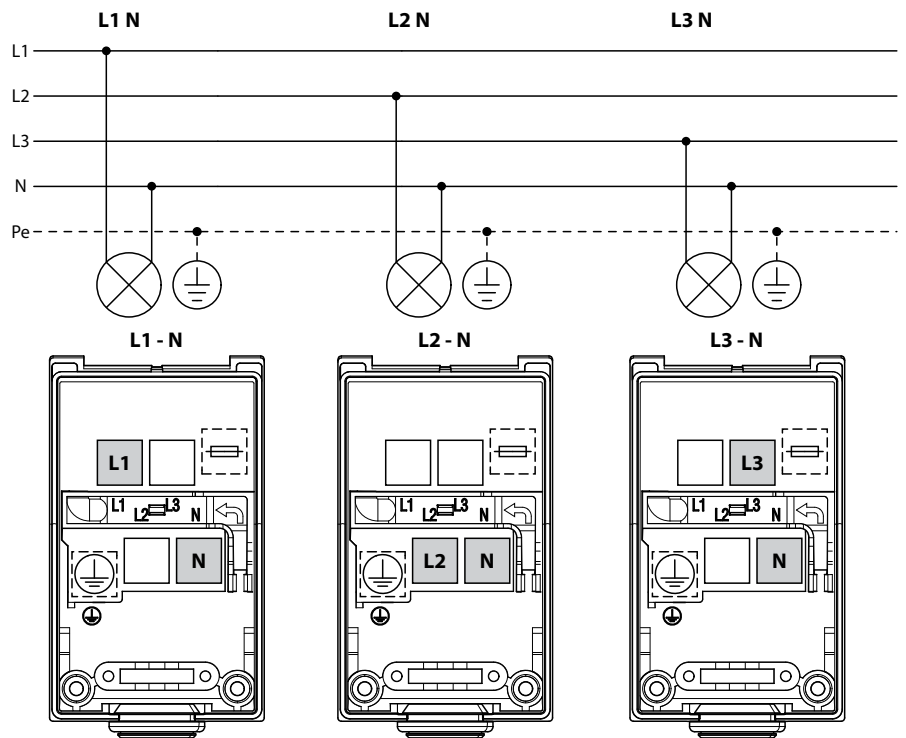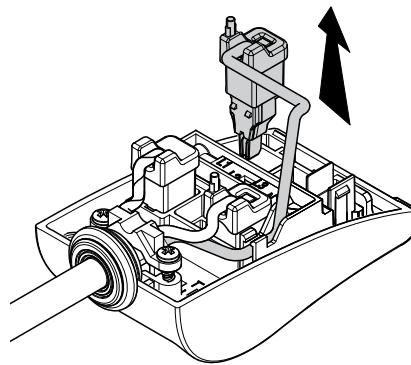

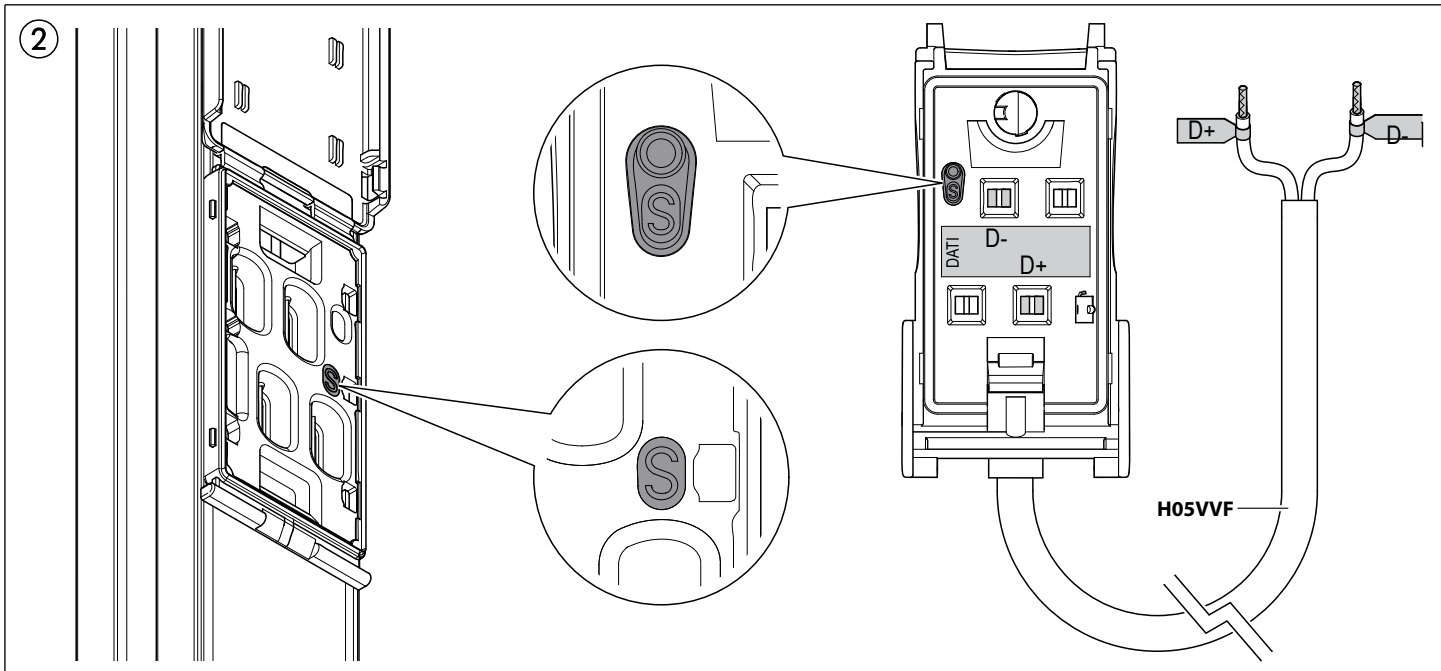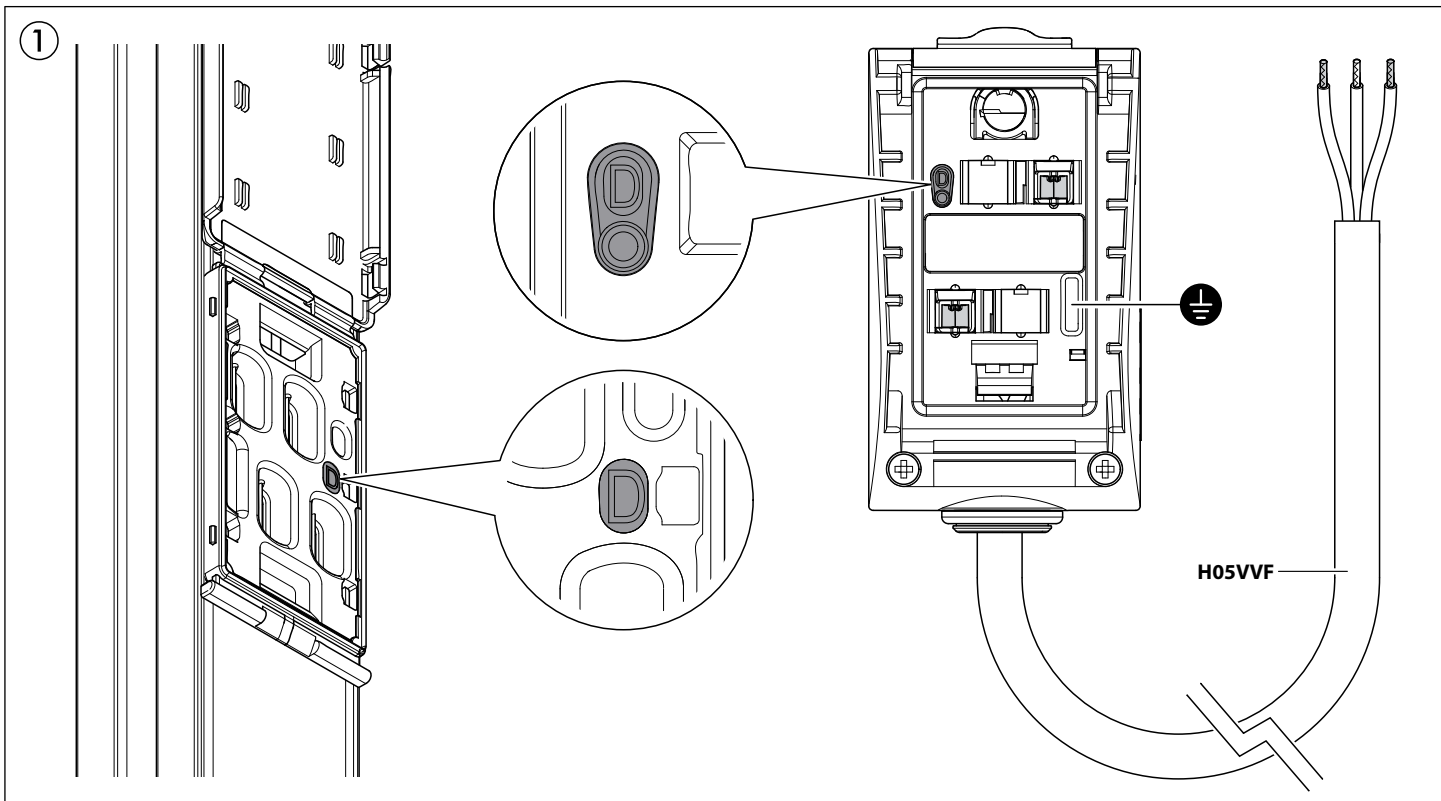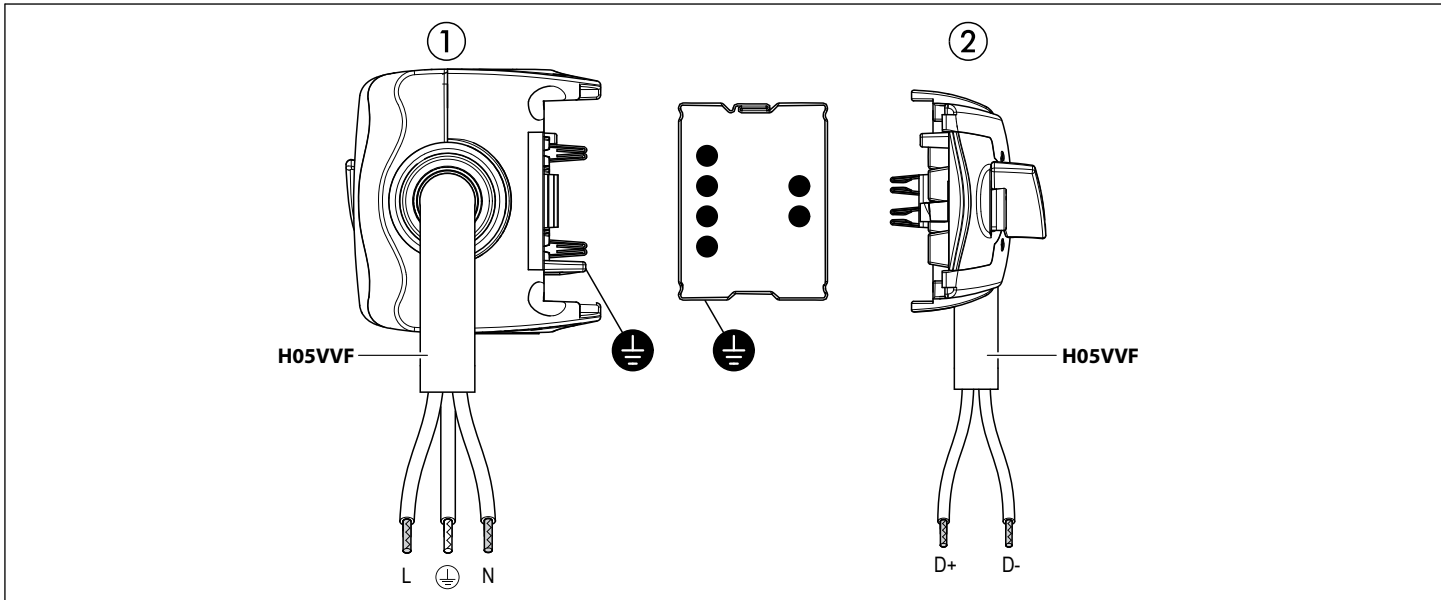


1P + N + DATA

① 1P+N

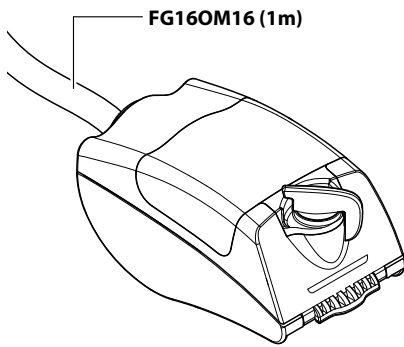


+




② DATA
D+ D-



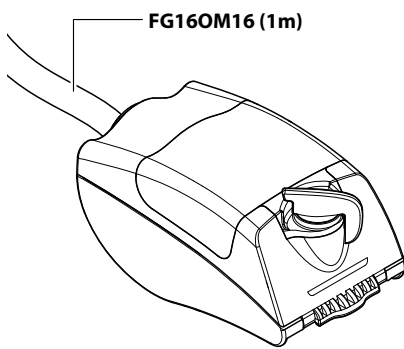


75005008D

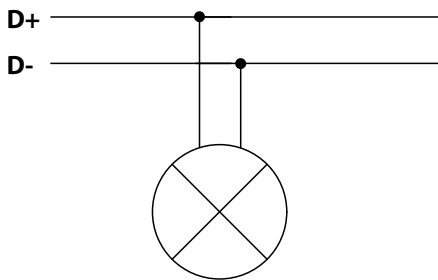

① 1P+N

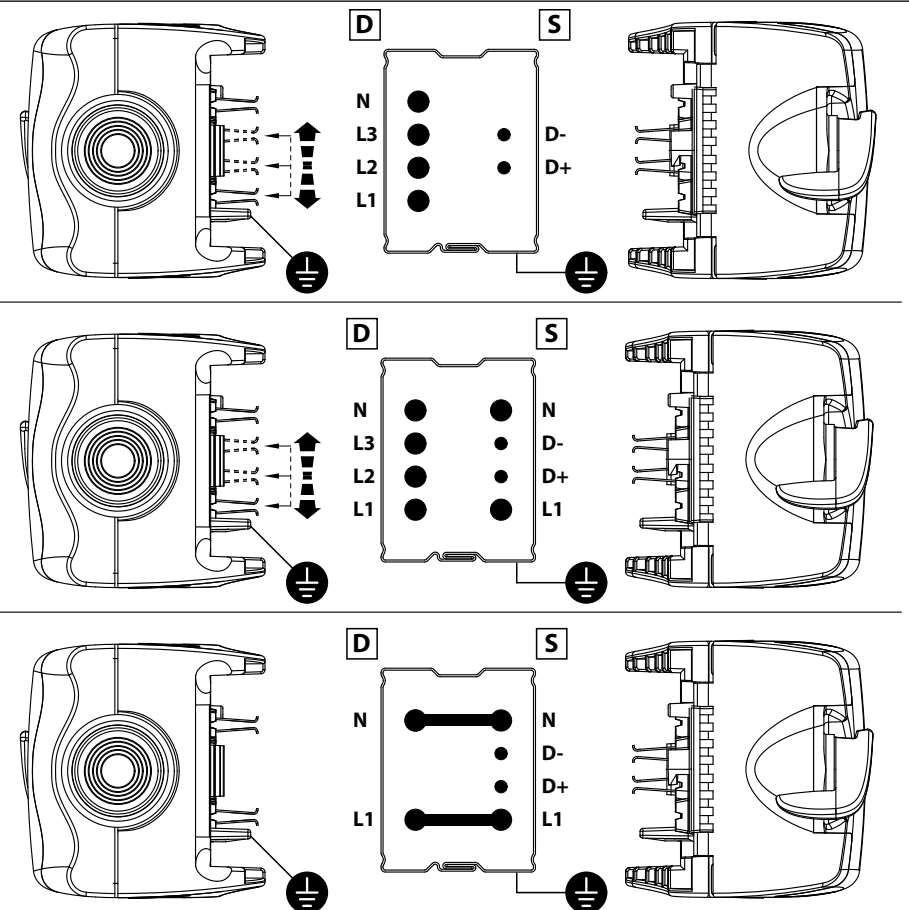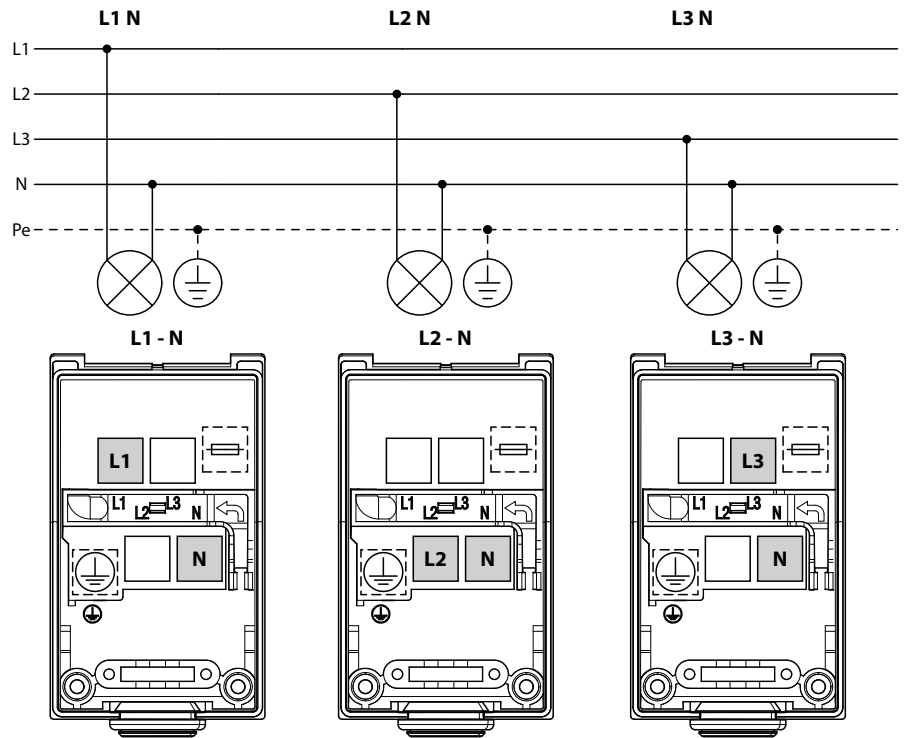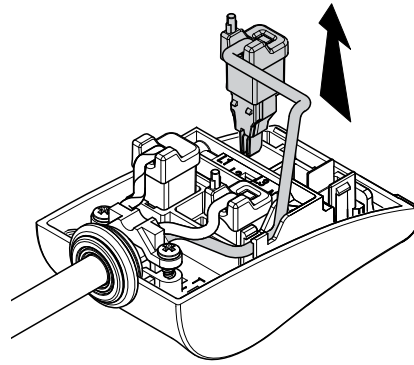

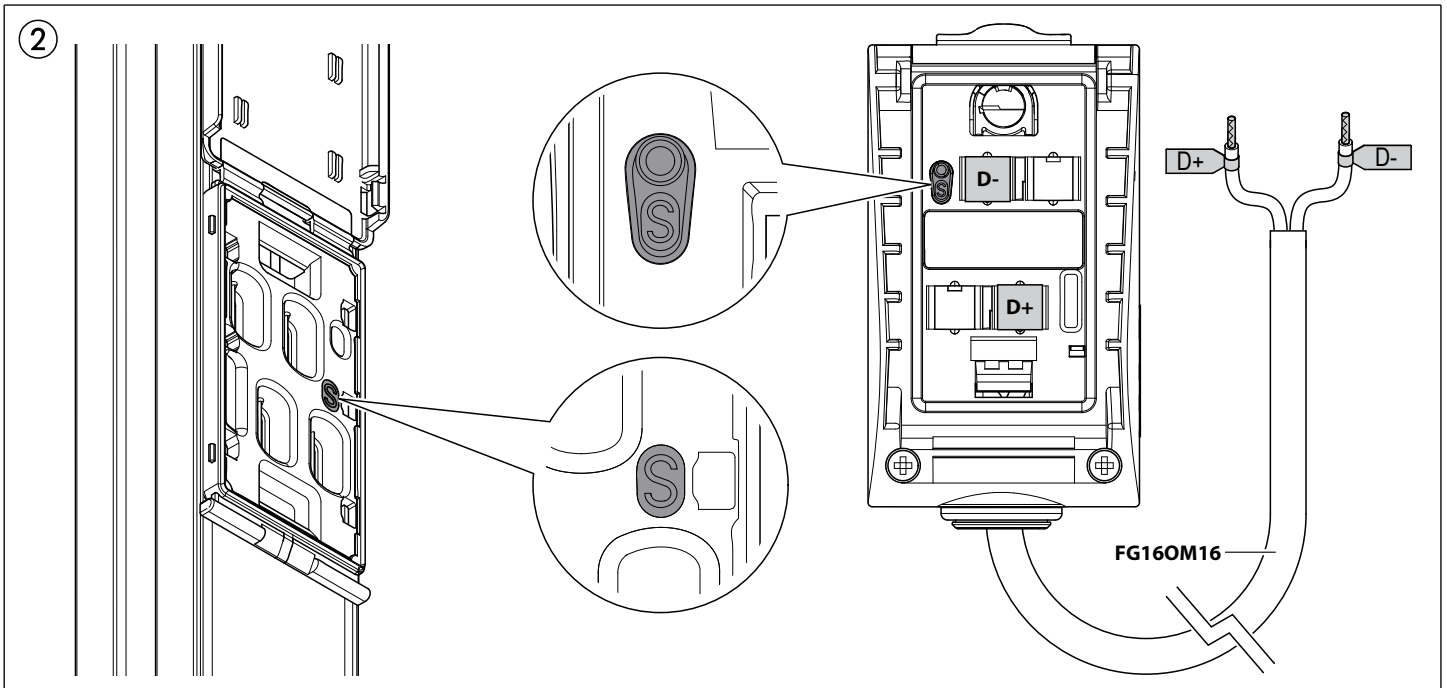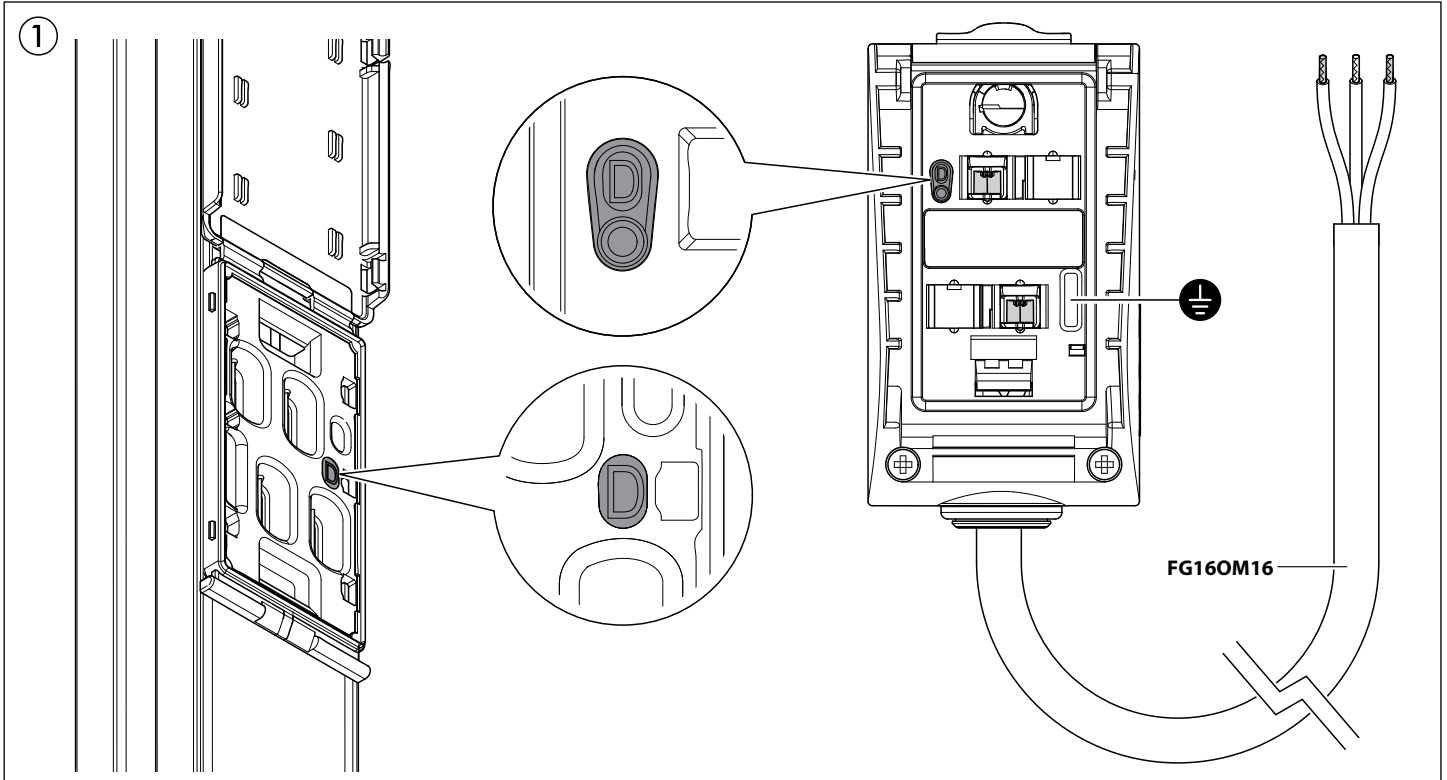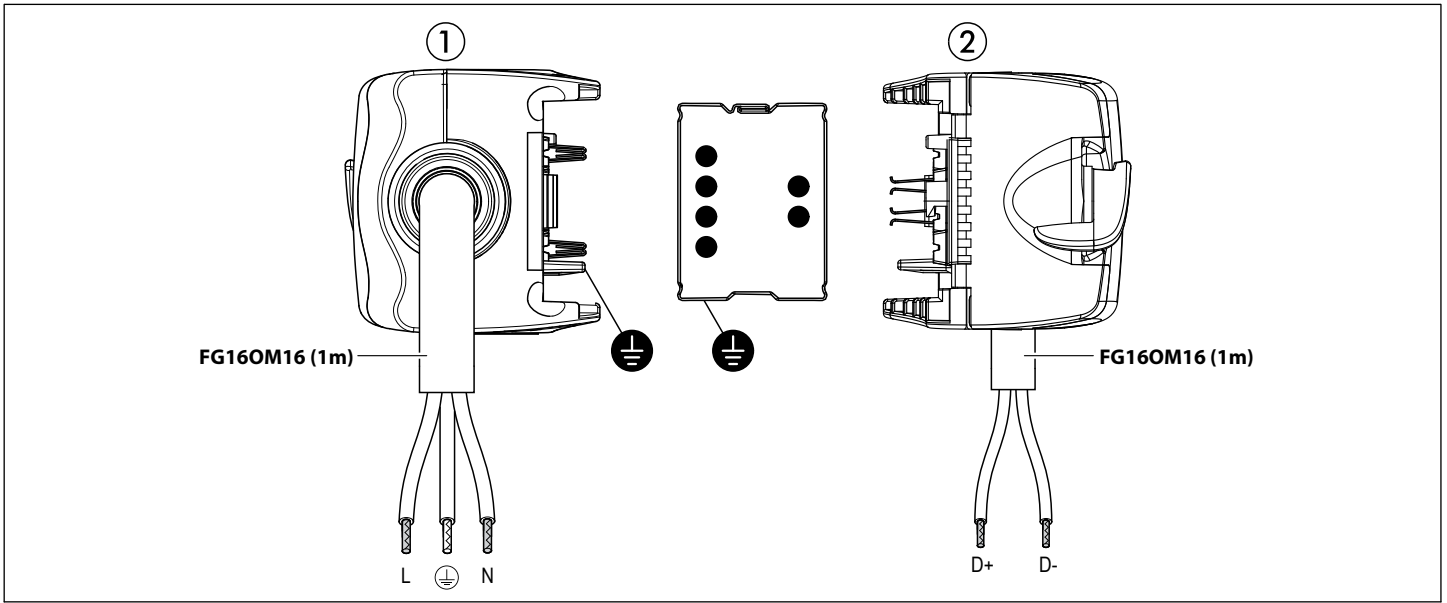

75005000D
75005004D

