


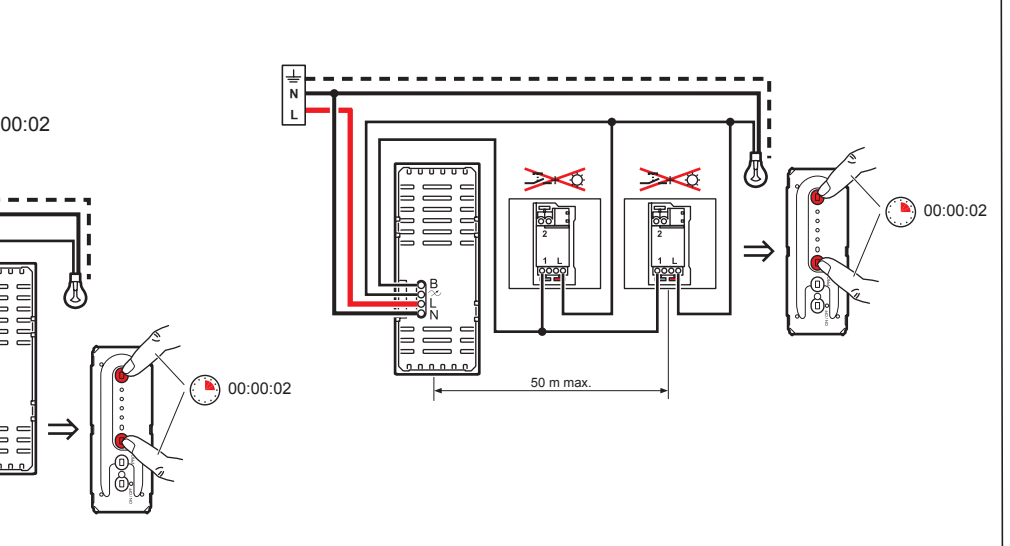
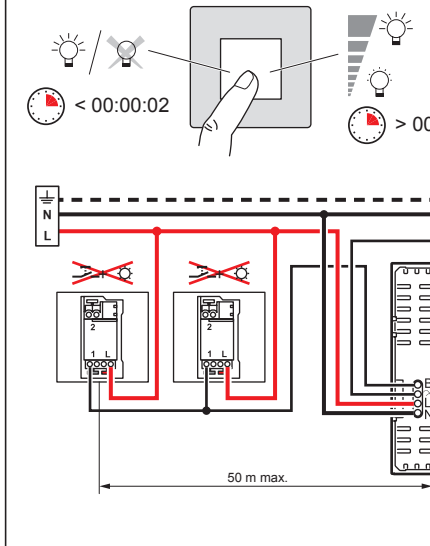
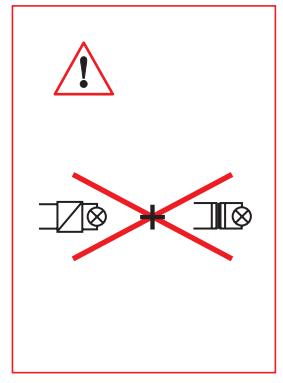
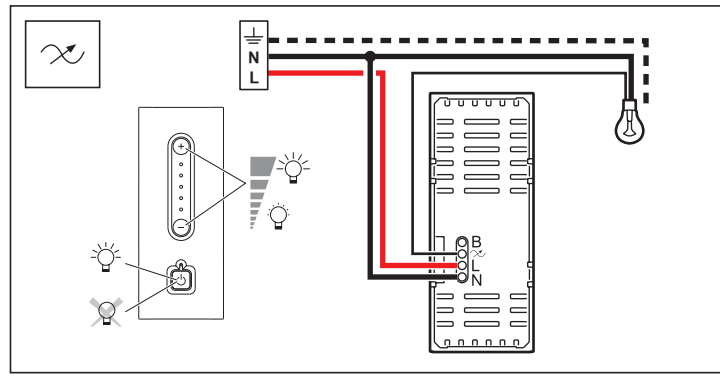
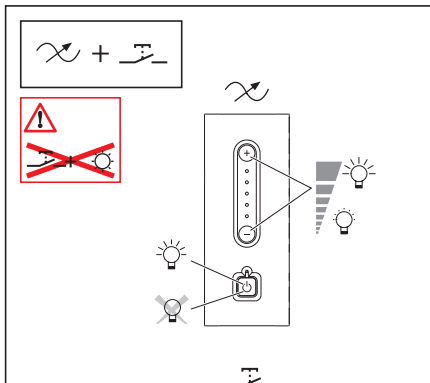
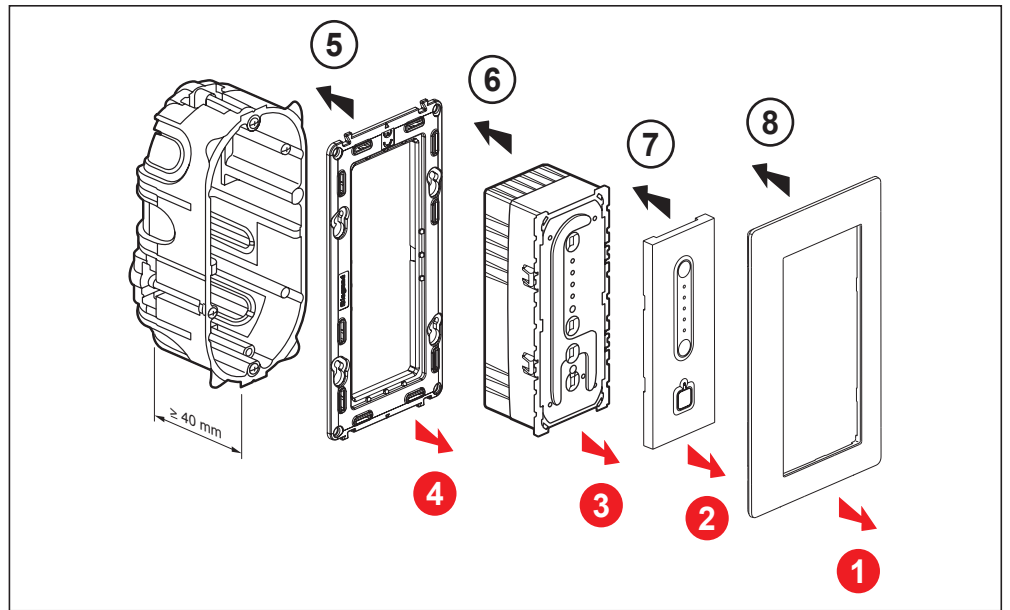
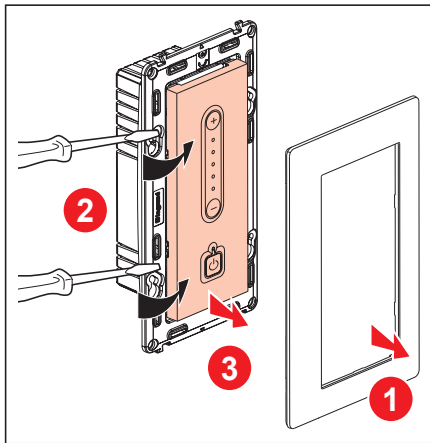
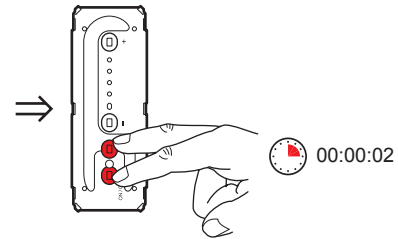
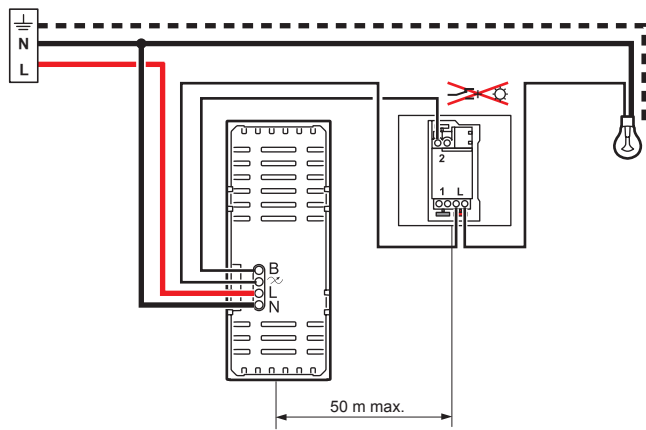
 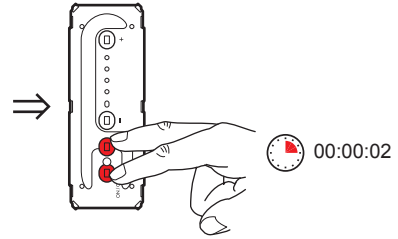
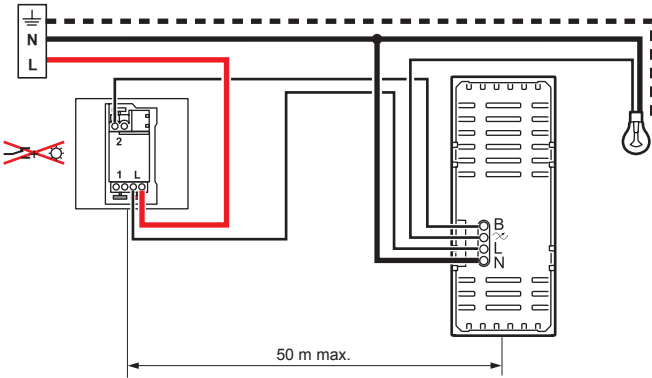


-10°C ... +75°C	40 mm	100 V Max. Min.	500 W 50 W	500 W 50 W	500 VA 50 VA	500 VA 50 VA	500 VA 50 VA	500 VA 50 VA	500 VA 50 VA

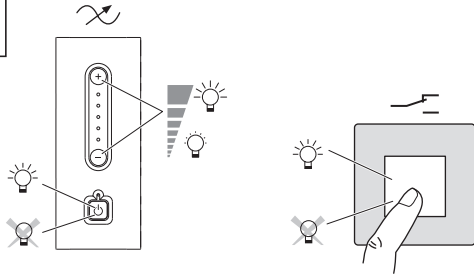



MEM

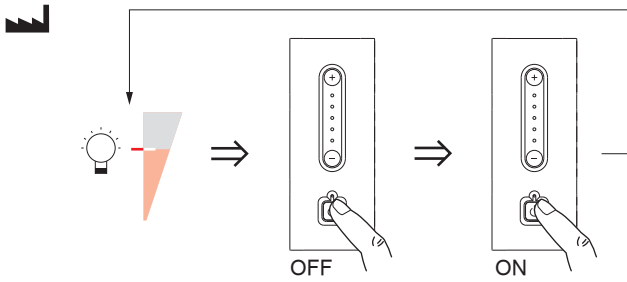

~~MEM~~

