


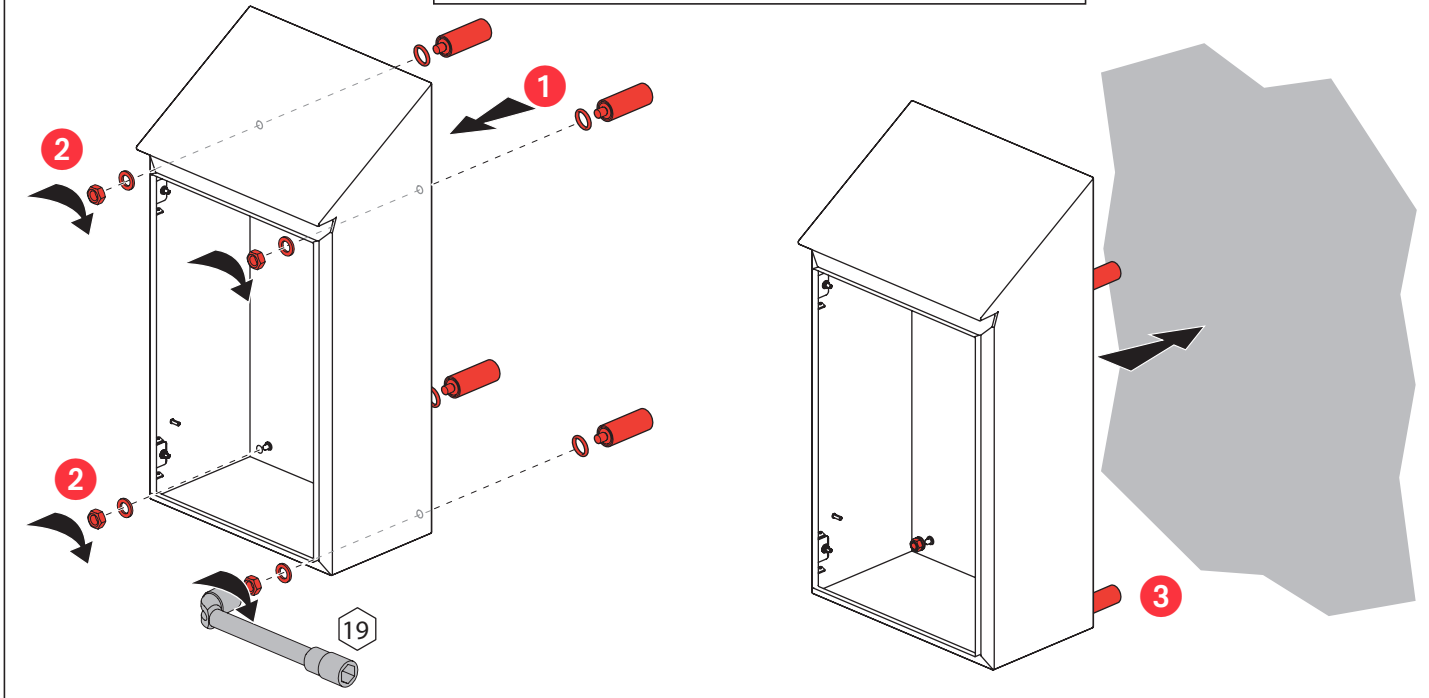


| Référence | A (mm) |
|-----------|--------|
| 0 352 34  | 375    |
| 0 352 36  | 575    |
| 0 352 38  | 775    |
| 0 352 39  | 975    |

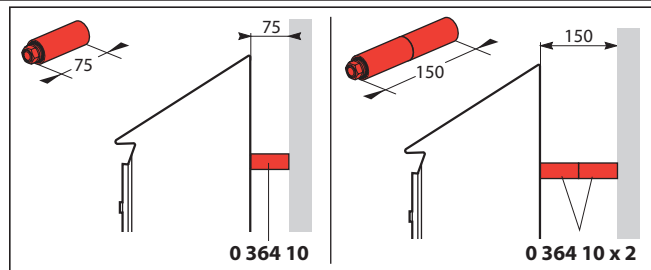

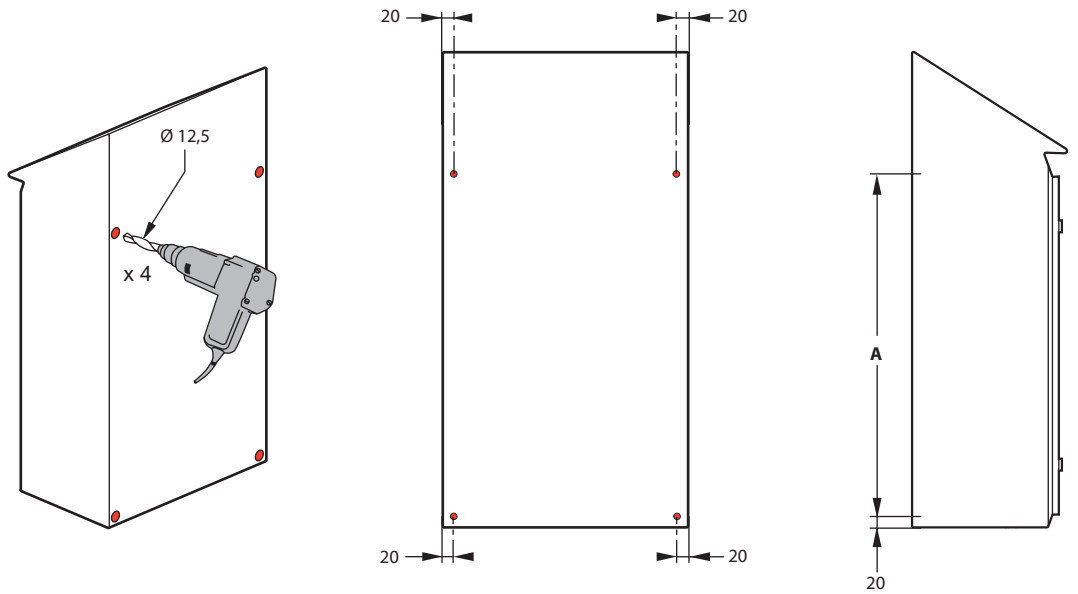

| Référence | A (mm) | B (mm) |
|-----------|--------|--------|
| 0 352 34  | 155    | 95     |
| 0 352 36  | 205    | 75     |
| 0 352 38  | 255    | 75     |
| 0 352 39  | 255    | 75     |

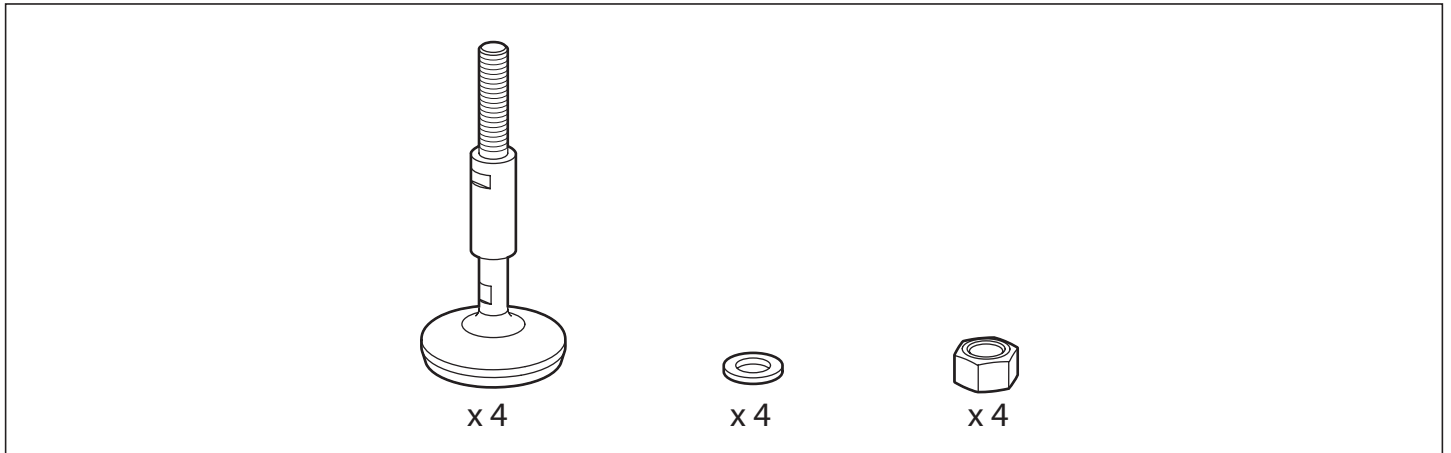