


### ● Characteristics


			IPXX	U	
-10°C ... +70°C	0°C ... +35°C	5A/130°C	IP 20	100... 240 V~ 50 / 60 Hz	8 mm 1...2,5 mm²

	R	L	C/L	Dimmable	Dimmable LED
200 V-240 V 50/60 HZ	5... 300 W	5... 300 VA	5... 300 VA	5... 300 VA	5... 75W ≤10x
100 V-200 V 50/60 HZ	5... 150 W	5... 150 VA	5... 150 VA	5... 150 VA	5... 37W ≤10x


### ● Setting the minimum brightness

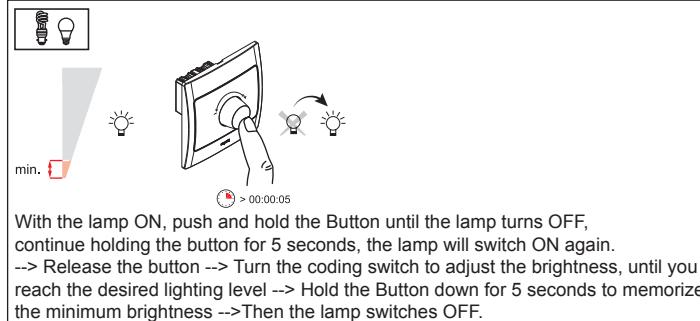


### ● Setting / Resetting the CFL Load

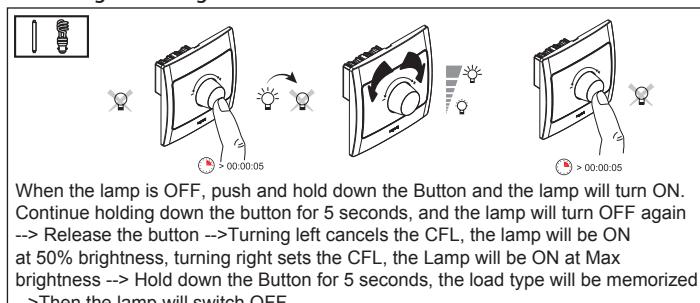

### ● Installation

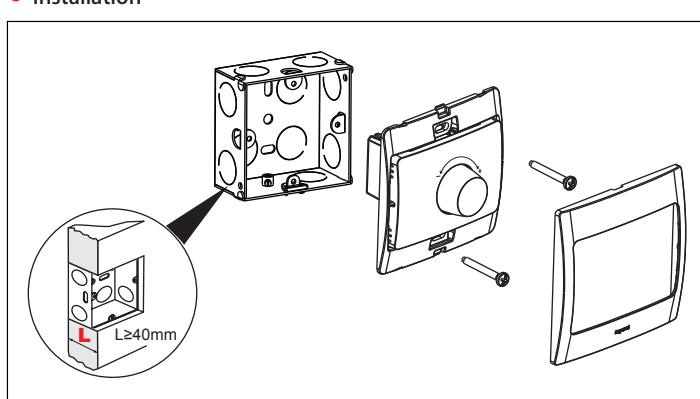


### ● Restoring the factory setting

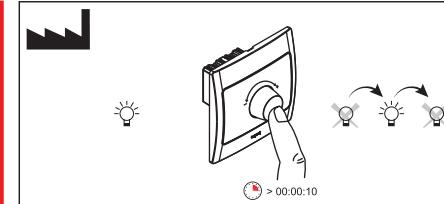


When the lamp is ON, push the Button, the lamp will turn OFF, continue holding for 5 seconds, then the lamp will turn ON again --> Continue for 5 seconds --> The lamp will turn OFF, the system has reset to the default value.

### ● Normal operation (no connection with long distance terminal)

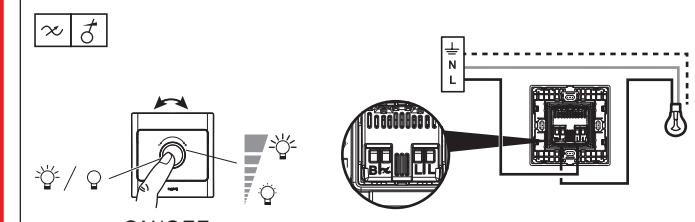

**Change brightness**  
When the load is ON (on the dimmer), turn left, brightness will decrease; turn right, brightness will increase.


### ● Normal operation (with long distance terminal)

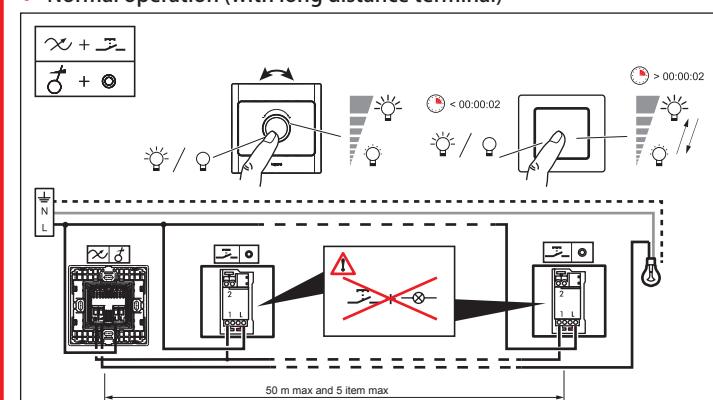

### Change brightness

-- When the load is ON (on the dimmer), turn left, brightness will decrease to the minimum; turn right, brightness will increase to the maximum.  
-- Press the button (on the switch connected to the long distance terminal) and hold for longer than 2 seconds, the brightness will increase to the maximum or decrease to the minimum.

### ● Load type selection

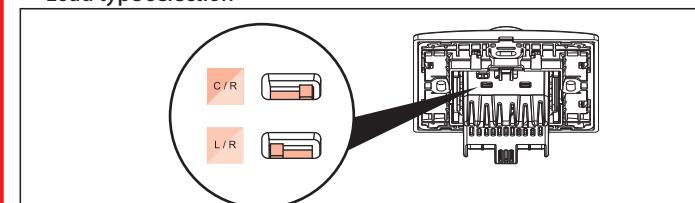

-- Knob of slide switch to the right, use for capacitive load or resistive load  
-- Knob of slide switch to the left, use for inductive load or resistive load

### ● Safety instructions




**⚠** This product should be installed in line with installation rules, preferably by a qualified electrician. Incorrect installation or use can lead to a risk of electric shock or fire.  
Before carrying out installation, read the instructions and take the product's specific mounting location into account.  
Do not open, dismantle, alter or modify the device except when specifically required to do so by the instructions. All Legrand products must be opened and repaired exclusively by personnel trained and approved by Legrand.  
Any unauthorised opening or repairs fully cancels all liabilities as well as the rights of replacement and any guarantees. Use only Legrand brand accessories.

(IE)

LE09453AB



- اشتغال عادي ( عدم التوصيل بمحطة بعيدة المدى )

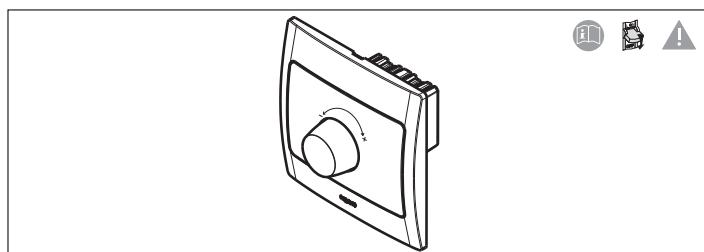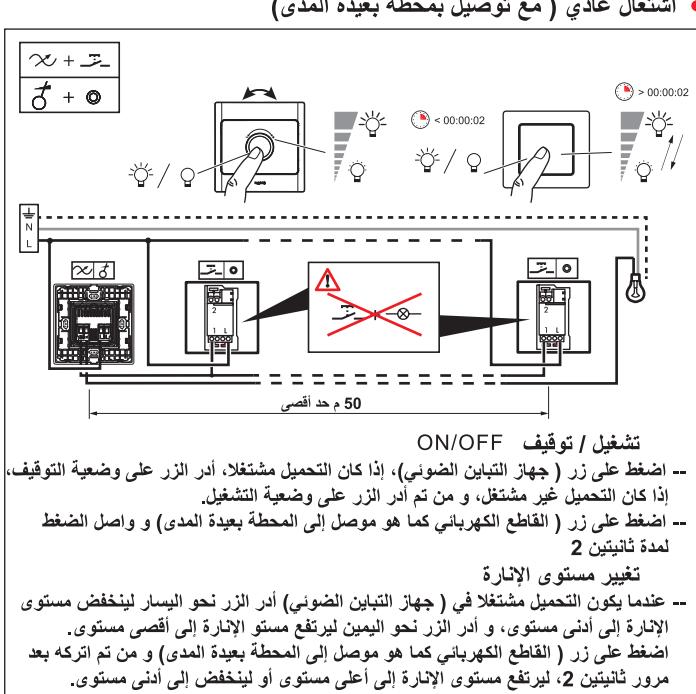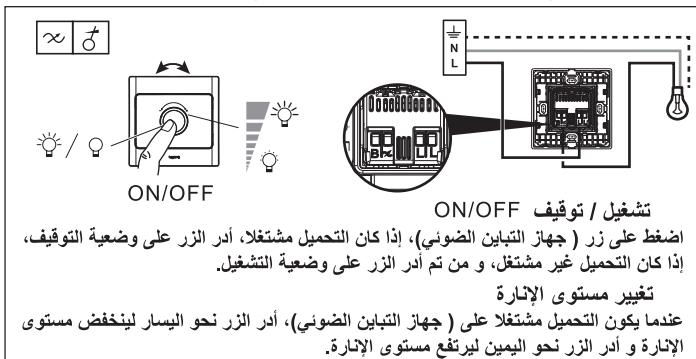

المواصفات

	الوحدة	مؤشر الحماية XX			
ملم 8 ملم 2.5...1	240 فولطـ 60/50	مؤشر الحماية 20	5 أمبير / 130 °	° 35 +... / ° 0	° 70 + ... / ° 10 -

مصابح الاشعاع بولي متريجي	تدريجي	C/L	L	R	
فولط 300...5 أمبير 10X <= 50 وطا	فولط 300...5 أمبير 10X <= 50 وطا				
فولط 300...5 أمبير 10X <= 50 وطا	فولط 300...5 أمبير 10X <= 50 وطا				

#### ● ضبط الإنارة على أدنى مستوى



- تشغيل / توقف تحمل **CFL** (مصباح الفلوريسنت المدمج)

