

 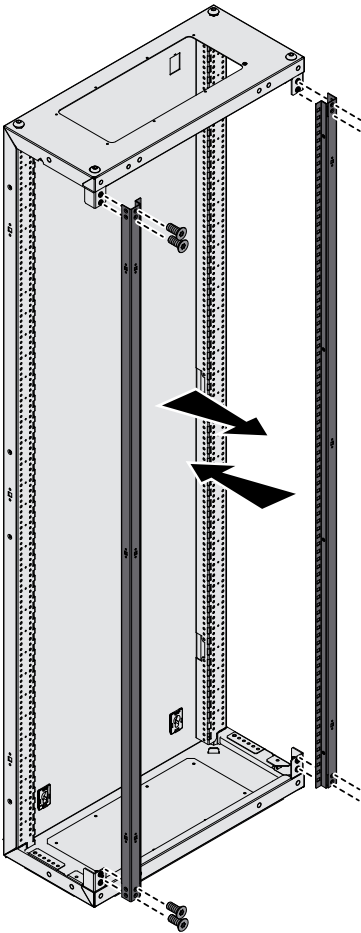
 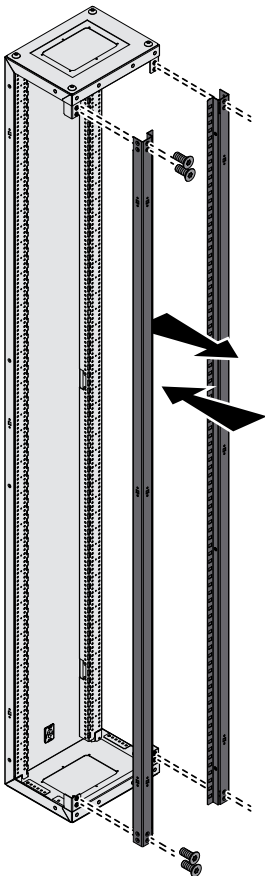
 








	L (mm)			L (mm)				
H (mm)	450	600	800	450	600	800		
750	3 375 21	3 375 22	3 375 23	3 382 02	3 382 03	3 382 04	3 379 32	
900	3 375 31	3 375 32	3 375 33				3 379 33	
1050	3 375 41	3 375 42	3 375 43				3 379 34	
1200	3 375 51	3 375 52	3 375 53				3 379 35	
1350	3 375 61	3 375 62	3 375 63				3 379 36	
1500	3 375 71	3 375 72	3 375 73				3 379 37	
1650	3 375 80	3 375 82	3 375 83				3 379 38	
1800	3 375 91	3 375 92	3 375 93				3 379 39	
1950	3 376 01	3 376 02	3 376 03				3 379 40	
2100	3 376 11	3 376 12	3 376 13				3 379 41	
2250	3 376 21	3 376 22	3 376 23				3 379 42	








		 	
		L (mm)	
H (mm)		350	
750	3 375 20	3 382 01	
900	3 375 30		
1050	3 375 40		
1200	3 375 50		
1350	3 375 60		
1500	3 375 70		
1650	3 375 80		
1800	3 375 90		
1950	3 376 00		
2100	3 376 10		
2250	3 376 20		

H (mm)			
750	3 378 62	3 382 00	3 382 05
900	3 378 63		
1050	3 378 64		
1200	3 378 65		
1350	3 378 66		
1500	3 378 67		
1650	3 378 68		
1800	3 378 69		
1950	3 378 70		
2100	3 378 71		
2250	3 378 72		



	A	B	C	D
3 375 20	667	-	900	281
3 375 21	667	210	900	381
3 375 22	667	360	900	531
3 375 23	667	560	900	731
3 375 30	817	-	1050	281
3 375 31	817	210	1050	381
3 375 32	817	360	1050	531
3 375 33	817	560	1050	731
3 375 40	967	-	1200	281
3 375 41	967	210	1200	381
3 375 42	967	360	1200	531
3 375 43	967	560	1200	731
3 375 50	1117	-	1350	281
3 375 51	1117	210	1350	381
3 375 52	1117	360	1350	531
3 375 53	1117	560	1350	731
3 375 60	1267	-	1500	281
3 375 61	1267	210	1500	381
3 375 62	1267	360	1500	531
3 375 63	1267	560	1500	731
3 375 70	1417	-	1650	281
3 375 71	1417	210	1650	381
3 375 72	1417	360	1650	531
3 375 73	1417	560	1650	731
3 375 80	1567	-	1800	281
3 375 81	1567	210	1800	381
3 375 82	1567	360	1800	531
3 375 83	1567	560	1800	731
3 375 90	1717	-	1950	281
3 375 91	1717	210	1950	381
3 375 92	1717	360	1950	531
3 375 93	1717	560	1950	731
3 376 00	1867	-	2100	281
3 376 01	1867	210	2100	381
3 376 02	1867	360	2100	531
3 376 03	1867	560	2100	731
3 376 10	2017	-	2250	281
3 376 11	2017	210	2250	381
3 376 12	2017	360	2250	531
3 376 13	2017	560	2250	731
3 376 20	2167	-	2400	281
3 376 21	2167	210	2400	381
3 376 22	2167	360	2400	531
3 376 23	2167	560	2400	731

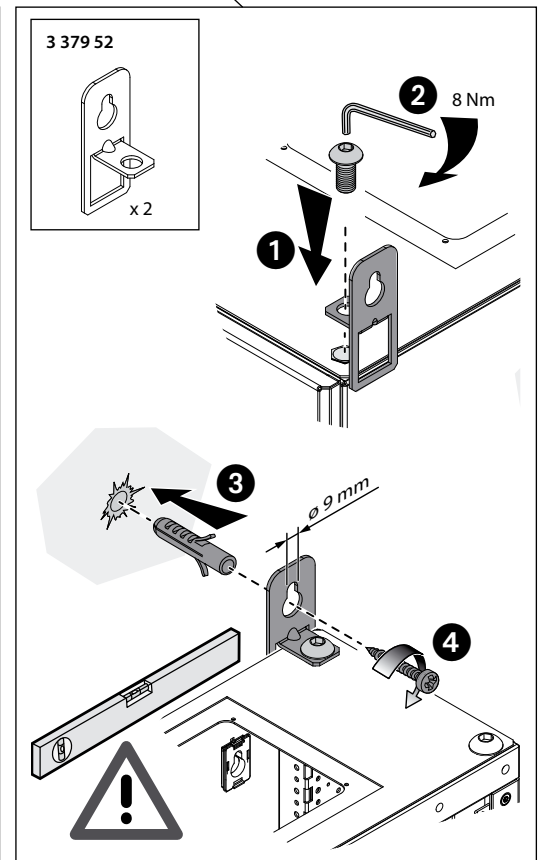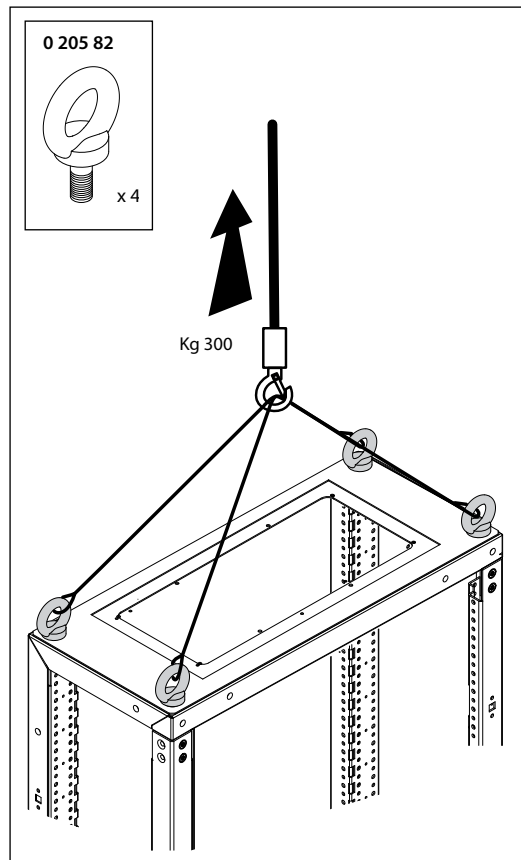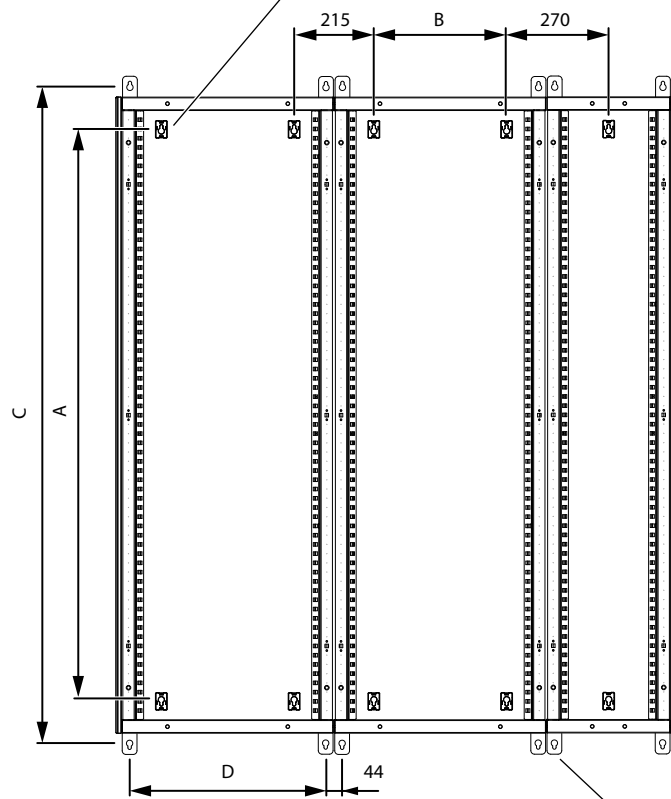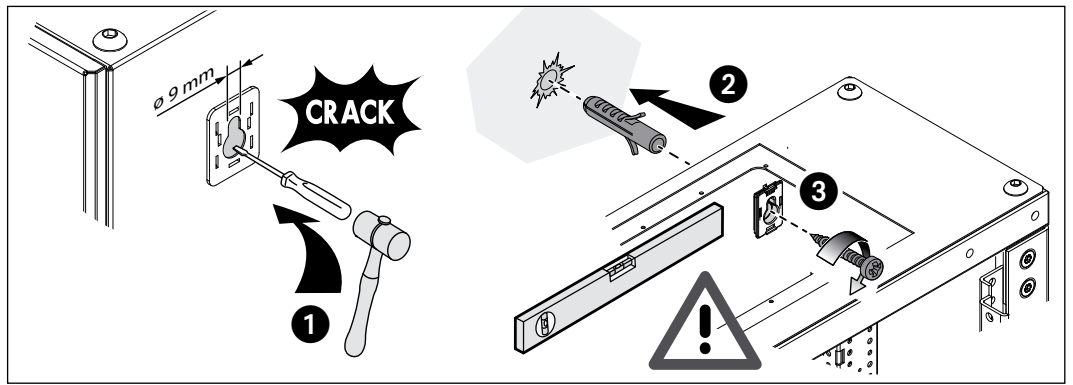


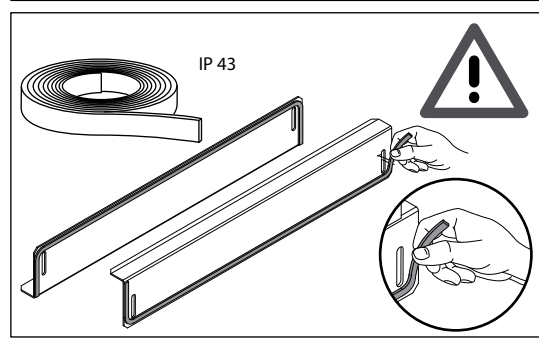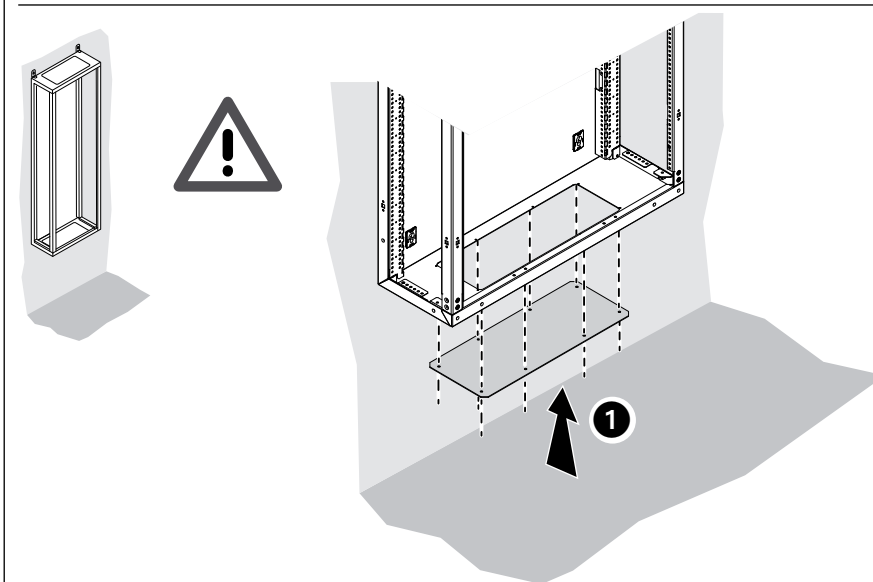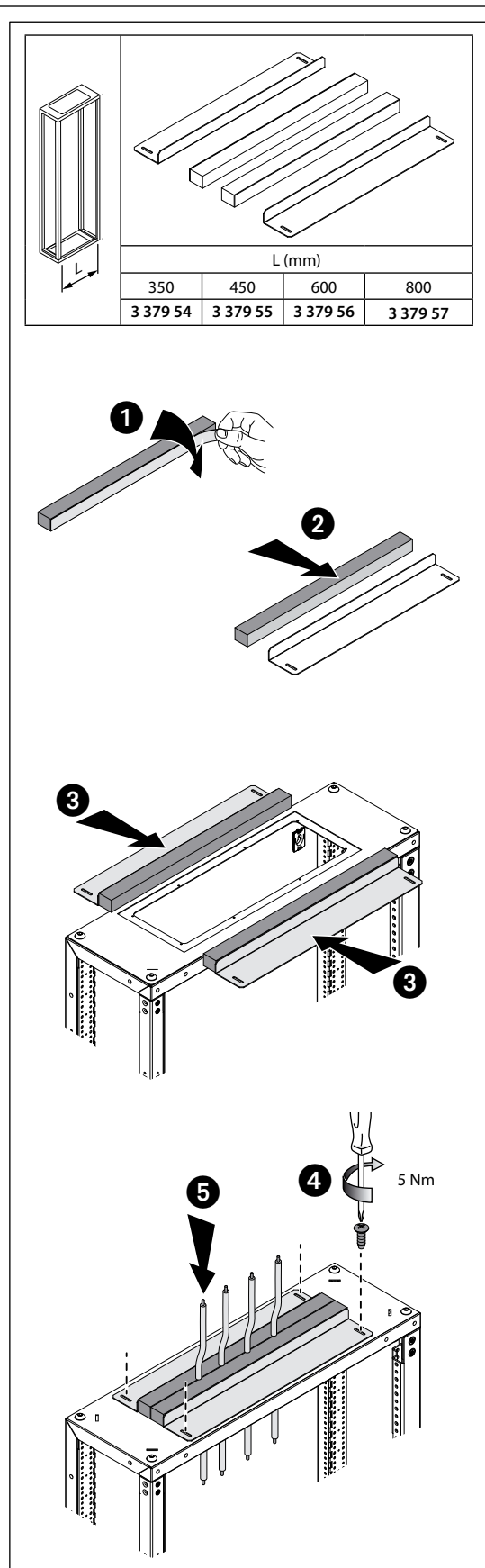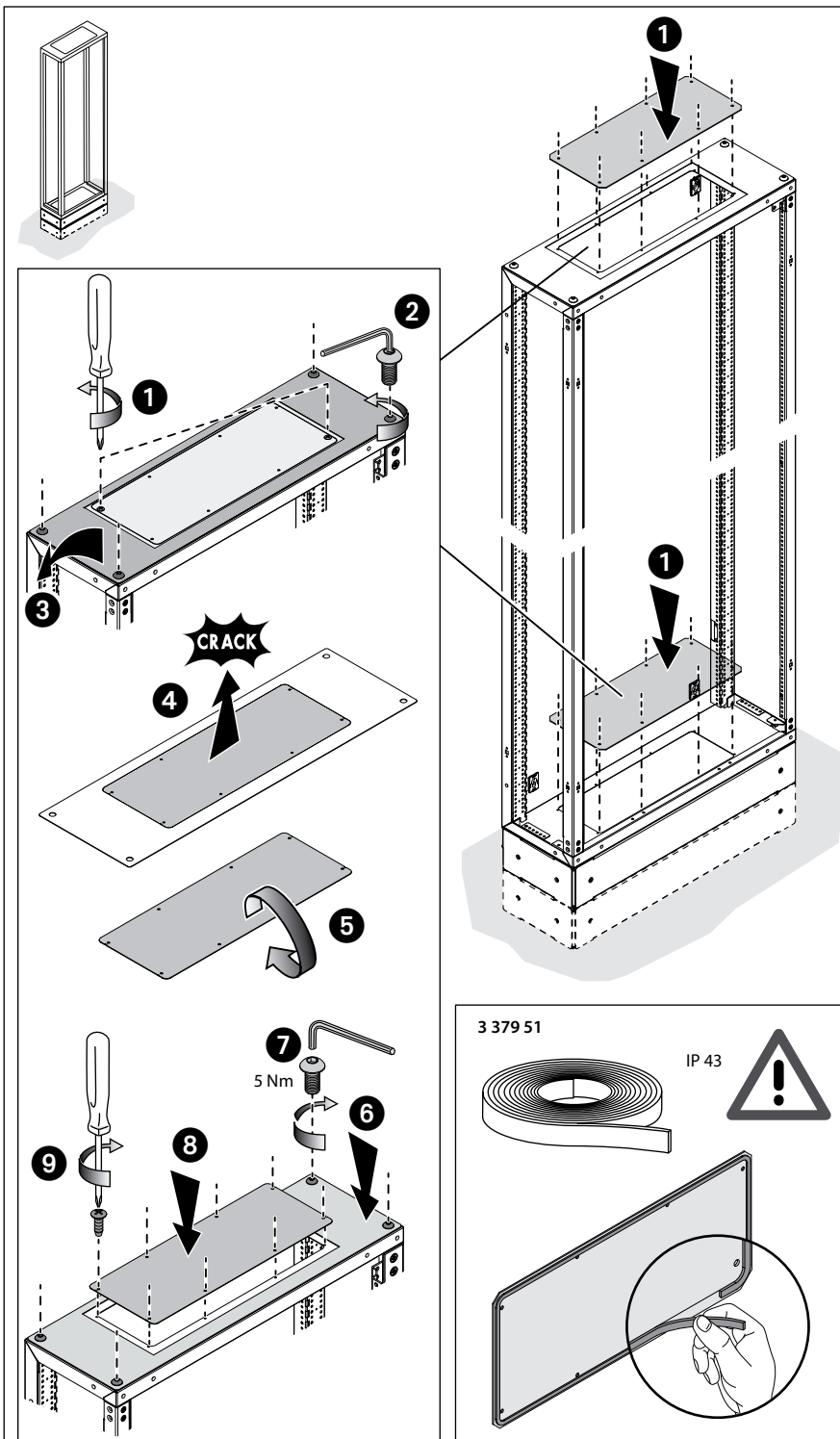

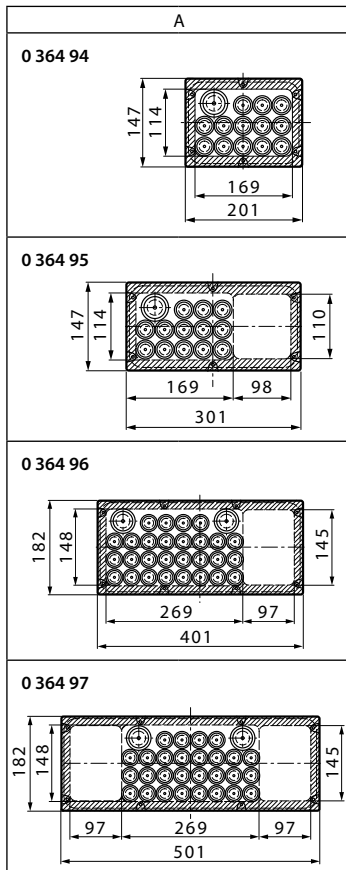

	A
3 375 20	0 364 94
3 375 21	0 364 95
3 375 22	0 364 96
3 375 23	0 364 97
3 375 30	0 364 94
3 375 31	0 364 95
3 375 32	0 364 96
3 375 33	0 364 97
3 375 40	0 364 94
3 375 41	0 364 95
3 375 42	0 364 96
3 375 43	0 364 97
3 375 50	0 364 94
3 375 51	0 364 95
3 375 52	0 364 96
3 375 53	0 364 97
3 375 60	0 364 94
3 375 61	0 364 95
3 375 62	0 364 96
3 375 63	0 364 97
3 375 70	0 364 94
3 375 71	0 364 95
3 375 72	0 364 96
3 375 73	0 364 97
3 375 80	0 364 94
3 375 81	0 364 95
3 375 82	0 364 96
3 375 83	0 364 97
3 375 90	0 364 94
3 375 91	0 364 95
3 375 92	0 364 96
3 375 93	0 364 97
3 376 00	0 364 94
3 376 01	0 364 95
3 376 02	0 364 96
3 376 03	0 364 97
3 376 10	0 364 94
3 376 11	0 364 95
3 376 12	0 364 96
3 376 13	0 364 97
3 376 20	0 364 94
3 376 21	0 364 95
3 376 22	0 364 96
3 376 23	0 364 97

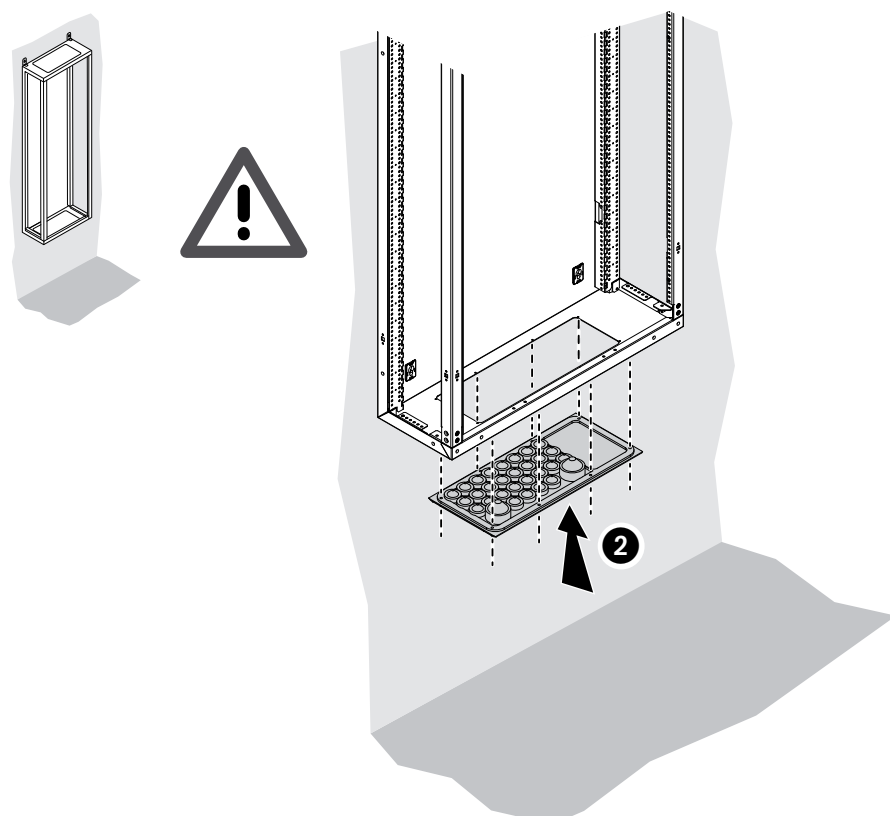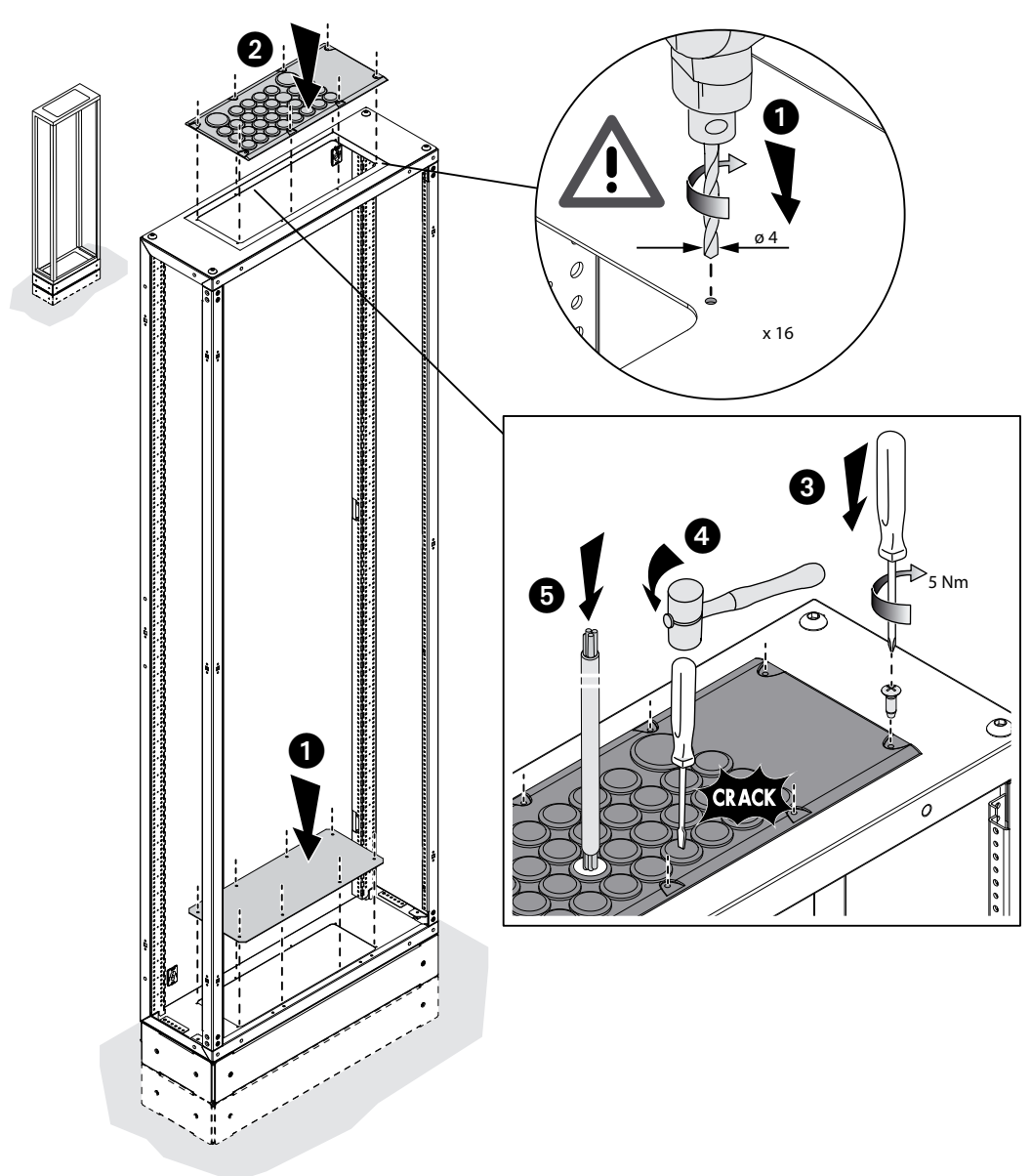


 

x 2


L (mm)			
350	450	600	800
3 382 01	3 382 02	3 382 03	3 382 04

 3 382 05




x 2


3 382 00

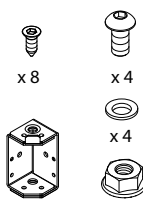



x 8 x 4
x 4 x 4

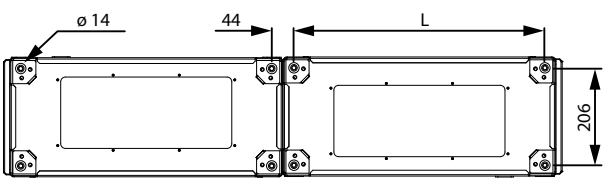



	L		L		L
3 375 20	281	3 375 60	281	3 376 00	281
3 375 21	381	3 375 61	381	3 376 01	381
3 375 22	531	3 375 62	531	3 376 02	531
3 375 23	731	3 375 63	731	3 376 03	731
3 375 30	281	3 375 70	281	3 376 10	281
3 375 31	381	3 375 71	381	3 376 11	381
3 375 32	531	3 375 72	531	3 376 12	531
3 375 33	731	3 375 73	731	3 376 13	731
3 375 40	281	3 375 80	281	3 376 20	281
3 375 41	381	3 375 81	381	3 376 21	381
3 375 42	531	3 375 82	531	3 376 22	531
3 375 43	731	3 375 83	731	3 376 23	731
3 375 50	281	3 375 90	281		
3 375 51	381	3 375 91	381		
3 375 52	531	3 375 92	531		
3 375 53	731	3 375 93	731		

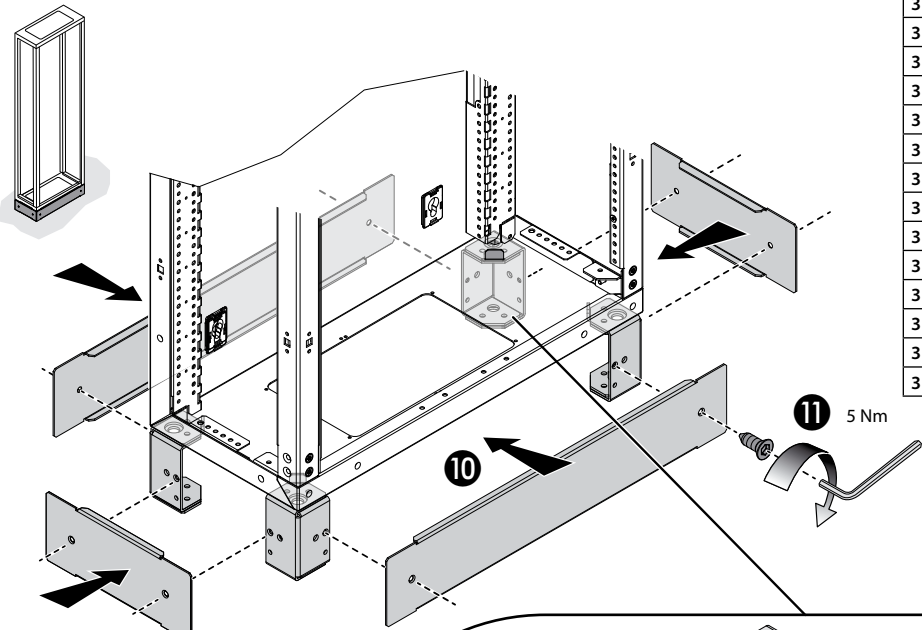


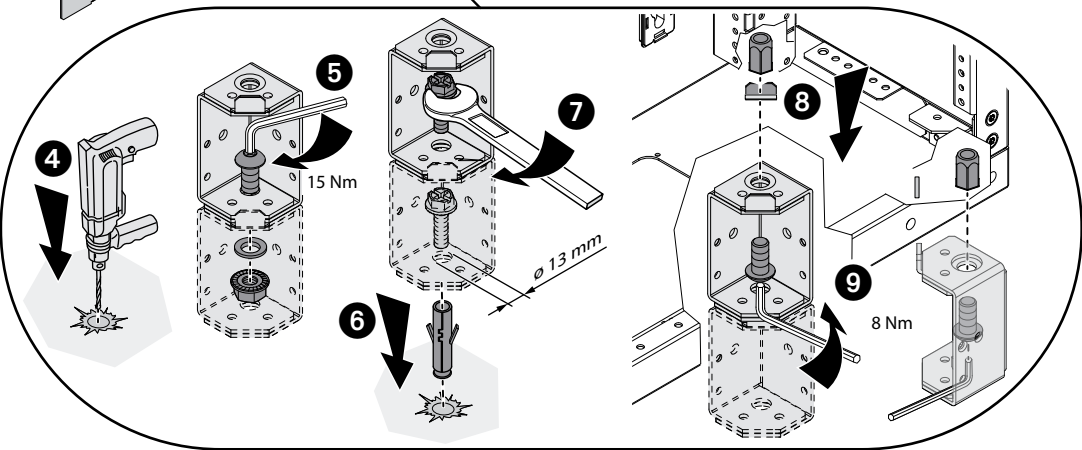


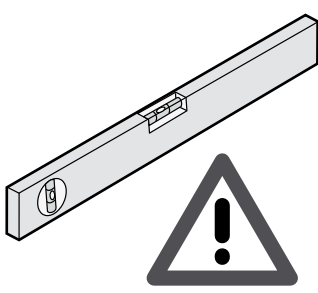

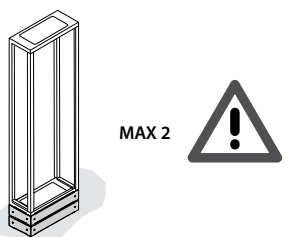


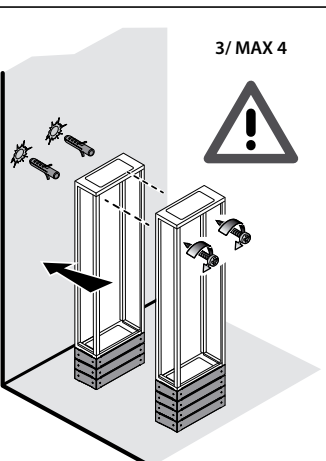

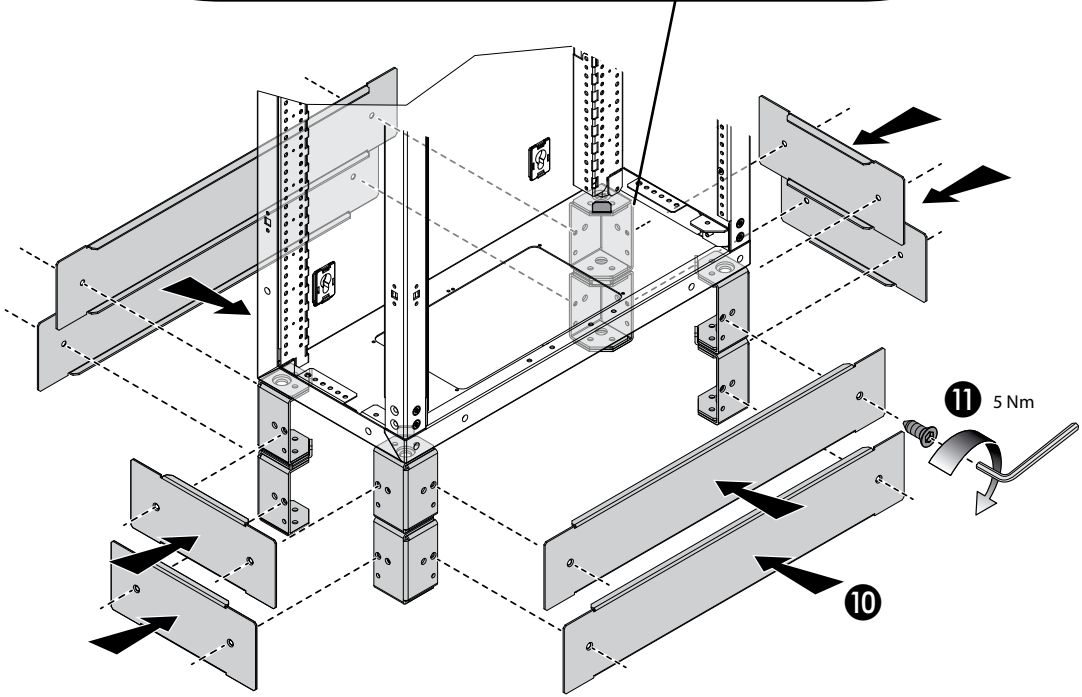

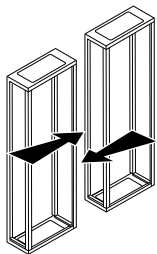

3 379 49
x 2

 

x 1



x 3

(> 200 Kg)



x 16

3 379 50 (< 200 Kg)











x 6





x 8




x 2

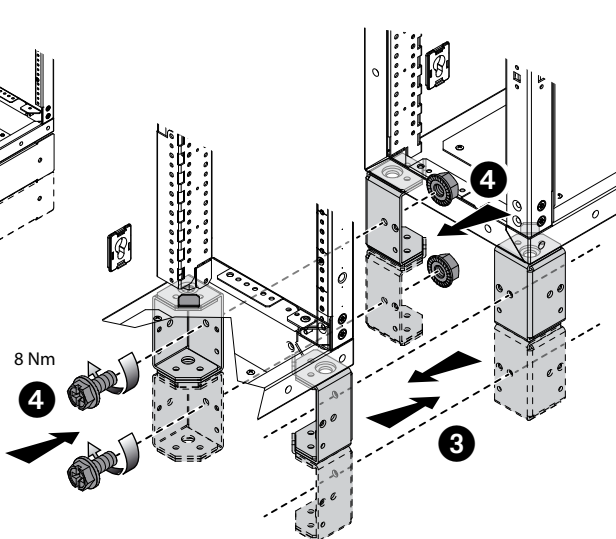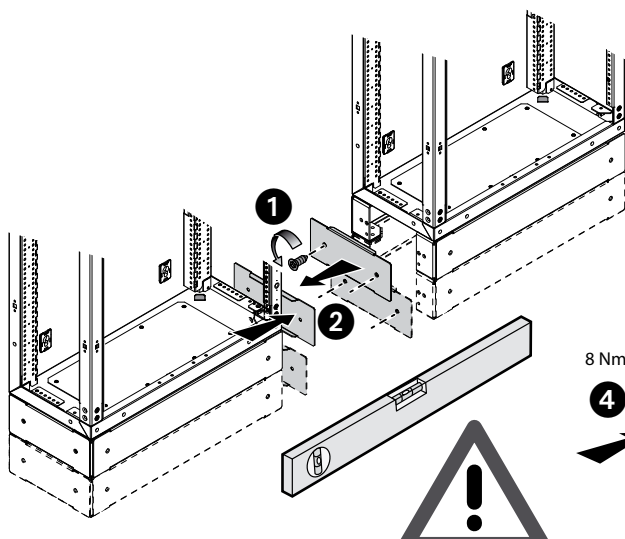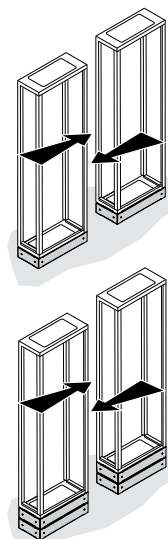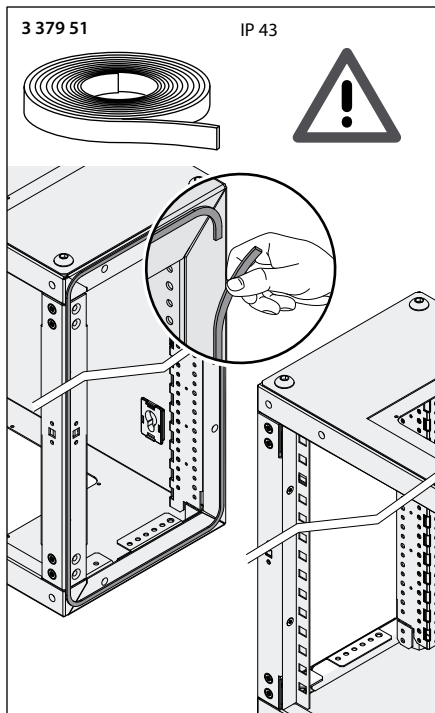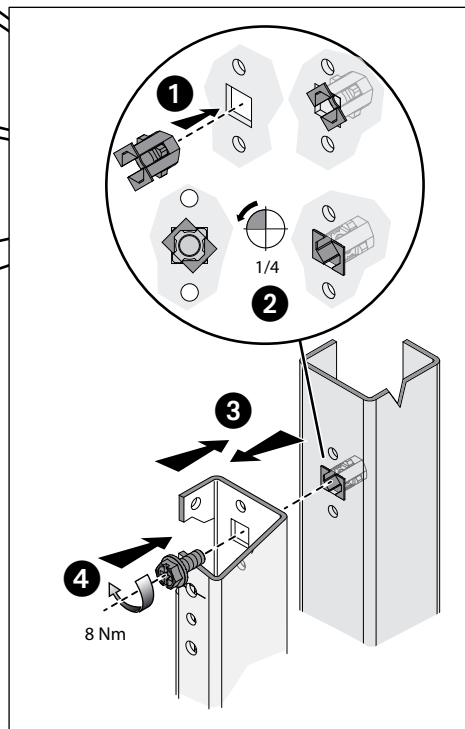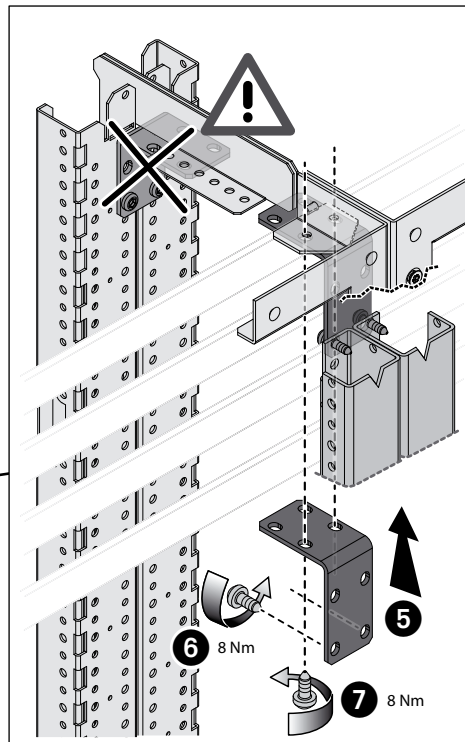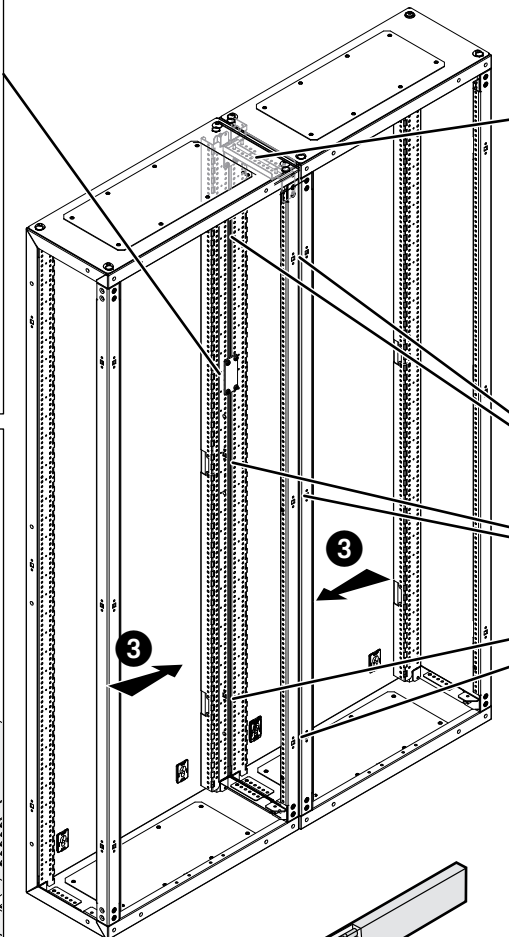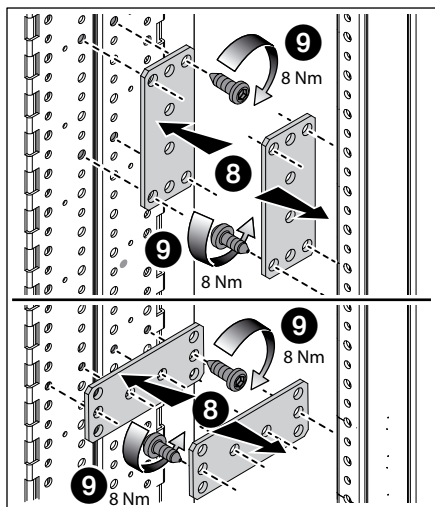

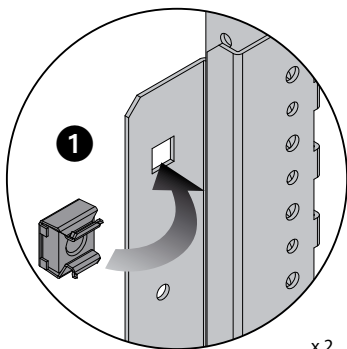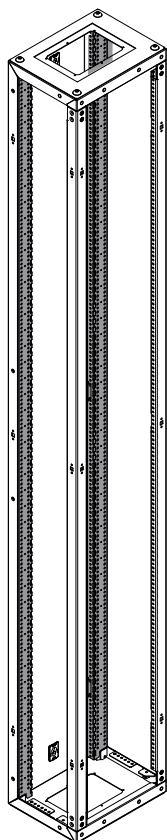

x 2

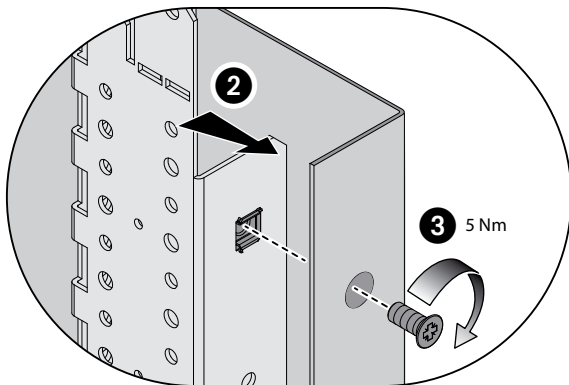

L 350	
	x 2 x 8 x 8
H (mm)	
750	3 379 86
900	3 379 87
1050	3 379 88
1200	3 379 89
1350	3 379 90
1500	3 379 91
1650	3 379 92
1800	3 379 93
1950	3 379 94
2100	3 379 95
2250	3 379 96

