













	H mm	P mm			
		400	600	800	
	2000 mm	3 380 40	3 380 41	3 380 42	
	2200 mm	3 380 50	3 380 51	3 380 52	

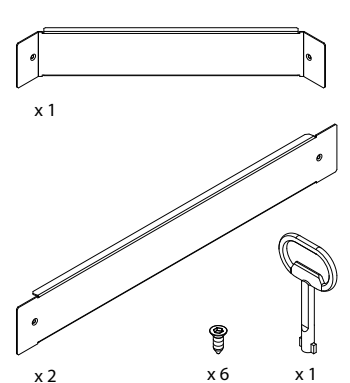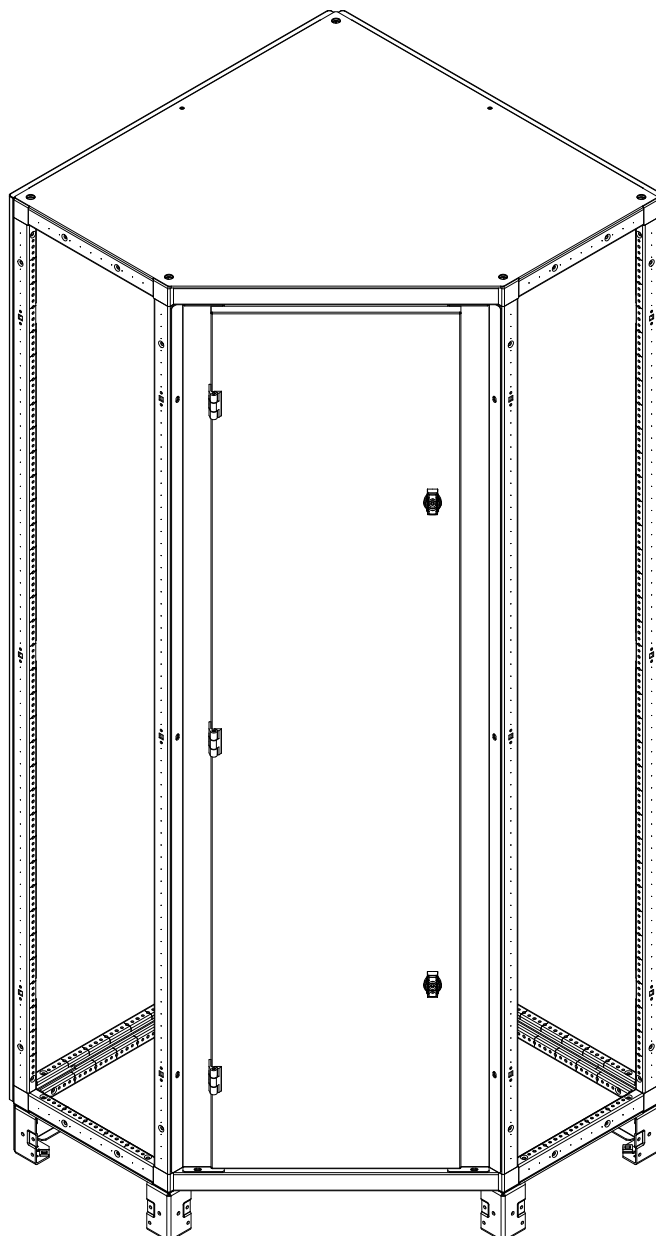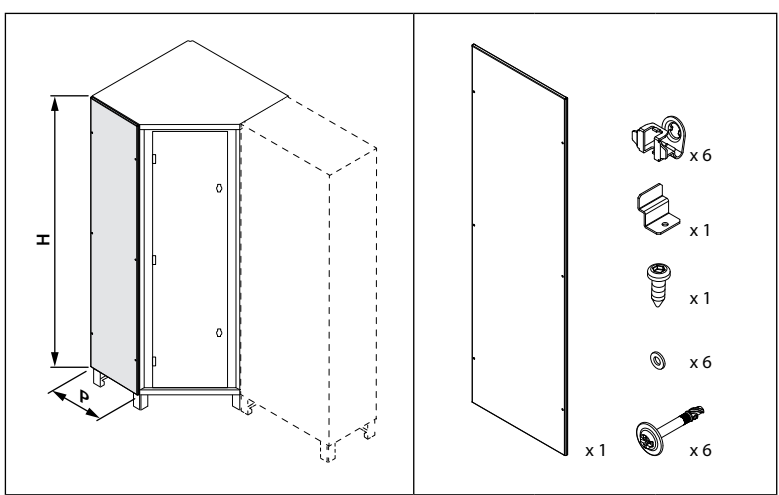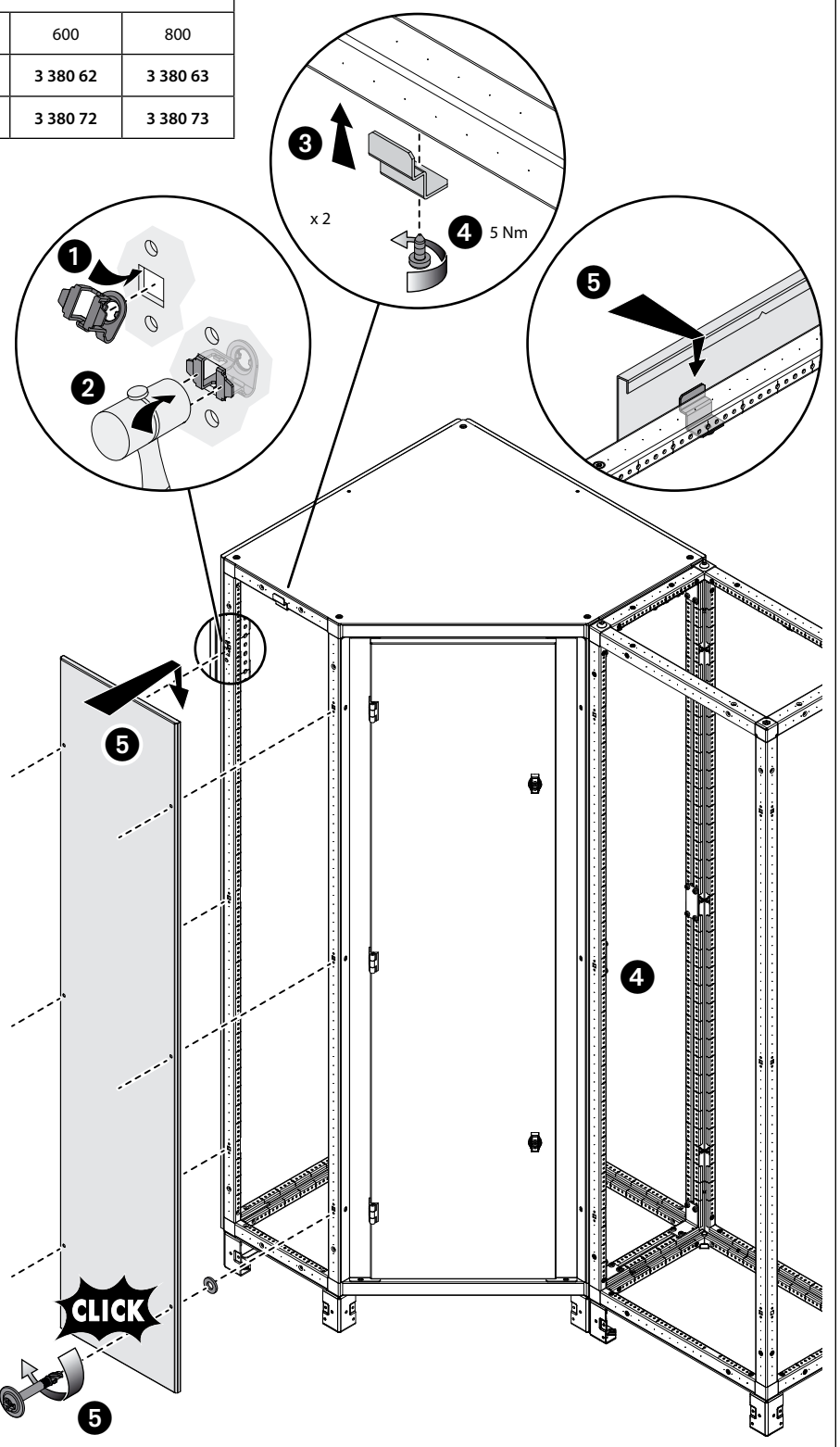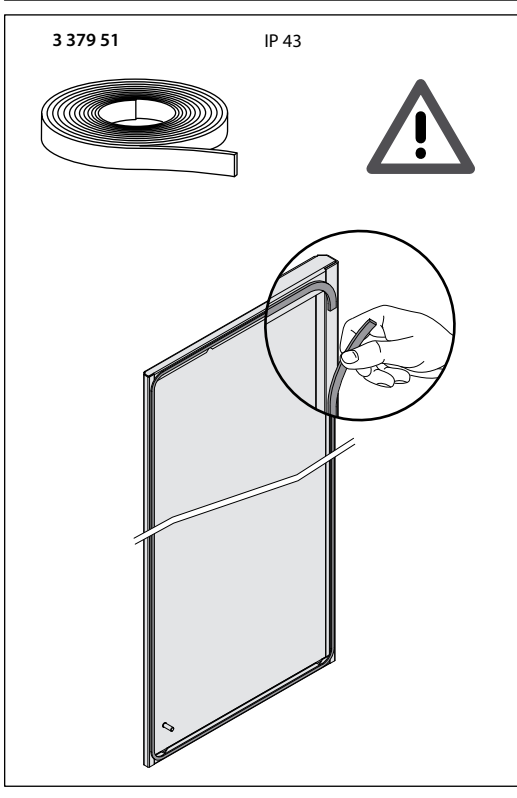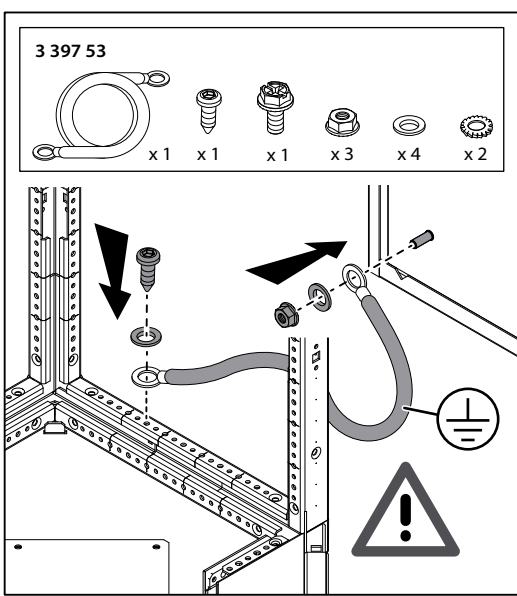
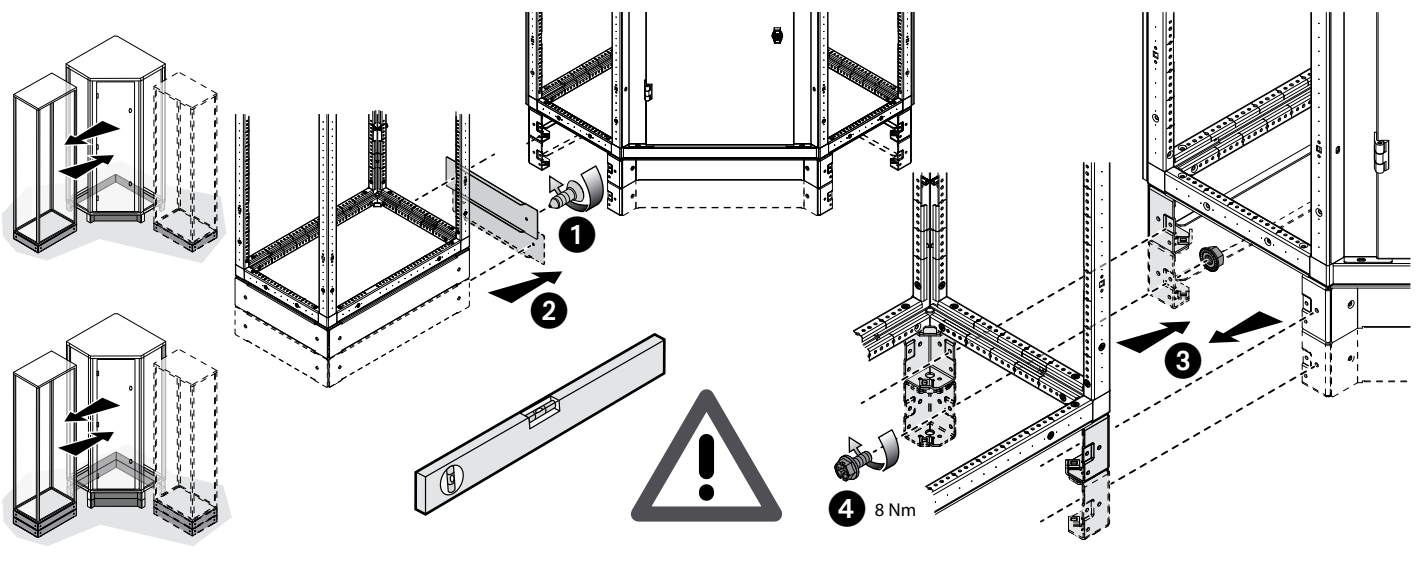
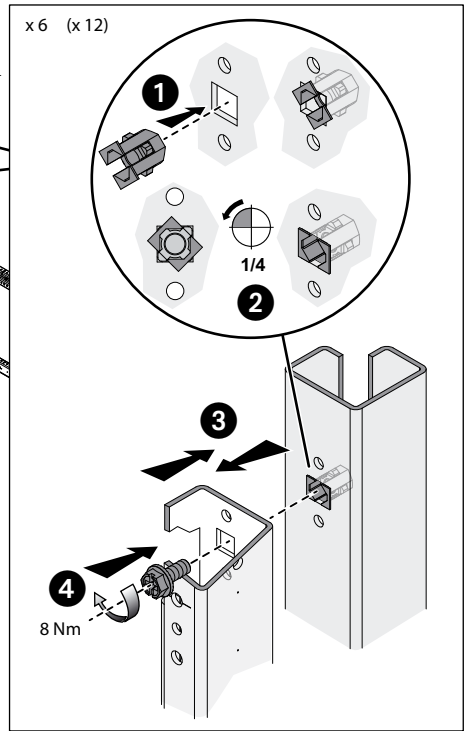
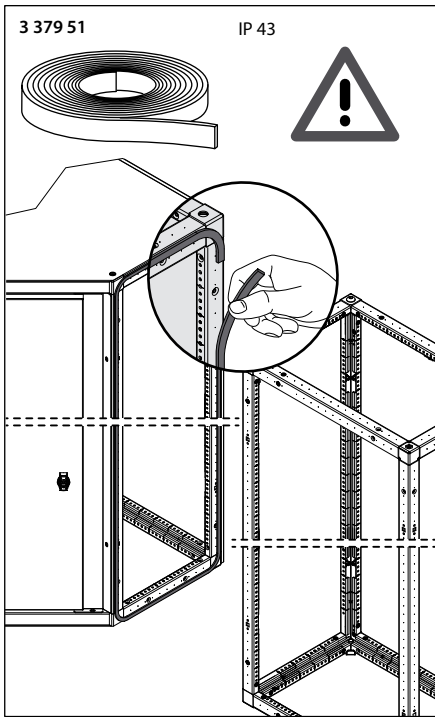
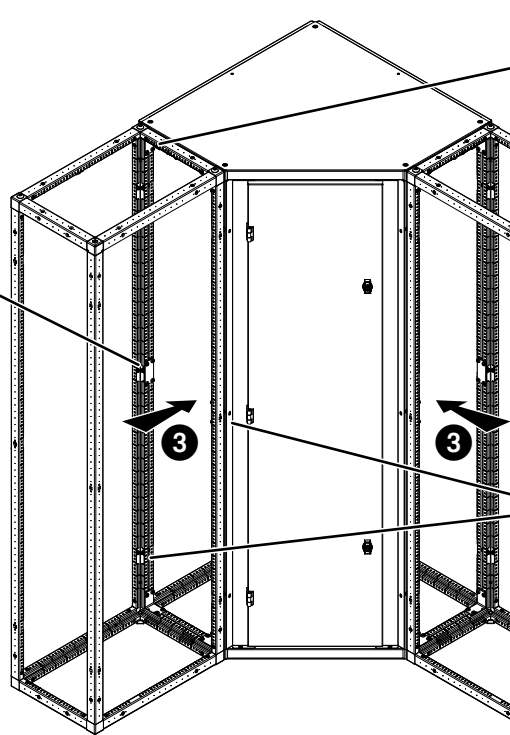
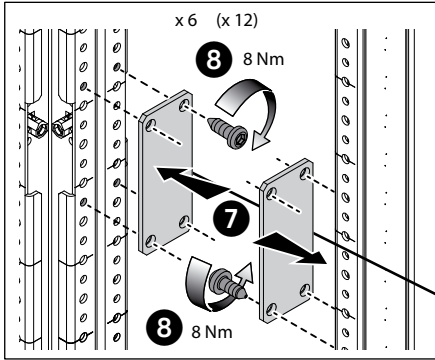


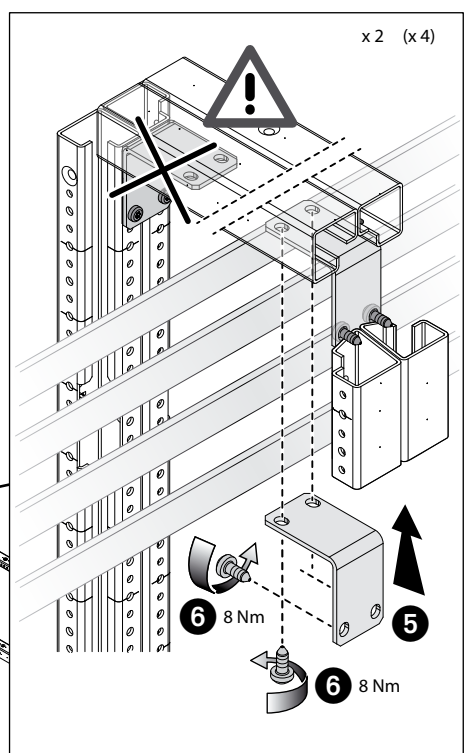

H mm	P mm		
	400	600	800
2000	3 380 61	3 380 62	3 380 63
2200	3 380 71	3 380 72	3 380 73

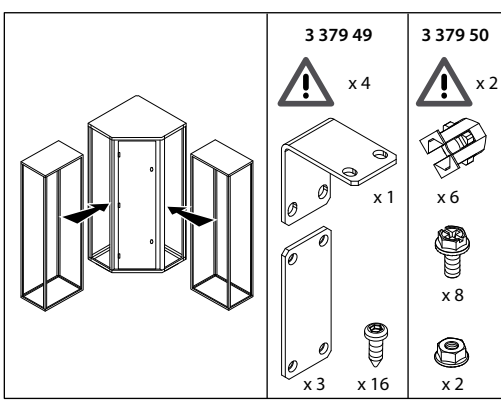

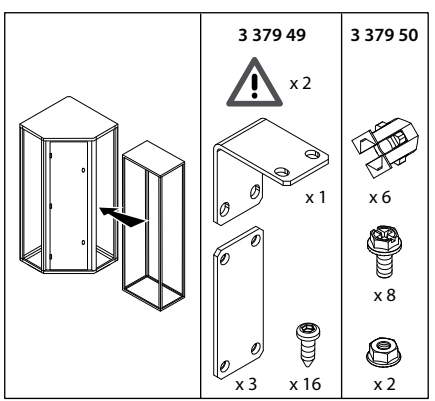

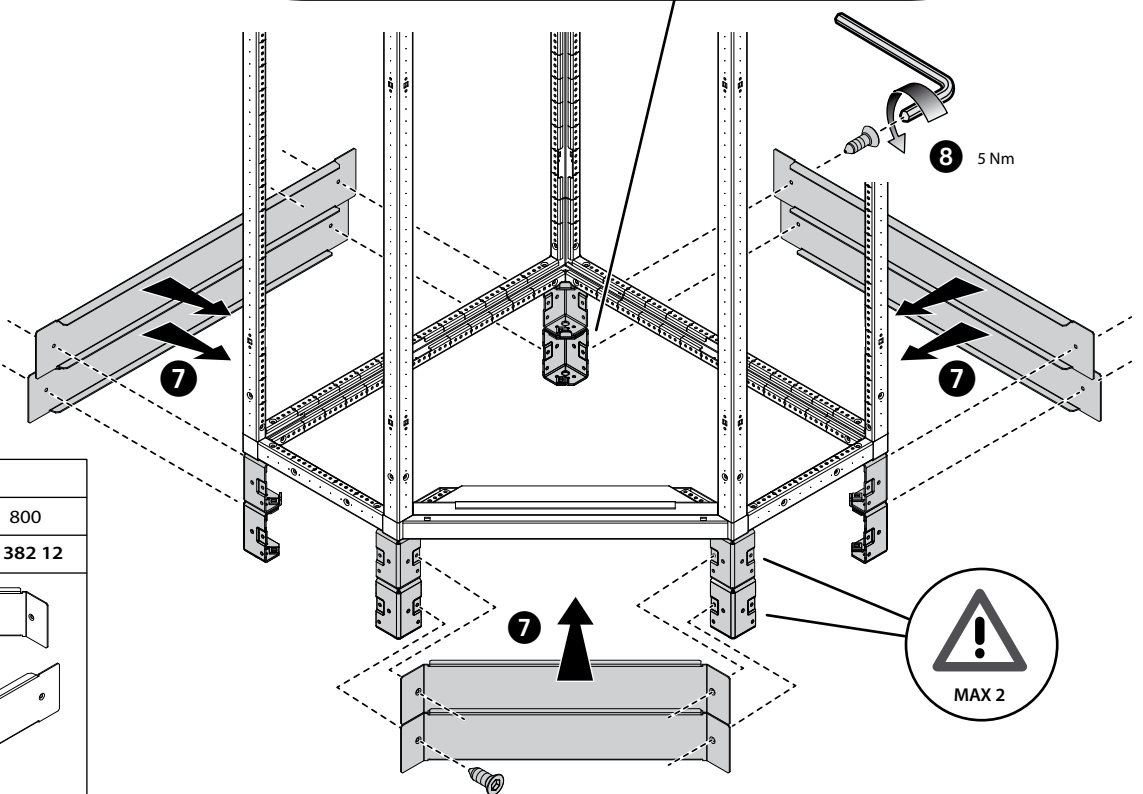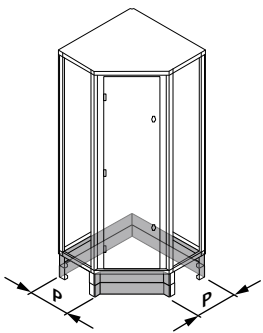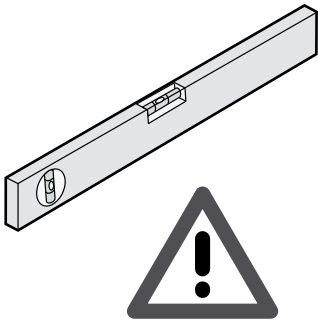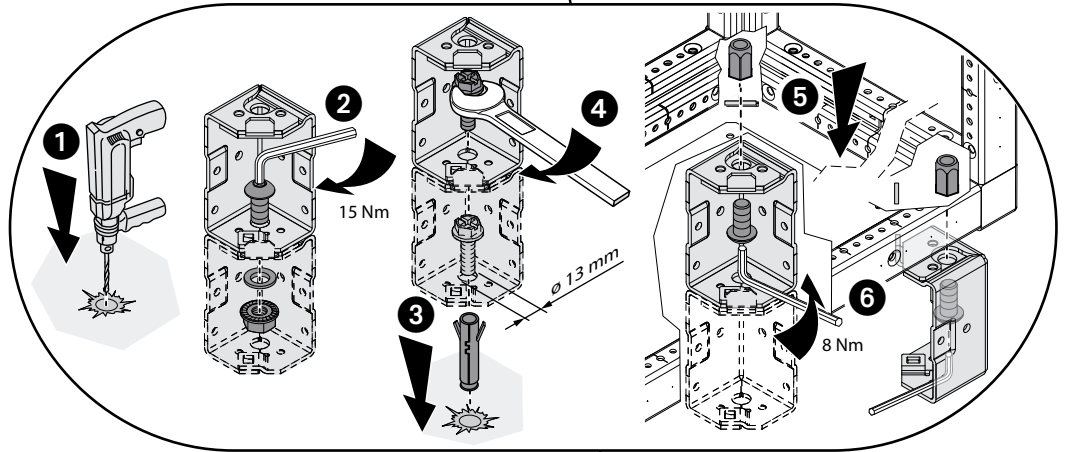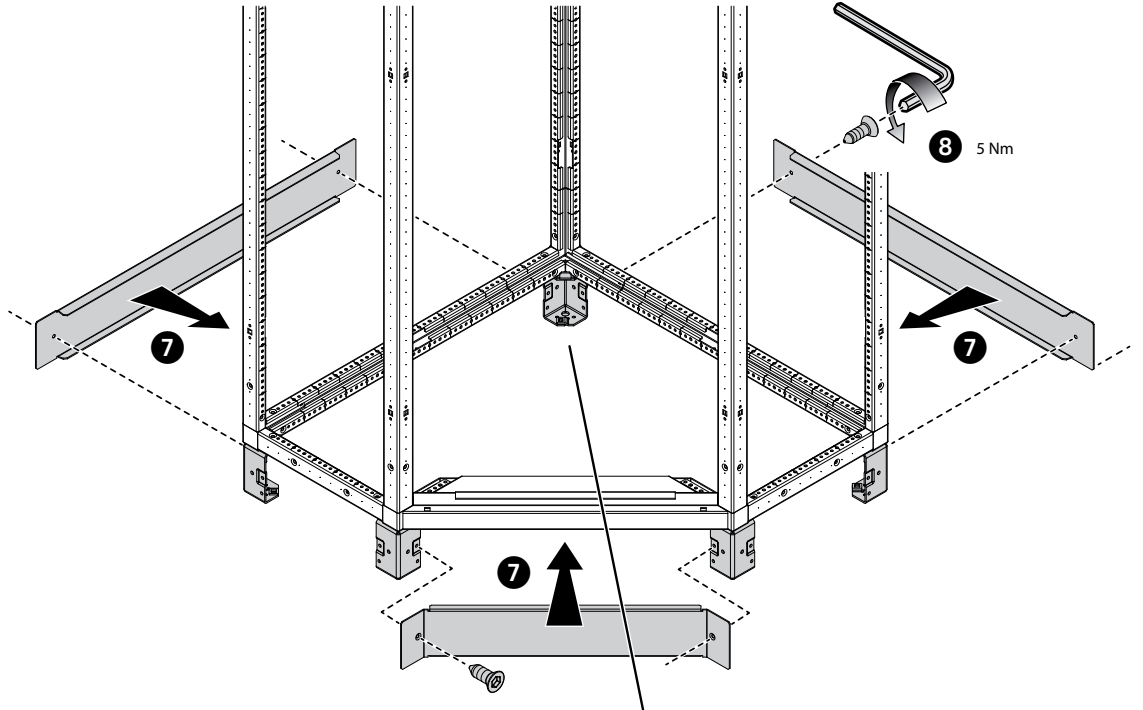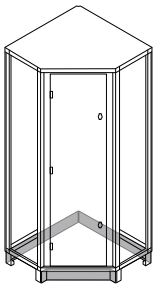

P mm		
400	600	800
3 382 10	3 382 11	3 382 12