

- **Installation**
 - **Installatie**
 - **Installation**

• L'installation doit être réalisée conformément à la norme en vigueur.
Amplitude aux chocs thermiques 110 °C

• De installatie moet uitgevoerd worden overeenkomstig geldende normen.
Amplitude bij thermische schokken van 110 °C

• The installation must be done in accordance with applicable standard.
Heat shock resistance amplitude 110 °C


• Montage und Anschluß müssen entsprechend den gültigen Vorschriften durchgeführt werden.
Temperaturwechselfestigkeitsspanne 110 °C

• Debe realizarse conforme a la norme en vigor.
Rango máximo de temperatura 110 °C

• L'installazione deve essere realizzata conformemente alla norma in vigore.
Escursione agli shock termici 110 °C
- **Installation**
 - **Instalación**
 - **Installazione**

IP55 **CE**

- **Fixation**
 - **Bevestiging**
 - **Fixing**
- **Befestigung**
 - **Fijación**
 - **Fissaggio**

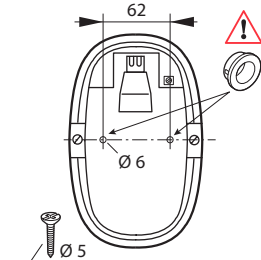


- non fournie
 - niet bijgeleverd
 - not supplied
- nicht mitgeliefert
 - no abastecido
 - non fornita

- **Raccordement**
 - **Aansluiting**

- **Connection**
 - **Anschluß**

- **Conexiones**
 - **Collegamento**

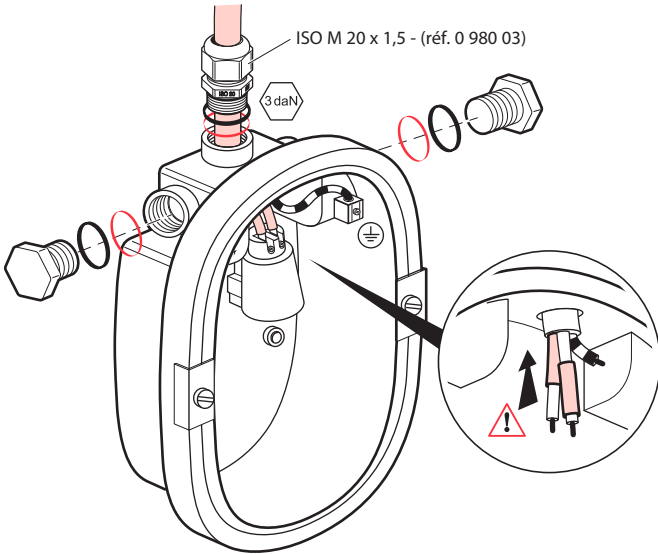

 E 27	 E 27	 E 27
55 W maxi	17 W maxi	8 W maxi

- **Accessoire**

- **Toebehoren**

- **Accessory**

- **Zubehör**

- **Accesorio**

- **Accessorio**



0 605 08

- Grille de protection
 - Rooster
 - Protective grill
- Schutzgitter
 - Rejilla de proteccion
 - Griglia di protezione