



Requires you to buy and install the «... with Netatmo» connected starter pack

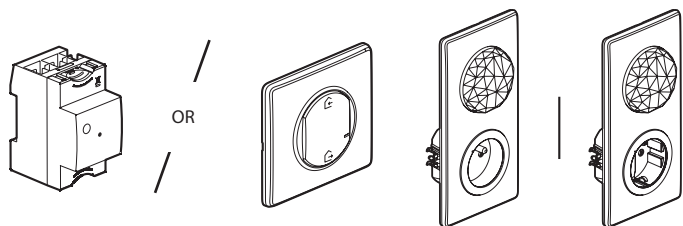

Control Modul

Gateway power outlet control and Home/away wireless Master control

Pack contents :

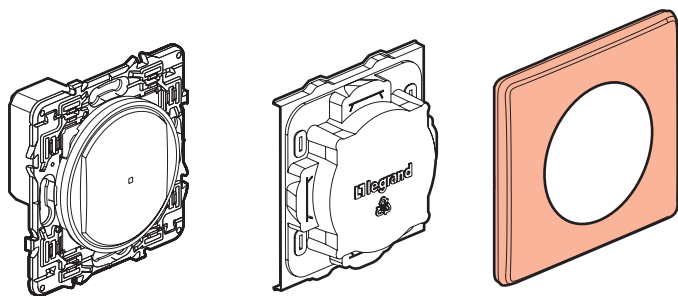

Connected switch with neutral (with dimmer option)


Site protection

Finishing plate

LET2005AE


Before starting : wiring precautions

If you plan to install two-way light switches, read the following precautions :
To control a light with **two or more switches**, only use the following products :

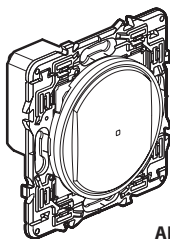


Connected switch with neutral (with dimmer option)

AND

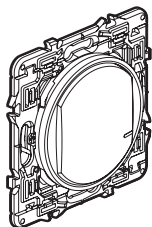


x 1 or several

AND/OR

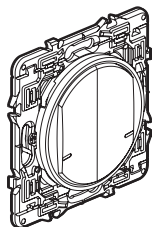

x 1 or several

AND/OR

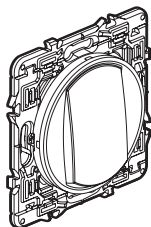

x 1 or several

Wireless switches for all control points (not included in this pack)

up to 5 push buttons (not included in this pack)

Do not use: two connected switches (with dimmer option) to control the same lighting point.

Characteristics

In default operating mode (on/off), this switch works with the following bulbs :

Do not use a smart bulb with the connected switch with neutral (with dimmer option).

| | | | | | |
|--|-----------------------------|---------|-----------------------|---------|---------|
| +45° C -5° C 110-240 VAC 50/60 Hz | 2 x 1,5 mm ² | LED | LED | LED | LED |
| | | | | | |
| 240 VAC | Maxi. | 150 W | ^(*) 150 VA | 150 VA | 150 VA |
| 110 VAC | Maxi. | 75 W | ^(*) 75 VA | 75 VA | 75 VA |

^(*) or 15 bulbs max. For comfortable lighting, we recommend using bulbs of the same type and make.


Product NOT COMPATIBLE with ferromagnetic transformer
Risk of product breaking

Do not use: In dimmer option operating mode (which can be activated via the App), this switch functions only with dimmable bulbs (identifiable by the logo on packaging).



Tip if replacing a two-way switch:

old flush-mounted switch replaced by the wireless switch.

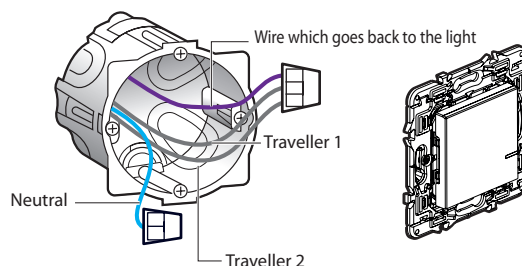


Use a **connector** to connect all 3 wires together (travellers 1 and 2 and lamp return wire).
Use an other connector for neutral wire.

1 Necessary safety precautions




 Switch off the power at the main circuit breaker




Make sure that the power is off before continuing with the installation.

 
2 Wire the connected switch with neutral (with dimmer option)



Remove the old switch

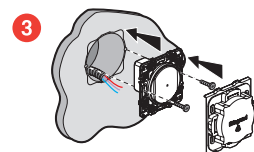

2 Wire the connected switch

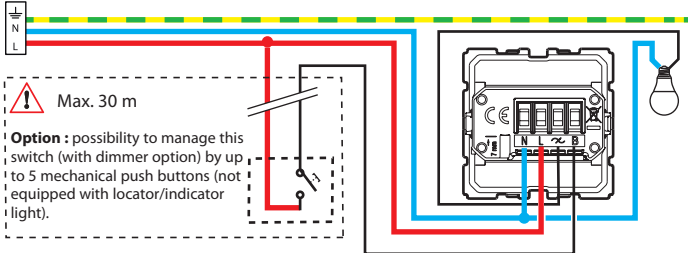

Frequency bands: 2.4 - 2.4835 GHz
Power level: < 100 mW

N (neutral) = blue
L (live) = any except blue and green/yellow
(earth) = green/yellow

Attention, the dimmer must be installed on the lamp side

Do not use: The connected light switch (with dimmer option) works with standard bulbs or dimmable bulbs including LEDs. Using dimmable LEDs is mandatory if dimmer mode is activated.


③ To add a connected product to your connected installation, you should follow the instructions:

- in the **Home + Control application** (Settings/Add a new product section)
- or consult the user manual on **legrand.fr**



www.legrand.fr

LEGRAND - Pro and Consumer Service - BP 30076
87002 LIMOGES CEDEX FRANCE • www.legrand.com

 **Safety instructions**

This product should be installed in compliance with installation rules, preferably by a qualified electrician. Incorrect installation and/or incorrect use can lead to risk of electric shock or fire. Before carrying out the installation, read the instructions and take account of the product's specific mounting location. Do not open up, dismantle, alter or modify the device except where specifically required to do so by the instructions. All **Legrand** products must be opened and repaired exclusively by personnel trained and approved by **Legrand**. Any unauthorised opening or repair completely cancels all liabilities and the rights to replacement and guarantees. Use only **Legrand** brand accessories.

SIMPLIFIED EU DECLARATION OF CONFORMITY

The undersigned,

Legrand

declares that the radio-electric equipment referred to in these instructions complies with directive 2014/53/EU.

The full text of the EU declaration of conformity is available on the following website :

www.legrandoc.com