


2 gang connected switch with neutral  
7 221 82 - 7 222 82 - 7 223 82 - 7 224 82




 
Requires you to buy and install the Suno with Netatmo connected starter pack first.

Control Module

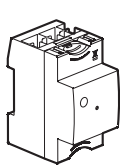


OR

Gateway Power Outlet and Home/Away wireless control

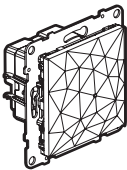

Pack contents

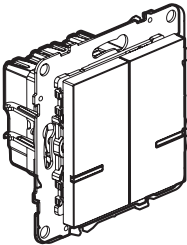

2 gang connected switch with neutral

Characteristics

This switch works with the following loads :

 + 45°C + 5°C	 2 x 1,5 mm²		<b>LED Dimmable</b> 			<b>(**)</b> 
110-240 V~ 50/60 Hz						
240 V~	Maxi.	250 W	(*) 50 VA	50 VA	250 VA	250 VA
110 V~	Maxi.	125 W	(*) 25 VA	25 VA	125 VA	125 VA

(\*) or 10 bulbs max. For comfortable lighting, we recommend using bulbs of the same type and manufacturer.


(\*\*) Ferromagnetic transformers must be loaded to more than 60% of their nominal power. When calculating the permissible power, the efficiency of ferromagnetic transformers must be taken into account. It is necessary to connect a load before programming and using the product.

Safety instructions

This product should be installed in compliance with installation rules, preferably by a qualified electrician. Incorrect installation and/or incorrect use can lead to risk of electric shock or fire. Before carrying out the installation, read the instructions and take account of the product's specific mounting location. Do not open up, dismantle, alter or modify the device except where specifically required to do so by the instructions. All **Legrand** products must be opened and repaired exclusively by personnel trained and approved by **Legrand**. Any unauthorised opening or repair completely cancels all liabilities and the rights to replacement and guarantees. Use only **Legrand** brand accessories.


## Before starting : wiring precautions

If you plan to install two-way light switches, read the following precautions:  
To control 1 light with 2 or more points of control, use only the following products :

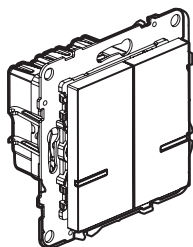


x 1  
2 gang connected switch  
with neutral

AND

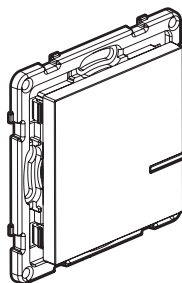

x 1  
or several

AND/OR

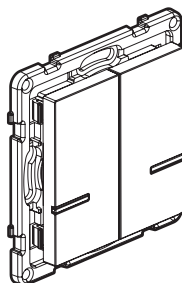

x 1  
or several

Wireless lighting controls (not included in this pack).  
Up to 20 maximum



**Do not use:** two 2gang connected switches to control the same lighting point.

## 1 Necessary safety precautions

1



Switch off the power  
at the main circuit  
breaker

OFF


2



**Make sure that the power is  
off before continuing with  
the installation.**


## 2 Install the connected 2 gang switch

1

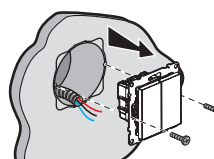


Remove the existing switch

3

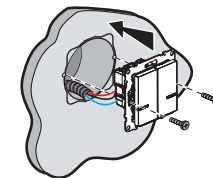

## 2 Wire the connected 2G switch



— N (neutral) = blue  
— L (Live) = all except blue  
and green/yellow  
— ⚬ (earth) = green/yellow

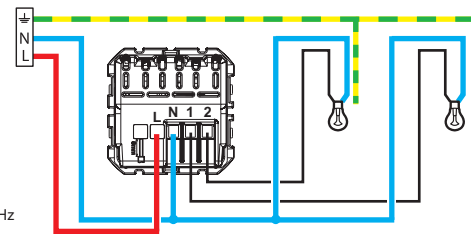

Frequency bands: 2.4 - 2.4835 GHz  
Power level: < 100 mW

Tip if replacing an existing 2-way switch

The travellers 1 and 2 of the old switch must be wired together in terminal 1 or 2 of the new connected switch

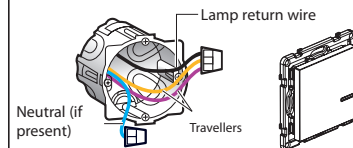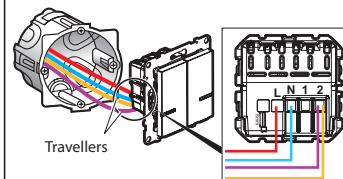

Use a connector to connect all 3 wires together (travellers 1 and 2 and lamp return wire). Use a separate connector to insulate the neutral wire

3

**To add a connected product to your connected installation, you should follow the instructions:**

- in the **Legrand Home + Control application (Settings/Add a new product section)**
- r consult the user manual on **legrand.com**



**[www.legrand.com](http://www.legrand.com)**

LEGRAND - Pro and Consumer Service - BP 30076  
87002 LIMOGES CEDEX FRANCE • [www.legrand.com](http://www.legrand.com)

## **SIMPLIFIED EU DECLARATION OF CONFORMITY**

The undersigned,

***Legrand***

declares that the radio-electric equipment referred to in these instructions complies with directive 2014/53/EU. The full text of the EU declaration of conformity is available on the following website :

***[www.legrand.com/ecatalogue](http://www.legrand.com/ecatalogue)***