


This product is a connected accessory which **requires** you to buy and install the Mallia senses with Netatmo connected starter pack first.


Pack contents

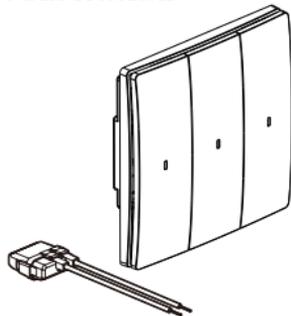

0 401 49 Bleeder 		110-240V~
		50/60 Hz
		0.4 W
		+5° C → +35° C

Connected switch + bleeder

 Characteristics

 +35°C +5°C 110-240V~ 50/60Hz	 8 mm 1.5-4mm ²	①	②	③ (**)	④	⑤
		  	 	 		
240V	Max.	200W	120VA	120VA	120VA	(*)100VA
	Min.	15W	15VA	15VA	15VA	15VA
110V	Max.	100W	60VA	60VA	60VA	(*)50VA
	Min.	15W	15VA	15VA	15VA	15VA

(*) Or 10 lamps max. For comfortable lighting, we recommend using bulbs of the same type and brand.

(**) Use only with transformers designed to function with electronic switches.


Take account of transformer losses when calculating power.

Transformers must be loaded at more than 60% of their power.

Before you start: wiring precautions

If you plan to install two-way light switches, read the following precautions:

To control a light **with two or more switches**, only use the products:

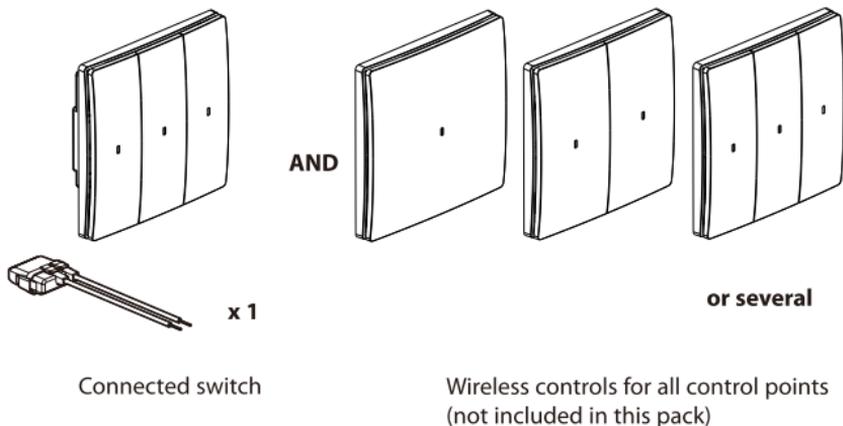


Do not use: two connected switches to control the same lighting point.

Tip if replacing a two-way switch:

old flush-mounted switch replaced by the wireless control.

Use a **connector** to connect live wire and traveller wires 1 and 2.

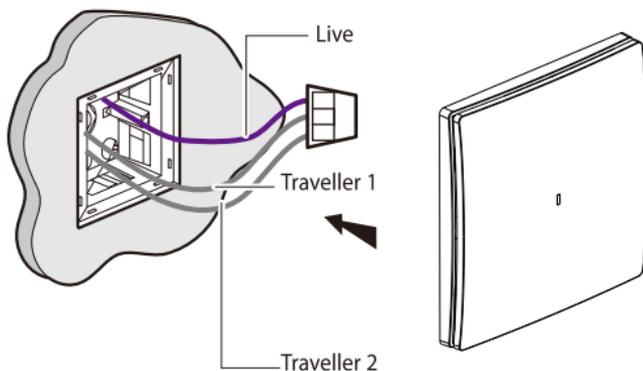

① Necessary safety precautions

1



OFF

Switch OFF the power at the main circuit breaker

2




Make sure that the power is OFF before continuing with the installation.


② Install the connected switch

1

Remove the existing switch

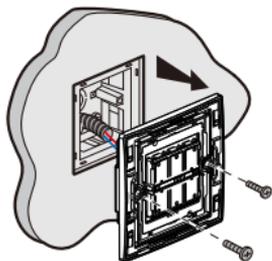

3

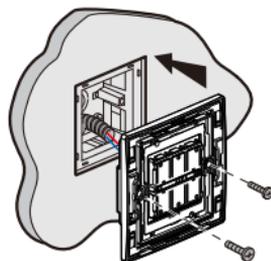


② Wire the connected switch

To ensure that your connected switch works correctly, you **must** wire **the bleeder** provided as close to the load as possible and put **a bulb** in before turning the power on.

Bleeder (mandatory)

- N (neutral) = blue
- L (live) = any except blue and green/yellow
- \perp (earth) = green/yellow

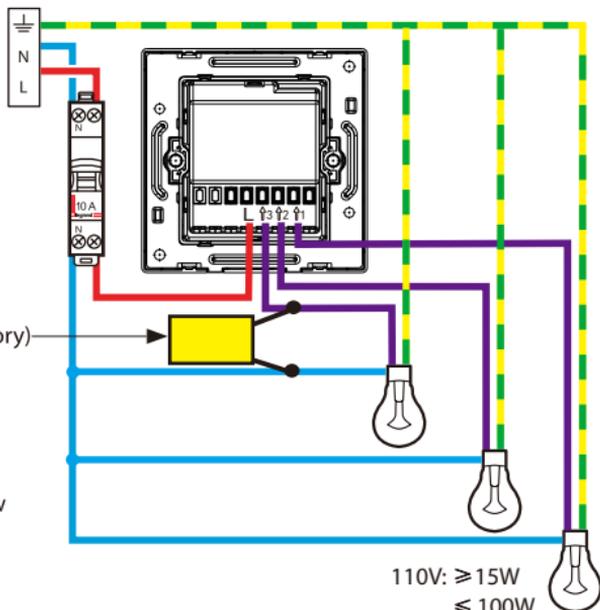

Frequency bands: 2.4 - 2.4835 GHz
Power level: < 100 mW

110V: $\geq 15W$
 $\leq 100W$
240V: $\geq 15W$
 $\leq 200W$

③ **To add a connected product to your connected installation, you should follow the instructions:**

- in the **user guide in your connected starter pack**
- in the **Legrand Home + Control application (Settings/Add a new product section)**
- or consult the user manual on **legrand.com**



www.legrand.com/reference/281507MW

LEGRAND - Pro and Consumer Service - BP 30076
87002 LIMOGES CEDEX FRANCE • www.legrand.com

⚠ Safety instructions

This product should be installed in compliance with installation rules, preferably by a qualified electrician. Incorrect installation and/or incorrect use can lead to risk of electric shock or fire.

Before carrying out the installation, read the instructions and take account of the product's specific mounting location.

Do not open up, dismantle, alter or modify the device except where specifically required to do so by the instructions. All Legrand products must be opened and repaired exclusively by personnel trained and approved by Legrand. Any unauthorised opening or repair completely cancels all liabilities and the rights to replacement and guarantees. Use only Legrand brand accessories.

SIMPLIFIED EU DECLARATION OF CONFORMITY

The undersigned,

Legrand

declares that the radio-electric equipment referred to in these instructions
complies with directive 2014/53/EU.

The full text of the EU declaration of conformity
is available on the following website:

www.legrandoc.com

هذا المنتج هو جهاز متصل يتطلب منك أولاً شراء وتركيب علبة المنتجات الأساسية
المتصلة ماركة Netatmo مع Mallia senses

محتويات العلبة



المفتاح المتصل + صمام تفريغ

0 401 49 صمام التفريغ 		110-240V~
		50/60 Hz
		0.4 W
		+5° C → +35° C

Characteristics

 +35°C +5°C 110-240V~ 50/60Hz	 8 mm 1.5-4mm ²	1   	2  	3 (**)  	4 	5 
						
240V	Max.	200W	120VA	120VA	120VA	(*)100VA
	Min.	15W	15VA	15VA	15VA	15VA
110V	Max.	100W	60VA	60VA	60VA	(*)50VA
	Min.	15W	15VA	15VA	15VA	15VA

(*) أو 10 مصابيح بحد أقصى. لتوفير أجواء إضاءة مريحة للعينين، نوصي باستخدام مصابيح من نفس النوع والماركة.

(**) لا تُستخدم سوى مع المحولات المصممة للعمل مع المفاتيح الإلكترونية.


يجب مراعاة الفقد الحاصل في قدرة المحول عند حساب القدرة.

يجب أن يكون الحمل الواقع على المحولات أكثر من القدرة المقررة لها بنسبة 60%.

قبل بدء العمل: الاحتياطات الخاصة بتوصيلات الأسلاك

إذا كنت تنوي تركيب مفاتيح إضاءة ذات تحويلتين، فاقراً الاحتياطات التالية:


للتحكم في مصباح إضاءة باستخدام مفتاحين أو أكثر، لا تستخدم سوى المنتجات التالية:

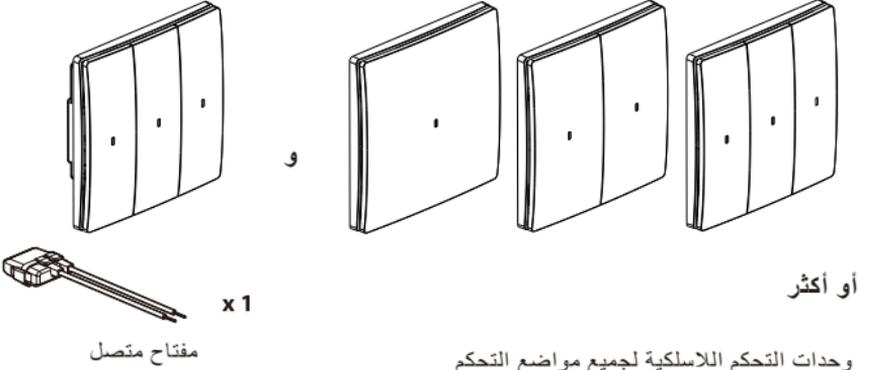

يحظر استخدام: مفتاحان متصلان للتحكم في نفس موضع الإضاءة ⚠️

استخدم أداة وصل لتوصيل السلك الكهربائي والأسلاك الناقلة رقمي 1 و 2.

نصيحة في حالة استبدال مفتاح ذي تحويلتين: استبدال المفتاح القديم المركب داخل الجدار بوحدة التحكم اللاسلكية.

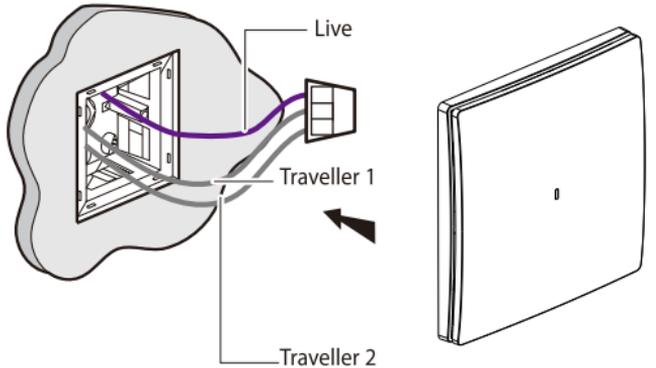

① احتياطات السلامة الضرورية



مفصول


افصل التيار الكهربائي
من القاطع الرئيسي
للدائرة الكهربائية

تأكد من فصل التيار الكهربائي قبل متابعة
خطوات عملية التركيب




② تركيب المفاتيح المتصل

1

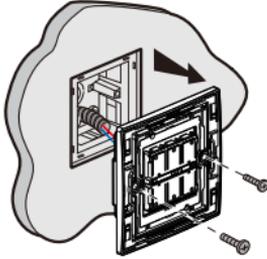

3

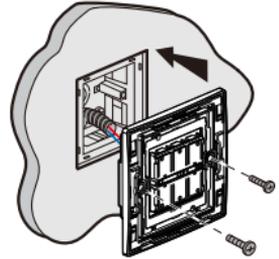


قم بإزالة المفاتيح الموجود

② قم بتوصيل أسلاك المفاتيح المتصل

لضمان عمل المفاتيح المتصل الخاص بك (مع مفاتيح
تغيير شدة الإضاءة الاختياري) بصورة صحيحة،
يجب توصيل صمام التفريغ المرفق في أقرب
موضع ممكن من الحمل وتركيب مصباح قبل
توصيل التيار الكهربائي

صمام التفريغ (الزامي)

نطاقات التردد: 2.4 - 2.4835 جيجاهرتز
مستوى القدرة: > 100 ميلي واط

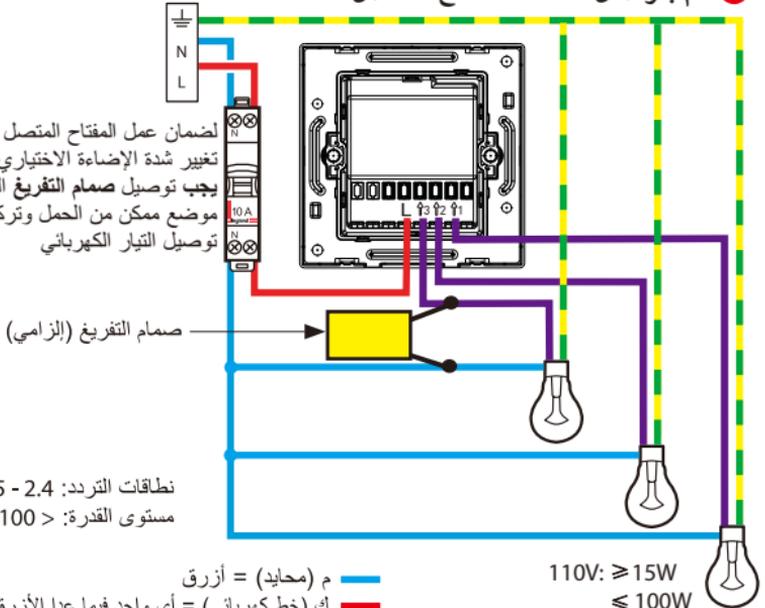

— م (محايد) = أزرق
— ك (خط كهربائي) = أي واحد فيما عدا الأزرق والأخضر/الأصفر
— (أرضي) = أخضر/أصفر

110V: $\geq 15W$
 $\leq 100W$
240V: $\geq 15W$
 $\leq 200W$

إضافة منتج متصل إلى المنتجات المتصلة المركبة لديك،
③ يجب اتباع الإرشادات:

في دليل المستخدم في علبة المنتجات الأساسية المتصلة
الموجودة في التطبيق **Control + Home** الخاص
بشركة **Legrand** (القسم الإعدادات/إضافة منتج
أو راجع دليل المستخدم المتوفر على legrand.com



www.legrand.com/reference/281507MW

LEGRAND - Pro and Consumer Service - BP 30076
87002 LIMOGES CEDEX FRANCE • www.legrand.com

إرشادات الأمان: ⚠

يجب تركيب هذا المنتج طبقاً لقواعد التركيب ويفضل أن يقوم بالتركيب كهربائي مؤهل. فقد يؤدي التركيب الخاطئ و/أو الاستخدام الخاطئ إلى مخاطر التعرض لصدمة كهربائية أو نشوب حريق.
اقرأ النشرة قبل التركيب، وأفرد مكاناً لتركيب المنتج خاصاً به.
لا تفتح أو تفك أو تعدل أو تحور المنتج ما لم يُشَرَّ إلى ذلك بشكل محدد في النشرة. فكل منتجات **Legrand** يجب فتحها وإصلاحها حصراً من قبل فنيين مدربين ومؤهلين لدى **Legrand**. وكل فتح أو إصلاح غير مسموح به يبطل المسؤوليات وحقوق الاستبدال والضمانات. لا تستخدم سوى إكسسوارات من ماركة **Legrand** حصراً.

SIMPLIFIED EU DECLARATION OF CONFORMITY

The undersigned,

Legrand

declares that the radio-electric equipment referred to in these instructions
complies with directive 2014/53/EU.

The full text of the EU declaration of conformity
is available on the following website:

www.legrandoc.com