


Characteristics



				U	
	-10°C...+70°C	0°C...+35°C	≥35mm	220-240V~ 50/60Hz	8 mm 1~ 2,5 mm ²

	R	
Max	500W	
Min	60W	

Wiring

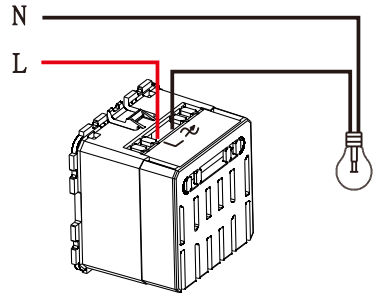

Operation

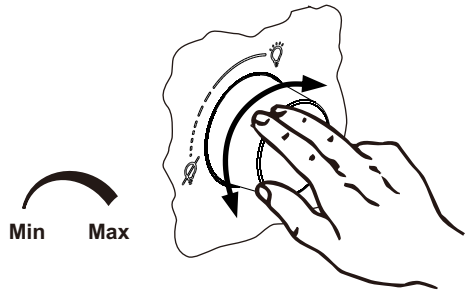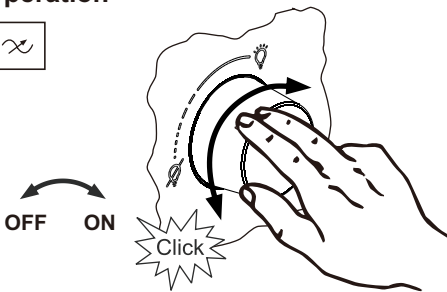

Fixing

