



Characteristics

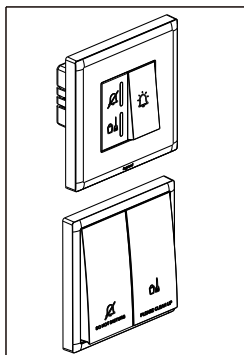


			U	
-10°C...+70°C	0°C...+35°C	≥35mm	230V~ 50/60Hz	8 mm 1~ 2,5 mm ²
-10°C...+70°C	0°C...+35°C	≥35mm	16AX 230V~	12mm 1~ 4 mm ²

Description


Call indicator

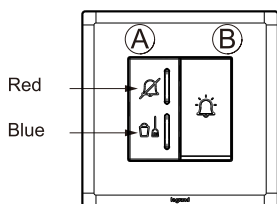


Call control

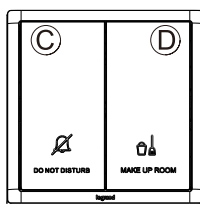

Buzzer

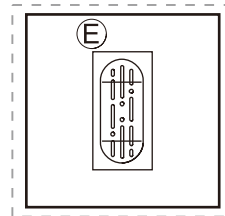



Wiring

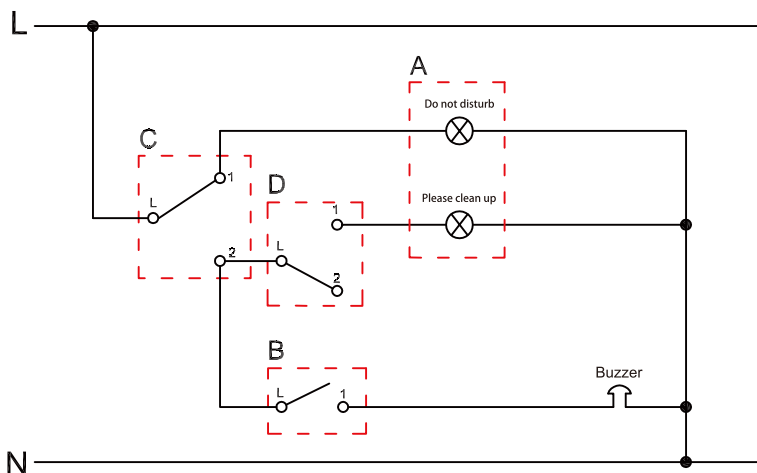


Operation

1- Instruction : « Do not disturb »




Bedroom

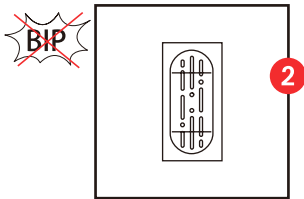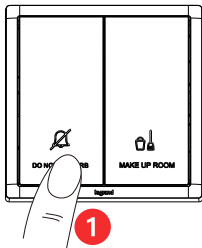

Corridor

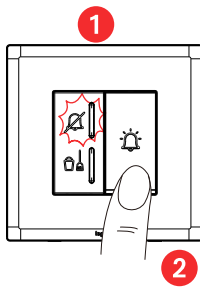


2- Instruction : « Please clean up »

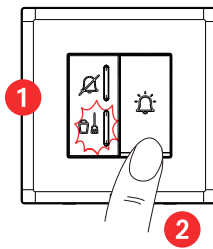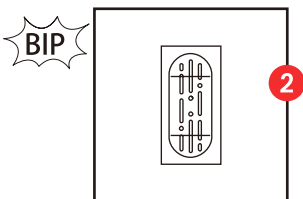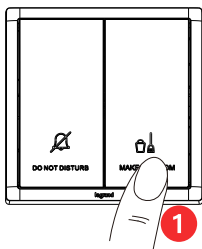


Note

If both buttons are pressed simultaneously, priority is given to the « Do not disturb » call

Bedroom

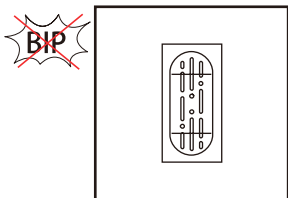

Corridor

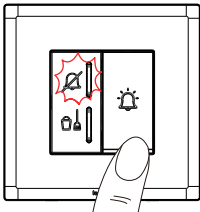

If both buttons are not pressed, only door bell work.

