


Connected lighting micromodule (with dimmer option)

0 648 99



This pack is a connected accessory which requires you to buy and install the «... with Netatmo». connected starter pack first.

Pack contents

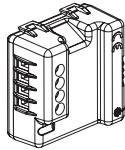

Connected lighting micromodule (with dimmer option)

Characteristics

Using the mode by default (ON/OFF), this micromodule works with the following loads :



Do not use a connected bulb with the micromodule with dimer option

 110-240 VAC 50/60 Hz	 2 x 2,5 mm ²	 			
240 VAC	Maxi.	150 W	(*)150 VA	150 VA	150 VA
110 VAC	Maxi.	75 W	(*)75 VA	75 VA	75 VA

(*) Or 15 bulbs max. For comfortable lighting, we recommend using bulbs of the same type and brand.

Product NOT COMPATIBLE with ferromagnetic transformer loads

Product break risk



Using the dimmer mode (activable from the App), this micromodule works only with dimmable bulbs (identifiable thanks to the logo on the packaging)




LE13719AA

Before you start: wiring precautions


If you plan to install two-way light switches, read the following precautions:

To control a light with two or more switches, only use the products:

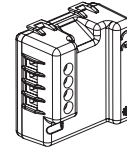


Connected micromodule with neutral (with dimmer option)


AND

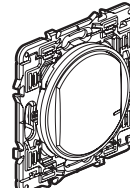

AND/OR

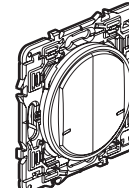

AND/OR

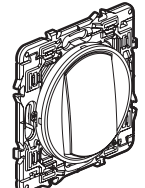

x1
or several

x1
or several

x1
or several

Up to 20 wireless lighting controls for all control point (not included in this pack)

Up to 5 mechanical push-buttons (not included in this pack)



Do not use: two connected light micromodules (with dimmer option) to control the same lighting point.

1 Safety warnings

1



OFF


Switch off the power at the main circuit breaker

2




Make sure that the power is off before continuing with the installation.

- ② The connected lighting micromodule (with dimmer option) can be installed in a ceiling light or in wall lights.

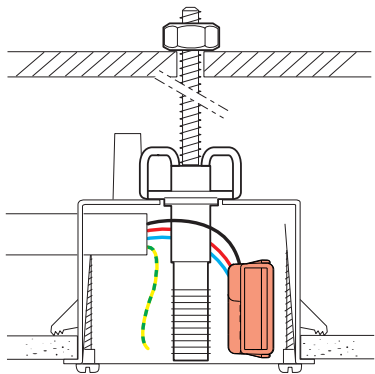

- N (neutral) = blue
- L (live) = any except blue and green/yellow
- (earth) = green/yellow

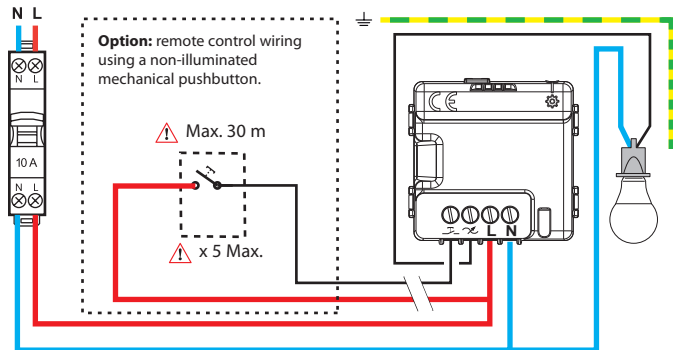

Frequency bands: 2.4 - 2.4835 GHz
Power level: < 100 mW

- ③ To add a connected product to your connected installation, you should follow the instructions:

- in the **Legrand Home + Control** application (Settings/Add a new product section)
- or consult the user manual on **legrand.fr**



www.legrand.fr/reference/064899

LEGRAND - Pro and Consumer Service - BP 30076
87002 LIMOGES CEDEX FRANCE • www.legrand.com

⚠ Safety instructions

This product should be installed in compliance with installation rules, preferably by a qualified electrician. Incorrect installation and/or incorrect use can lead to risk of electric shock or fire. Before carrying out the installation, read the instructions and take account of the product's specific mounting location. Do not open up, dismantle, alter or modify the device except where specifically required to do so by the instructions. All **Legrand** products must be opened and repaired exclusively by personnel trained and approved by **Legrand**. Any unauthorised opening or repair completely cancels all liabilities and the rights to replacement and guarantees. Use only **Legrand** brand accessories.

SIMPLIFIED EU DECLARATION OF CONFORMITY

The undersigned,
Legrand

declares that the radio-electric equipment referred to in these instructions complies with directive 2014/53/EU.

The full text of the EU declaration of conformity is available on the following website:

www.legrandoc.com