 
 
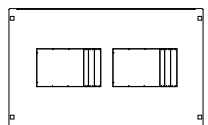
 
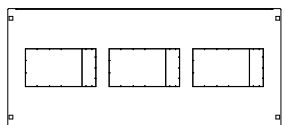


 


	24 M		36 M	
 63/100 A P100	 3 398 00	 3 398 08	 3 398 01	 3 398 09
 63/100 A P125	3 398 02	3 398 08	3 398 03	3 398 09
 160 A	3 398 04	3 398 10	3 398 05	3 398 11
 250 A	3 398 06	3 398 12	3 398 07	3 398 13

