




3 982 05A/38A/39A/40A - 6 653 22A - 6 654 22A - 7 211 35A/76A
 7 212 76A - 7 213 35A/76A - 7 214 35A/76A - 7 520 70A
 7 521 70A/72A/77A - 7 522 70A/72A - 7 523 70A/72A - 7 527 70A
 7 528 70A - 7 529 70A - 7 621 83A - 7 622 83A - 7 623 83A
 7 624 83A - 7 645 83A - 7 646 83A - 7 647 83A - 7 650 37 - 7 681 13A
 7 682 13A - 7 683 13A - 7 684 13A - 7 685 13A - 7 686 13A - 7 688 13A
 7 689 13A - 8 631 48A/50A - 8 633 48A/50A - 8 634 48A/50A
 8 635 48A/50A - 8 640 10A - NP2512BK/MG/WH - 3 982 05B/38B/39B/
 40B - 8 631 48B/50B - 8 633 48B/50B - 8 634 48B/50B - 8 635 48B/50B
 8 640 10B - NND2512BL/WH

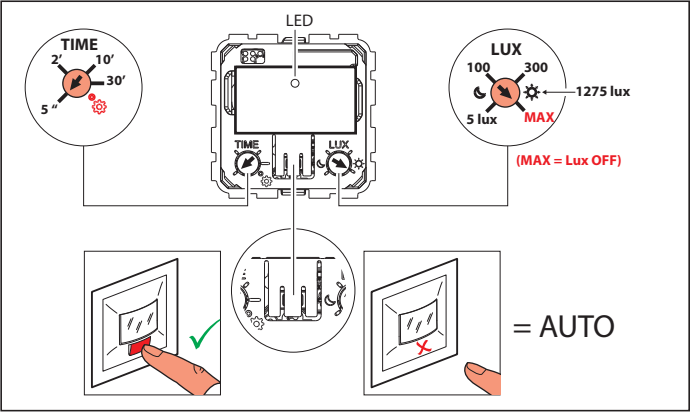

+35°C +5°C		LED		LED		LED		LED		LED		LED	
1 x 2,5 mm²		LED		LED		LED		LED		LED		LED	
240 V~	Max.	150 W	100 VA	100 VA	150 VA	150 VA	150 VA	150 VA	150 VA	150 VA	150 VA	150 VA	150 VA
	Min.	2 W	2 VA	2 VA	2 VA	2 VA	2 VA	2 VA	2 VA	2 VA	2 VA	2 VA	2 VA
110 V~	Max.	75 W	50 VA	50 VA	75 VA	75 VA	75 VA	75 VA	75 VA	75 VA	75 VA	75 VA	75 VA
	Min.	2 W	2 VA	2 VA	2 VA	2 VA	2 VA	2 VA	2 VA	2 VA	2 VA	2 VA	2 VA

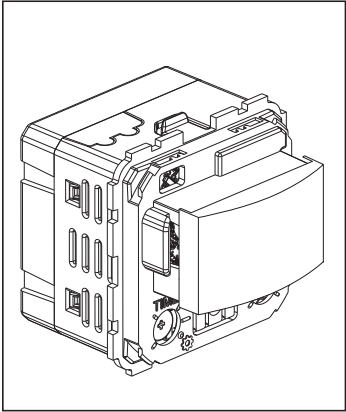

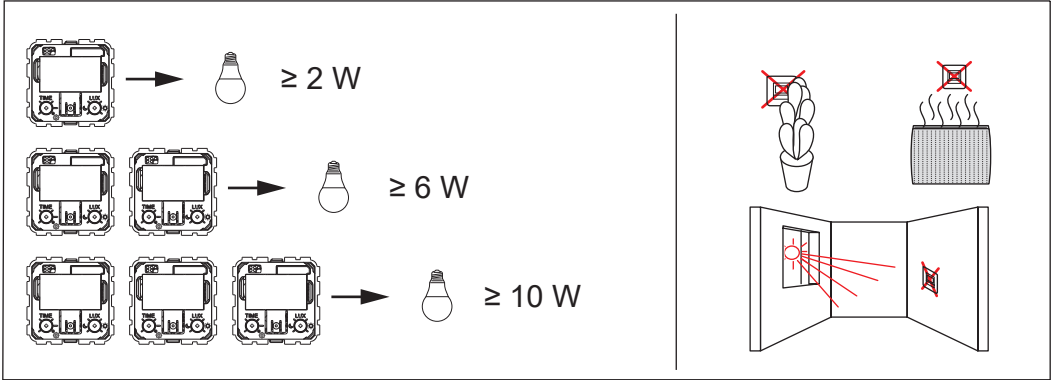

LUX	MAX
TIME	5 s
	4 m

