



NILOÉ™
 NP270BK/MG/WH


 NP270..	 -5°C ... +40°C	 U, f, I	100 W max.  LED
 -10°C ... +70°C	40 mm 250 V~ 50 / 60 Hz 6 A	12 mm  1...2,5 mm²	

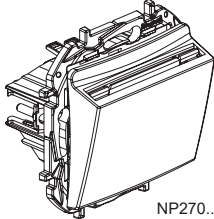

NP270..

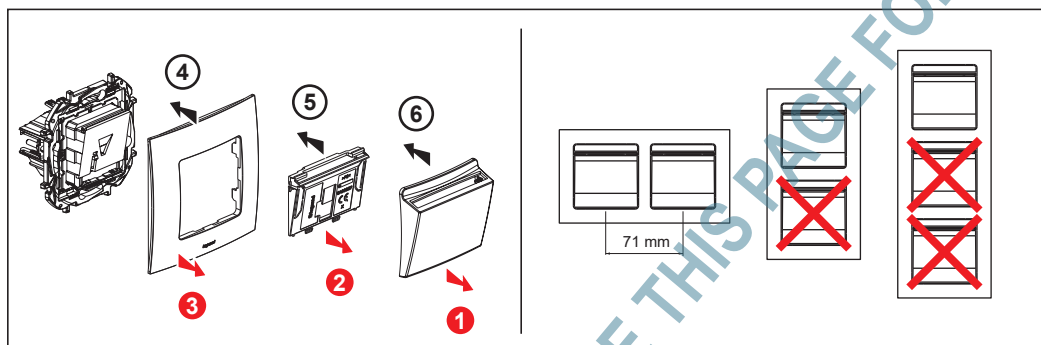