




PW29200/01/02

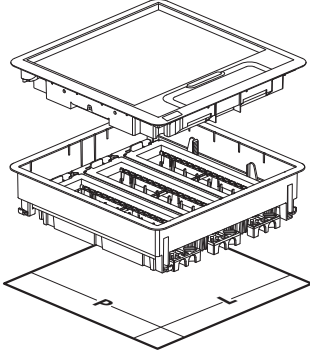


PW29203/04/05

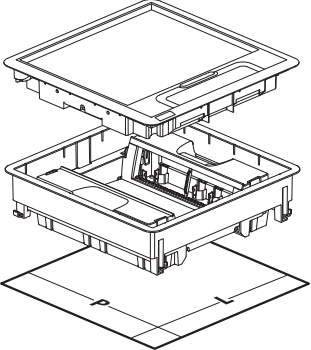


PW29206/07/08

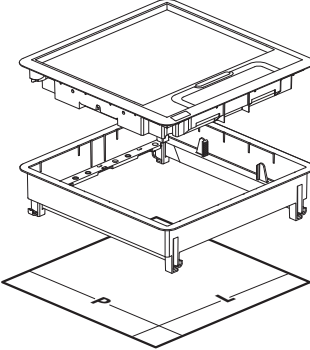


PW29218/19/20

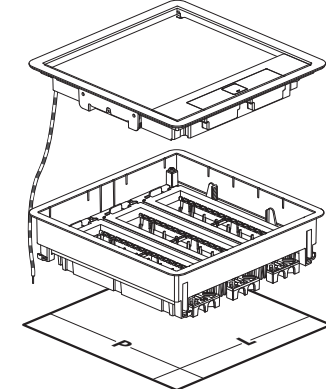





PW29221/22/23

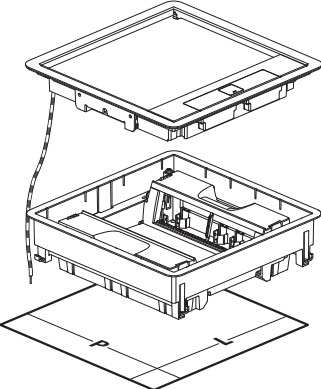

PW29224/25/26



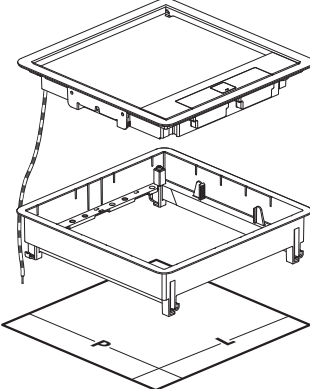


	P (mm)	L (mm)
PW29200/03/06/18/21/24	265	182
PW29201/04/07/19/22/25	265	220
PW29202/05/08/20/23/26	265	265

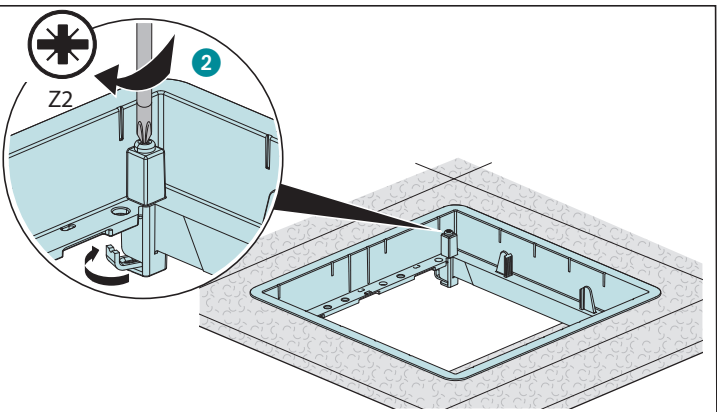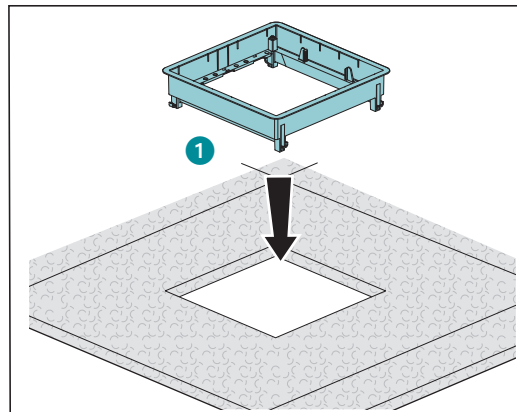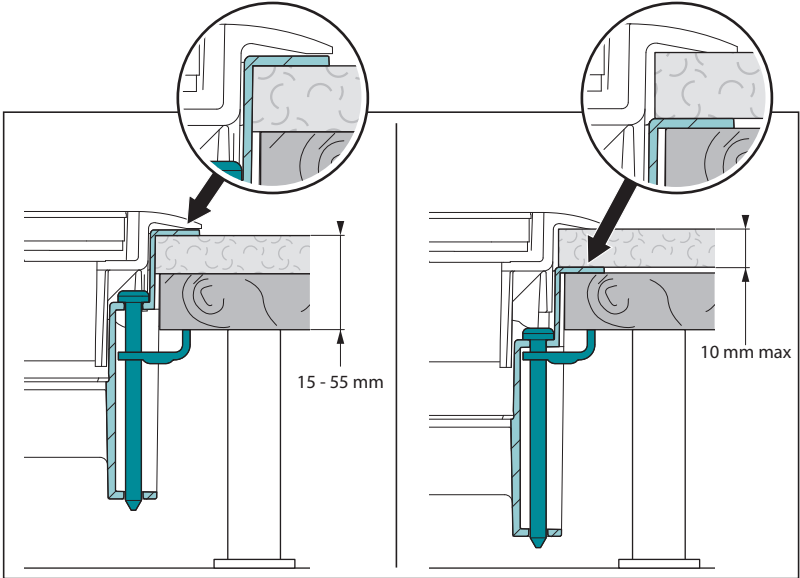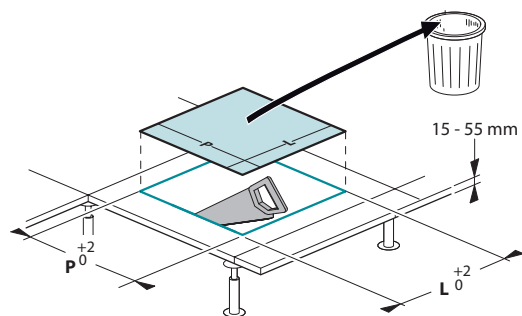




PW29200/01/02
PW29218/19/20



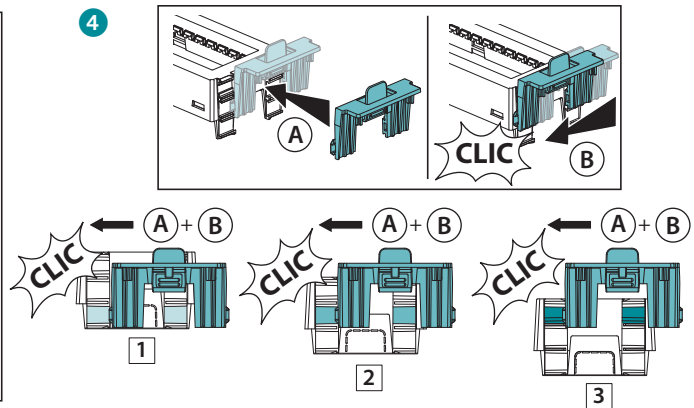
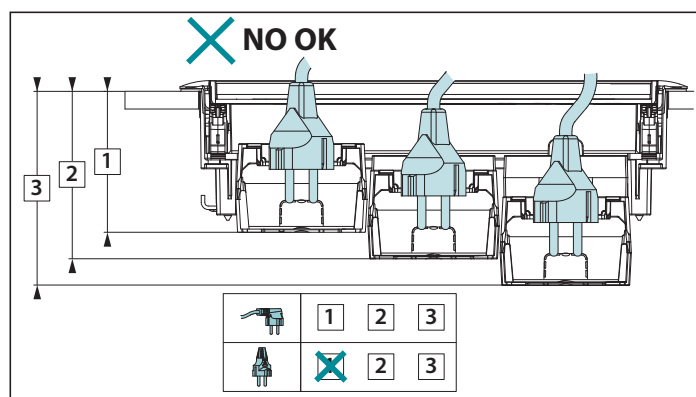
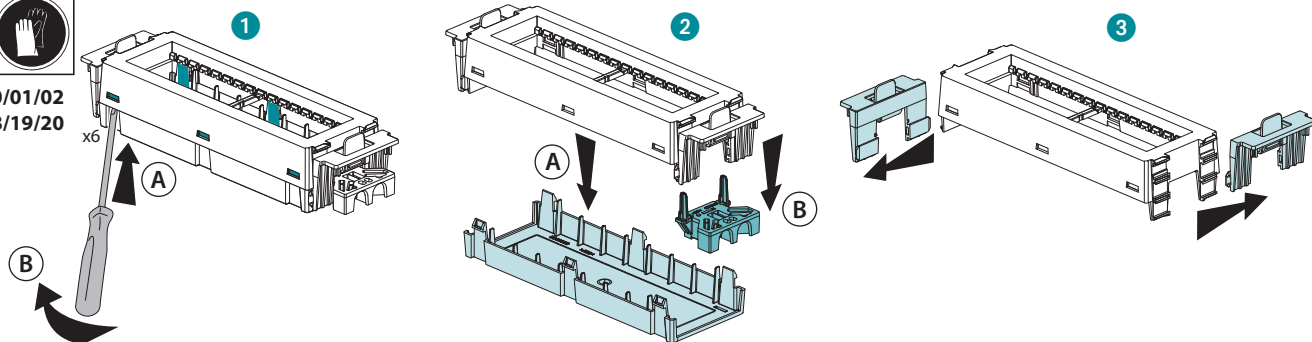


5

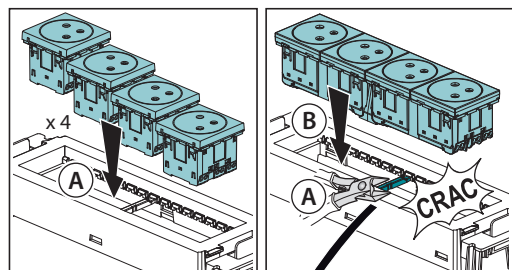


C PW29218/19/20


	L (mm)
12 modules	110
18 modules	155
24 modules	200

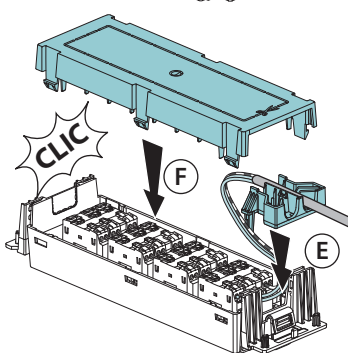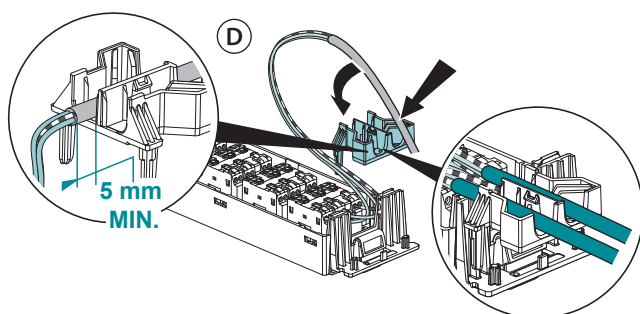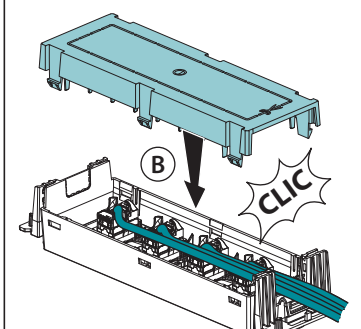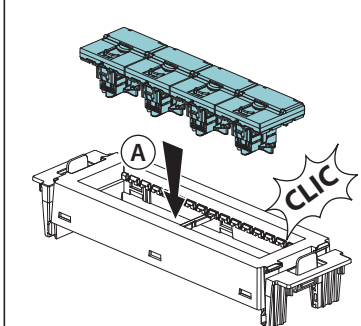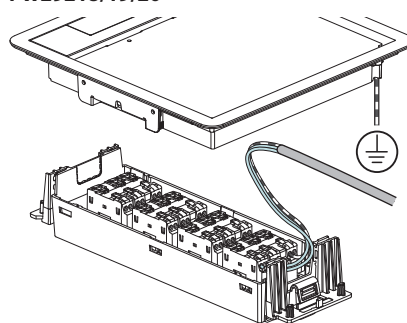

6


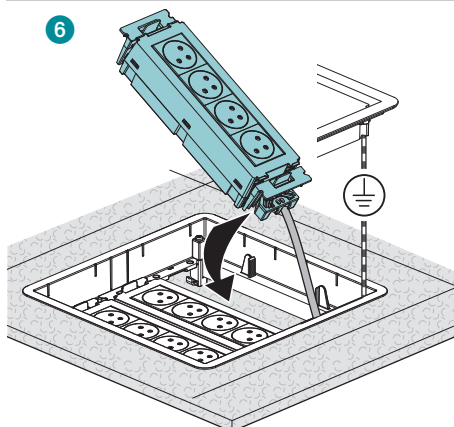


7





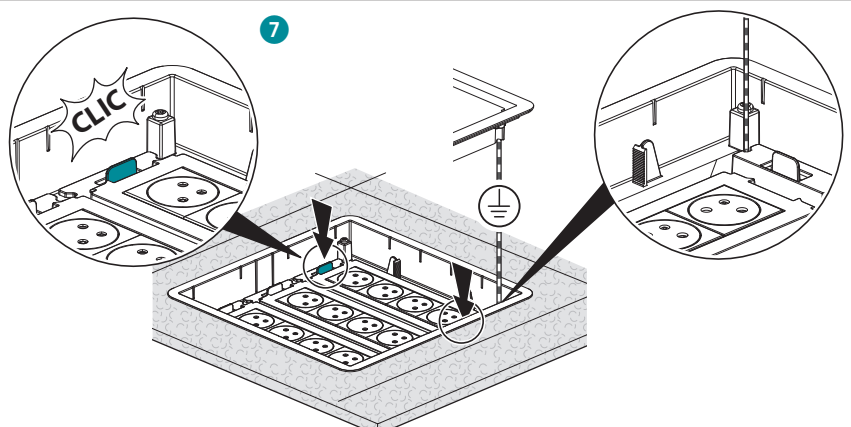








PW29203/04/05
PW29221/22/23

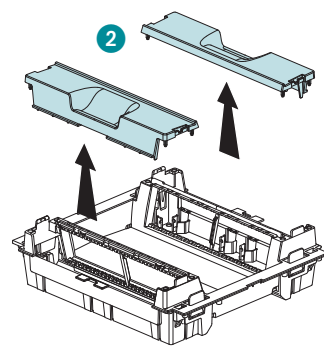
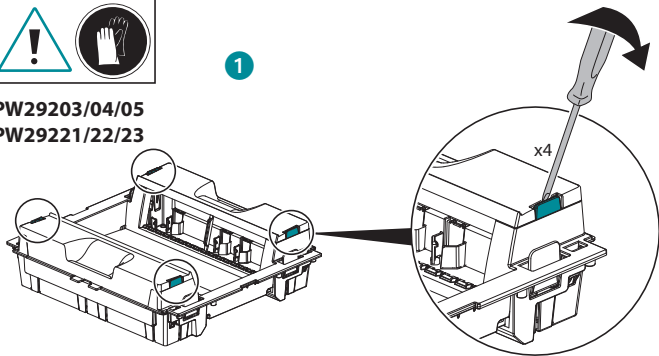


PW29221/22/23

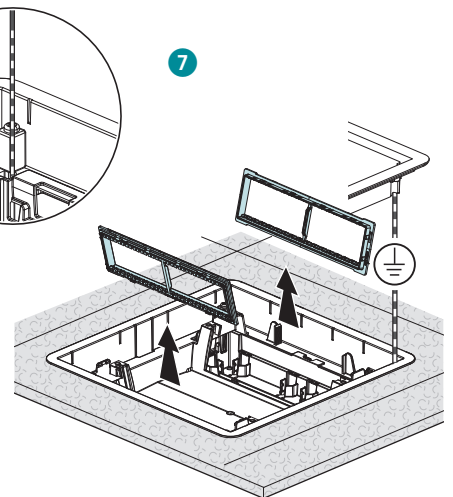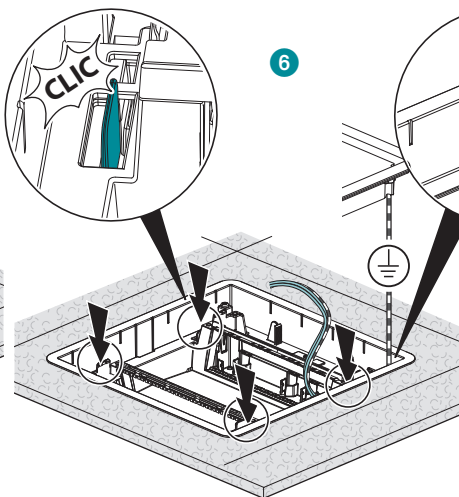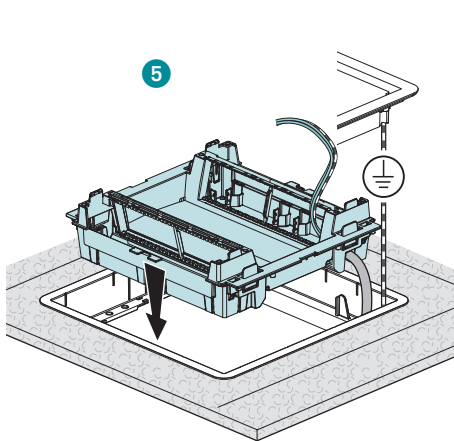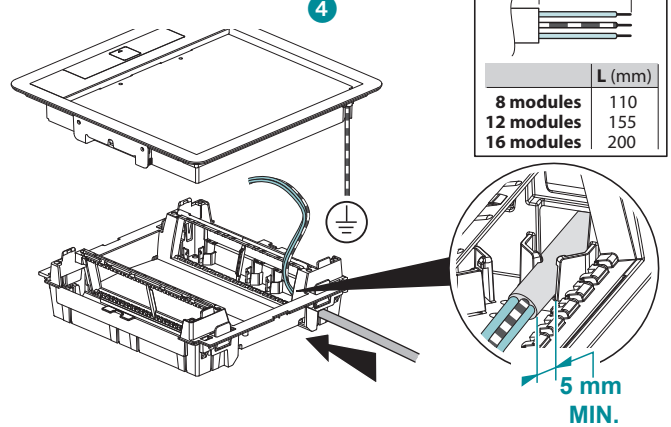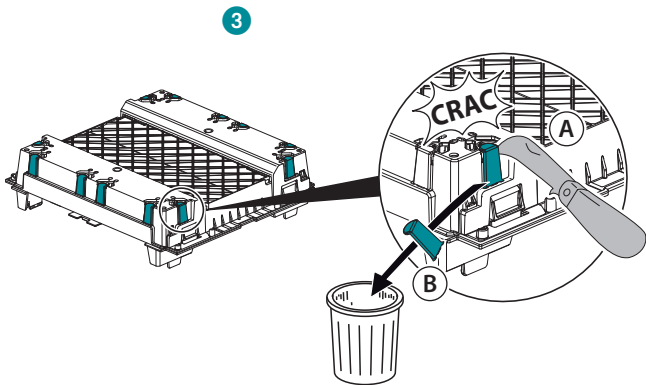

8

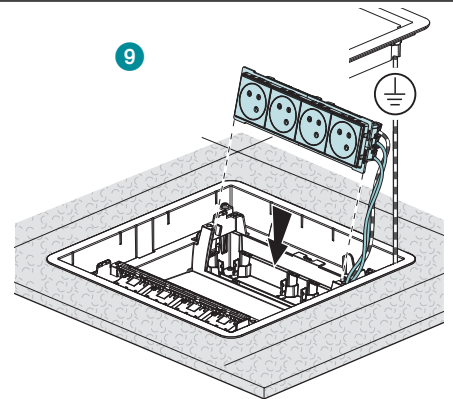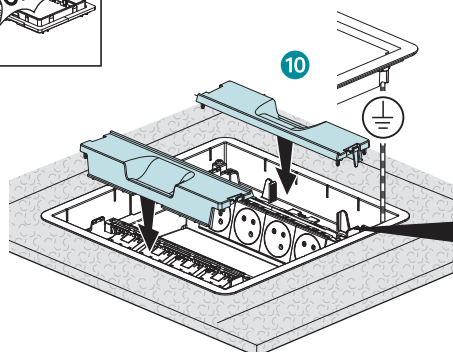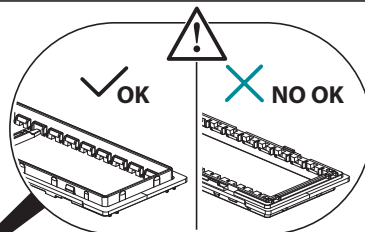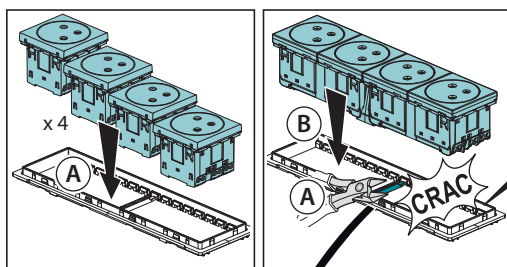

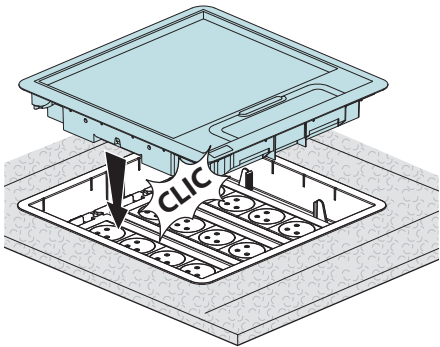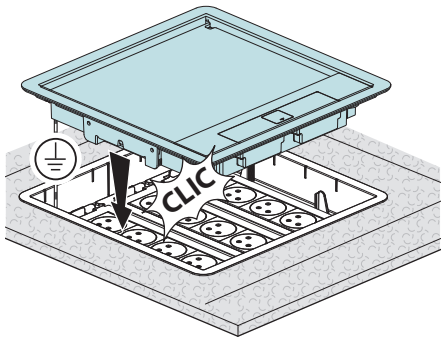

	A (mm)	B (mm)
PW29218/21/24	248	116
PW29219/22/25	248	154
PW29220/23/26	248	199

	A (mm)	B (mm)
PW29200/03/06	244	116
PW29201/04/07	244	154
PW29202/05/08	244	199

