

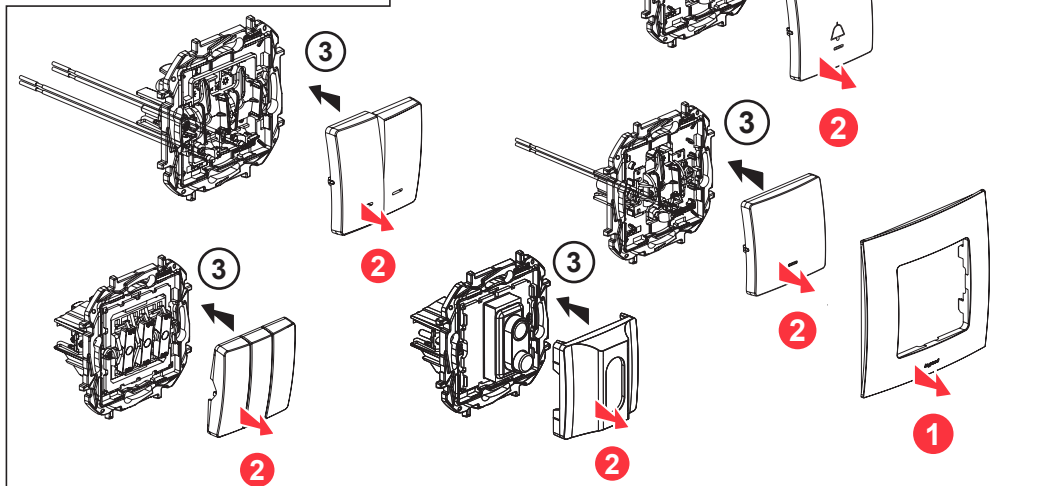
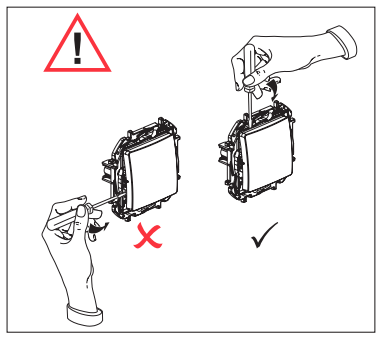


NP2010BK/MG/WH, NP2020BK/MG/WH, NP2110BK/MG, NP2111BK/MG/WH, NP2113BK/MG/WH,
NP2117BK/MG/WH, NP2130BK/MG/WH, NP2210BK/MG, NP2211BK/MG/WH, NP2220BK/MG/WH,
NP2310BK/MG, NP2311BK/MG/WH, NP2315BK/MG/WH, NP2316BK/MG/WH, NP2317BK/MG/WH,
NP2318BK/MG/WH, NP2319WH, NP2326BK/MG, NP7310BK/MG/WH

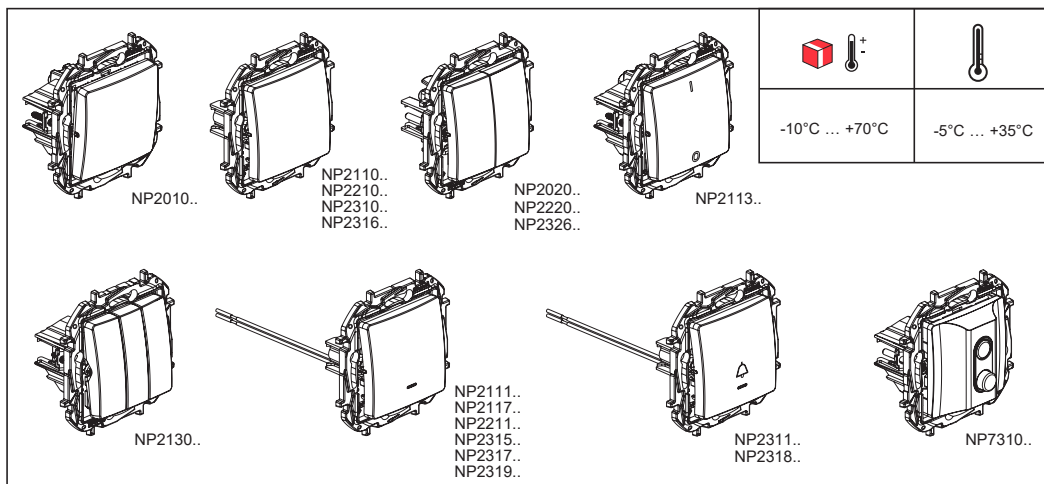


NP2010..

100 W max.		10 AX - 250 V~
		 $\leq 2,5 \text{ mm}^2$
		 10 mm

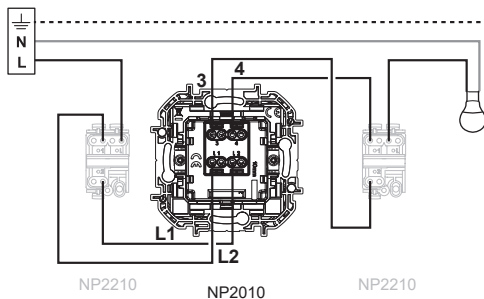


NP2020..

100 W max.		10 AX - 250 V~
		 $\leq 2,5 \text{ mm}^2$
		 9 mm

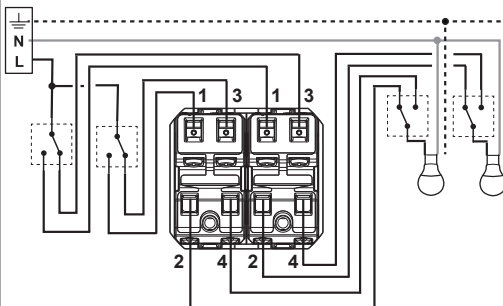


NP2110..

100 W max.		10 AX - 250 V~
		 $\leq 2,5 \text{ mm}^2$
		 13 mm

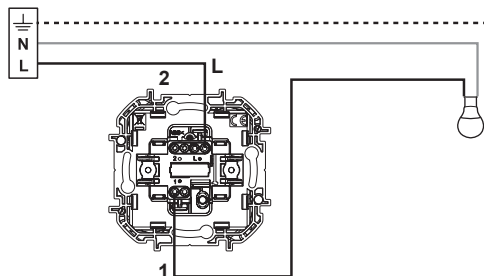


NP2111..

100 W max.		10 AX - 250 V~
		 $\leq 2,5 \text{ mm}^2$
		 13 mm

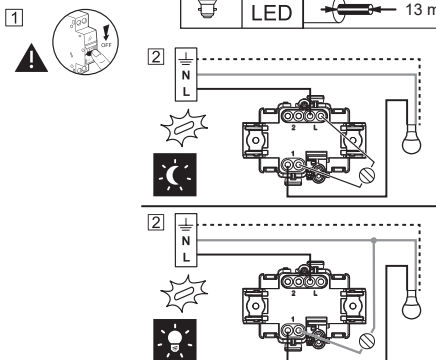


NP2113..

100 W max.		10 AX - 250 V~
		 $\leq 2,5 \text{ mm}^2$
		 10 mm

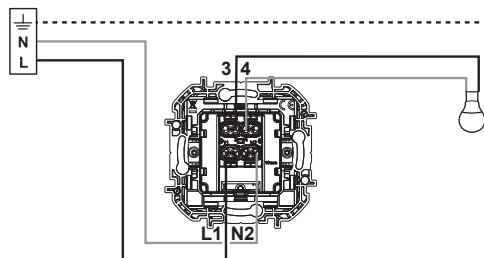


NP2117..

100 W max.		10 AX - 250 V~
		 $\leq 2,5 \text{ mm}^2$
		 13 mm

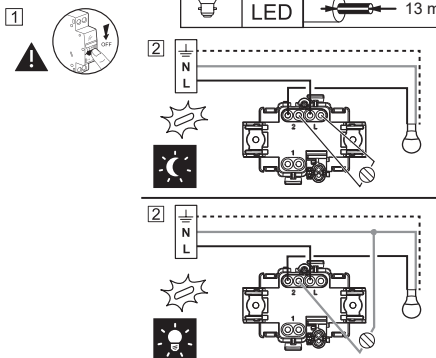


NP2130..

250 W max.   LED	20 AX - 250 V~  $\leq 4 \text{ mm}^2$  10 mm
---	---

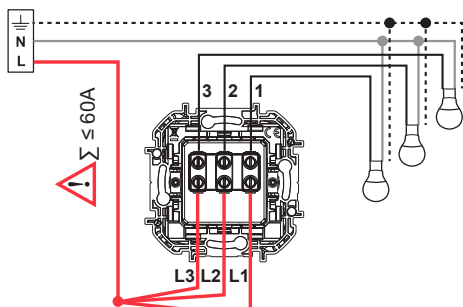


NP2210..

100 W max.   LED	10 AX - 250 V~  $\leq 2,5 \text{ mm}^2$  13 mm
---	---

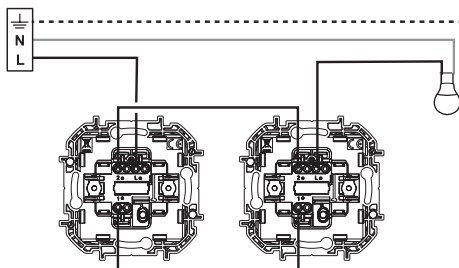


NP2211..

100 W max.   LED	10 AX - 250 V~  $\leq 2,5 \text{ mm}^2$  13 mm
---	---

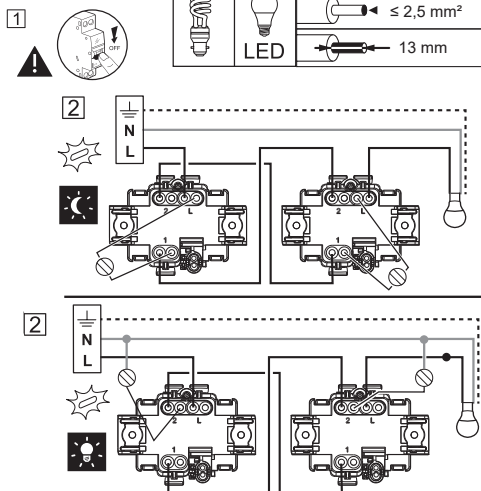


NP2220..


100 W max.   LED	10 AX - 250 V~  $\leq 2,5 \text{ mm}^2$  13 mm
---	---

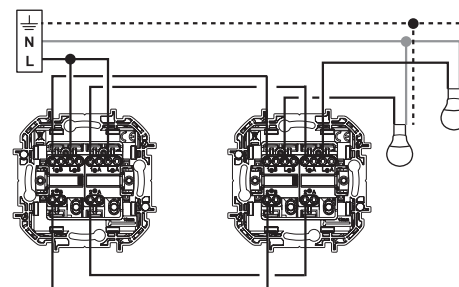


NP2310..

6 A - 250 V~  $\leq 2,5 \text{ mm}^2$  13 mm

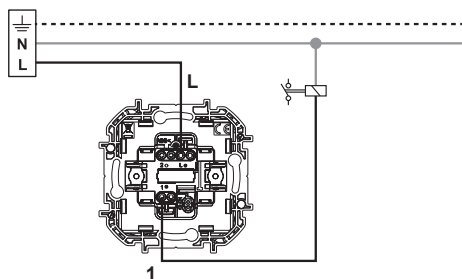NP2311..
NP2315..

 6 A - 250 V~  $\leq 2,5 \text{ mm}^2$  13 mm	 
---	---

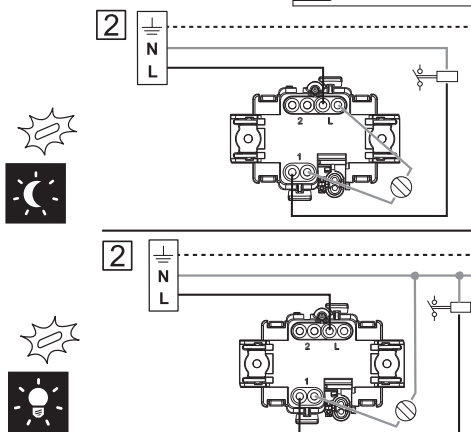


NP2316..

6 A - 250 V~

≤ 2,5 mm²

13 mm

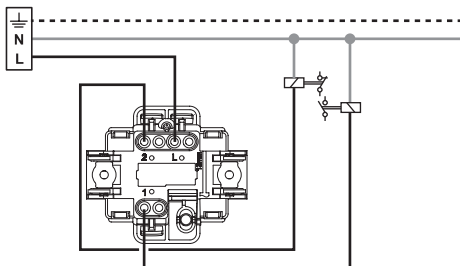NP2318..
NP2319..

1



6 A - 250 V~


≤ 2,5 mm²

13 mm

2

N


L

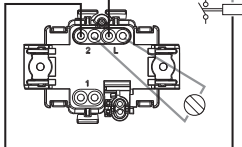

2

N

L

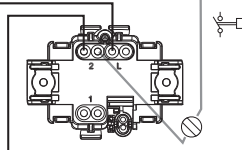

NP2317..

6 A - 250 V~

≤ 2,5 mm²

13 mm


1



2

N


L

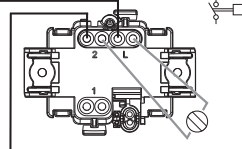

2

N

L

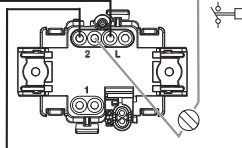


NP2326..

6 A - 250 V~

≤ 2,5 mm²

13 mm

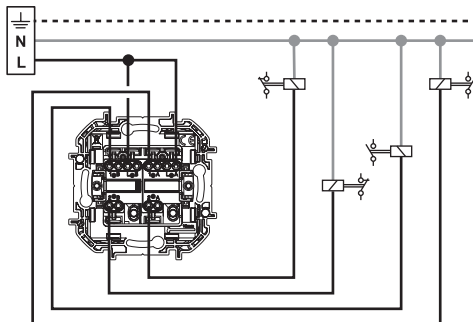

NP7310..

240 W max.

20 A - 250 V~



LED

≤ 4 mm²

10 mm

