


This product is a connected accessory which **requires** you to buy and install the Arteor with Netatmo connected starter pack first.

Pack contents

AC52104MW/MB/MT AA52104MW/MB/MT

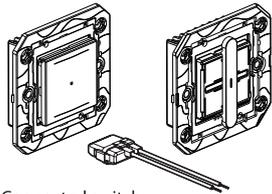

Connected switch (with dimmer option)+ bleeder

0 401 49 Bleeder 		110-240V~
		50/60 Hz
		0.4 W
		+5° C → +35° C

Characteristics

In default operating mode (on/off), this switch works with the following bulbs:

 +35° C +5° C	 8 mm		Dimmable 				
240 VAC	Max.	300 W	(*)60 VA	60 VA	300 VA	300 VA	
	Min.	7 W	5 VA	9 VA	10 VA	35 VA	
110 VAC	Max.	150 W	(**)30 VA	30 VA	150 VA	150 VA	
	Min.	7 W	5 VA	9 VA	10 VA	35 VA	

(*) Or 10 lamps max. For comfortable lighting, we recommend using bulbs of the same type and brand.

(**) Use only with transformers designed to function with electronic switches. Take account of transformer losses when calculating power. Transformers must be loaded at more than 60% of their power.


With the dimmer option operating mode (which can be activated with the App), this switch only works with variable intensity bulbs (which can be identified by the logo on the packaging).



LE15045AA


Before you start: wiring precautions

If you plan to install two-way light switches, read the following precautions:
 To control a light **with two or more switches**, only use the products:

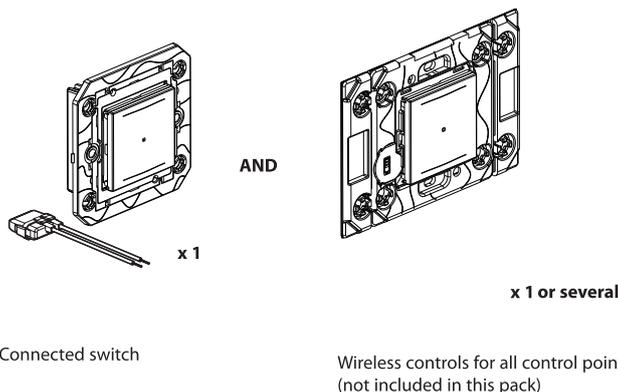

Do not use: two connected switches to control the same lighting point.

Tip if replacing a two-way switch:
 old flush-mounted switch replaced by the wireless control.

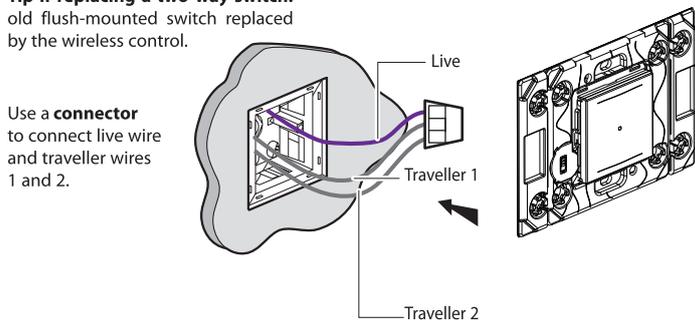


1 Necessary safety precautions

1 **OFF**
 Switch OFF the power at the main circuit breaker

2 **Make sure that the power is OFF before continuing with the installation.**


2 Install the connected switch

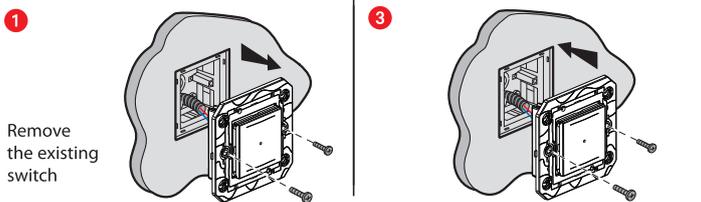

2 Wire the connected switch

To ensure that your connected switch (with dimmer option) works correctly, you must wire the bleeder provided as close to the load as possible and put a bulb in before turning the power on.

- N (neutral) = blue
- L (live) = any except blue and green/yellow
- \perp (earth) = green/yellow

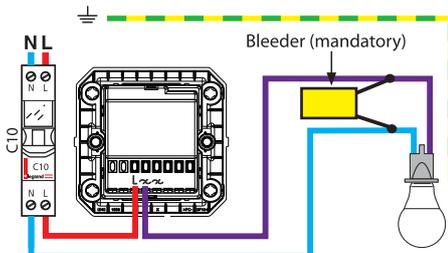

The connected switch (with dimmer option) works with standard bulbs or dimmable bulbs including LEDs over 5 W. Using dimmable LEDs is **strongly recommended** for optimal installation results.

If you have wired your bleeder but you are using non-dimmable LED bulbs, it is possible that your bulbs will not go out fully or will flicker. If this is the case, refer to the table of recommended bulbs on the legrand.com website.

3 To add a connected product to your connected installation, you should follow the instructions:

- in the **Legrand Home + Control application** (Settings/Add a new product section)
- or consult the user manual on **legrand.com**



www.legrand.com/ecatalogue/en

LEGRAND - Pro and Consumer Service - BP 30076
 87002 LIMOGES CEDEX FRANCE • www.legrand.com

Safety instructions

This product should be installed in compliance with installation rules, preferably by a qualified electrician. Incorrect installation and/or incorrect use can lead to risk of electric shock or fire. Before carrying out the installation, read the instructions and take account of the product's specific mounting location. Do not open up, dismantle, alter or modify the device except where specifically required to do so by the instructions. All Legrand products must be opened and repaired exclusively by personnel trained and approved by Legrand. Any unauthorised opening or repair completely cancels all liabilities and the rights to replacement and guarantees. Use only Legrand brand accessories.

SIMPLIFIED EU DECLARATION OF CONFORMITY

The undersigned,
Legrand

declares that the radio-electric equipment referred to in these instructions complies with directive 2014/53/EU. The full text of the EU declaration of conformity is available on the following website:

www.legrand.com/ecatalogue

