



8 640 03B / 07B / 08B / 11B / 12B / 16B / 28B / 29B / 30B / 31B / 32B
8 641 13B

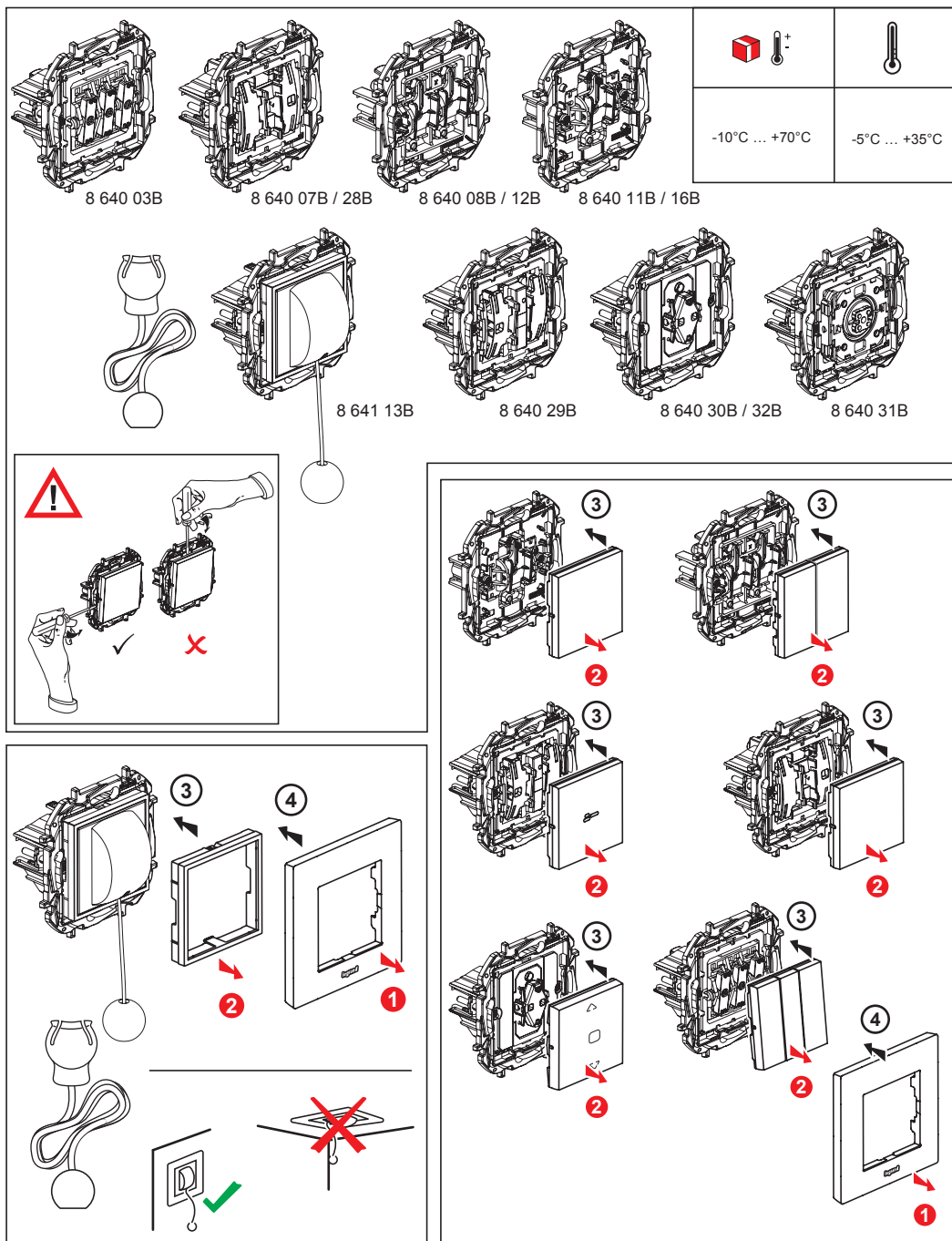


8 640 03B

250 W max.	20 AX - 250 V~
	
	 $\leq 4 \text{ mm}^2$
	 10 mm

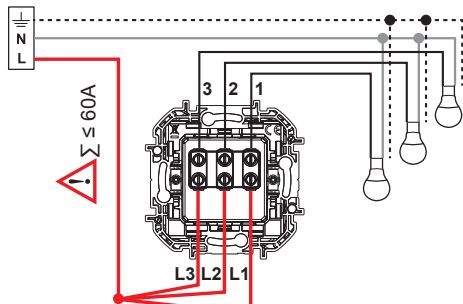

8 640 07B

100 W max.	10 AX - 250 V~
	
	 $\leq 2,5 \text{ mm}^2$
	 13 mm

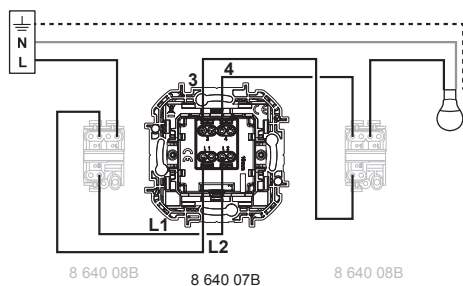


8 640 08B

8 640 07B

8 640 08B


8 640 08B

100 W max.	10 AX - 250 V~
	
	 $\leq 2,5 \text{ mm}^2$
	 13 mm

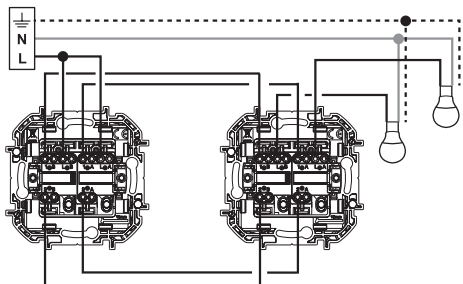


8 640 11B

6 A - 250 V~
 $\leq 2,5 \text{ mm}^2$
 13 mm

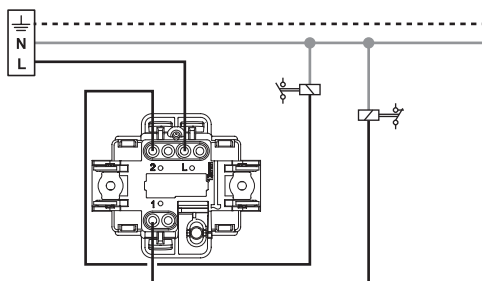


8 640 12B

6 A - 250 V~
 $\leq 2,5 \text{ mm}^2$
 13 mm

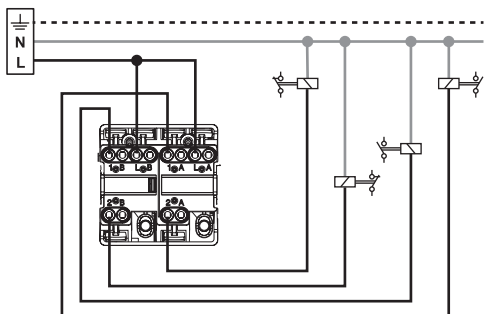


8 640 16

200 W max.	16 AX - 250 V~
	
	 $\leq 2,5 \text{ mm}^2$
	 13 mm

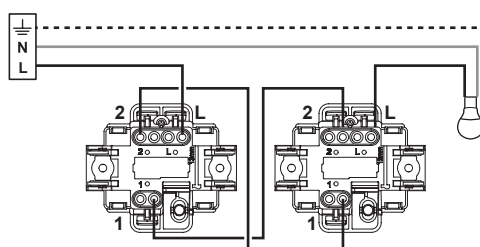


8 640 28B

	100 W max.	10 AX - 250 V~
		 $\leq 2,5 \text{ mm}^2$
		 13 mm
	LED	

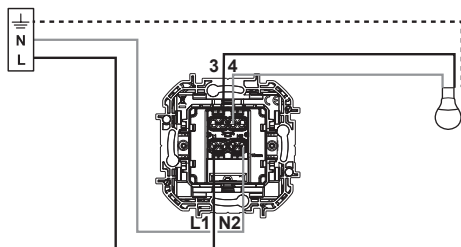


8 640 29B

	100 W max.	10 AX - 250 V~
		 $\leq 2,5 \text{ mm}^2$
		 13 mm
	LED	

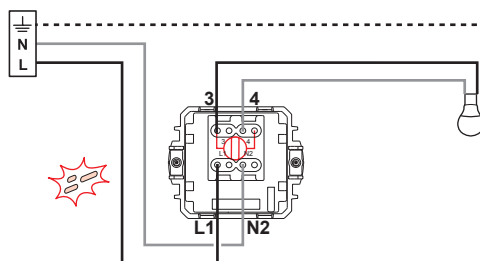


8 640 30B

	6 A - 250 V~
	$\leq 2,5 \text{ mm}^2$
	8 mm

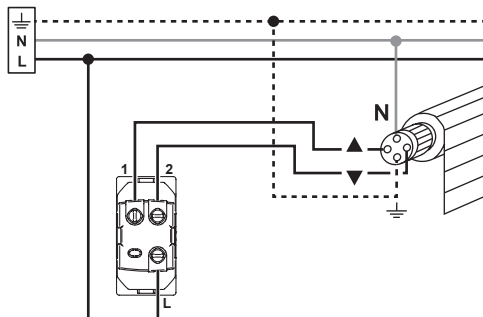


8 640 31B

	100 W max.	6 AX - 250 V~
		 $\leq 2,5 \text{ mm}^2$
		 13 mm
	LED	

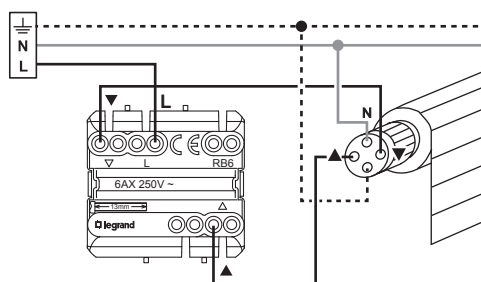

8 640 32B

	100 W max.	10 AX - 250 V~
		 $\leq 2,5 \text{ mm}^2$
		 8 mm
	LED	

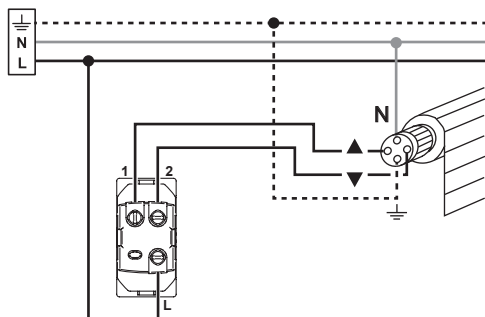

8 641 13B

	6 A - 250 V~ m
	$\leq 2,5 \text{ mm}^2$
	12 mm

