


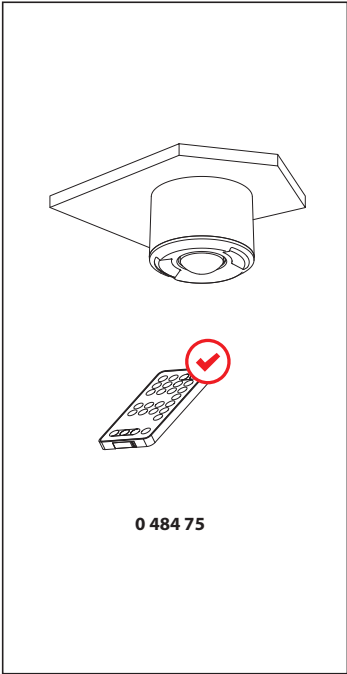
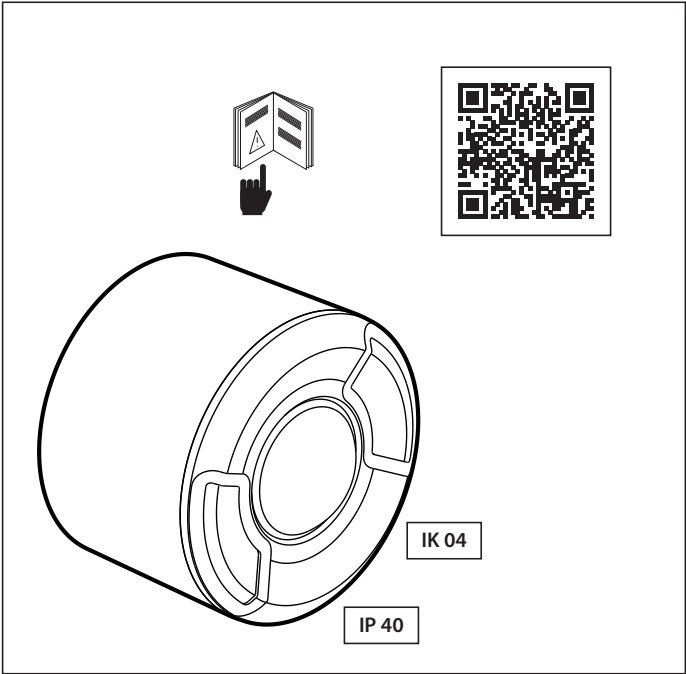
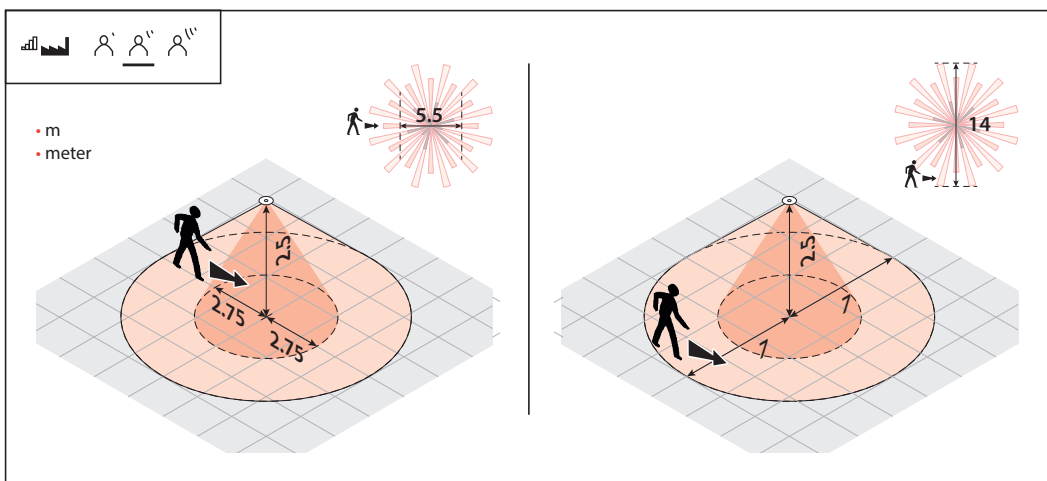
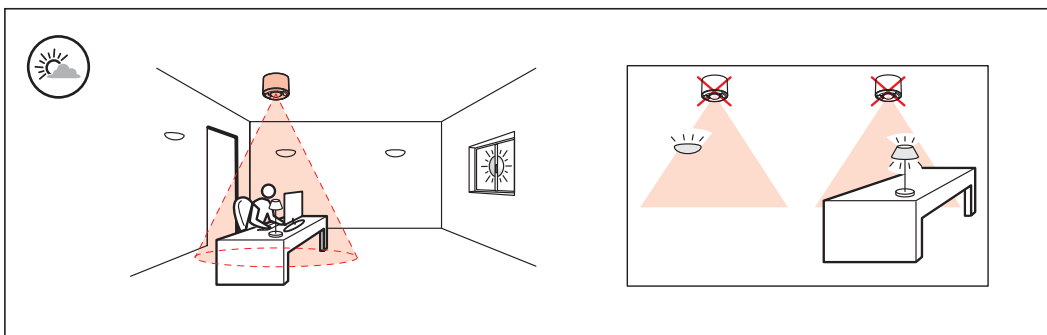
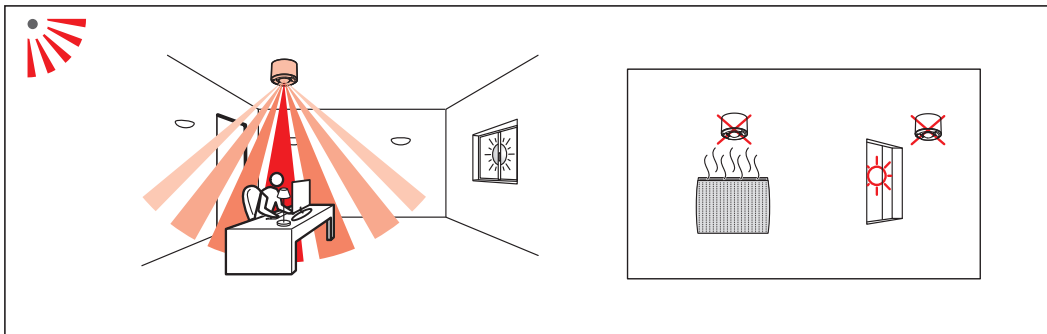


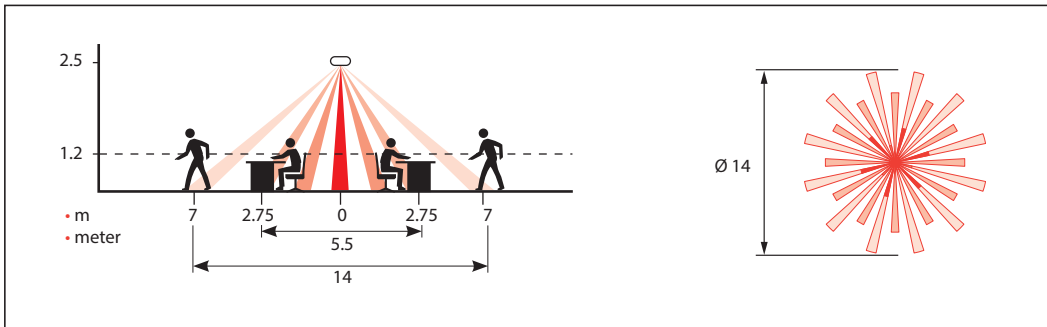

	• 100 - 240 V~ • 100 - 240 Volt~	 • PIR (Passive Infra Red) • IV • IR • PIR (인체감지)			
	50 / 60 Hz				
	2 x 1.5mm ² 1 x 2.5mm ²			Garantie Guaranted	Maximun
	7 mm			 16 V  56 mA	 16 V  75 mA
	-5°C / 30°C			10s	
					
	2000 lux			• Ø 14 m • Ø 14 meter	

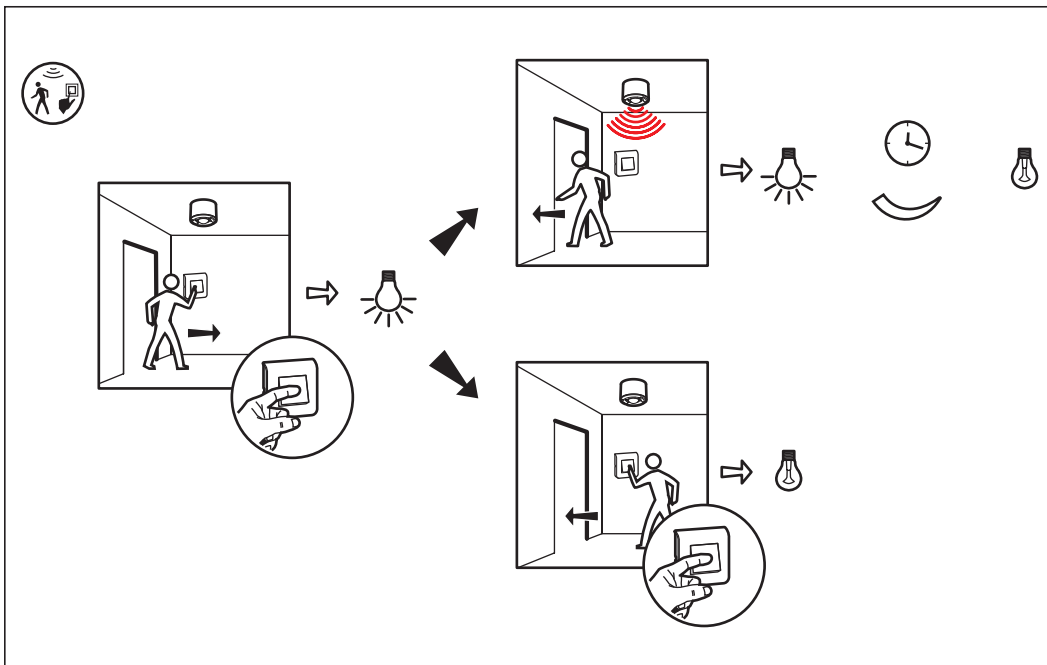

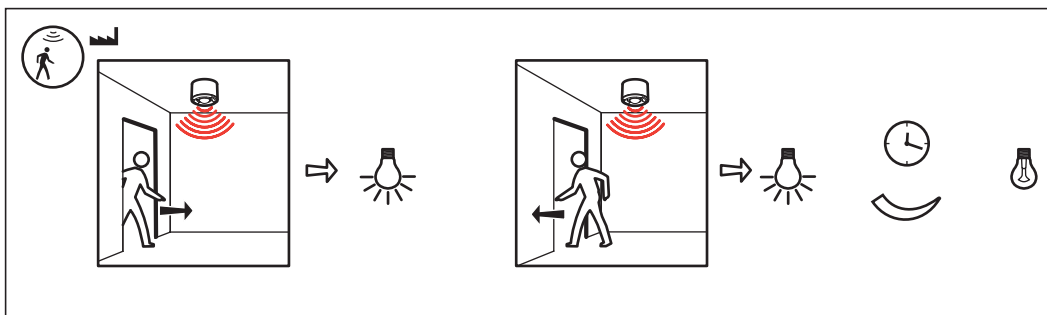


1

2

3

lux	
5	300
50	500
150	1 k
200	2 k

Time	
10''	10'
1'	15'
2'	30'
5'	45'

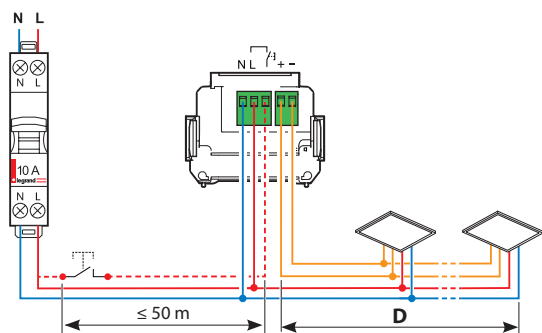

Bus DALI / DALI Bus

D	
≤ 100 m	0.5 mm ²
≤ 150 m	0.75 mm ²
≤ 300 m	1.5 mm ²

