 






IP 55

 
 
IK 04













0 484 75

 • 100 - 240 V~ • 100 - 240 Volt~	 -5°C / 30°C	 • PIR (Passive Infra Red) • IV • IR • PIR (인체감지)
 50 / 60 Hz	 2000 LUX	   
 2 x 1.5mm² / 1 x 2.5mm²	 10s	 • Ø 14 m • Ø 14 meter
 7 mm		

													
LED													
240 V~	350 VA	3 A	2000 W	8.5 A	1000 VA	4.3 A	10x(2x36 W)	4.3 A	I ≤ 2A	500 VA	2.1 A	1000 VA	4.3 A
100 V~	175 VA		1000 W		500 VA		5x(2x36 W)			250 VA		500 VA	

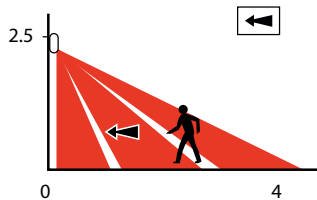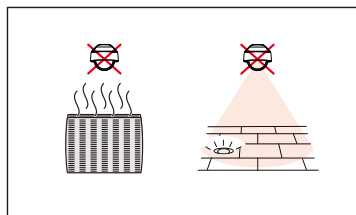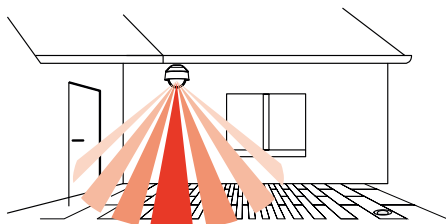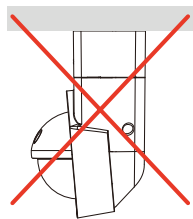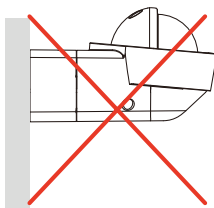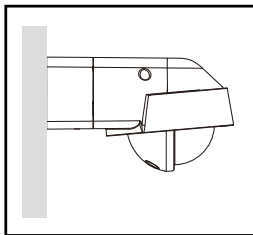

• m
• meter

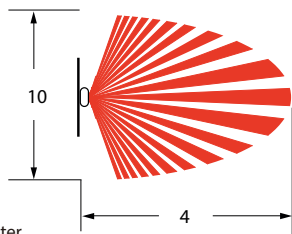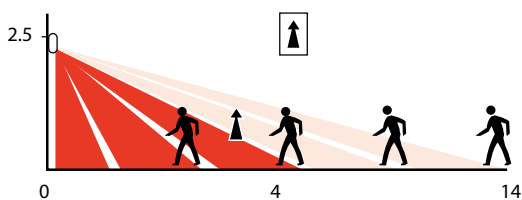

• m
• meter

