


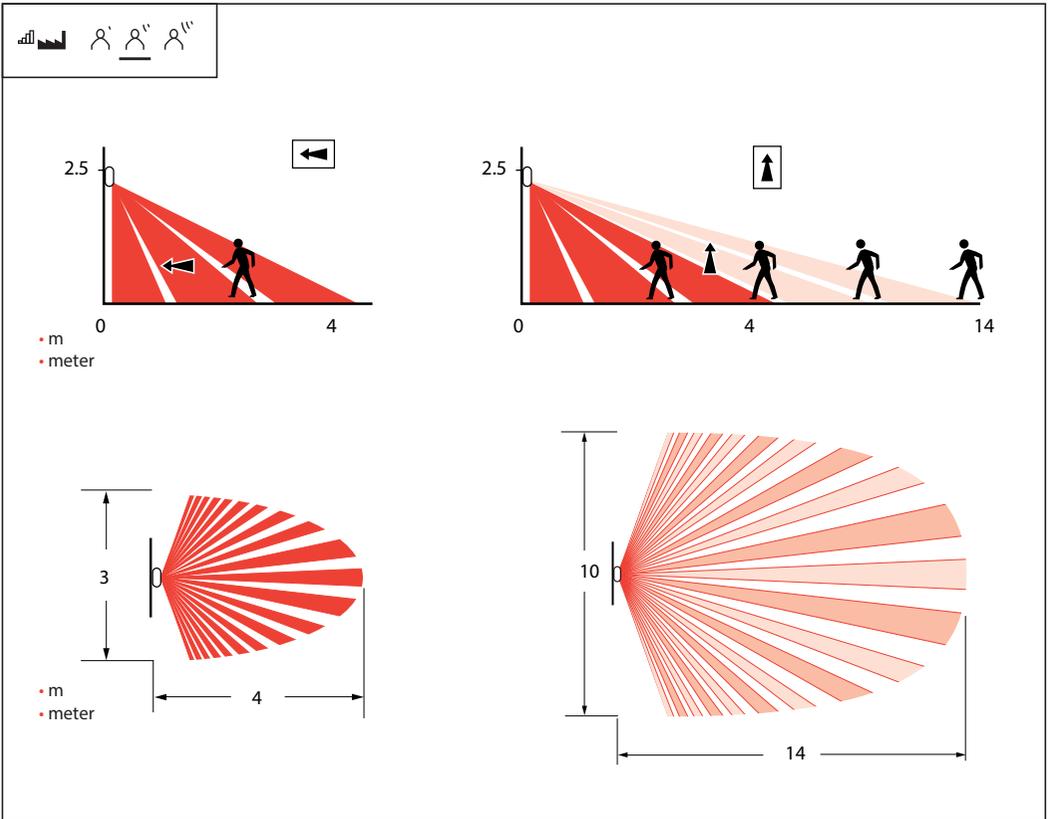
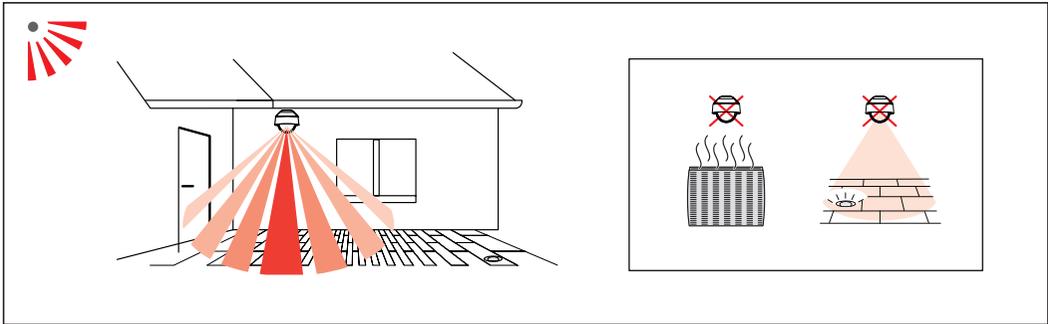
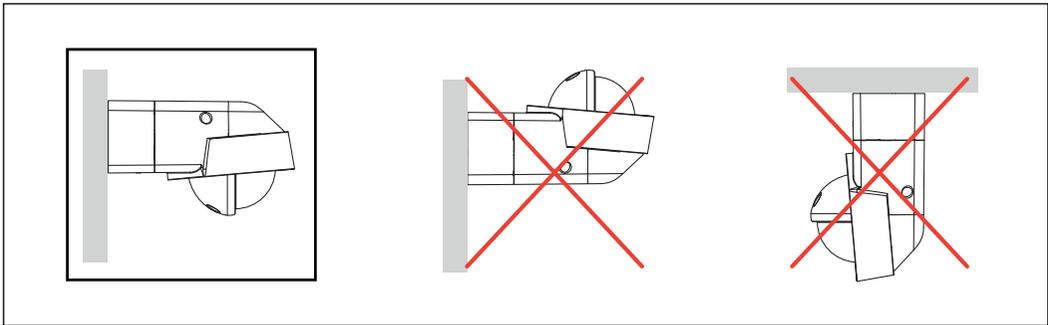
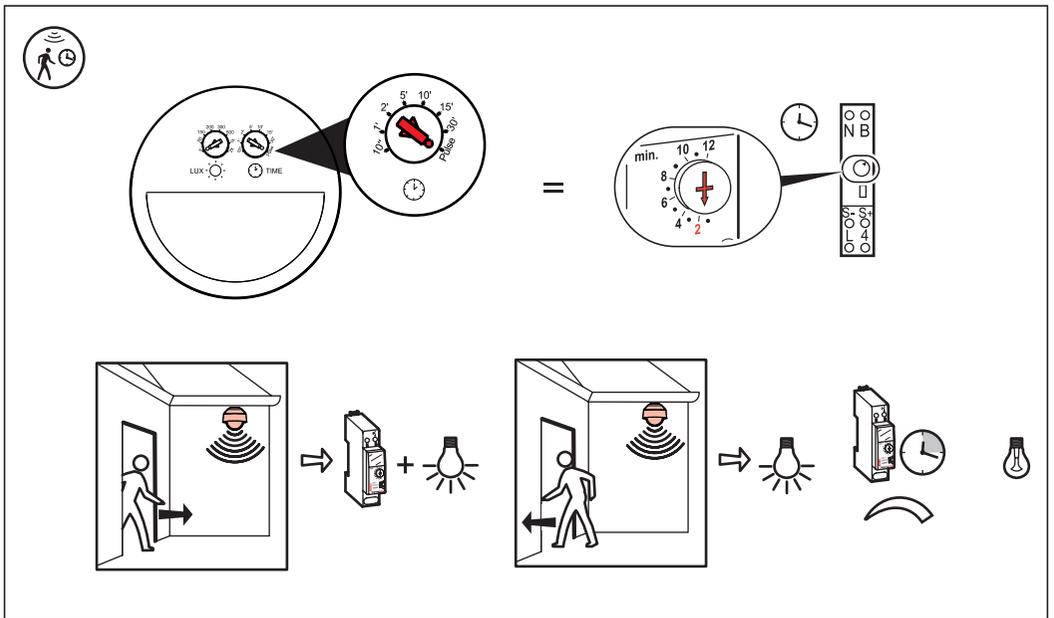


	<ul style="list-style-type: none"> • 100 - 240 V~ • 100 - 240 Volt~ 		-5°C / 30°C		<ul style="list-style-type: none"> • PIR (Passive Infra Red) • IV • IR • PIR (인체감지)
	50 / 60 Hz		2000 LUX		<ul style="list-style-type: none"> • 14 m • 14 meter
	2 x 1.5mm ² / 1 x 2.5mm ²		10s		<ul style="list-style-type: none"> • 14 m • 14 meter
	7 mm				


LED										
240 V~	350 VA	3 A	2000 W	1000 VA	4.3 A	10x(2x36 W)	4.3 A	500 VA	1000 VA	4.3 A
100 V~	175 VA		1000 W	500 VA		5x(2x36 W)		250 VA	500 VA	
			8.5 A					2.1 A		

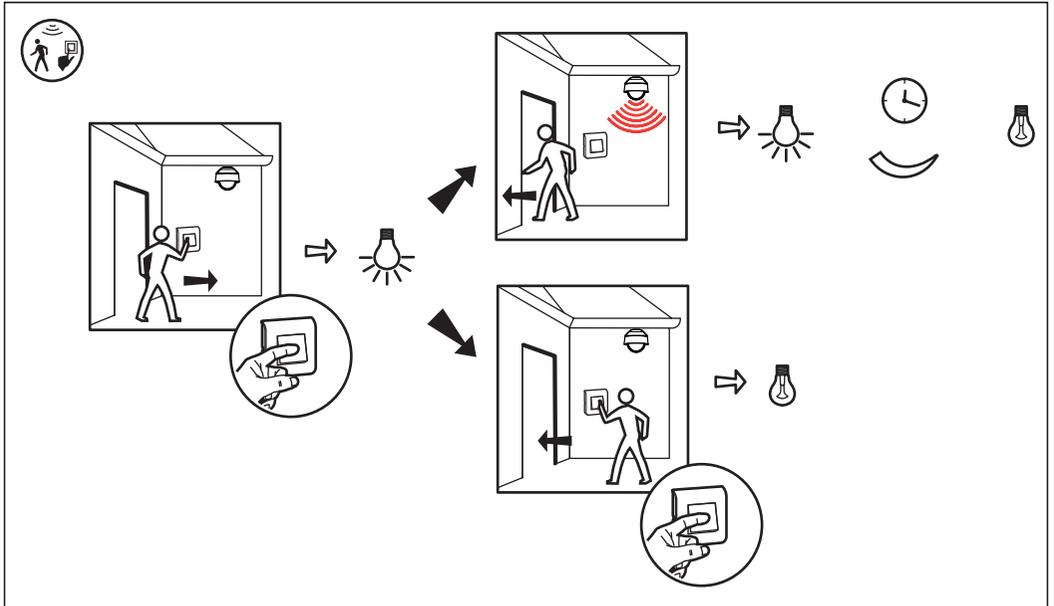

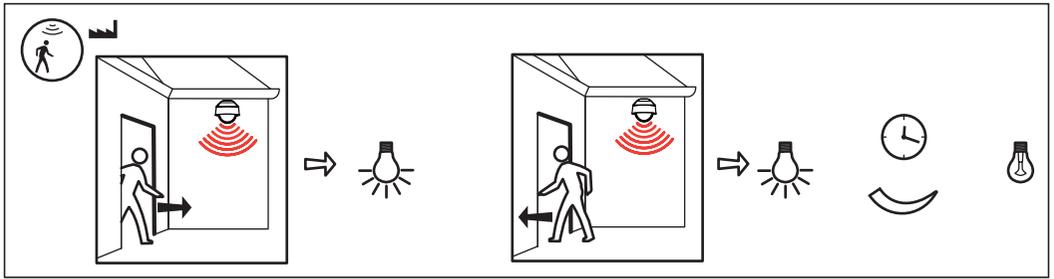

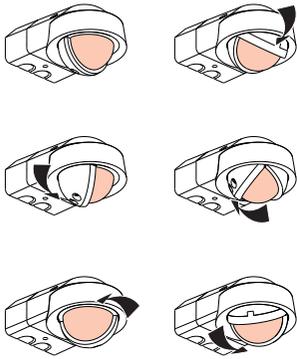

☀ lux
5
50
150
200
300
500
1 k
2 k

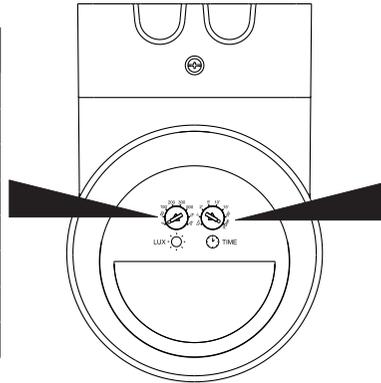

🕒
10"
1'
2'
5'
10'
15'
30'
Pulse

