


IK 04











IP 20




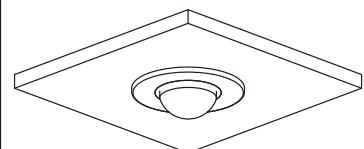


0 484 75

	<ul style="list-style-type: none"> • 100 - 240 V~ • 100 - 240 Volt~
	50 / 60 Hz
	2 x 1.5mm ² / 1 x 2.5mm ²
	8mm
	-5°C / 30°C
	2000 lux

	Garanti Guaranteed	Maximum
	<ul style="list-style-type: none"> —V— 16 V —A— 56 mA 	<ul style="list-style-type: none"> —V— 16 V —A— 75 mA
	<ul style="list-style-type: none"> • PIR (Passive Infra Red) • IV • IR • PIR (인체감지) 	
	10 s	
	2.5 m	<ul style="list-style-type: none"> • Ø 9 m • Ø 9 meter

 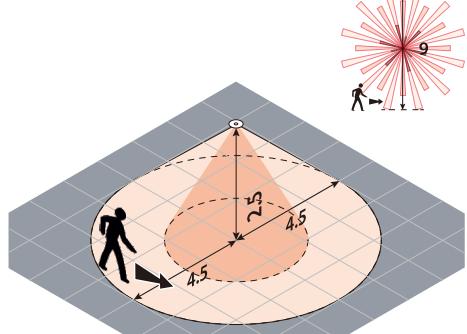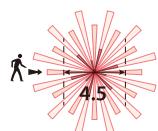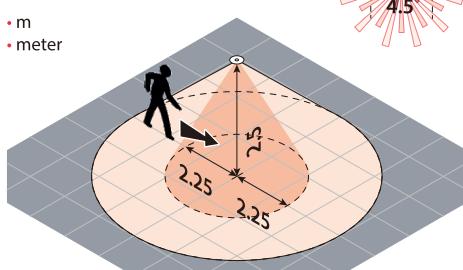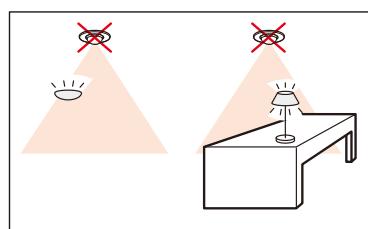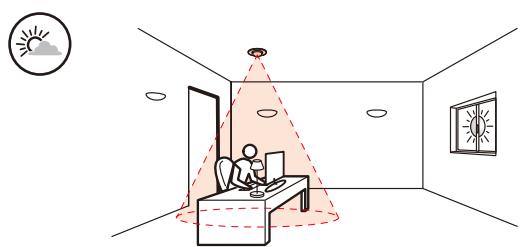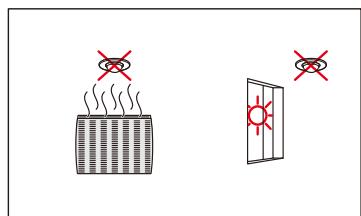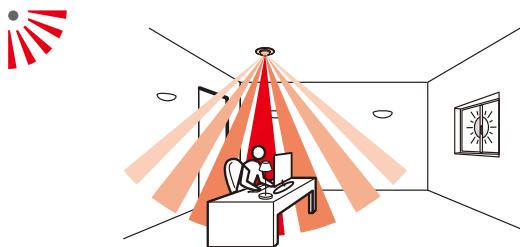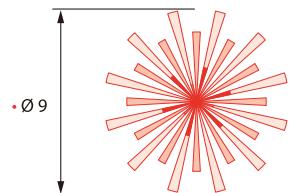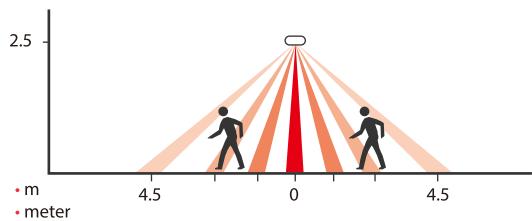

 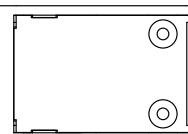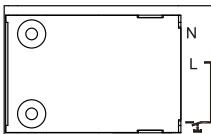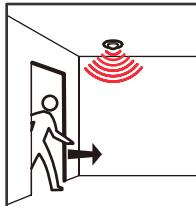


Time ⏱

10"	10'
1'	15'
2'	30'
5'	45'



lux

5	300
50	500
150	1 k
200	2 k

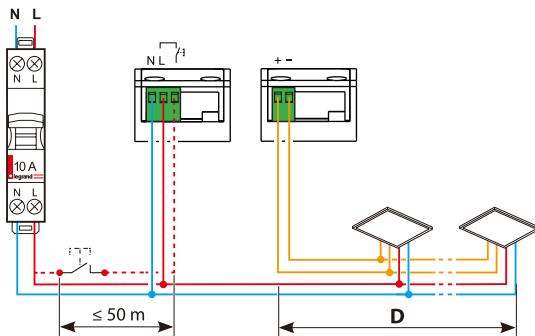

Bus DALI / DALI Bus


D	Wire cross-section
≤ 100 m	0.5 mm ²
≤ 150 m	0.75 mm ²
≤ 300 m	1.5 mm ²

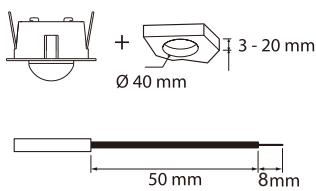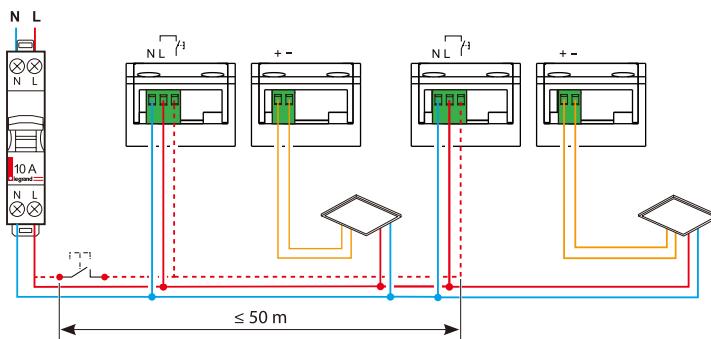

1



 
2




3



4

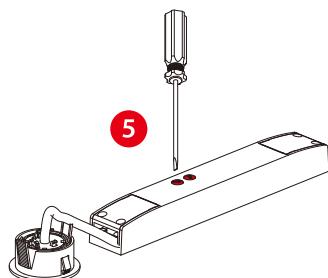

5

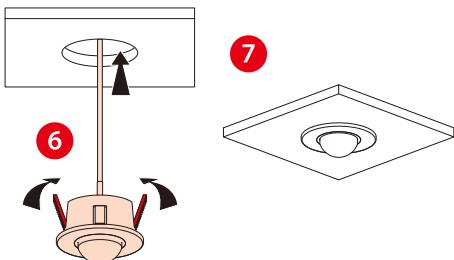

6

7