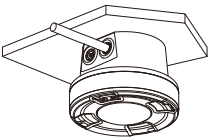


IP 55

IK 04



 
 
 






0 484 75

 • 100 - 240 V~ • 100 - 240 Volt~	 -5°C / 30°C	  • PIR (Passive Infra Red) • IV • IR • PIR (인체감지)
 50 / 60 Hz	 2000 LUX	 
 2 x 1.5mm² / 1 x 2.5mm²	 10s	 • Ø 20 m • Ø 20 meter
 7 mm		

						
						
240 V~ 350 VA 3 A	2000 W 8.5 A	1000 VA 4.3 A	10x(2x36 W) 4.3 A	I ≤ 2A 4.3 A	500 VA 2.1 A	1000 VA 4.3 A
100 V~ 175 VA	1000 W	500 VA	5x(2x36 W)		250 VA	500 VA

