



False ceiling mounted loudspeaker


5739 82

Description

20 W ceiling-mounted loudspeakers. Thanks to its small size (diameter 10 cm) and easy hooking (by springs) the loudspeaker can be installed with just a few operations.

Technical data

Type:	wide band
Power:	10 Wrms/20 W musical
Impedance:	8 Ω
Frequency range:	200 – 20 kHz
Sensitivity:	86 dB (1 W/1 m)
Feature:	loudspeaker to be installed on the ceiling
Weight:	400 g
Mounting hole diameter:	90 mm
External diameter:	100 mm
Depth:	57 mm

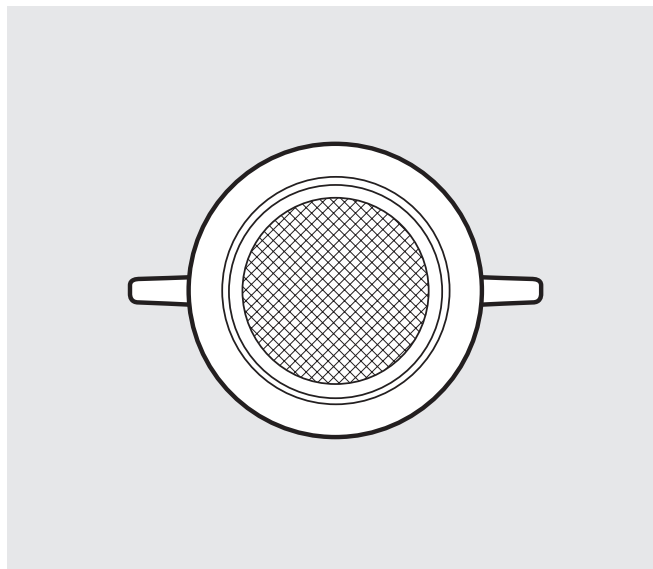

Dimensional data

