




775 954

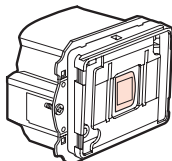


B 780 167

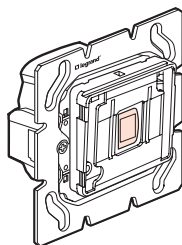


BM 780 117

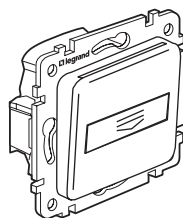

770 234
774 134 / 774 234

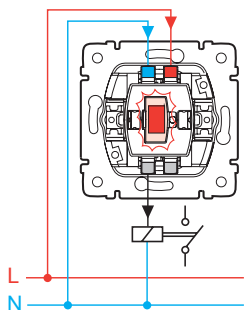


10 A 250 V ~

 

54 mm


ON

 HOTEL




775 890


1

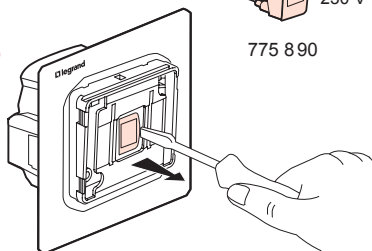


2

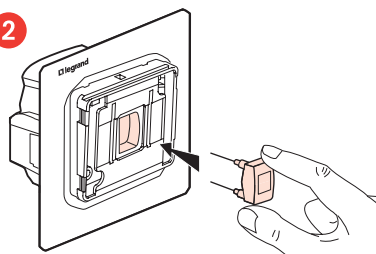


Valena™

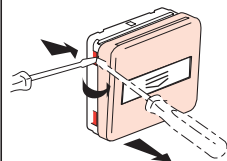


770 234 / 774 134 / 774 234

 

PRO 21™ / Solfà™

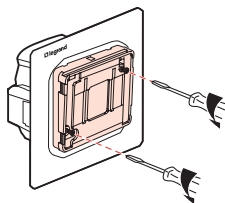

780 117 / 780 167 / 776 054 / 776 254

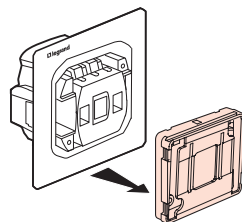

PRO 21™

775 954

+


777 054

771 254

771 354

771 454

771 554

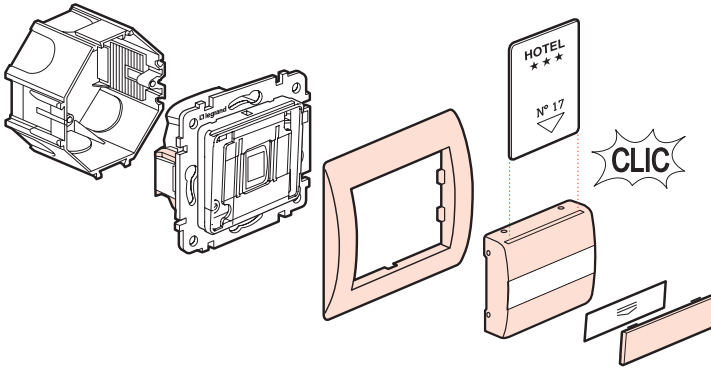

PRO 21™

775 954

+

776 054


776 254

Valena™

774 134

774 234

770 234

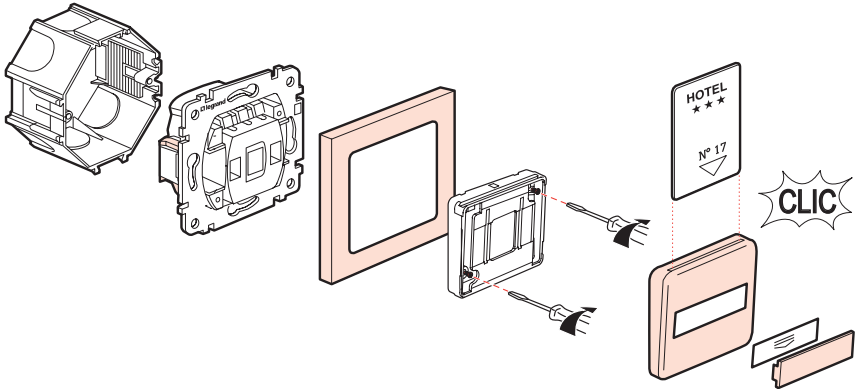

Solfà™

780 117

780 167

