


Zero U universal fixing kit

Cat. No(s): 0 321 03

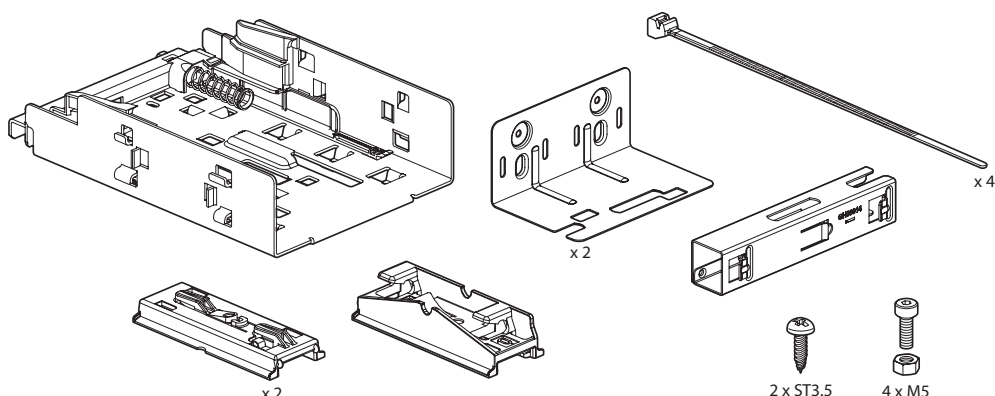

1. PRESENTATION

 
 
 
 
Zero U remote patch solution for universal mounting: 19" panel, subfloor, wire and sheet metal cable tray, cabinet structure, etc.
Compatible with all high-density fibre optic and copper cassettes in the LCS3 range.


The combination with a self-extracting cassette allows easy installation and maintenance.

Delivered with its specific accessories for fixing:






- on sheet metal or wire cable tray
- on cabinet uprights or cable trays
- on Minkels cabinet uprights
- on the floor or wall


2. KIT CONTENTS

	Fixing bracket (x2)		Metal screw (2 x ST3.5)
	Wire mesh rail interface		Screw + nut (4 x M5)
	Sheet metal rail interface (x2)		Cable tie (x4) (Cat. No. 0 320 58)
	Minkels cabinet interface		

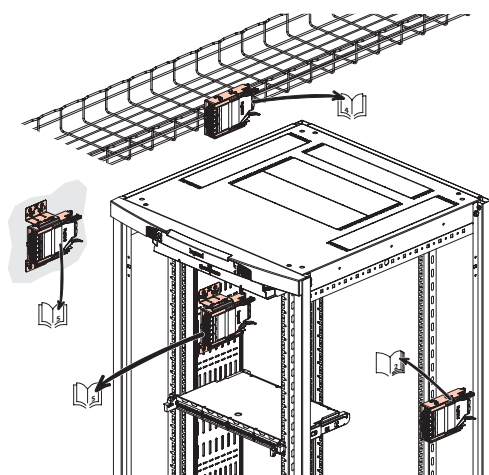


Minkels configuration

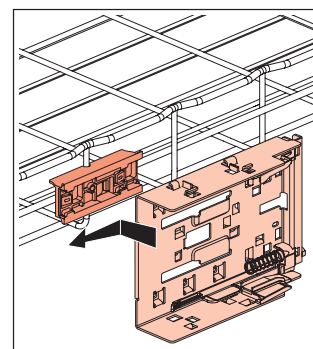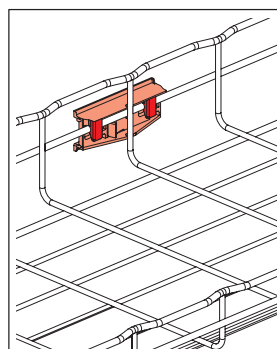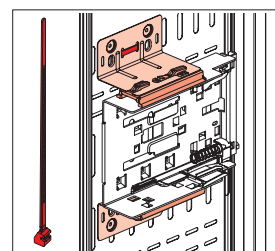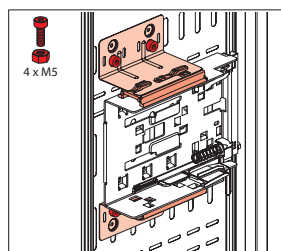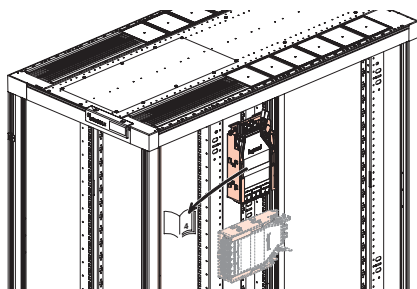


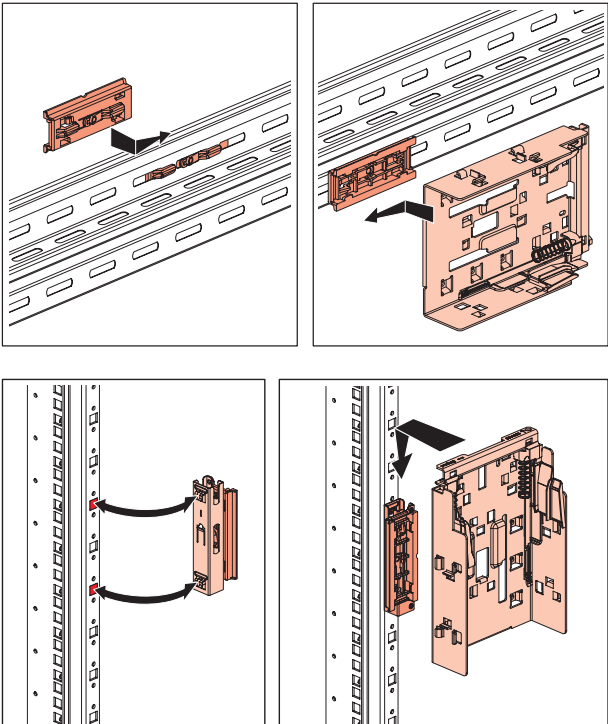


3. DIMENSIONS (mm)

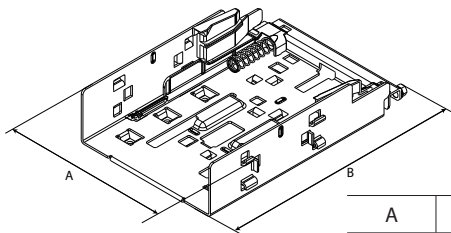



A	B	C
123	179	46

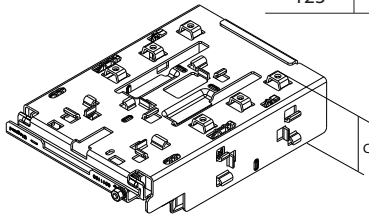

With sheet metal rail interface


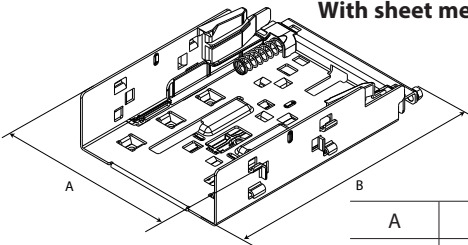


A	B	C
123	179	56

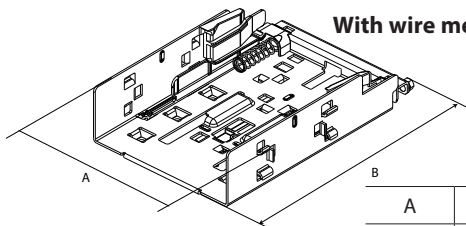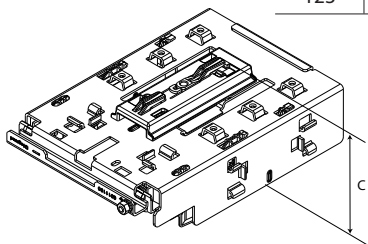


With wire mesh rail interface

A	B	C
123	179	62

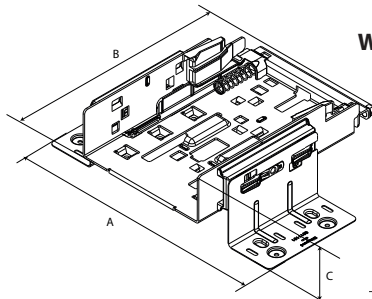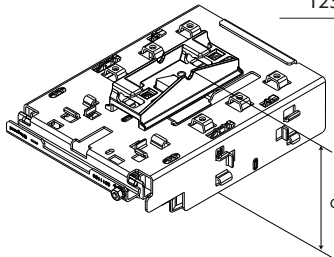

With fixing brackets

A	B	C
216	179	64

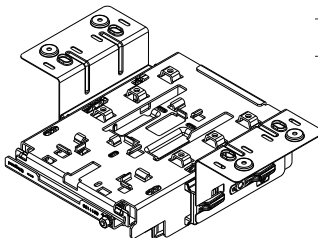

4. TECHNICAL CHARACTERISTICS

The Zero-U holder can accommodate splice, pre-connected or copper cassettes.

Maximum capacity:


- 24 LC connectors
 - 12 SC connectors
 - 12 high density RJ45 connectors
- Equipped with a grounding solution.

Material: Main support: pre-galvanized steel
Slides (left/right): ABS - Black (Ral 9017)
Accessories for wire/sheet metal rail: ABS grey
Brackets: steel

Zero U weight (with brackets/interface): 510 g
Operating and storage temperature: -20°C to +60°C

5. COMPATIBILITY

				Universal polarity					A/C polarity					HD cassette holder	Accessories
				OS2/UPC	OS2/APC	OM4 Aqua	OM4 Violet	OM5	OS2/UPC	OS2/APC	OM4 Aqua	OM4 Violet	OM5		
Base 12	Slim cassette	12F MTP-LC		260021	-	260022	260023	260024	On-demand	-	On-demand	On-demand	On-demand	032138 	032139 
		2x 12F MTP-SN		260025	-	260026	-	260027	On-demand	-	On-demand	-	On-demand		
		2x 12F MTP-MDC		On-demand	-	On-demand	-	On-demand	-	-	-	-	-		
	HD cassette	12F MTP-LC		260050	On-demand	260048	-	-	On-demand	On-demand	On-demand	-	-	260054 	-
		2x 12F MTP-LC		260051	On-demand	260049	-	-	On-demand	On-demand	On-demand	-	-		
		12F MTP-SC		260053	On-demand	260052 *Beige	-	-	On-demand	On-demand	On-demand *Beige	-	-		

 	Splice cassette	Blocks for splice cassette									Copper cassettes	Copper cassette connectors				
		SM Blue	SM APC Green	MM Aqua	MM Violet	MM Beige	MM Lime	UTP	FTP	STP						
Base 12	032141  PG 11 x 2	12 fibres	LC		032114	032116	032137	HVBL12	-	032258	033755 		Cat5e	033753	033754	-
			SC		032111	-	-	-	032121	-						
		6 fibres	LC		032113	-	032136	-	-	-	033795 		Cat6	033763	033764	033765
			SC		032110	032112	-	-	032120	-						
					SM Red cap		MM Black cap						Cat6A	033773	-	033775
			ST		032117		032127									