



Arteor Advance™ Preterminated HDMI socket

Cat. No(s): AC4411MB/MT/MW/CH/DB/RS
AC4412MB/MT/MW/CH/DB/RS

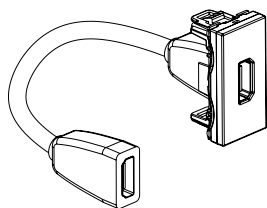

AC4411MB/MT/MW/CH/DB/RS

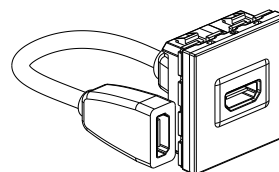

AC4412MB/MT/MW/CH/DB/RS

1. USE

HDMI sockets are used to transmit High Definition digital audio/video streams between a source (computer, DVD ou Blu-Ray player, etc) and a compatible receiver (TV, video projector, etc).



To ensure a high-quality result, the connection between the two devices should not exceed a certain distance (see audio/video characteristics table). For longer connections, it is necessary to provide a booster system in the installation. The connectors are type A and conform to the HDMI standard. Equipped with a 15 cm cord and 2 female connectors.

2. RANGE


Description	Cat. No.	Modules	Fixing method	Connection method
Preterminated HDMI socket Champagne cover plate	AC4411CH	1	Clips	Plug-in
Preterminated HDMI socket Dark Bronze cover plate	AC4411DB	1	Clips	Plug-in
Preterminated HDMI socket Matt Black cover plate	AC4411MB	1	Clips	Plug-in
Preterminated HDMI socket Matt Titanium cover plate	AC4411MT	1	Clips	Plug-in
Preterminated HDMI socket Matt White cover plate	AC4411MW	1	Clips	Plug-in
Preterminated HDMI socket Rose cover plate	AC4411RS	1	Clips	Plug-in
Preterminated HDMI socket Champagne cover plate	AC4412CH	2	Clips	Plug-in
Preterminated HDMI socket Dark Bronze cover plate	AC4412DB	2	Clips	Plug-in
Preterminated HDMI socket Matt Black cover plate	AC4412MB	2	Clips	Plug-in
Preterminated HDMI socket Matt Titanium cover plate	AC4412MT	2	Clips	Plug-in
Preterminated HDMI socket Matt White cover plate	AC4412MW	2	Clips	Plug-in
Preterminated HDMI socket Rose cover plate	AC4412RS	2	Clips	Plug-in

3. DIMENSIONS (mm)

AC4411MB/MT/MW/CH/DB/RS

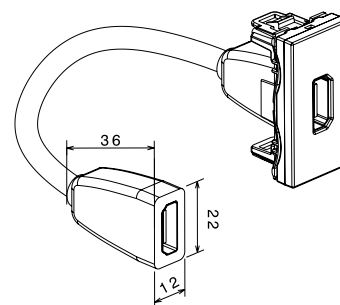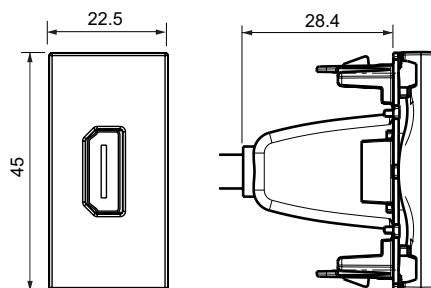

AC4412MB/MT/MW/CH/DB/RS

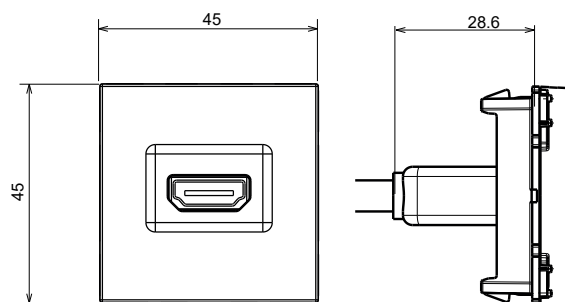


4. TECHNICAL CHARACTERISTICS

■ 4.1 Audio/Video characteristics

Values indicated for an installation set up in accordance with best practice and connected in compliance with existing standards. Any additional accessories and cords should comply with these same criteria.

HDMI version 1.4

Max. resolution (pixels) : 1080 p

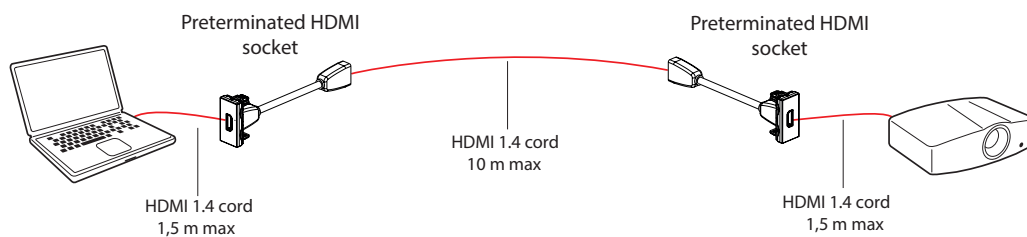


HDMI version 2.0

Max. resolution (pixels) : 2160p


Format 16/9 : 2160p, 60Hz, RGB

Format 21/9 : 3840 x 2160p, 60Hz, RGB

Configuration 1

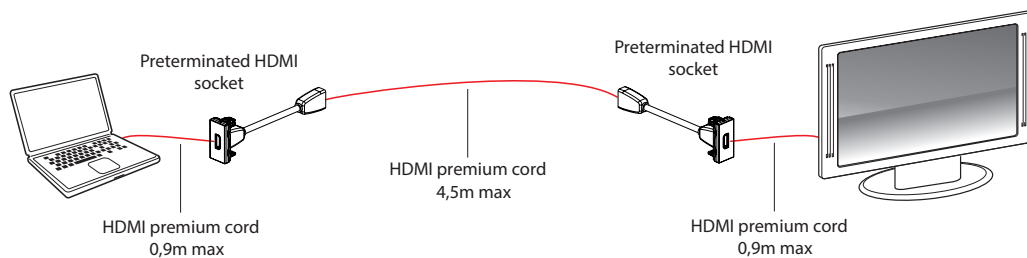

Configuration 2

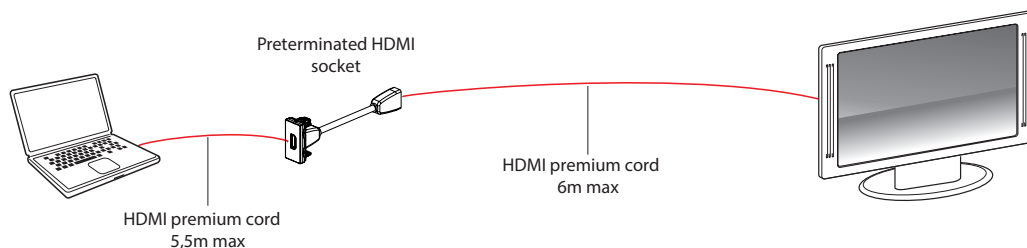

4. TECHNICAL CHARACTERISTICS *(continued)*

■ 4.2 Mechanical characteristics

Min. depth of box : 50 mm

Impact tests : IK 04

Penetration by solid/liquid matter : IP 40

■ 4.3 Material characteristics

Cover plate : ABS

Self-extinguishing : 650°C/30 s

■ 4.4 Climate characteristics

Storage temperature : - 10°C to + 70°C

Usage temperature : - 5°C to + 50°C

5. CARE

Clean the surface with a cloth.

Do not use acetone, tar-removing cleaning agents or trichloroethylene.

■ 5.1 Resistance to cleaning products

Resistant to the following products : - Hexane (EN 60669-1)

- Methylated spirit
- Soapy water
- Diluted ammonia
- Bleach diluted to 10%
- Window-cleaning products
- Pre-impregnated wipes

■ 5.2 Resistance to hospital-grade cleaning products

Resistant to the following products : - Anios

- Surfanios
- Bactilysine
- Hydrogen peroxide
(35% oxygenated water)

Caution : Always test before using other special cleaning products.

6. STANDARDS AND APPROVALS

Compliance with installation and manufacturing standards.

Refer to e. catalogue.