


Arteor™ Advance RJ45 copper feedthrough socket

Cat. No(s): AC4315MB/MT/MW
AC4316MB/MT/MW

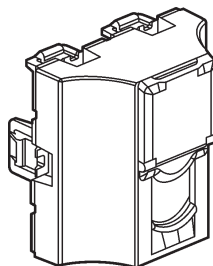

1. INTRODUCTION

2-module Mosaic Category 6 or 6A copper feedthrough sockets.




2. DESCRIPTION

Easy connection at the rear through simply attaching a male plug.
Provide network access for the RJ45 socket.

Used to create Cat. 6 and Cat. 5e links in accordance with standards ISO 11801 Ed.2 (2011), EN 50173-1 and EIA/TIA 568 C2 in the context of use with zone distribution boxes.


Multidirectional cable entry.

Can be installed in any support with a minimum 40 mm depth.

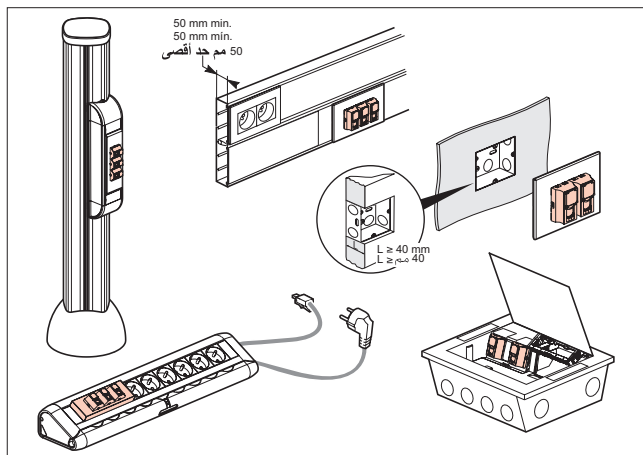

Description	Colour	Cat. No.	Modules
RJ45 REAR CAT6 UTP SOCKET	Matt Black	AC4315MB	2
	Matt Titanium	AC4315MT	2
	Matt White	AC4315MW	2
RJ45 REAR CAT6A STP SOCKET	Matt Black	AC4316MB	2
	Matt Titanium	AC4316MT	2
	Matt White	AC4316MW	2

3. DIMENSIONS

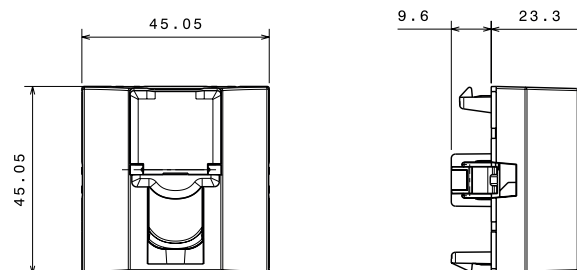

4. ACCESSOIRES

Cable Cat. No.	Type	Cat.	U/UTP	F/UTP	S/FTP	Length (m)
0 517 57	RJ45/bare	6	x			8
0 517 58	RJ45/bare	6	x			15
0 517 59	RJ45/bare	6	x			20
0 517 96	RJ45/bare	6		x		8
0 517 97	RJ45/bare	6		x		15
0 517 98	RJ45/bare	6		x		20
0 517 86	RJ45/bare	6A			x	8
0 517 87	RJ45/bare	6A			x	15
0 517 89	RJ45/bare	6A			x	20
0 515 10	RJ45/RJ45	6	x			8
0 515 11	RJ45/RJ45	6	x			15
0 515 12	RJ45/RJ45	6	x			20
0 515 13	RJ45/RJ45	6		x		8
0 515 14	RJ45/RJ45	6		x		15
0 515 15	RJ45/RJ45	6		x		20
0 515 23	RJ45/RJ45	6A			x	8
0 515 24	RJ45/RJ45	6A			x	15
0 515 25	RJ45/RJ45	6A			x	20