

**Description**

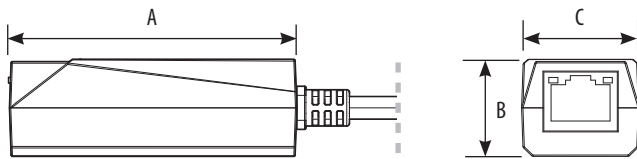
PoE converter to install BTicino IP DES devices with 24V PoE in 48V PoE network. The converter must be plug-in into the indoor unit, entrance panel or guard station. For entrance panel it can be fit in the flush-mounted dedicated box. For indoor unit it can be fit in the 503 and the BS UA2 flush-mounted boxes.

**Note:**

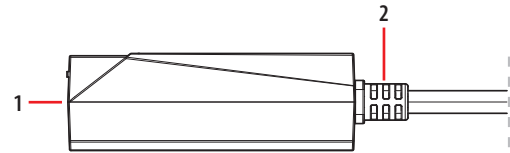
- Do not use BT-375012 PoE converter together with devices already compatible with PoE+ network (i.e. BT-373008).
- Do not install BT-375012 PoE converter in the same box of main voltage distribution network wires.

**Technical data**

Input voltage: 44 – 57 Vdc  
Output voltage: 24 Vdc

**Dimensional data**

A	B	C
63.5 mm	21.5 mm	26 mm

**Front view****Legend**

1. Input connector: RJ4510/100 Base T - IEEE 802.3at POE 44V-57V
2. Output cable: RJ4510/100 Base T - 24 V