



1

BMSA2202

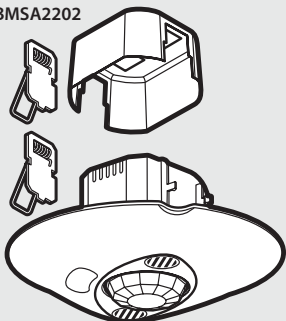



BMSA2201

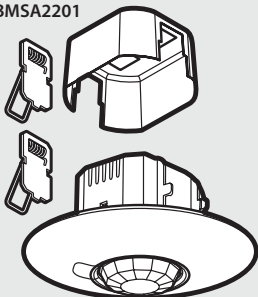


	BMSA2202	BMSA2201
	100 - 240 V~	100 - 240 V~
	50 / 60 Hz	50 / 60 Hz
	2 x 2,5 mm ²	2 x 2,5 mm ²
	-5°C / +45°C	-5°C / +45°C
	Ø 65 mm	Ø 65 mm
	500 lux	500 lux
	15 mn	15 mn






230 V~	2000 W	8,5 A	2000 W	8,5 A	1000 VA	4,3 A	10x(2x36 W)	4,3 A	500 VA	2,1 A	1000 VA	4,3 A	I max. ≤ 2A
110 V~	1000 W	8,5 A	1000 W	8,5 A	500 VA	4,3 A	5x(2x36 W)	4,3 A	250 VA	2,1 A	500 VA	4,3 A	

2

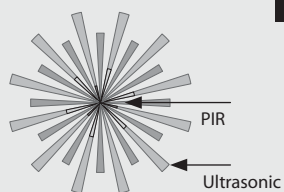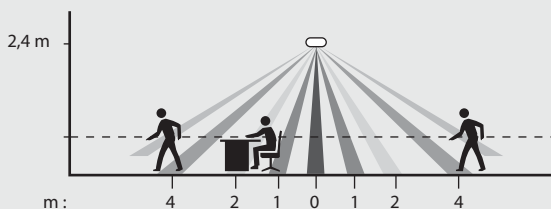


	BMSA2202	BMSA2201
	90 m ²	45 m ²

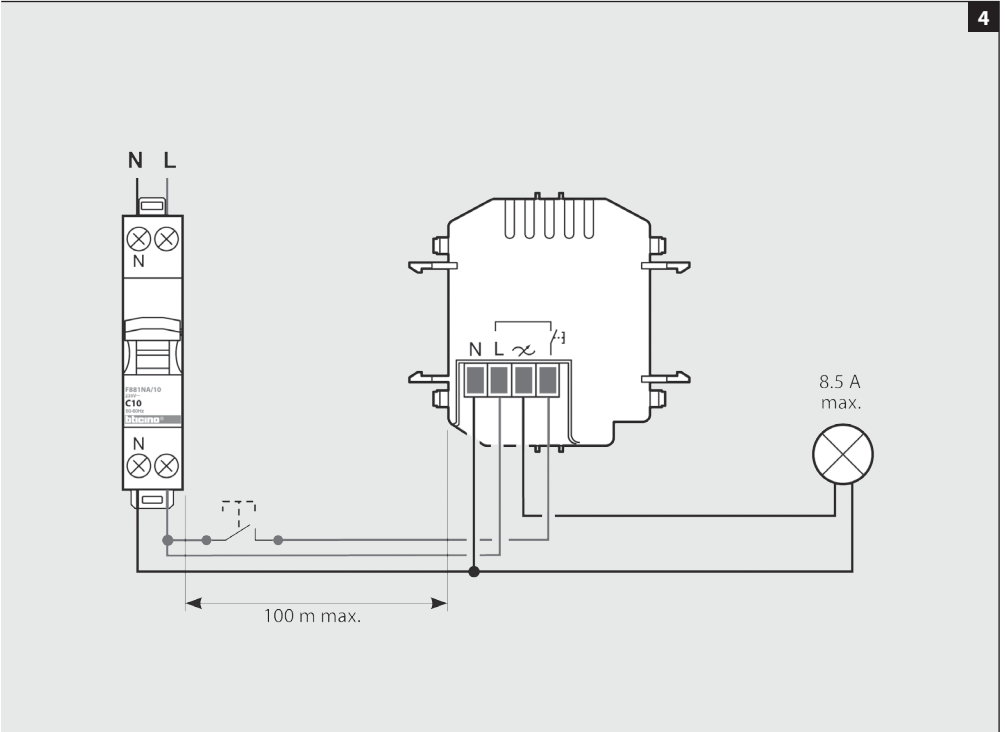


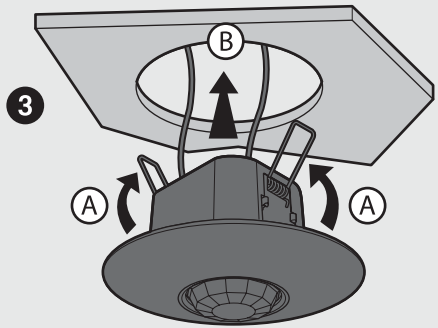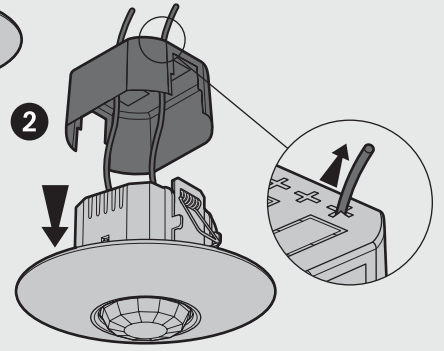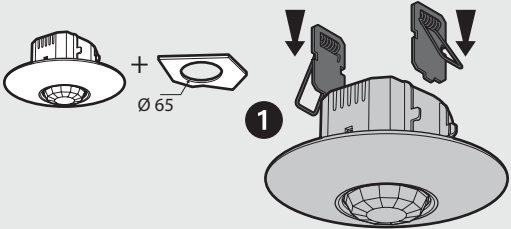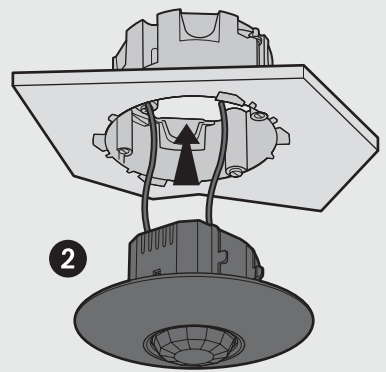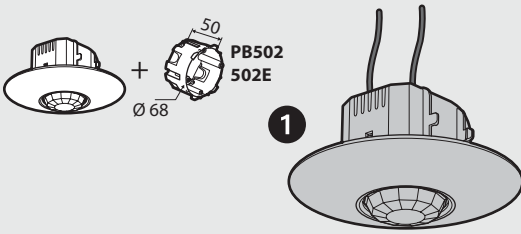


BMSA2202

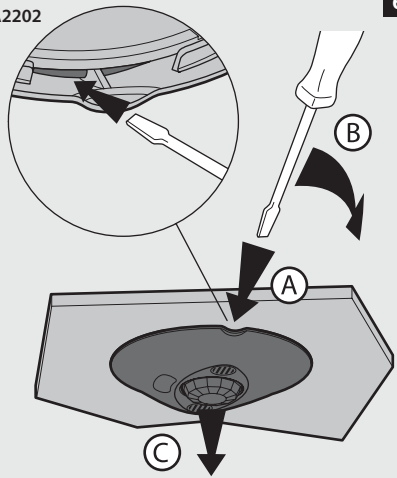

BMSA2201

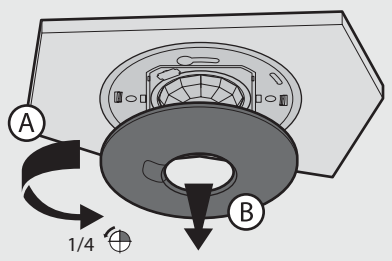

Auto

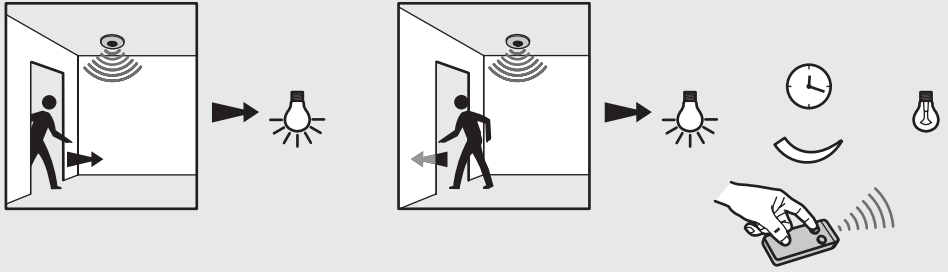

Eco

