


Off-door control Make up the room / do not disturb

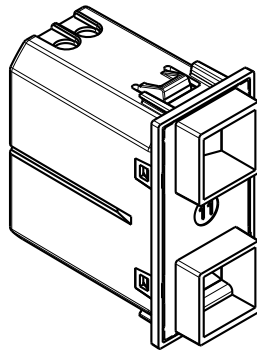

Use

Lampholder with two built-in LEDs, green and red.
Can be used as out of room visual signal with double notification:
do not disturb and make up the room
the LEDs cannot be replaced - 127/ 230 VA power supply - 1 module

Connection

Terminal type: screw clamp
Terminal capacity: 2 x 1,5 mm² max
Stripping length: 8 mm
Screwdriver: flat 3
Compatible with flexible or rigid cables

Range

Designation	Cat. No.	Related Cover Codes
Lampholder	K4373	<input type="checkbox"/> KW11H <input type="checkbox"/> KM11H <input checked="" type="checkbox"/> KG11H

Technical characteristics

- Protection index
(considering a complete installation, including cover plate)
Penetration by solid bodies/liquid: IP40

- Mechanical characteristics
Impact test: IK 04

- Material characteristics

Material:
Case and Key cover: PC (Polycarbonate)
UV resistant.

Self-extinguishing:

850° C / 30 s for insulating parts holding live parts in place
650° C / 30 s for other parts made of insulating materials

- Electrical characteristics


Voltage: 250V a.c.
Power consumption : 2 x 0.15 W- 2 x 0.5 W

- Climatic characteristics

Storage temperature: - 10° C to + 70° C Use
temperature: - 5° C to + 35° C

Colours code: White Sand Black

Overall dimensions (mm)

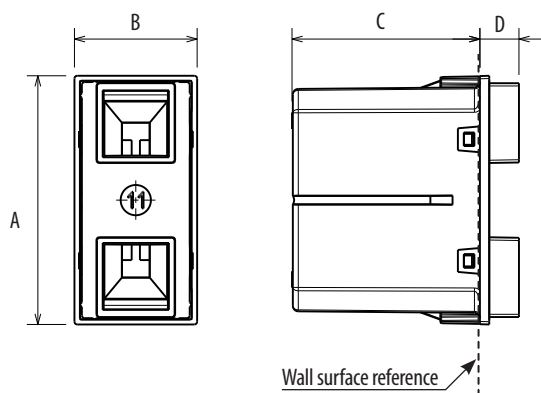

	A	B	C	D
K4373	45.2	22.3	34.2	7.1

Cleaning

Clean the surface with a cloth.
Do not use acetone, tar-removing cleaning agents or trichloroethylene.
Caution: Always test before using special cleaning products.

Standards and approvals

Compliance with standards IEC/EN 60598-2-2
Refer to e.catalogue.