


2025

# POWER AND PROTECT

ELECTRICAL ENCLOSURE & SWITCHBOARD SOLUTIONS

## CATALOGUE

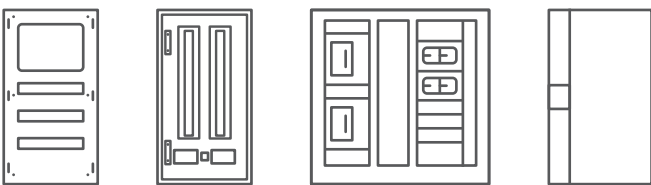

Discover our solutions at [trical.co.nz](https://trical.co.nz)

# Proudly New Zealand Made

## MADE WITH A RICH HERITAGE



TRICAL is one of New Zealand's leading suppliers of electrical enclosures and switchboard solutions, serving the electrical trades across industrial, commercial, and residential markets for over 60 years. As part of the Legrand Group since 2018, we are proud to be New Zealand made, with a rich heritage. Representing market-leading brands, we manufacture 'best in class' products you can trust, supported by a passionate, skilled, and expert team.



With four iconic brands (Gael, Teubel, Signet, ETL) brought together in one purpose-built manufacturing, engineering, and administration facility, TRICAL delivers consistent, quality products and services. Innovation is the foundation of our business, and our brands reflect our passion and commitment to providing the very best products for you. With a technical approach, where confidence and trust in supply and design are critical to the success of a project, we deliver well-engineered products, on time, within budget, and with friendly, supportive service expertise.



TRICAL product ranges are complementary to Legrand Group commercial and residential offers, bringing you a **complete solution** for your projects.

## RESIDENTIAL METERING AND DISTRIBUTION BOARDS

TEUBEL is proud of its history in manufacturing electrical componentry and metalwork products, including residential meter boxes, distribution boards, and commercial switchboards. Significant investment in machinery and technology allows TEUBEL to continue this tradition, delivering exceptional quality products with the expertise of a skilled team.

## CABINET ENCLOSURES

Enclosure Technology specializes in manufacturing and supplying 19" rack enclosures for the computer, broadcasting, and telecommunications industries. ETL offers a wide range of server cabinets compatible with Compaq, HP, IBM, and Siemens-Nixdorf servers, all of which can be fitted with various accessories like sliding keyboard shelves, monitor shelves, power distribution, and fan cooling.

### RESIDENTIAL METERING AND DISTRIBUTION BOARDS



**P. 6**  
Outdoor Meter Boxes



**P. 12**  
Temporary Builders Box

### CABINET ENCLOSURES



**P. 21**  
Wall Mount Cabinets



**P. 22**  
E-Tech 19" Fully Built Cabinets

### RESIDENTIAL DATA ENCLOSURES AND HOME AUTOMATION



**P. 30**  
Networking Enclosures



**P. 32**  
Data Patch Panels

### COMMERCIAL DISTRIBUTION BOARDS



**P. 34**  
Econoboard Distribution Boards



**P. 35**  
G200 Assembled Distribution Boards

## RESIDENTIAL DATA ENCLOSURES AND HOME AUTOMATION

SIGNET addresses the growing demand for home networking solutions. Designed and manufactured in New Zealand, SIGNET continues to innovate with the support of Trical's expert team. As a leader in the home networking market, SIGNET offers a wide range of products, including Fibre To The Home (FTTH), data cabinets, RJ45 and patch panels, telecommunications, communications, AV, and RF products.

## COMMERCIAL DISTRIBUTION BOARDS

GAEL is known for its iconic modular distribution boards and control panels. GAEL Switchboards maintains its reputation for high-quality, reliable products at affordable prices while expanding its product range, engineering, support services, and capabilities. GAEL products are found across various industry sectors, manufacturing low and high voltage main switchboards, motor control centres, power factor correction units, control panels, and distribution boards.



**P. 12**  
Outdoor Metering and Distribution Boards



**P. 13**  
Indoor Metering and Distribution Boards




**P. 16**  
Switchboard Components



**P. 23**  
E-Tech 19" Open Frames



**P. 24**  
Wall Frames & Bases

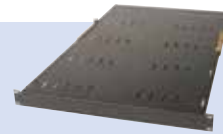

**P. 24**  
Accessories



**P. 32**  
Accessories



**P. 33**  
TV, AV & RF Components



 
**P. 33**  
Telecommunications



**P. 33**  
Halong Tools




**P. 41**  
Distribution Board Parts



**P. 48**  
MCB Chassis

## Outdoor meter boxes

### Slide rail

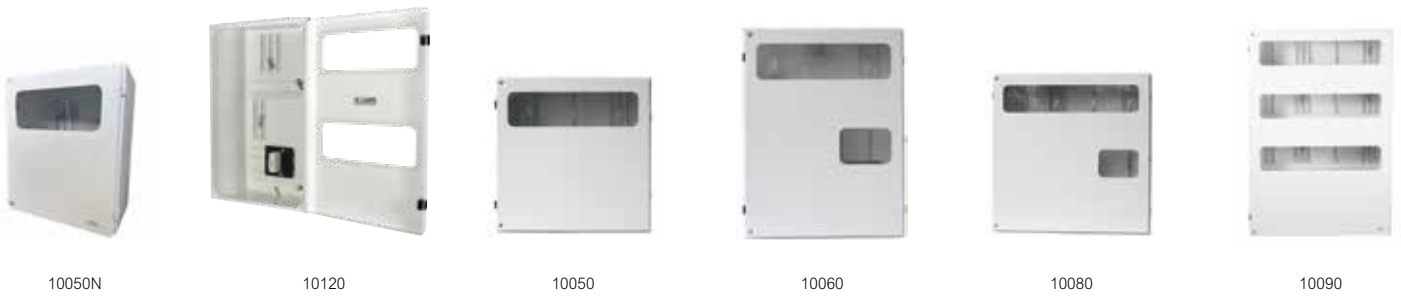

Cat. No.	Description	Box Size W x H (mm)	Panels W x H (mm)	Meters or relays	TRADE PRICE \$ (ex GST)
<b>Outdoor meter boxes with slide rail</b>					
<b>S Type: Northland, Auckland, Hamilton, Taupo and Rotorua</b>					
Depth 220 mm. Including 25 mm door, IP Rating: IPX4					
10050N	NDC1S 25 mm deep door with window – Back wired	360 x 430	230 x 150	2	336.61
10020	NDC1S 25 mm deep door with window – Front wired	360 x 430	120 x 110	2	336.61
10120	DCB1S 25 mm deep door with window	400 x 600	120 x 110	4	348.15
10119	DCB1S Back wired	400 x 600	240 x 150	4	348.15
10111	DCB1S Top hung – Back wired	400 x 600	240 x 150	4	348.15
10110	DCB1S 25 mm deep door with window Top hung	400 x 600	120 x 110	4	348.15
10050	DC2S 25 mm deep door with window	500 x 500	455 x 200	3	394.36
10060	DC3S 25 mm deep door with window	500 x 650	305 x 355	4	508.44
10080	DC4S 25 mm deep door with window	650 x 650	305 x 355	6	658.33
10090	DC5S 25 mm deep door with window	650 x 950	305 x 200	12	1446.68

# Outdoor meter boxes

## Full panel



Cat. No.	Description	Box Size W x H (mm)	Panels W x H (mm)	TRADE PRICE \$ (ex GST)
<b>Outdoor meter boxes with full panel</b>				
<b>DC: Northland, Auckland, Hamilton, Taupo and Rotorua</b>				
Depth 220 mm. Including 25 mm Door 65 mm Clearance behind panel IP Rating: IPX4				
11040	DC1 25 mm deep door with window – 1 window	350 x 500	310 x 445	232.91
11041	DC1 25 mm deep plain door	350 x 500	310 x 445	214.18
11042	DC1 25 mm deep door with window Top hung – 1 window	350 x 500	310 x 445	232.93
11043	DC1 25 mm deep plain door Top hung	350 x 500	310 x 445	214.18
11050N	NDC1 25 mm deep door with window – 1 window	360 x 430	310 x 390	318.88
11051N	NDC1 25 mm deep plain door	360 x 430	310 x 390	318.88
11050	DC2 25 mm deep door with window – 1 window	500 x 500	455 x 455	520.84
11051	DC2 25 mm deep plain door	500 x 500	455 x 455	520.84
11060	DC3 25 mm deep door with window – 2 windows	500 x 650	455 x 610	643.09
11080	DC4 25 mm deep door with window – 2 windows	650 x 650	610 x 610	864.55
11081	DC4 25 mm deep plain door	650 x 650	610 x 610	864.55
11097	DC5 25 mm deep door with window – 3 windows	650 x 950	610 x 915	1576.73
<b>NP: New Plymouth</b>				
11555	NP2 25 mm deep door with window – 1 window	500 x 500	455 x 455	365.98
11566	NP3 25 mm deep door with window – 2 windows	500 x 650	455 x 610	498.87
<b>DHB: Hawkes Bay</b>				
11300N	NDHB 25 mm deep door with window – 1 window	360 x 430	310 x 390	319.15
11301N	NDHB 25 mm deep plain door	360 x 430	310 x 390	319.15

## Outdoor meter box components



Cat. No.	Description	Size W x H (mm)	TRADE PRICE \$ (ex GST)	Cat. No.	Description	TRADE PRICE \$ (ex GST)
<b>Outdoor meter box components</b>				<b>Flashing Kits</b>		
<b>Replacement Windows Round</b>				The Department of Building and Housing requires that all meter boxes have Flashing Kits installed as per the standard: Acceptable Solutions E2/AS.1 Failure to install a flashing kit may well result in a Code of Compliance Certificate not being issued. Important: Match the flashing depth on the box to fit the type of cladding.		
19001	Window NDC1S/DC4S – Round	280 x 126	17.48	44336	Flashing kit 430 x 360 meter box	82.05
19002	Window DCB1S – Round	330 x 126	19.11	45050	Flashing kit 500 x 500 meter box	82.05
19003	Window DC2/DC3 – Round	430 x 126	23.48	46040S	Slim flashing 600 x 400 DCB1S	16.02
19004	Window DC4/DC5 – Round	565 x 126	29.70	46050	Flashing kit 500 x 350 DC1	82.05
19005	Window relay DC3/4 – Round	176 x 126	9.72	46060	Flashing kit 600 x 600 M2	98.46
<b>Replacement Windows Square</b>				46550	Flashing kit 650 x 500	98.46
19001S	Window NDC1S/DC4S – Square	280 x 126	17.48	46565	Flashing kit 650 x 650 DC4S	114.84
19002S	Window DCB1S – Square	330 x 126	19.11	49565	Flashing kit 950 x 650 DC5S	131.25
19003S	Window DC2/DC3 – Square	430 x 126	23.48			
19004S	Window DC4/DC5 – Square	565 x 126	29.70			
19005S	Window relay DC4/5 – Square	176 x 126	9.72			
<b>Hinges, Screws &amp; Catch</b>						
MBH	Outdoor meter box hinge set		4.69			
MBS	Outdoor meter box screw		1.06			
MLD07	Outdoor meter box catch pairs		2.77			

## Outdoor meter boxes



10912



10916



17050



17081

Cat. No.	Description	Box Size W x H (mm)	TRADE PRICE \$ (ex GST)
<b>Outdoor meter boxes</b>			
<b>M Range</b>			
Depth 220 mm. Including 25 mm Door IP Rating: IPX4			
10900	M1 – 1 window	400 x 600	236.94
10901	M1 with Plain Panel – 1 window	400 x 600	347.15
10902	M1 Top hung with Plain Panel – 1 window	400 x 600	347.15
10906	M1 – 2 windows	400 x 600	246.16
10907	M1 with Plain Panel – 2 windows	400 x 600	347.15
10910	M1 Top hung – 2 windows	400 x 600	246.16
10912	M1 Top hung – 1 window	400 x 600	236.94
10916	M2 – 2 windows	600 x 600	328.94
10918	M2 with plain Panel – 2 windows	600 x 600	397.02
10920	M2 Top hung – 2 windows	600 x 600	328.94
10930	M0 Hinged Plastic Panel	400 x 600	214.18


Cat. No.	Description	TRADE PRICE \$ (ex GST)
<b>Outdoor meter box replacement doors</b>		
<b>Meter Box Replacement Doors</b>		
25 mm deep door		
17050	LID DC2/DC2S door with window	95.83
17051	LID DC2/DC2S plain door	75.04
17060	LID DC3/DC3S door with window	128.51
17061	LID DC3/DC3S plain door	75.92
17080	LID DC4/DC4S door with window	153.6
17081	LID DC4/DC4S plain door	92.2
17090	LID DC5/DC5S door with window	249.75
17091	LID DC5/DC5S plain door	125.84
17120	LID DCB1S door with window	82.33
17121	LID DCB1S plain door	76.79
17200	LID NDC1 door with window	76.28
<b>Meter Box Replacement Doors</b>		
17201	NDC1 Door, plain, 25 mm deep	52.75
17801	DC1 Door, plain, side hung	82.33
17802	DC1 Door, plain, top hung	82.33
17803	DC1 Door, 1 window, side hung	88.32
17804	DC1 Door, 1 window, top hung	88.32
17900	LID M1 – 1 window	73.98
17901	LID M1 – 1 window, top hung	74.02
17915	LID M2 – 2 window, top hung	93.41
17916	LID M2 25 mm deep door with window	85.24
17919	Lid builders box NDB1	65.72
17922	LID DCB1S 25 mm deep door with window, Top hung	82.33

### Notes

Custom doors available on request. Lead time applies

# Meterbox replacement door selection


## Selection chart

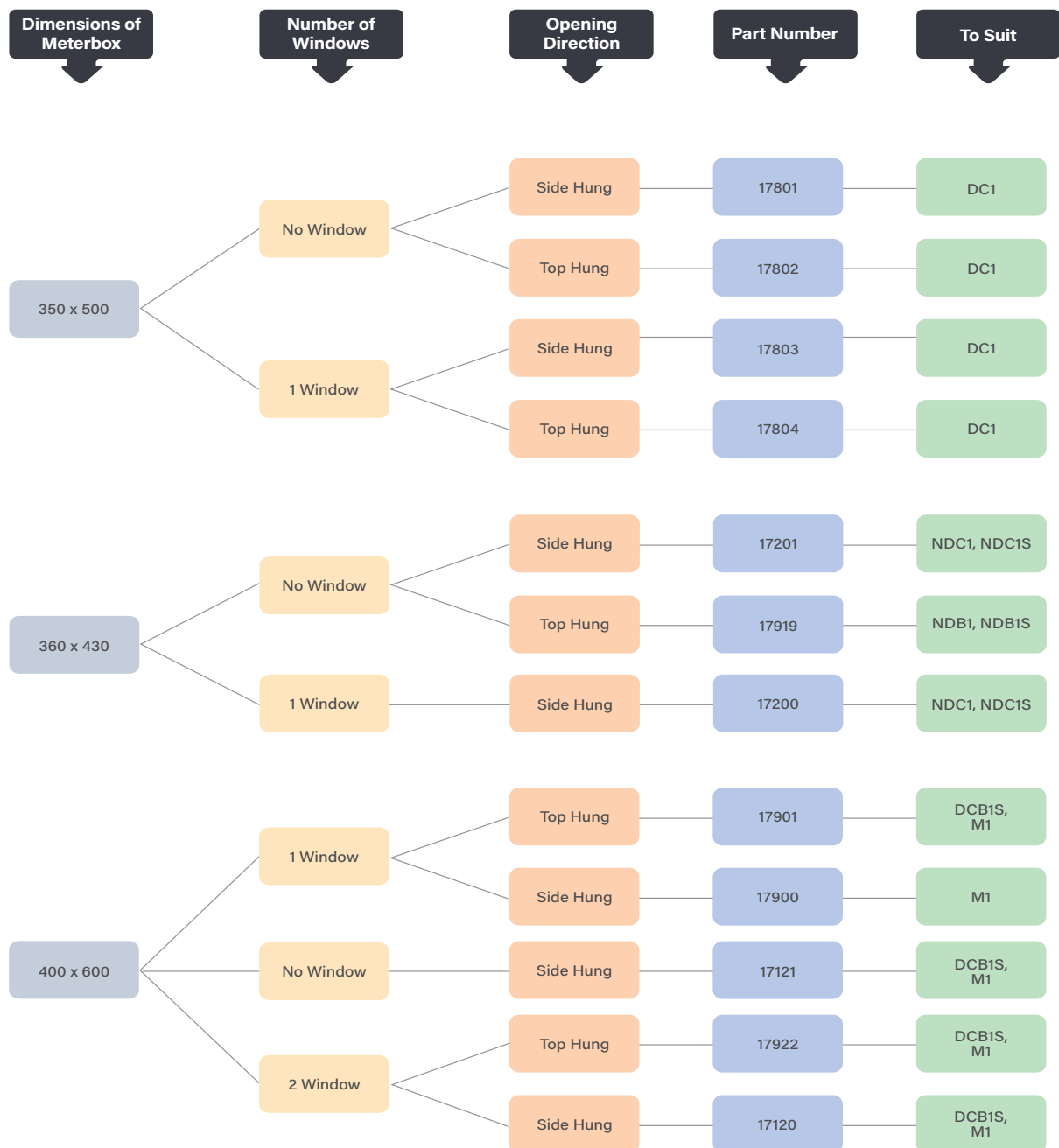

Can't find your meterbox door? Trical can manufacture a 'one off' meterbox door to suit.

# Meterbox replacement door selection

## Selection chart

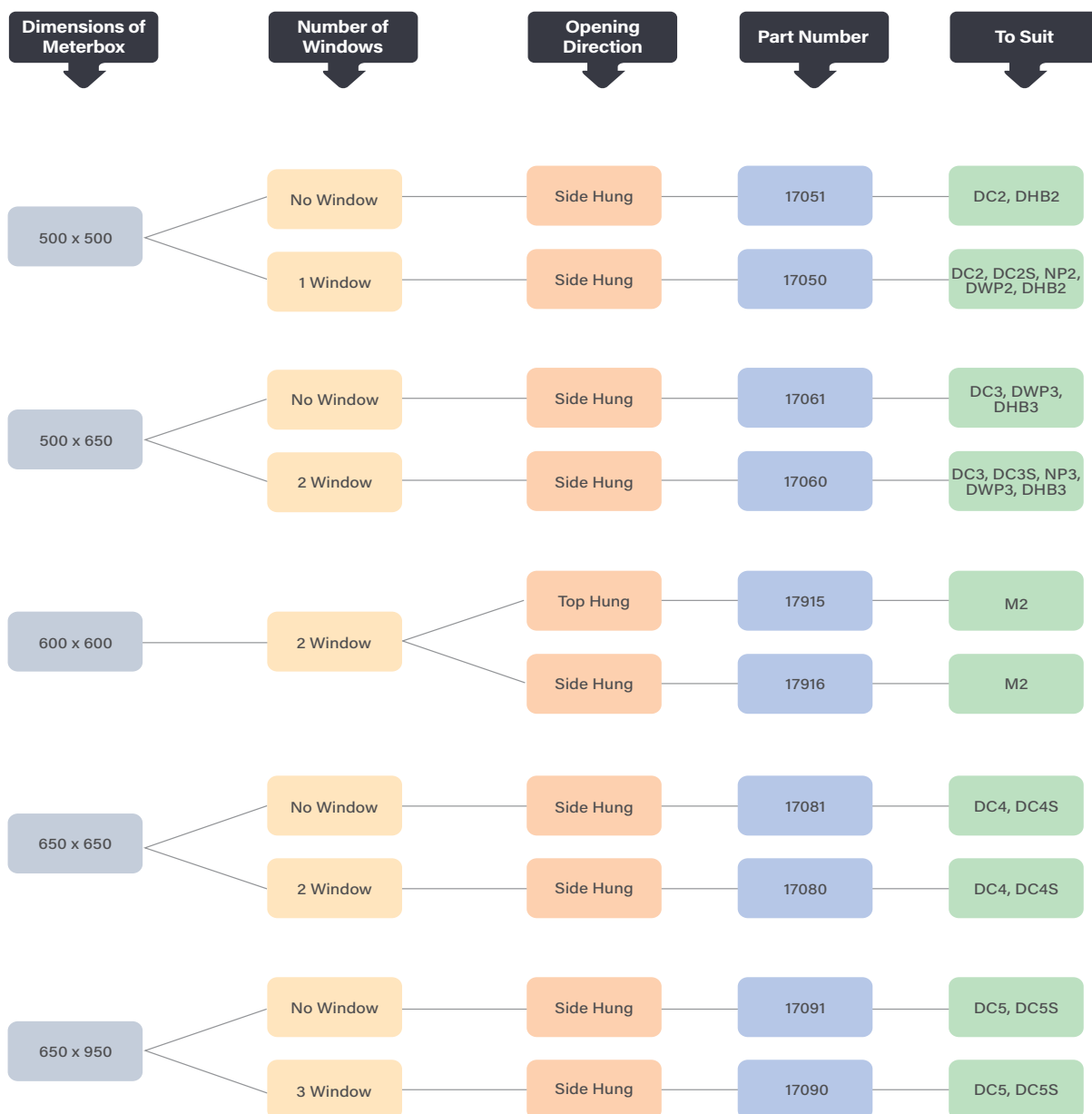

Can't find your meterbox door? Trical can manufacture a 'one off' meterbox door to suit.

## Temporary builders boxes



12011N



12013N



12616



12860

Cat. No.	Description	TRADE PRICE \$ (ex GST)
<b>Temporary Builders Boxes</b>		
Door size 360 (W) x 430 (H) mm Builder box fitted with Wired Panels include: 1 x 63A Main Switch 1 x RCBO 20A + 30mA 1 x Double Switched Socket Unit 10A 2 x 63A 2 stud 2 way earth / neutral bars IP Rating: IPX4		
12011N	NDB1 with full panel – plain lid	289.93
12013N	NDB1 with full wired panel – plain lid	943.69
12031N	NDB1S with half panel – plain lid	289.93
12033N	NDB1S with half wired panel – plain lid	975.07

Part No.	Description	Box Size W x H (mm)	TRADE PRICE \$ (ex GST)
<b>Outdoor Meter Distribution</b>			
Does not include circuit breakers Depth 220 mm IP Rating: IPX4			
12616	DCB1S-D16 16 Way – 1 Window	400 x 600	430.07
10064	DC3S-D30 30 Way – 2 Window	500 x 650	691.33
12860	DC5S-D60 60 Way – 3 Window	650 x 950	1446.68

## Indoor meter distribution boards

### Ezywire PLUS



EZC617



EZC834

Cat. No.	Description	Door Size W x H (mm)	Cut-Out Size W x H X D (mm)	TRADE PRICE \$ (ex GST)
<b>Ezywire PLUS indoor boards</b>				
<b>Indoor meter boards</b>				
Flush mounted boards. Plain door, Depth 90 mm				
EZM4	Indoor Meter Board – to fit one smart Single Pole Meter	400 x 475	355 x 425 x 90	211.57
EZM6	Indoor Meter Board – to fit two smart Single Pole Meters	400 x 625	355 x 575 x 90	267.39
<b>Indoor meter and distribution boards</b>				
Combination meter and distribution boards. Flush mounted. Fit two smart single pole meters. Meters can be mounted at top or bottom of the board.				
EZC617	17 Way – 1 row	400 x 625	355 x 575 x 90	347.16
EZC834	34 Way – 2 rows	400 x 775	355 x 725 x 90	379.21
EZC851	51 Way – 3 rows	400 x 775	355 x 725 x 90	395.02
EZC1068	68 Way – 4 rows	400 x 1000	355 x 950 x 90	502.50
<b>Indoor distribution boards</b>				
Distribution boards. Flush mounted.				
EZP217	17 Way – 1 row	400 x 325	355 x 275 x 90	182.90
EZP434	34 Way – 2 rows	400 x 475	355 x 425 x 90	229.55
EZP651	51 Way – 3 rows	400 x 625	355 x 575 x 90	306.00
EZP868	68 Way – 4 rows	400 x 775	355 x 725 x 90	369.32

Cat. No.	Description	Door Size W x H (mm)	TRADE PRICE \$ (ex GST)
<b>Ezywire PLUS components</b>			
<b>Replacement Door Ezywire PLUS</b>			
Plain replacement doors. Come with latches			
EZ2DR	Fits EZP217	400 x 325	37.02
EZ4DR	Fits EZM4, EZP434	400 x 475	36.78
EZ6DR	Fits EZM6, EZC617, EZP651	400 x 625	48.34
EZ8DR	Fits EZC834, EZC851, EZP868	400 x 775	50.66
EZ10DR	Fits EZC1068	400 x 1000	67.68

## Indoor distribution board components

### Ezywire PLUS



Cat. No.	Description	Door Size W x H (mm)	TRADE PRICE \$ (ex GST)	Cat. No.	Description	TRADE PRICE \$ (ex GST)
<b>Ezywire PLUS components</b>				<b>Replacement Surround – Meter Boards</b>		
<b>Surface Mount Kit</b>				EZM4F	Fits EZM4	46.06
EZSM2	Fits EZ2 Series	400 x 325	79.41	EZM6F	Fits EZM6	57.01
EZSM4	Fits EZ4 Series	400 x 475	93.69	<b>Replacement Surround – Meter Distribution Boards</b>		
EZSM6	Fits EZ6 Series	400 x 625	101.84	EZC6F	Fits EZC617	65.49
EZSM8	Fits EZ8 Series	400 x 775	114.05	EZC834F	Fits EZC834	99.94
EZSM10	Fits EZ10 Series	400 x 1000	145.54	EZC851F	Fits EZC851	102.24
<b>Replacement Surround – Distribution Boards</b>				EZC10F	Fits EZC1068	111.22
EZP2F	Fits EYP217		38.97	<b>Ezywire Components</b>		
EZP4F	Fits EYP434		52.33	EZLOCK-KIT	Ezywire Door Lock Kit	105.81
EZP6F	Fits EYP651		63.46	MLD28	MCB Blank – White – Covers 5 Spaces	4.53
EZP8F	Fits EYP868		70.69	MLD51	Ezywire PLUS Hinge & Pin	2.63
				MLD43	Ezywire PLUS Magnetic Latch	4.05

# Indoor meter distribution boards


## Ezywire jumbo



JEZMP8-482



JEZMP6-241D

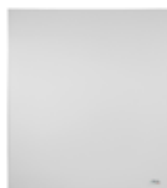

JEZ6DP




JEZMP8-482DF

Cat. No.	Description	Door Size W x H (mm)	Cut-Out Size W x H X D (mm)	TRADE PRICE \$ (ex GST)	Cat. No.	Description	TRADE PRICE \$ (ex GST)
<b>Ezywire Jumbo indoor boards</b>					<b>Replacement doors and frames</b>		
Jumbo Boards are 500 mm wide					Door have latches. Surround frames have hinges		
<b>Indoor Meter Distribution Board, Shallow</b>					<b>Replacement Door Meter Distribution (Plain)</b>		
JEZMP8-482	50 Way – 2 rows	520 x 745	500 x 725 x 90	419.16	JEZ6DP	Fits JEZ6	57.06
JEZMP10-723	75 Way – 3 rows	520 x 970	500 x 950 x 90	530.28	JEZ8DP	Fits JEZ8	56.18
					JEZ10DP	Fits JEZ10	64.76
<b>Indoor Meter Distribution Board, Deep</b>					<b>Replacement Surround Meter Distribution</b>		
JEZMP6-241D	25 Way – 1 Row	520 x 595	500 x 575 x 140	437.39	JEZMP6-241DF	Fits JEZMP6-241D	105.34
JEZMP8-482D	50 Way – 2 rows	520x745	500 x 725 x 140	457.28	JEZMP8-482F	Fits JEZMP8-482	73.85
JEZMP10-723D	75 Way – 3 Rows	520 x 970	500 x 950 x 140	568.38	JEZMP8-482DF	Fits JEZMP8-482D	101.24
					JEZMP10-723DF	Fits JEZMP10-723D	188.08
					JEZMP10-723F	Fits JEZMP10-723	78.87
<b>Indoor Distribution Board, Plain Door</b>					<b>Replacement Surround Distribution</b>		
JEZP8-723	75 Way – 3 Rows	520 x 745	500 x 725 x 90	425.11	JEZP8-723F	Fits JEZP8-723	51.79
JEZP10-1205	125 Way – 5 Rows	520 x 970	500 x 950 x 90	498.26	JEZP10-1205F	Fits JEZP10-1205	65.85
<b>Surface Mount Kits</b>							
JEZSM6	Fits JEZ 6 Series		558 x 635	136.27			
JEZSM8	Fits JEZ 8 Series		558 x 785	155.69			
JEZSM10	Fits JEZ 10 Series		558 x 1010	175.10			

## Residential switchboard components
 
### Earth neutral busbars – 63A



Cat. No.	Description	Length (mm)	TRADE PRICE \$ (ex GST)	Part No.	Description	Length (mm)	TRADE PRICE \$ (ex GST)
<b>63A rating. 6 mm pitch</b>				<b>63A rating. 9.5 mm pitch</b>			
<b>1 Stud</b>				<b>1 Stud</b>			
34041	4 Way	57	9.47	30041	4 Way	80	10.21
34061	6 Way	65	11.90	30061	6 Way	101	13.23
34081	8 Way	77	13.76	30081	8 Way	120	16.63
34101	10 Way	89	17.04	30101	10 Way	139	19.85
34121	12 Way	101	20.18	30121	12 Way	158	23.45
34181	18 Way	140	29.99	30141	14 Way	177	27.35
34241	24 Way	173	38.96	30161	16 Way	196	29.31
<b>2 Studs</b>				<b>2 Studs</b>			
34042	4 Way	70	11.18	30181	18 Way	214	36.56
34062	6 Way	80	15.89	30201	20 Way	234	38.18
34082	8 Way	92	17.59	<b>2 Studs</b>			
34102	10 Way	104	20.63	30042	4 Way	100	11.55
34122	12 Way	116	23.18	30062	6 Way	118	16.10
34142	14 Way	128	25.50	30082	8 Way	138	19.06
34162	16 Way	140	28.89	30102	10 Way	157	21.96
34182	18 Way	152	32.39	30122	12 Way	175	24.95
34202	20 Way	164	33.64	30162	16 Way	213	31.32
34242	24 Way	188	42.18	30202	20 Way	251	38.74
34302	30 Way	224	49.69	30242	24 Way	289	47.31
34362	36 Way	260	60.49	<b>3 Studs</b>			
<b>3 Studs</b>				<b>3 Studs</b>			
34063	6 Way	94	18.31	30063	6 Way	140	19.85
34083	8 Way	106	21.00	30083	8 Way	159	22.30
34103	10 Way	118	23.25	30103	10 Way	178	25.50
34123	12 Way	130	26.04	30123	12 Way	197	29.31
34143	14 Way	142	29.47	30143	14 Way	216	32.14
34163	16 Way	154	32.14	30163	16 Way	235	35.13
34183	18 Way	167	36.93	30183	18 Way	255	41.57
34203	20 Way	178	37.81	30203	20 Way	273	42.89
34243	24 Way	202	48.35	30243	24 Way	311	52.33
34303	30 Way	238	59.19				
34363	36 Way	274	72.75				

## Switchboard components

### Earth neutral busbars – 90A & 165A



NL 12



39324D



39312D

Cat. No.	Description	Length (mm)	TRADE PRICE \$ (ex GST)	Cat. No.	Description	Length (mm)	TRADE PRICE \$ (ex GST)
<b>90A rating. 12.7 mm pitch</b>				<b>165A rating</b>			
<b>No stud</b>				<b>Single screw – 3 Studs</b>			
NL3	3 Way	33	9.39	39312S	12 Way	176	33.34
NL12	12 Way	114	22.91	39324S	24 Way	252	64.48
NL16	16 Way	141	26.68	39336S	36 Way	328	81.47
NL24	24 Way	186	36.76	39348S	48 Way	404	89.03
NL36	36 Way	261	49.92	39360S	60 Way	481	111.20
				39372S	72 Way	557	133.45
				<b>Double screw – 3 Studs</b>			
				39312D	12 Way	176	36.86
				39324D	24 Way	252	66.40
				39336D	36 Way	328	88.48
				39348D	48 Way	404	95.95
				39360D	60 Way	481	121.69
				39372D	72 Way	557	143.84

# Switchboard components

## Stud bars



32006



20004



40006



6306S

Cat. No.	Description	Length (mm)	TRADE PRICE \$ (ex GST)	Cat. No.	Description	Length (mm)	TRADE PRICE \$ (ex GST)
<b>Stud Bars</b> <b>180A</b> Stainless Steel studs 6 mm at 16 mm centres. Thickness: 3.2 mm				<b>Stud bars (continued)</b> <b>400A</b> Stainless Steel studs 8 mm at 25 mm centres. Thickness: 6.4 mm			
32003	3 Way	80	15.30	40006	Copper 6 Stud	200	88.12
32004	4 Way	96	23.20	40009	Copper 9 Stud	275	132.18
32005	5 Way	112	28.57	40012	Copper 12 Stud	350	176.25
32006	6 Way	128	35.83	<b>630A</b> Stainless Steel studs 10 mm at 30 mm centres. Thickness 8.0 mm			
32007	7 Way	144	42.36	6306S	6 Way	240	184.03
32008	8 Way	160	49.05	6309S	9 Way	330	245.15
32009	9 Way	176	60.77	63012S	12 Way	420	305.54
32010	10 Way	192	67.47				
32012	12 Way	224	79.92				
32014	14 Way	256	91.42				
32016	16 Way	288	107.36				
32020	20 Way	352	150.51				
<b>250A</b> Stainless Steel studs 8 mm at 25 mm centres. Thickness: 3.2 mm							
20003	3 Way	125	35.37				
20004	4 Way	150	47.17				
20005	5 Way	175	58.98				
20006	6 Way	200	70.77				
20008	8 Way	250	94.35				
20009	9 Way	275	106.15				
20012	12 Way	300	141.55				
20014	14 Way	400	165.11				
20016	16 Way	450	188.71				
20020	20 Way	550	235.89				

## Residential switchboard components

### Insulating stand offs



DB17



SS10



ES10



RS21



RS21M6

Cat. No.	Description	Dimensions (mm)	TRADE PRICE \$ (ex GST)
<b>Insulating Stand Offs</b>			
DB17	Stepped Support	17 x 8.5	3.84
SS10	Single Support	26 x 10	3.84
ES10	Stepped Support	8 x 11.5	3.84
RS21	Stepped Support	21 x 10	3.60
RS21M6	Stepped Support	21 x 6	3.60

## Switchboard components

### Links, earth clamps, bonding strip, PVC panels



20000



33001



33120



Earth Strap



VF101/100



NL3P

Cat. No.	Description	Pack Quantity	TRADE PRICE \$ (ex GST)
<b>Miscellaneous components</b>			
<b>Danger Signs</b>			
20000	Danger signs each – MOQ 40	40	5.10
<b>Links</b>			
33001	B/Bar links-packs of 50	50	2.69
20050	250A Copper Link	1	11.11
<b>Earth Clamps and Straps</b>			
33120	Earth clamp 5/8 ea (MOQ OF 50)	50	8.49
EC100	EC100 Earth Strap Max 3/4"	5	18.87
EC200	EC200 Earth Strap Max 1 1/2"	10	26.38
EC400	EC400 Earth Strap Max 4"	10	34.80
<b>Flush Frames</b>			
VF101/100	Plastic Flush Frame – suitable for retrofitting switches and powerpoints	100	1.45
<b>Neutral Peg</b>			
NL3P	Neutral PEG RCD 3 Way		9.20
<b>Din Rails</b>			
ANTI-TAMPER-2P	Din rail mount anti-tamper 2P	1	50.50
ANTI-TAMPER-3P	Din rail mount anti-tamper 3P	1	47.32

Cat. No.	Description	Dimensions W x H x D (mm)	TRADE PRICE \$ (ex GST)
<b>PVC blank panels, grey</b>			
51212	PVC panel 12 x 12 x 4	305 x 305 x 4.5	25.84
51218	PVC panel 12 x 18 x 4	305 x 457 x 4.5	38.39
51818	PVC panel 18 x 18 x 5	457 x 457 x 4.5	74.13
51824	PVC panel 18 x 24 x 5	457 x 610 x 4.5	90.10
52424	PVC panel 24 x 24 x 6	610 x 610 x 6	126.55
52436	PVC panel 24 x 36 x 6	610 x 915 x 6	202.94
55500	PVC panel M2	555 x 555 x 4.5	123.14
55536	PVC panel M1	360 x 555 x 4.5	79.24

Special sizes available on request

## Wall mount cabinets

### Swing and fixed



WS61045

Cat. No.	Description	TRADE PRICE \$ (ex GST)
	<b>Swing Range</b>	
	<b>600 x 600 mm</b>	
WS61050	6RU	406.87
WS91050	9RU	553.84
WS121050	12RU	715.12
WS151050	15RU	801.67
WS181050	18RU	889.41
WS241050	24RU	1031.24
	<b>600 x 550 mm</b>	
WS61045	6RU	402.65
WS91045	9RU	549.28
WS121045	12RU	639.41
WS151045	15RU	734.44
WS181045	18RU	841.34
WS241045	24RU	986.76
	<b>Fixed Range</b>	
	<b>600 x 450 mm</b>	
WF445	4RU	272.62
WF645	6RU	322.31
WF945	9RU	390.62
WF1245	12RU	471.14
WF1545	15RU	542.06
WF1845	18RU	612.99
WF2445	24RU	685.09

## E-Tech 19" standard fully built cabinets




EC45U600800

Cat. No.	Description	TRADE PRICE \$ (ex GST)	Cat. No.	Description	TRADE PRICE \$ (ex GST)
<b>Freestanding cabinets</b>			<b>Freestanding cabinets (continued)</b>		
<b>47U</b>			<b>38U</b>		
EC47U600800	600 x 800 mm	3144.32	EC38U600600	600 x 600 mm	2461.24
EC47U6001000	600 x 1000 mm	3507.25	EC38U600800	600 x 800 mm	2691.08
EC47U6001200	600 x 1200 mm	3799.07	EC38U6001000	600 x 1000 mm	3231.62
EC47U800800	800 x 800 mm	3625.70	EC38U800600	800 x 600 mm	3067.82
EC47U8001000	800 x 1000 mm	4081.75	EC38U800800	800 x 800 mm	3282.23
EC47U8001200	800 x 1200 mm	4453.45	EC38U8001000	800 x 1000 mm	3763.84
<b>45U</b>			<b>33U</b>		
EC45U600600	600 x 600 mm	2765.91	EC33U600600	600 x 600 mm	2345.31
EC45U600800	600 x 800 mm	3010.64	EC33U600800	600 x 800 mm	2520.011
EC45U6001000	600 x 1000 mm	3358.14	EC33U6001000	600 x 1000 mm	3037.72
EC45U6001200	600 x 1200 mm	3664.67	<b>12U</b>		
EC45U800800	800 x 800 mm	3472.91	EC12U600600	600 x 600 mm	1886.51
EC45U8001000	800 x 1000 mm	3909.72	EC12U600800	600 x 800 mm	2024.47
EC45U8001200	800 x 1200 mm	4453.45	EC12U6001000	600 x 1000 mm	2303.14
<b>42U</b>					
EC42U600800	600 x 800 mm	2808.93			
EC42U6001000	600 x 1000 mm	3133.15			
EC42U6001200	600 x 1200 mm	3419.65			
EC42U800800	800 x 800 mm	3240.24			
EC42U8001000	800 x 1000 mm	3647.76			
EC42U8001200	800 x 1200 mm	4201.38			

## E-Tech 19" standard open frames



ECF476001000

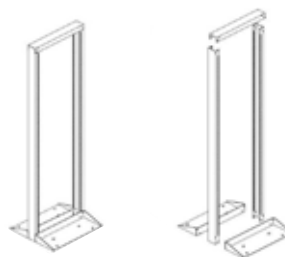

EFSCR45

Cat. No.	Description	TRADE PRICE \$ (ex GST)	Cat. No.	Description	TRADE PRICE \$ (ex GST)
<b>Open Frames</b>			<b>Open frames (continued)</b>		
<b>47U</b>			<b>33U</b>		
ECF47600800	600 x 800 mm	2163.01	ECF33600600	600 x 600 mm	1708.49
ECF476001000	600 x 1000 mm	2438.05	ECF33600800	600 x 800 mm	1776.79
ECF476001200	600 x 1200 mm	2730.63	ECF336001000	600 x 1000 mm	2202.56
ECF47800800	800 x 800 mm	2577.91	<b>24U</b>		
ECF478001000	800 x 1000 mm	2969.42	ECF24600600	600 x 600 mm	1543.48
ECF478001200	800 x 1200 mm	3325.76	ECF24600800	600 x 800 mm	1638.39
<b>45U</b>			ECF246001000	600 x 1000 mm	1920.15
ECF45600600	600 x 600 mm	1892.18	ECF24800600	800 x 600 mm	1881.94
ECF45600800	600 x 800 mm	2071.05	ECF24800800	800 x 800 mm	1989.21
ECF456001000	600 x 1000 mm	2334.41	ECF248001000	800 x 1000 mm	2291.22
ECF456001200	600 x 1200 mm	2614.43	<b>18U</b>		
ECF45800800	800 x 800 mm	2469.27	ECF18600600	600 x 600 mm	1462.18
ECF458001000	800 x 1000 mm	2844.28	ECF18600800	600 x 800 mm	1538.28
ECF458001200	800 x 1200 mm	3184.24	ECF186001000	600 x 1000 mm	1679.08
<b>42U</b>			<b>12U</b>		
ECF42600800	600 x 800 mm	1932.29	ECF12600600	600 x 600 mm	1412.96
ECF426001000	600 x 1000 mm	2178.00	ECF12600800	600 x 800 mm	1468.95
ECF426001200	600 x 1200 mm	2439.37	ECF126001000	600 x 1000 mm	1629.42
ECF42800800	800 x 800 mm	2303.82	<b>Free Standing Open Racks</b>		
ECF428001000	800 x 1000 mm	2653.72	EFSCR45	45U	653.80
ECF428001200	800 x 1200 mm	3184.45	EFSCR38	38U	632.38
<b>38U</b>					
ECF38600600	600 x 600 mm	1809.92			
ECF38600800	600 x 800 mm	1918.07			
ECF386001000	600 x 1000 mm	2301.83			
ECF38800600	800 x 600 mm	2239.59			
ECF38800800	800 x 800 mm	2328.48			
ECF388001000	800 x 1000 mm	2623.78			

## Cabinet accessories



EWF2U200



EWFTB200



ECAFS450760



ECACS1U270



ECA3UMCBD15T

Cat. No.	Description	TRADE PRICE \$ (ex GST)	Cat. No.	Description	TRADE PRICE \$ (ex GST)
<b>Cabinet accessories</b>					
<b>Steel Wall Frame</b>					
EWF2U200	2U x 200 mm deep	49.25	ECAFS450460	1U x 460 mm deep	255.52
EWF2U300	2U x 300 mm deep	53.58	ECAFS450660	1U x 660 mm deep	279.57
EWF4U200	4U x 200 mm deep	73.87	ECAFS450760	1U x 760 mm deep	323.99
EWF4U300	4U x 300 mm deep	79.65	<b>Lockable Drawer</b>		
EWF4U400	4U x 400 mm deep	86.90	ECALSD2U	2U 19" Lockable Storage Drawer	376.83
EWF6U200	6U x 200 mm deep	92.68	<b>Sliding Shelves</b>		
EWF6U300	6U x 300 mm deep	94.13	45kg load capacity		
EWF6U400	6U x 400 mm deep	104.29	ECASS460	1U x 460 mm deep	368.81
<b>Top / Bottom Base</b>					
EWFTB200	200 mm	41.24	ECASS660	1U x 660 mm deep	396.38
EWFTB300	300 mm	44.91	ECASS760	1U x 760 mm deep	451.12
EWFTB400	400 mm	53.58	<b>Cantilever Shelves</b>		
<b>Fixed Shelves</b>					
45kg load capacity					
<b>Power Distribution</b>					
5U Mounting Rack 180 mm deep					
ECA3UMCBDIST	3U 19" MCB Distribution Panel (No CB & Comb Bus Bar Included)	627.01	ECACS1U190	1U x 190 mm deep	51.57
<b>Lockable Drawer</b>					
2U 19" Lockable Storage Drawer					
<b>Sliding Shelves</b>					
45kg load capacity					
<b>Cantilever Shelves</b>					
45kg load capacity					
<b>Power Distribution</b>					
5U Mounting Rack 180 mm deep					
3U 19" MCB Distribution Panel (No CB & Comb Bus Bar Included)					

## Cabinet accessories



ECACML1U100



ECACMB1U100



ECAVJUMPRING100CM



ECT47U300

Cat. No.	Description	TRADE PRICE \$ (ex GST)
<b>Cabinet accessories</b>		
<b>Cable Management</b>		
ECMV38U106	38U Vertical T-Finger CM w/ Covers	460.97
ECMV45U106	45U Vertical T-Finger CM w/ Covers	482.70
ECMV47U106	47U Vertical T-Finger CM w/ Covers	504.15
ECACML1U60	1U 19" 60 mm Loop	57.33
ECACML1U100	1U 19" 100 mm Loop	58.70
ECACMB1U60	1U 19" 60 mm Bar	64.14
ECACMB1U100	1U 19" 100 mm Bar	66.73
ECACMB2U60	2U 19" 60 mm Bar	79.11
ECACMB2U100	2U 19" 100 mm Bar	123.45
ECAVJUMPRING60	1U x 60 mm Jumper Ring	26.32
ECAVJUMPRING60CS	1U x 60 mm Jumper Ring (Centre Slot)	26.32
ECAVJUMPRING100	1U x 100 mm Jumper Ring	28.30
ECAVJUMPRING100CM	1U x 100 mm Jumper Ring (Centre Mount)	27.74
ECACML1U60SINGLE	1U x 60 mm Single Loop	23.54
ECACML1U100SINGLE	1U x 100 mm Single Loop	24.52
ECACM1U16PUL	1U 19" 16 Port Unloaded	82.50

Cat. No.	Description	TRADE PRICE \$ (ex GST)
<b>Vertical Cable Trays</b>		
ECT24U100	24U – 100 mm long	116.91
ECT33U100	33U – 100 mm long	136.84
ECT33U300	33U – 300 mm long	147.35
ECT38U100	38U – 100 mm long	156.75
ECT38U150	38U – 150 mm long	162.21
ECT38U300	38U – 300 mm long	168.03
ECT42U100	42U – 100 mm long	157.30
ECT42U150	42U – 150 mm long	164.52
ECT42U300	42U – 300 mm long	173.30
ECT45U100	45U – 100 mm long	157.88
ECT45U150	45U – 150 mm long	166.78
ECT45U300	45U – 300 mm long	178.56
ECT47U100	47U – 100 mm long	164.91
ECT47U150	47U – 150 mm long	174.15
ECT47U300	47U – 300 mm long	186.27

## Cabinet accessories



BLANK PANELS



CHIMNEYS



ECAPLINTH600600



ECABOLTDOWN600



ECCASTORSET50

Cat. No.	Description	TRADE PRICE \$ (ex GST)	Cat. No.	Description	TRADE PRICE \$ (ex GST)
<b>Cabinet accessories</b> <b>Folded Blank Panels</b>			<b>Fixed Plinths</b>		
ECAFBLANK1U	1U	24.71	ECAPLINTH600600	600 x 600 mm	296.72
ECAFBLANK2U	2U	29.32	ECAPLINTH600800	600 x 800 mm	360.87
ECAFBLANK3U	3U	38.24	ECAPLINTH600900	600 x 900 mm	392.95
ECAFBLANK4U	4U	53.58	ECAPLINTH6001000	600 x 1000 mm	441.06
ECAFBLANK5U	5U	65.06	ECAPLINTH800800	800 x 800 mm	441.06
<b>Baying Kits</b>			ECAPLINTH800900	800 x 900 mm	473.14
ECAJOINERKIT	Four Joiner Clamps & Top Joiner Plate Pair	186.19	ECAPLINTH8001000	800 x 1000 mm	504.66
ECAJOINERPLATE	Top Joiner Plates Pair	36.49	<b>Aluminium Bolt Down Kits (pair)</b>		
<b>Cooling Fans</b>			ECABOLTDOWN600	600 mm long	200.55
ECATP2FAN	2 Fan Top Panel with Thermostat	482.49	ECABOLTDOWN800	800 mm long	230.24
ECATP4FAN	4 Fan Top Panel with Thermostat	617.48	ECABOLTDOWN900	900 mm long	259.97
<b>Chimneys – 2 Part Retrofit, Cable Cover</b>			ECABOLTDOWN1000	1000 mm long	289.67
ECACHIMNEY430	E-TEC Chimney 430 mm	266.51	ECABOLTDOWN1200	1200 mm long	347.61
ECACHIMNEY650	E-TEC Chimney 650 mm	297.86	<b>Castor Wheels</b>		
ECACHIMNEY900	E-TEC Chimney 900 mm	335.10	ECCASTORSET50	Castor Set (4 Castors) Max Load 50-60kgs	69.52
			ECCASTORSET100	Castor Set (4 Castors) Max Load 70-100kgs	170.19

# ETL standard cabinet

## Lockable steel side panels



ESP45U800


Cat. No.	Description	TRADE PRICE \$ (ex GST)
<b>Side panels</b>		
<b>For 600 mm Deep Cabinets</b>		
ESP45U600	45U	277.76
ESP38U600	38U	226.84
ESP33U600	33U	219.04
ESP24U600	24U	190.59
ESP18U600	18U	255.15
ESP12U600	12U	217.28
<b>For 800 mm Deep Cabinets</b>		
ESP47U800	47U	355.19
ESP45U800	45U	340.08
ESP42U800	42U	317.30
ESP38U800	38U	314.72
ESP33U800	33U	292.66
ESP24U800	24U	240.96
ESP18U800	18U	306.17
ESP12U800	12U	274.39
<b>For 1000 mm Deep Cabinets</b>		
ESP47U1000	47U	442.81
ESP45U1000	45U	423.98
ESP42U1000	42U	395.58
ESP38U1000	38U	457.92
ESP33U1000	33U	401.26
ESP24U1000	24U	317.91
ESP18U1000	18U	382.06
ESP12U1000	12U	366.56
<b>For 1200 mm Deep Cabinets</b>		
ESP47U1200	47U	478.22
ESP45U1200	45U	474.60
ESP42U1200	42U	443.05

# ETL standard cabinet

## cabinet doors



EDS38U600

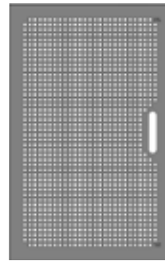

EDPN18U600

Cat. No.	Cabinet Height	Cabinet Depth (mm)	TRADE PRICE \$ (ex GST)	Cat. No.	Cabinet Height	Cabinet Depth (mm)	TRADE PRICE \$ (ex GST)
<b>Cabinet doors</b>				<b>Square Punched Steel Door</b>			
<b>Perspex Doors</b>				<b>Square Punched Steel Double Door Set</b>			
EDP47U600	47U	600	595.16	EDPN47U600	47U	600	559.88
EDP45U600	45U	600	569.85	EDPN45U600	45U	600	536.09
EDP42U600	42U	600	531.67	EDPN42U600	42U	600	500.17
EDP38U600	38U	600	439.16	EDPN38U600	38U	600	412.82
EDP33U600	33U	600	417.78	EDPN33U600	33U	600	392.72
EDP24U600	24U	600	352.40	EDPN24U600	24U	600	331.25
EDP18U600	18U	600	317.23	EDPN18U600	18U	600	298.18
EDP12U600	12U	600	276.62	EDPN12U600	12U	600	260.02
EDP47U800	47U	800	690.15	EDPN47U800	47U	800	681.20
EDP45U800	45U	800	661.05	EDPN45U800	45U	800	652.51
EDP42U800	42U	800	616.77	EDPN42U800	42U	800	608.79
EDP38U800	38U	800	601.86	EDPN38U800	38U	800	565.74
EDP24U800	24U	800	433.81	EDPN24U800	24U	800	407.80
<b>Steel Doors</b>							
EDS47U600	47U	600	428.52	EDPN47U600-L/R	47U	600	947.88
EDS45U600	45U	600	410.31	EDPN45U600-L/R	45U	600	907.44
EDS42U600	42U	600	382.81	EDPN42U600-L/R	42U	600	846.78
EDS38U600	38U	600	349.90	EDPN38U600-L/R	38U	600	698.89
EDS33U600	33U	600	344.19	EDPN33U600-L/R	33U	600	664.89
EDS24U600	24U	600	292.56	EDPN24U600-L/R	24U	600	560.85
EDS18U600	18U	600	240.85	EDPN18U600-L/R	18U	600	504.84
EDS12U600	12U	600	216.21	EDPN12U600-L/R	12U	600	440.20
EDS47U800	47U	800	517.11	EDPN47U800-L/R	47U	800	1153.30
EDS45U800	45U	800	495.31	EDPN45U800-L/R	45U	800	1063.59
EDS42U800	42U	800	462.13	EDPN42U800-L/R	42U	800	1030.67
EDS38U800	38U	800	509.57	EDPN38U800-L/R	38U	800	957.79
EDS24U800	24U	800	335.82	EDPN24U800-L/R	24U	800	690.38

# Home networking enclosures

## Signet is the Best Choice

- BEST** range of solutions
- BEST** and simplest installation features
- BEST** pricing for enclosures and networking components
- Recessed or Surface mounted
- Preferred supplier to CHORUS


Made in New Zealand for New Zealand homes.  
**Signet – Supplying Home Networking Solutions Since 2001**



## Enclosure range

### ST1000 series

Designed for small home installations such as Apartments, Retirement Units. Also ideal as Auxiliary or secondary enclosure for RF, CCTV, Security, Power supply or Fibre termination. Recessed or Surface Mount options.  
355 x 275 x 90 mm  
Fits exactly between 400 mm Centre Studs

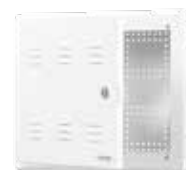

ST1010

### ST1500 series

Recessed or Surface Mount options.  
ST1510 355 x 425 x 90 mm



ST2010

### ST2000 series

The home networking standard before Fibre to the Home. ST2000 is still the best for copper serviced homes and can be suitable for Fibre in smaller homes and apartments. Recessed or Surface Mount options.  
355 x 575 x 90 mm  
Fits exactly between 400 mm Centre Studs



ST3010

### ST3000 series

To suit every need whether copper or fibre to the home. Hinged, lockable and latched door. Separate door assembly and enclosure. Comprehensive holes matrix for complete flexibility. Up to 4 x 230V surface sockets (ST192)  
Fits exactly between 400 mm centre studs

# Home networking enclosures



Cat. No.	Description	Cut-Out Size W X H X D (mm)	TRADE PRICE \$ (ex GST)
<b>Home networking enclosures</b>			
<b>Ezydata PLUS</b>			
EZD2	Size 2	355 x 275 x 90	101.26
EZD4	Size 4	355 x 425 x 90	117.93
EZD6	Size 6	355 x 575 x 90	139.73
EZD8	Size 8	355 x 725 x 90	171.77
EZD10	Size 10	355 x 950 x 90	219.19
<b>Jumbo data enclosures</b>			
JEZDV12	Jumbo Data Enclosure and Door	500 x 1175 x 90	432.06
<b>Surface mount kits</b>			
EZSM2	Fits EZD2		79.41
EZSM4	Fits EZD4		93.69
EZSM6	Fits EZD6		101.84
EZSM8	Fits EZD8		114.05
EZSM10	Fits EZD10		145.54

Cat. No.	Description	Cut-Out Size W X H X D (mm)	TRADE PRICE \$ (ex GST)
<b>Home networking enclosures (continued)</b>			
All enclosures include: Unique plastic knockouts at the top for cable way, Comprehensive Holes matrix, Separate door assembly, 'Push out Tabs' or Flange for locating enclosure on studwork – allowing the door assembly to mount neatly over the Gib and, Standard cutouts for mounting surface 230v socket PDL570s (ST192)			
<b>ST Series with Home Hub included</b>			
ST1000	ST1000 Series Home Net Centre inc. ST2208 Voice / Data Hub	355 x 275 x 90	175.95
ST1510	ST1510 Series Home Net Centre	355 x 425 x 90	139.73
ST2000	ST2000 Series Home Net Centre inc. ST25 NETBOX1	355 x 575 x 90	351.63
<b>ST series – Enclosure only</b>			
ST1010	ST1000 Series Enclosure and Door ONLY	355 x 275 x 90	123.72
ST2010	ST2000 Series Enclosure and Door ONLY	355 x 575 x 90	170.70
ST3010	ST3000 Series Enclosure and Door ONLY	355 x 725 x 90	203.58
ST3020	ST3020 Series Enclosure and Door ONLY	355 x 950 x 90	235.52
<b>ST series – Enclosure shallow</b>			
75mm deep, ideal for installing in steel framing			
ST2010S	ST2010 Series Enclosure and Door ONLY Shallow	355 x 575 x 75	170.70
ST3010S	ST3000 Series Enclosure and Door ONLY Shallow	355 x 725 x 75	203.62

## Slimline data enclosure



STSL6



STSL8

Cat. No.	Description	Cover Size W X H (mm)	Cut-Out Size W X H X D (mm)	TRADE PRICE \$ (ex GST)	Cat. No.	Description	TRADE PRICE \$ (ex GST)
<b>Slimline data enclosures</b>					<b>Replacement doors</b>		
<b>Slimline Enclosure – Steel Lid</b>					Replacement doors comes with latches		
STSL2	Size 2	375 x 295	355 x 275 x 90	95.55	<b>Replacement door Ezydata PLUS</b>		
STSL4	Size 4	375 x 445	355 x 425 x 90	109.02	EZ2DR	Fits EZD2	37.02
STSL6	Size 6	375 x 595	355 x 575 x 90	121.14	EZ4DR	Fits EZD4	36.78
STSL8	Size 8	375 x 745	355 x 725 x 90	148.06	EZ6DR	Fits EZD6	48.34
STSL10	Size 10	375 x 970	355 x 950 x 90	195.16	EZ8DR	Fits EZD8	50.66
<b>Slimline Enclosure – Plastic Lid</b>					EZ10DR	Fits EZD10	67.68
STSL2P	Size 2	375 x 295	355 x 275 x 90	104.76	<b>Replacement Door ST series – Front vented</b>		
STSL4P	Size 4	375 x 445	355 x 425 x 90	140.01	Supplied with key lock		
STSL6P	Size 6	375 x 595	355 x 575 x 90	151.43	ST2DV	Fits ST1010	42.80
STSL8P	Size 8	375 x 745	355 x 725 x 90	191.31	ST4DV	Fits ST1510	56.11
STSL10P	Size 10	375 x 970	355 x 950 x 90	240.62	ST6DV	Fits ST2010	53.79
					ST8DV	Fits ST3010	56.11
					ST10DV	Fits ST3020	67.68

## Patch panels

Patch panels, voice modules

## Home networking accessories

Patch leads, TV/video, Netboxes




ST1024C6H



ST2206



 STPPB8W



STPPB12W



ST006RDPK8



ST052U

Cat. No.	Description	TRADE PRICE \$ (ex GST)	Cat. No.	Description	TRADE PRICE \$ (ex GST)
<p><b>Home network accessories</b></p> <p><b>Data Patch Panels</b></p>			<p><b>Home network accessories (continued)</b></p> <p><b>Accessories</b></p>		
ST1008C6	Cat6 RJ45 Patch panel, 8port	67.98	ST192	PDL 570S 230v Power socket, Square	33.26
ST1012C6H	Cat6 Loaded Patch Panel, 12port, c/w: ST2012PPB for Home Net	105.02	ST2012PPB	Patch Panel Bracket (Pair)	17.52
ST1016C6H	Cat6 Loaded Patch panel, 16port, c/w: ST2012PPB for Home Net	113.69	<b>Patch Leads</b>		
ST1016H	Cat5e Loaded Patch panel, 16port, c/w: ST2012PPB for Home Net	105.02	ST002BK03	RJ12 to RJ45 Lead, 300 mm Black	2.80
ST1024C6H	Cat6 Loaded Patch panel, 24port, c/w: ST2012PPB for Home Net	157.54	ST003WH01	Cat3 White RJ45 Flat-Lead 100 mm to suit ST2208 Phone/Data Module	0.88
ST2012PPB	Patch Panel Bracket (Pair)	17.52	ST006RD02PK	Cat6 Red RJ45 Lead pack, 200 mm x 4, #568A spec	13.13
STPPB8W	8 Port Unloaded Patch Panel	27.83	ST006RD03PK	Cat6 Red RJ45 Lead pack, 300 mm x 4, #568A spec	14.01
STPPB12W	12 Port Unloaded Patch Panel	27.83	ST006RD05PK	Cat6 Red RJ45 Lead pack, 500 mm x 4, #568A spec	15.75
<b>Voice Modules</b>			ST006RDPK8	Cat6 Red Patch Lead Pack (4 x 200 mm + 4 x 300 mm) #568A spec	22.77
ST2206	Voice hub for xDSL/Copper, RJ45, 2-line, with DSL mount	70.01	<b>TV / Video</b>		
ST2208	8port "All-in-one" Voice / Data / DSL connect module	61.25	ST052U	RG6 Universal Compression Crimp Sky Approved (Bag x 50)	1.57
			ST23BRKT2	ST23DDM8 Mounting bracket	24.49
			<b>Netboxes</b>		
			ST25NETBOX1	Comes with ST2206, ST2208, ST1008, ST192 & ST006RDPK8 (Patch Leads 4 x 200 mm & 4 x 300 mm) For Copper	160.59
			ST25NETBOX1F	Comes with ST2210, ST2208, ST1008, ST192 & ST006RDPK8, ST002BK03 (Patch Leads 4 x 200 mm & 4 x 300 mm) For Copper	160.59

## Data accessories

### RJ45 adapters, Splitters and patch panels

## Telecommunication accessories

### Connectors, Splitters, Distribution boxes and Hanlong Tools



Cat. No.	Description	TRADE PRICE \$ (ex GST)
<b>Data &amp; Telecom accessories</b>		
<b>RJ45 Jacks, Adapters &amp; Joiners</b>		
ST060WH	In-Line Junction Box Cat5e, IDC, White	7.89
ST065WH1	Single Cat5e Surface Mount Box	7.89
ST062WH	RJ45 Cat5e, In-line Coupler, Wh	6.99
<b>RJ45 Splitters</b>		
ST071	RJ45 Splitter for Data / Data	9.62
ST072	RJ45 Splitter for Voice / Voice	9.62
ST073	RJ45 Splitter for Data / Voice	9.62
ST074	RJ45 Splitter – Bridged 8 Pin	9.62
ST076	RJ45 Splitter – 4Way 'Bridged'	17.52
<b>Patch Panels</b>		
ST1016C6	Cat6 Loaded Patch panel, 16 port	87.53
ST1024C6	Cat6 Loaded Patch Panel, 24port	140.04

Cat. No.	Description	TRADE PRICE \$ (ex GST)
<b>Data &amp; Telecom accessories (continued)</b>		
<b>Leads</b>		
ST002BK03	RJ12 to RJ45 Lead, 300 mm Black	2.80
ST003WH01	Cat3 White RJ45 Flat-Lead 100 mm to suit ST2208 Phone/Data Module	0.88
<b>Connectors</b>		
ST040	UY connector (2wire) per 100	14.01
ST041	UR2 connector (3wire) per 100	19.83
<b>Splitters &amp; Adapters</b>		
ST072	RJ45 Splitter for Voice / Voice	9.62
ST080	RJ45 to BT Master Adaptor, White	4.37
ST084	RJ45 to BT Master Adaptor, Flush Style	6.13
<b>Distribution Boxes &amp; Disconnect Modules</b>		
STDBOX100	Distribution Box, Indoor, 100 Pr	43.76
STDBOX30	Distribution Box, Indoor, 30 Pr	12.26
STDBOX50	Distribution Box, Indoor, 50 Pr	31.51
STDISC10	Disconnect Module, 10pr, 1.25mu	4.99
<b>Data, Comms &amp; AV Tools</b>		
STT2008AR	Hanlong Professional Modular Crimper, Ratchet inc. Stripper	144.45
STT323	Hanlong Stripper, RG58, 59, 6, 7, 11 – 2 Blade	21.26
<b>Data, Comms &amp; AV Tools (cont.)</b>		
STTPRST	Promo Punch-down Tool, 110, inc. stripper	5.10

## ECO DB Econoboard



E36W100A



E60W100A



EM36W100A

Cat. No.	Description	Door Size W X H (mm)	Cut-Out Size W X H X D (mm)	TRADE PRICE \$ (ex GST)
<b>Distribution Boards</b>				
<b>ECO DB</b>				
E36W100A	DB 36 Way 100A	450 x 900	450 x 900 x 140	941.39
E60W100A	DB 60 Way 100A	450 x 900	450 x 900 x 140	1306.50
<b>ECO DB + metering</b>				
EM36W100A	DB + M 36 Way 100A	750 x 750	750 x 750 x 140	1381.87

## G200 distribution boards

### Meter and distribution 63A - 100A



G 212 M 63

Legrand DX<sup>3</sup> 3 pole main switch  
60 way chassis  
60 way neutral and earth busbar  
Powder coated 1.2 mm metal work.  
Colour RAL9003 white  
1200 mm (H) x 600 mm (W) x 235 mm (D)  
Available with key lock – optional accessory  
Standards AS/NZS 61439



G 212 MC 63

Legrand DX<sup>3</sup> 3 pole main switch  
60 way chassis  
60 way neutral and earth busbar  
Powder coated 1.2 mm metal work.  
Colour RAL9003 white  
1200 mm (H) x 900 mm (W) x 235 mm (D)  
Available with key lock – optional accessory  
Standards AS/NZS 61439

Pack	Cat. No.	Description
		<b>Meter and distribution 63A</b>
		63A 3 Phase Fitted with a Legrand 63A main switch Chassis 60 way
1	G 212 M 63	Distribution on top Metering on bottom
1	G 212 M 63-B	Distribution on bottom Metering on top
		<b>Meter and distribution 100A</b>
		100A 3 Phase Fitted with a Legrand 100A main switch Chassis 60 way
1	G 212 M 100	Distribution on top Metering on bottom
1	G 212 M 100-B	Distribution on bottom Metering on top

Pack	Cat. No.	Description
		<b>Meter, distribution and cableway 63A</b>
		63A 3 Phase Fitted with a Legrand 63A main switch Chassis 60 way
1	G 212 MC 63	Distribution on top Metering on bottom Cableway on right
1	G 212 MC 63-B	Distribution on top Metering on bottom Cableway on left
		<b>Meter, distribution and cableway 100A</b>
		100A 3 Phase Fitted with a Legrand 100A main switch Chassis 60 way
1	G 212 MC 100	Distribution on top Metering on bottom Cableway on right
1	G 212 MC 100-B	Distribution on top Metering on bottom Cableway on left

## G200 distribution boards

### Meter, distribution and cableway 160A – 200A



G 215 MCD 160

Legrand DPX 3 pole main switch  
Distribution chassis  
Neutral and earth busbar  
Powder coated 1.2 mm metal work.  
Colour RAL9003 white  
1500 mm (H) x 1350 mm (W) x 235 mm (D)  
Available with key lock – optional accessory  
Standards AS/NZS 61439



G 212 DC 100

Legrand 3 pole main switch  
60 way chassis  
60 way neutral and earth busbar  
6 way neutral and earth stud bar  
Powder coated 1.2 mm metal work.  
Colour RAL9003 white  
1200 mm (H) x 900 mm (W) x 235 mm (D)  
Available with key lock – optional accessory  
Standards AS/NZS 61439

Pack	Cat. No.	Description
		<b>Meter, distribution and cableway 160A</b>
1	G 215 MC 160	160A 3 Phase Fitted with a Legrand 160A main switch 60 way distribution 60 way neutral and earth busbar Distribution on right Metering on left
1	G 215 MCD 160	120 way distribution 120 way neutral and earth busbar 6 way stud bar Distribution on right Metering on left
		<b>Meter, distribution and cableway 200A</b>
1	G 215 MC 200	200A 3 Phase Fitted with a Legrand 250A main switch 60 way distribution 60 way neutral and earth busbar Distribution on right Metering on left
1	G 215 MCD 200	120 way distribution 120 way neutral and earth busbar Distribution on right 6 way stud bar Metering on left

Pack	Cat. No.	Description
		<b>Distribution and cableway 100A</b>
1	G 212 DC 100	100A 3 Phase Fitted with a Legrand DX <sup>3</sup> 100A main switch Chassis 60 way Distribution on left Cableway on right
1	G 212 DC 100-B	Distribution on right Cableway on left
		<b>Distribution and cableway 200A</b>
1	G 212 DC 200	200A 3 Phase Fitted with a Legrand DPX 250A main switch Chassis 60 way Distribution on left Cableway on right
1	G 212 DC 200-B	Distribution on right Cableway on left

## G200 distribution boards

### Distribution and cableway 250A



G 215 DC 250

Legrand Vistop 3 pole main switch  
60 way chassis  
60 way neutral and earth busbar  
6 way neutral and earth stud bar  
Powder coated 1.2 mm metal work.  
Colour RAL9003 white  
1500 mm (H) x 900 mm (W) x 235 mm (D)  
Available with key lock – optional accessory  
Standards AS/NZS 61439

## G200 distribution boards

### Distribution and cableway with apartment metering 200A



G 215 DC 200-M

Legrand Vistop 3 pole main switch  
24 way chassis  
12 way neutral and earth busbar  
6 way neutral and earth stud bar  
9 way neutral and earth stud bar  
Powder coated 1.2 mm metal work.  
Colour RAL9003 white  
1500 mm (H) x 1650 mm (W) x 235 mm (D)  
Available with key lock – optional accessory  
Standards AS/NZS 61439

Pack	Cat. No.	Description
		<b>Distribution and cableway 250A</b>
		250A 3 Phase Fitted with a Legrand 250A main switch Chassis 60 way
1	G 215 DC 250	Distribution on left Cableway on right
1	G 215 DC 250-B	Distribution on right Cableway on left

Pack	Cat. No.	Description
		<b>Distribution, cableway with apartment metering 200A</b>
1	G 215 DC 200-M	200A 3 Phase Fitted with a Legrand 200A main switch Chassis 24 way

## Econoboard Assembled

### Distribution board commercial



EF450/900S



EH750/750S

Cat. No.	Description	Panels W x H (mm)	TRADE PRICE \$ (ex GST)	Cat. No.	Description	Panels W x H (mm)	TRADE PRICE \$ (ex GST)
	<b>MCB cabinet shallow – surface mount</b>				<b>MCB cabinet shallow – surface mount</b>		
	For Cabinets fitted with MCB Chassis, replace XX with the chassis type: MS (for Schneider and Chint) or VS (for Vynco, NHP Mod6 and ABB) or HS (for Legrand, Hager, Eaton, GE red line)				For Cabinets fitted with MCB Chassis, replace XX with the chassis type: MS (for Schneider and Chint) or VS (for Vynco, NHP Mod6 and ABB) or HS (for Legrand, Hager, Eaton, GE red line)		
	<b>Empty Cabinet</b>				<b>160A Isolator – fitted with MCB Chassis</b>		
	135mm deep cabinets				135mm deep cabinets		
EF450/600S	Cabinet Fixed Cover	450 x 600	348.97	E4TM160S-XX	Chassis 4TP (12SP)	450 x 600	1554.60
EF450/900S	Cabinet Fixed Cover	450 x 900	425.35	E8TM160S-XX	Chassis 8TP (24SP)	450 x 600	1658.83
EH450/600S	Cabinet Hinged Door	450 x 600	348.97	E12TM160S-XX	Chassis 12TP (36SP)	450 x 900	1937.44
EH450/900S	Cabinet Hinged Door	450 x 900	425.35	E16TM160S-XX	Chassis 16TP (48SP)	450 x 900	2139.43
EH750/750S	Cabinet Hinged Door	750 x 750	711.00	E20TM160S-XX	Chassis 20TP (60SP)	450 x 900	2373.40
	<b>No Isolator – fitted with MCB Chassis</b>				<b>250A Isolator – fitted with MCB Chassis</b>		
E4TMS-XX	Chassis 4TP (12SP)	450 x 600	1016.57	E4TM250S-XX	Chassis 4TP (12SP)	450 x 600	1824.72
E8TMS-XX	Chassis 8TP (24SP)	450 x 600	1139.91	E8TM250S-XX	Chassis 8TP (24SP)	450 x 900	2028.83
E12TMS-XX	Chassis 12TP (36SP)	450 x 600	1276.02	E12TM250S-XX	Chassis 12TP (36SP)	450 x 900	2201.14
E16TMS-XX	Chassis 16TP (48SP)	450 x 900	1516.35	E16TM250S-XX	Chassis 16TP (48SP)	450 x 900	2403.19
E20TMS-XX	Chassis 20TP (60SP)	450 x 900	1846.00	E20TM250S-XX	Chassis 20TP (60SP)	450 x 900	2639.24
E24TMS-XX	Chassis 24TP (72SP)	450 x 900	2088.43		<b>Meter Cabinet, 100A Isolator, 3 Phase</b>		
E4TM100S-XX	Chassis 4TP (12SP)	450 x 600	1210.08	EMD12TP100S-XX	Meter DOL, 100A, 12T	750 x 750	2157.15
E8TM100S-XX	Chassis 8TP (24SP)	450 x 600	1339.81				
E12TM100S-XX	Chassis 12TP (36SP)	450 x 600	1469.56				
E16TM100S-XX	Chassis 16TP (48SP)	450 x 900	1786.44				
E20TM100S-XX	Chassis 20TP (60SP)	450 x 900	2039.52				
E24TM100S-XX	Chassis 24TP (72SP)	450 x 900	2281.95				

# Econoboard Assembled

## Distribution board commercial



E12TM100D-XX




EMD12TP100D-XX

Cat. No.	Description	Size W x H (mm)	TRADE PRICE \$ (ex GST)
	<b>MCB cabinet deep – surface mount</b> For Cabinets fitted with MCB Chassis, replace XX with the chassis type: MS (for Schneider and Chint) or VS (for Vynco, NHP Mod6 and ABB) or HS (for Legrand, Hager, Eaton, GE red line)		
	<b>Empty Cabinet</b> 235mm deep cabinets		
EF450/600D	Cabinet Fixed Cover	450 x 600	372.17
EF450/900D	Cabinet Fixed Cover	450 x 900	457.25
EH450/600D	Cabinet Hinged Door	450 x 600	372.17
EH450/900D	Cabinet Hinged Door	450 x 900	457.25
EH750/750D	Cabinet Hinged Door	750 x 750	883.57
	<b>No Isolator – fitted with MCB Chassis</b>		
E4TMD-XX	Chassis 4TP (12SP)	450 x 600	1199.43
E8TMD-XX	Chassis 8TP (24SP)	450 x 600	1331.35
E12TMD-XX	Chassis 12TP (36SP)	450 x 600	1529.10
E16TMD-XX	Chassis 16TP (48SP)	450 x 900	1758.79
E20TMD-XX	Chassis 20TP (60SP)	450 x 900	2126.72
E24TMD-XX	Chassis 24TP (72SP)	450 x 900	2388.30
	<b>100A Isolator – fitted with MCB Chassis</b>		
E4TM100D-XX	Chassis 4TP (12SP)	450 x 600	1386.63
E8TM100D-XX	Chassis 8TP (24SP)	450 x 600	1520.49
E12TM100D-XX	Chassis 12TP (36SP)	450 x 600	1716.26
E16TM100D-XX	Chassis 16TP (48SP)	450 x 900	2028.83
E20TM100D-XX	Chassis 20TP (60SP)	450 x 900	2313.08
E24TM100D-XX	Chassis 24TP (72SP)	450 x 900	2577.50


Cat. No.	Description	Size W x H (mm)	TRADE PRICE \$ (ex GST)
	<b>MCB cabinet deep – surface mount</b> For Cabinets fitted with MCB Chassis, replace XX with the chassis type: MS (for Schneider and Chint) or VS (for Vynco, NHP Mod6 and ABB) or HS (for Legrand, Hager, Eaton, GE red line)		
	<b>160A Isolator – fitted with MCB Chassis</b> 235mm deep cabinets		
E4TM160D-XX	Chassis 4TP (12SP)	450 x 600	1848.11
E8TM160D-XX	Chassis 8TP (24SP)	450 x 600	1979.96
E12TM160D-XX	Chassis 12TP (36SP)	450 x 900	2260.70
E16TM160D-XX	Chassis 16TP (48SP)	450 x 900	2490.39
E20TM160D-XX	Chassis 20TP (60SP)	450 x 900	2832.78
	<b>250A Isolator – fitted with MCB Chassis</b>		
E4TM250D-XX	Chassis 4TP (12SP)	450 x 600	2135.21
E8TM250D-XX	Chassis 8TP (24SP)	450 x 900	2352.17
E12TM250D-XX	Chassis 12TP (36SP)	450 x 900	2549.93
E16TM250D-XX	Chassis 16TP (48SP)	450 x 900	2777.95
E20TM250D-XX	Chassis 20TP (60SP)	450 x 900	3122.03
	<b>Meter Cabinet, 100A Isolator, 3 Phase</b>		
EMD12TP100D-XX	Meter DOL, 100A, 12TP	750 x 750	2329.71
EMD16TP100D-XX	Meter DOL, 100A, 16TP	750 x 750	2467.77

## G200 Assembled


### Distribution board commercial

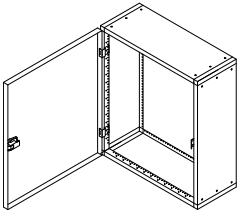


CH450/450D

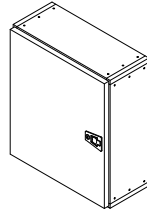

CH450/450D

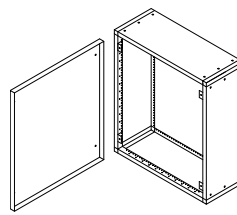

CF450/450D

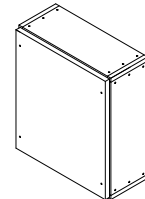


CF450/450D

Cat. No.	Description	Size W x H (mm)	TRADE PRICE \$ (ex GST)
<b>Cabinets – Hinged door</b>			
Cabinet 235 mm deep. Hinged door. Blank cabinets: Add – 0000 at the end of code Cabinets with gland plates Top and Bottom: add – 3030 at the end of code			
<b>Cabinet – 300 mm wide</b>			
CH300/300D	300 mm high	300 x 300	456.24
CH300/450D	450 mm high	300 x 450	492.75
CH300/600D	600 mm high	300 x 600	531.56
CH300/750D	750 mm high	300 x 750	645.59
CH300/900D	900 mm high	300 x 900	686.67
<b>Cabinet – 450 mm wide</b>			
CH450/300D	300 mm high	450 x 300	492.75
CH450/450D	450 mm high	450 x 450	542.94
CH450/600D	600 mm high	450 x 600	584.00
CH450/750D	750 mm high	450 x 750	729.98
CH450/900D	900 mm high	450 x 900	791.63
<b>Cabinet – 600 mm wide</b>			
CH600/300D	300 mm high	600 x 300	516.07
CH600/450D	450 mm high	600 x 450	567.00
CH600/600D	600 mm high	600 x 600	638.77
CH600/750D	750 mm high	600 x 750	777.39
CH600/900D	900 mm high	600 x 900	848.62
<b>Cabinet – 750 mm wide</b>			
CH750/300D	300 mm high	750 x 300	626.80
CH750/450D	450 mm high	750 x 450	708.74
CH750/600D	600 mm high	750 x 600	777.39
CH750/750D	750 mm high	750 x 750	883.94
CH750/900D	900 mm high	750 x 900	1053.95


Cat. No.	Description	Size W x H (mm)	TRADE PRICE \$ (ex GST)
<b>Cabinets – Fixed door</b>			
Cabinets 235mm deep. Fixed door. Blank cabinets: Add – 0000 at the end of code Cabinets with gland plates Top and Bottom: add – 3030 at the end of code			
<b>Cabinet – 300 mm wide</b>			
CF300/300D	300 mm high	300 x 300	441.26
CF300/450D	450 mm high	300 x 450	469.93
CF300/600D	600 mm high	300 x 600	441.26
CF300/750D	750 mm high	300 x 750	563.49
CF300/900D	900 mm high	300 x 900	656.06
<b>Cabinet – 450 mm wide</b>			
CF450/300D	300 mm high	450 x 300	492.75
CF450/450D	450 mm high	450 x 450	520.11
CF450/600D	600 mm high	450 x 600	563.46
CF450/750D	750 mm high	450 x 750	615.61
CF450/900D	900 mm high	450 x 900	656.06
<b>Cabinet – 600 mm wide</b>			
CF600/300D	300 mm high	600 x 300	471.32
CF600/450D	450 mm high	600 x 450	522.04
CF600/600D	600 mm high	600 x 600	326.21
CF600/750D	750 mm high	600 x 750	655.18

## G400 CKD parts

 
### Side channels & corners




SCB600D

 

SCS600S

 

SCB600E

 

SCS600E

Cat. No.	Description	TRADE PRICE \$ (ex GST)	Cat. No.	Description	TRADE PRICE \$ (ex GST)
<b>Side channels &amp; corners</b>			<b>Side channels &amp; corners</b>		
<b>Plain – 220 mm deep</b>			<b>Plain – 420 mm extra deep</b>		
SCB300D	300 mm long	41.75	SCB300E	300 mm long	62.63
SCB450D	450 mm long	53.11	SCB450E	450 mm long	79.67
SCB600D	600 mm long	61.91	SCB600E	600 mm long	92.85
SCB750D	750 mm long	84.11	SCB750E	750 mm long	126.20
SCB900D	900 mm long	90.08	SCB900E	900 mm long	135.12
SCB1200D	1200 mm long	123.56	SCB1200E	1200 mm long	185.34
SCB1500D	1500 mm long	149.54	SCB1500E	1500 mm long	224.29
SCB1800D	1800 mm long	171.76	SCB1800E	1800 mm long	257.65
SCB2100D	2100 mm long	204.00	SCB2100E	2100 mm long	306.02
<b>Slotted – 220 mm deep</b>			<b>Slotted side channel – 420 mm extra deep</b>		
SCS300D	300 mm long	46.51	SCS300E	300 mm long	69.78
SCS450D	450 mm long	57.80	SCS450E	450 mm long	86.71
SCS600D	600 mm long	66.71	SCS600E	600 mm long	100.06
SCS750D	750 mm long	89.14	SCS750E	750 mm long	133.72
SCS900D	900 mm long	95.25	SCS900E	900 mm long	142.86
SCS1200D	1200 mm long	129.52	SCS1200E	1200 mm long	194.28
SCS1500D	1500 mm long	155.38	SCS1500E	1500 mm long	233.08
SCS1800D	1800 mm long	177.72	SCS1800E	1800 mm long	266.58
SCS2100D	2100 mm long	210.71	SCS2100E	2100 mm long	316.04
<b>Corners</b>			<b>Corners</b>		
CNR210D	Corner 210 mm deep – Metal	6.42	CNR420E	Corner 420 mm extra deep – Metal	17.17
CNRP210D	Corner 210 mm deep – Plastic	3.21	CNRP420E	Corner 420 mm extra deep – Plastic	3.42

## G200 CKD parts

### Back plates



BP300/450



BP450/750



BP600/600



BP750/1500

Cat. No.	Description	Size W x H (mm)	TRADE PRICE \$ (ex GST)	Cat. No.	Description	Size W x H (mm)	TRADE PRICE \$ (ex GST)
<b>Back Plates 300 mm wide</b>				<b>Back Plates 600 mm wide</b>			
BP300/300	300 mm high	300 x 300	32.33	BP600/600	600 mm high	600 x 600	85.82
BP300/450	450 mm high	300 x 450	42.18	BP600/750	750 mm high	600 x 750	131.02
BP300/600	600 mm high	300 x 600	49.99	BP600/900	900 mm high	600 x 900	135.00
BP300/750	750 mm high	300 x 750	67.04	BP600/1200	1200 mm high	600 x 1200	208.71
BP300/900	900 mm high	300 x 900	75.10	BP600/1500	1500 mm high	600 x 1500	249.23
BP300/1200	1200 mm high	300 x 1200	129.86	BP600/1800	1800 mm high	600 x 1800	289.86
BP300/1500	1500 mm high	300 x 1500	159.65	BP600/2100	2100 mm high	600 x 2100	322.14
BP300/1800	1800 mm high	300 x 1800	189.55	<b>750 mm wide</b>			
BP300/2100	2100 mm high	300 x 2100	238.68	BP750/750	750 mm high	750 x 750	211.16
<b>450 mm wide</b>				BP750/900	900 mm high	750 x 900	240.13
BP450/450	450 mm high	450 x 450	59.01	BP750/1200	1200 mm high	750 x 1200	318.61
BP450/600	600 mm high	450 x 600	70.20	BP750/1500	1500 mm high	750 x 1500	373.62
BP450/750	750 mm high	450 x 750	107.91	BP750/1800	1800 mm high	750 x 1800	428.51
BP450/900	900 mm high	450 x 900	122.98	BP750/2100	2100 mm high	750 x 2100	484.04
BP450/1200	1200 mm high	450 x 1200	187.32				
BP450/1500	1500 mm high	450 x 1500	222.49				
BP450/1800	1800 mm high	450 x 1800	257.64				
BP450/2100	2100 mm high	450 x 2100	300.44				

## G200 & G400 CKD parts

### Fixed covers



FC300/750



FC600/900



HD300/300

Cat. No.	Description	Size W x H (mm)	TRADE PRICE \$ (ex GST)	Cat. No.	Description	Size W x H (mm)	TRADE PRICE \$ (ex GST)
<b>Fixed Covers</b>				<b>Hinged Doors</b>			
<b>300 mm wide</b>				<b>300 mm wide</b>			
FC300/300	300 mm high	300 x 300	72.03	HD300/300	300 mm high	300 x 300	98.14
FC300/450	450 mm high	300 x 450	79.38	HD300/450	450 mm high	300 x 450	105.47
FC300/600	600 mm high	300 x 600	96.53	HD300/600	600 mm high	300 x 600	122.60
FC300/750	750 mm high	300 x 750	118.58	HD300/750	750 mm high	300 x 750	146.39
FC300/900	900 mm high	300 x 900	126.26	HD300/900	900 mm high	300 x 900	171.56
<b>450 mm wide</b>				<b>450 mm wide</b>			
FC450/450	450 mm high	450 x 450	95.97	HD450/300	300 mm high	450 x 300	105.47
FC450/600	600 mm high	450 x 600	112.61	HD450/450	450 mm high	450 x 450	122.03
FC450/750	750 mm high	450 x 750	143.64	HD450/600	600 mm high	450 x 600	138.58
FC450/900	900 mm high	450 x 900	169.83	HD450/750	750 mm high	450 x 750	171.56
<b>600 mm wide</b>				<b>600 mm wide</b>			
FC600/600	600 mm high	600 x 600	139.38	HD450/900	900 mm high	450 x 900	214.88
FC600/750	750 mm high	600 x 750	178.79	HD600/300	300 mm high	600 x 300	122.47
FC600/900	900 mm high	600 x 900	199.36	HD600/450	450 mm high	600 x 450	138.58
<b>750 mm wide</b>				<b>750 mm wide</b>			
FC750/750	750 mm high	750 x 750	249.67	HD600/600	600 mm high	600 x 600	165.34
FC750/900	900 mm high	750 x 900	282.43	HD600/750	750 mm high	600 x 750	206.61
				HD600/900	900 mm high	600 x 900	244.72
				HD600/1800	1800 mm high	600 x 1800	551.83
				<b>750 mm wide</b>			
				HD750/300	300 mm high	750 x 300	146.50
				HD750/450	450 mm high	750 x 450	171.56
				HD750/600	600 mm high	750 x 600	206.61
				HD750/750	750 mm high	750 x 750	277.61
				HD750/900	900 mm high	750 x 900	327.69

## G200 CKD parts

### Gear trays



GTB750/450



DPB300D


Cat. No.	Description	Size W x H (mm)	TRADE PRICE \$ (ex GST)	Cat. No.	Description	TRADE PRICE \$ (ex GST)
<b>Gear Trays</b>				<b>Division plates</b>		
<b>300 mm wide</b>				Minimum 4 weeks lead time		
GTB300/300	300 mm high	300 x 300	40.16	DPB750S	<b>G100 Division Plate – Blank – 135 mm Shallow</b>	43.17
GTB300/450	450 mm high	300 x 450	52.67		Division Plate 750 Shallow	
GTB300/600	600 mm high	300 x 600	66.38	<b>Division Plate – Blank – 210 mm Deep</b>		
GTB300/750	750 mm high	300 x 750	83.79	DPB300D	Division Plate 300 deep	26.15
GTB300/900	900 mm high	300 x 900	94.13	DPB450D	Division Plate 450 deep	35.51
<b>450 mm wide</b>				DPB600D	Division Plate 600 deep	40.48
GTB450/300	300 mm high	450 x 300	52.66	DPB750D	Division Plate 750 deep	43.17
GTB450/450	450 mm high	450 x 450	66.38	<b>G400 Division Plate – Blank – 420 mm Extra Deep</b>		
GTB450/600	600 mm high	450 x 600	86.80	DPB300E	Division Plate 300 extra deep	39.23
GTB450/750	750 mm high	450 x 750	111.33	DPB450E	Division Plate 450 extra deep	53.26
GTB450/900	900 mm high	450 x 900	130.21	DPB600E	Division Plate 600 extra deep	60.70
<b>600 mm wide</b>				DPB750E	Division Plate 750 extra deep	64.76
GTB600/300	300 mm high	600 x 300	66.38			
GTB600/450	450 mm high	600 x 450	86.80			
GTB600/600	600 mm high	600 x 600	117.11			
GTB600/750	750 mm high	600 x 750	152.21			
GTB600/900	900 mm high	600 x 900	173.36			
<b>750 mm wide</b>						
GTB750/300	300 mm high	750 x 300	83.79			
GTB750/450	450 mm high	750 x 450	132.11			
GTB750/600	600 mm high	750 x 600	152.24			
GTB750/750	750 mm high	750 x 750	213.53			
GTB750/900	900 mm high	750 x 900	253.44			

## G200 & G400 CKD parts

### Masking panels



MPB300/900

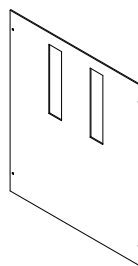

MPS4TP450/600

Cat. No.	Description	Size W x H (mm)	TRADE PRICE \$ (ex GST)	Cat. No.	Description	Size W x H (mm)	TRADE PRICE \$ (ex GST)
<b>Blank masking panels</b> Blank panels. 4 mm thick steel				<b>Slotted masking panels</b> Slotted panels. 405 mm wide. 4 mm thick steel			
<b>For 300mm wide cabinets</b>				<b>For 600mm high cabinets</b>			
MPB300/300	300 mm high	254 x 254	27.13	MPS4TP450/600	4TP	405 x 555	89.88
MPB300/450	450 mm high	254 x 405	34.11	MPS8TP450/600	8TP	405 x 555	89.88
MPB300/600	600 mm high	254 x 555	46.45	MPS12TP450/600	12TP	405 x 555	89.88
MPB300/750	750 mm high	254 x 703	56.88	MPS16TP450/600	16TP	405 x 555	87.26
MPB300/900	900 mm high	254 x 854	65.33	<b>For 900mm high cabinets</b>			
<b>For 450mm wide cabinets</b>				MPS8TP450/900	8TP	405 x 854	123.66
MPB450/450	450 mm high	405 x 405	42.88	MPS12TP450/900	12TP	405 x 854	123.66
MPB450/600	600 mm high	405 x 555	56.88	MPS16TP450/900	16TP	405 x 854	123.66
MPB450/750	750 mm high	405 x 703	73.77	MPS20TP450/900	20TP	405 x 854	123.66
MPB450/900	900 mm high	405 x 854	89.88	MPS24TP450/900	24TP	405 x 854	123.66
<b>For 600mm wide cabinets</b>							
MPB600/600	600 mm high	555 x 555	81.12				
MPB600/750	750 mm high	555 x 703	102.09				
MPB600/900	900 mm high	555 x 854	118.97				
<b>For 750mm wide cabinets</b>							
MPB750/750	750 mm high	705 x 705	147.33				
MPB750/900	900 mm high	705 x 854	189.55				

## G100, G200 & G400 CKD part

### Gland plates



Cat. No.	Description	Length (mm)	TRADE PRICE \$ (ex GST)	Cat. No.	Description	Length (mm)	TRADE PRICE \$ (ex GST)
<b>Gland Plates</b> 4 mm thick				<b>Mullions</b> <b>Mullion Front Horizontal</b>			
<b>Plastic Gland Plates – 110 mm Deep</b>				ML300	300 mm long	300	28.70
GPP450S	450 mm long	450	31.22	ML450	450 mm long	450	32.74
<b>Aluminium Gland Plates – 110 mm Deep</b>				ML600	600 mm long	600	37.23
GPA450S	450 mm long	450	41.67	ML750	750 mm long	750	45.93
<b>Plastic Gland Plates – 220 mm Deep</b>				ML900	900 mm long	900	52.24
GPP300D	300 mm long	300	23.99	<b>Mounting brackets and channels</b> <b>Hanging mounting brackets</b>			
GPP450D	450 mm long	450	31.22	MBH300	300 mm long	300	16.94
GPP600D	600 mm long	600	42.33	MBH450	450 mm long	450	20.00
GPP750D	750 mm long	750	50.22	MBH600	600 mm long	600	22.30
GPP900D	900 mm long	900	53.55	MBH750	750 mm long	750	25.47
<b>Aluminium Gland Plates – 220 mm Deep</b>				MBH900	900 mm long	900	28.39
GPA300D	300 mm long	300	28.00	MBE	Mounting Bracket Extension		6.76
GPA450D	450 mm long	450	41.67	<b>Mounting Channel (Slide Nut DIN Rail)</b> To mount onto MBH series hanging mounting brackets or gear trays			
GPA600D	600 mm long	600	59.21	MC150	DIN rail channel 150 mm	115	14.92
GPA750D	750 mm long	750	76.46	MC225	DIN rail channel 225 mm	190	16.80
GPA900D	900 mm long	900	93.34	MC300	DIN rail channel 300 mm	265	18.46
<b>Plastic Gland Plates – 420 mm Extra Deep</b>				MC375	DIN rail channel 375 mm	340	20.28
GPP300E	300 mm long	300	35.99	MC450	DIN rail channel 450 mm	415	21.97
GPP450E	450 mm long	450	46.83	MC525	DIN rail channel 525 mm	490	23.73
GPP600E	600 mm long	600	63.49	MC600	DIN rail channel 600 mm	565	26.16
GPP750E	750 mm long	750	75.32	MC750	DIN rail channel 750 mm	715	27.32
GPP900E	900 mm long	900	80.33	MC900	DIN rail channel 900 mm	865	31.65
<b>Aluminium Gland Plates – 420 mm Extra Deep</b>							
GPA300E	300 mm long	300	42.00				
GPA450E	450 mm long	450	62.48				
GPA600E	600 mm long	600	88.83				
GPA750E	750 mm long	750	114.66				
GPA900E	900 mm long	900	140.00				

## G200 & G400 CKD parts

### Components



CHA4



CL24TP



ENBS



ENBD



PABF



DINBLK

Cat. No.	Description	TRADE PRICE \$ (ex GST)	Cat. No.	Description	TRADE PRICE \$ (ex GST)
<b>Accessories</b> <b>Chart Holders</b>			<b>Accessories – continued</b> <b>Hinged Door Accessories</b>		
CHA4	A4	15.40	DC	Door Catch Assembly	10.49
CHA5	A5	13.23	DK144	Lock Barrel & 144 Key	20.44
<b>Chart Legends</b>			HDK	Hinged Door Kit	42.29
CL24TP	24TP Chart Legend	2.16	<b>Miscellaneous</b>		
<b>Earth Neutral Busbar Supports</b>			DINBLK/100	DIN Rail Mounting Block	2.80
ENBS	Earth Neutral Bracket Single	2.16	SNM5/200	DIN Rail Side Nuts	1.01
ENBD	Earth Neutral Bracket Double	2.68	PABF	MCB Pole Filler Blank	1.46
			PB235	Plinth End Bracket	14.28
			GF04	M5 x 10 CS Sq Drive Taptite	0.11
			GF07	M5 x 10 Pozi Drive Taptite	0.11
			GF10	M5 x 40 Pozi Drive Taptite	0.43
			CES150	Copper earth straps 150 mm	5.48
			LSM9100A	100A Link Set	14.89
			MLD28	MCB Blanks	4.53
			MPK	Masking Panel Kit	7.08

## Switchboard components

### 250A MCB Chassis



Cat. No.	Description	Height (mm)	TRADE PRICE \$ (ex GST)
	<p>Peak withstand current: 52.5kA                      Short Time withstand current: 25kA/0.1s                      fit all brands of MCBs                      235 mm wide                      Spacers are included to fit the below breaker types:</p> <ul style="list-style-type: none"> <li>• VS GE Vynco, NHP Mod6, ABB</li> <li>• MS Schneider, CHNT</li> <li>• HS Legrand, Hager, Eaton, GE Red Line</li> </ul> <p><b>Single ended</b></p> <p><b>Multi-Series Chassis</b></p>		
TPA 12 POLE	4 x 3 Pole	168	239.93
TPA 18 POLE	6 x 3 Pole	222	307.47
TPA 24 POLE	8 x 3 Pole	276	329.29
TPA 30 POLE	10 x 3 Pole	330	355.84
TPA 36 POLE	12 x 3 Pole	384	380.51
TPA 42 POLE	14 x 3 Pole	438	458.45
TPA 48 POLE	16 x 3 Pole	492	566.47
TPA 54 POLE	18 x 3 Pole	546	620.26
TPA 60 POLE	20 x 3 Pole	600	701.08
TPA 72 POLE	24 x 3 Pole	708	883.58

## Switchboard Quotation Sheet

---

### Main Switch

- 100A     160A     250A     320A     400A     630A

### Pan Assembly

- 4TP     8TP     12TP     16TP     20TP     24TP  
 2 x 12TP     2 x 16TP     2 x 20TP     2 x 24TP

Note: 2 x PAN Assemblies required for 320A, 400A, 630A main switch option

### TARIFF Metering

- Yes     No

Note: For metering over 100A, CT metering is required

### Control Cubicle

- Yes     No

If yes, minimum size: \_\_\_\_\_ W, \_\_\_\_\_ H

Additional Comments

---

---

---

---

If you have any additional requirements, please contact:  
sales.trical@legrand.com or phone 09 527 0072



## Trical New Zealand

T +64 9 527 0072

E [sales.trical@legrand.com](mailto:sales.trical@legrand.com)

80 McLaughlins Road

Wiri, Auckland 2104, PO Box 9487

Newmarket 1149

---

## FOLLOW US ON

---

@ [trical.co.nz](https://www.trical.co.nz)

<https://nz.linkedin.com/company/trical-nz>

<https://www.facebook.com/tricalnewzealand>

  
A brand of 