

# PLEXO™

With you, whatever the weather



**GLOBAL SPECIALIST** IN ELECTRICAL AND  
DIGITAL BUILDING INFRASTRUCTURES

 **legrand®**



# Contents

- p.4 **Plexo™ style**  
something to suit every taste
- p.6 **Plexo™**  
freedom of installation
- p.8 **Plexo™**  
horizontally or vertically
- p.10 **Plexo™**  
rugged and suitable for any situation
- p.12 **Plexo™**  
more than 100 accessible functions
- p.14 **Plexo™**  
lighting control units
- p.16 **Plexo™ functions**  
power distribution
- p.18 **Plexo™ functions**  
for even more possibilities
- p.20 **Plexo™ with Netatmo**  
connected functions
- p.22 **Catalogue pages**




An **iconic** name,

A **contemporary** design

**The go-to range of weatherproof wiring accessories**, Plexo has adopted **current trends** with **contemporary lines**.

A design with character.

A strong offer.

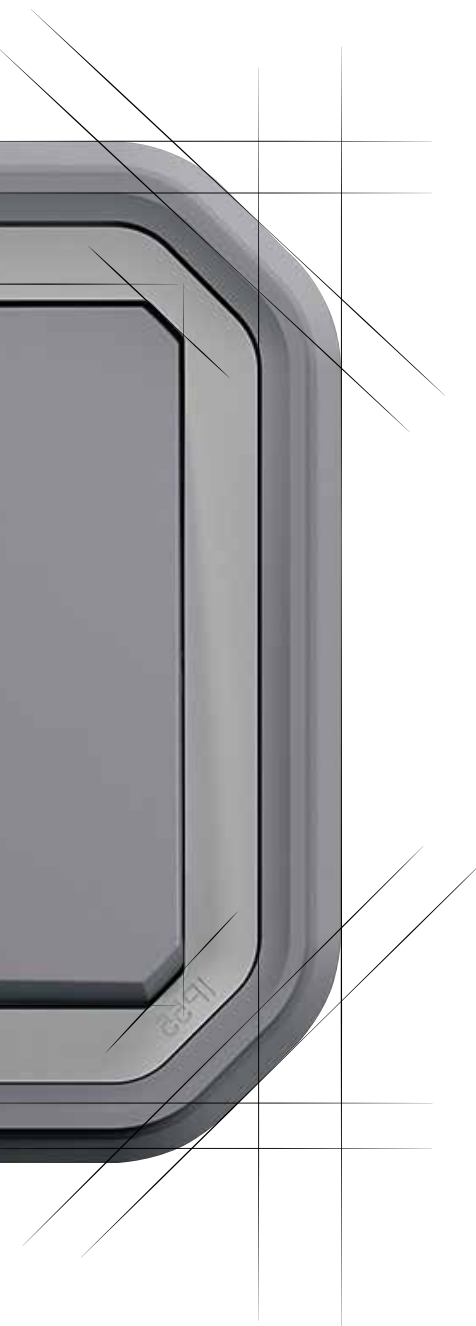


# No limit to where it can be used

The Plexo range of wiring accessories is designed to provide **protection** against splashing water and accumulation of dust.

Install Plexo:

- in **damp** places: garages, professional kitchens etc.
- **outdoors**: shopping centre shopfronts, public or private car parks etc.

Available either **surface-mounted** for renovation or **flush-mounted** for an understated, discreet finish.

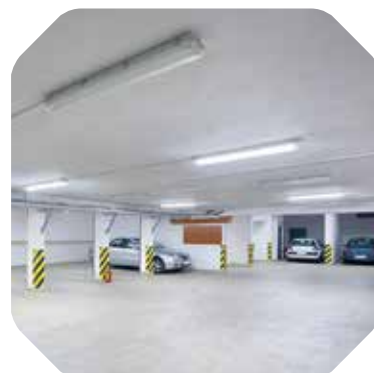



# Plexo™ style

something to suit every taste

The range has been expanded to **4 finishes** to fit in with every trend in any location.

You will find a colour **to suit all your projects**, both indoors and outdoors.



## Contemporary



**Anthracite**

## Essential



**Grey**




**Pure**



**White**

**Natural**

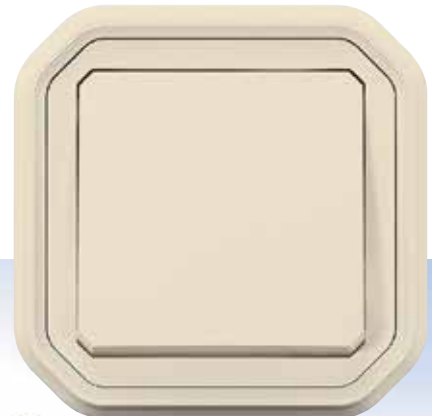

**Sand**

# Plexo™

LEGRAND  
PATENT

## freedom of installation

**Plexo has been updated** with a redesigned product architecture. Discover the new plate concept with shallow depth and **space** around the mechanism, making **wiring easier**.



## Guaranteed ease of installation

**EASY**



- Twice as much wiring space.
- Even simpler to install.
- Freedom of movement when wiring or creating tap-offs.







## Toolless

A movable mechanism.


## Wire up products as you please

2 possible wiring modes.



Clips in and out without tools

### Mechanism not clipped in place

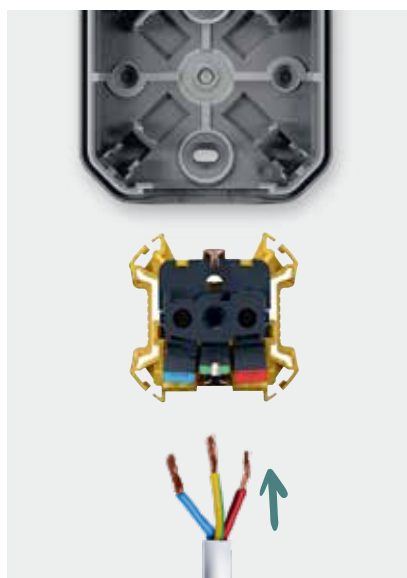

Wiring done off the plate and  
mechanism simply clips in place.

### Mechanism clipped in place



Wiring made easy by the plate's  
shallow depth.

# Plexo™

LEGRAND  
PATENT

## horizontally or vertically

Plexo **can adapt to any situation** and is **simple to install** in a multigang configuration.




### Save time on your projects...

**QUICK**

**ROTATABLE**


**Same catalogue number** for surface-mounting box and flush-mounting support, **whether for horizontal or vertical installation.**

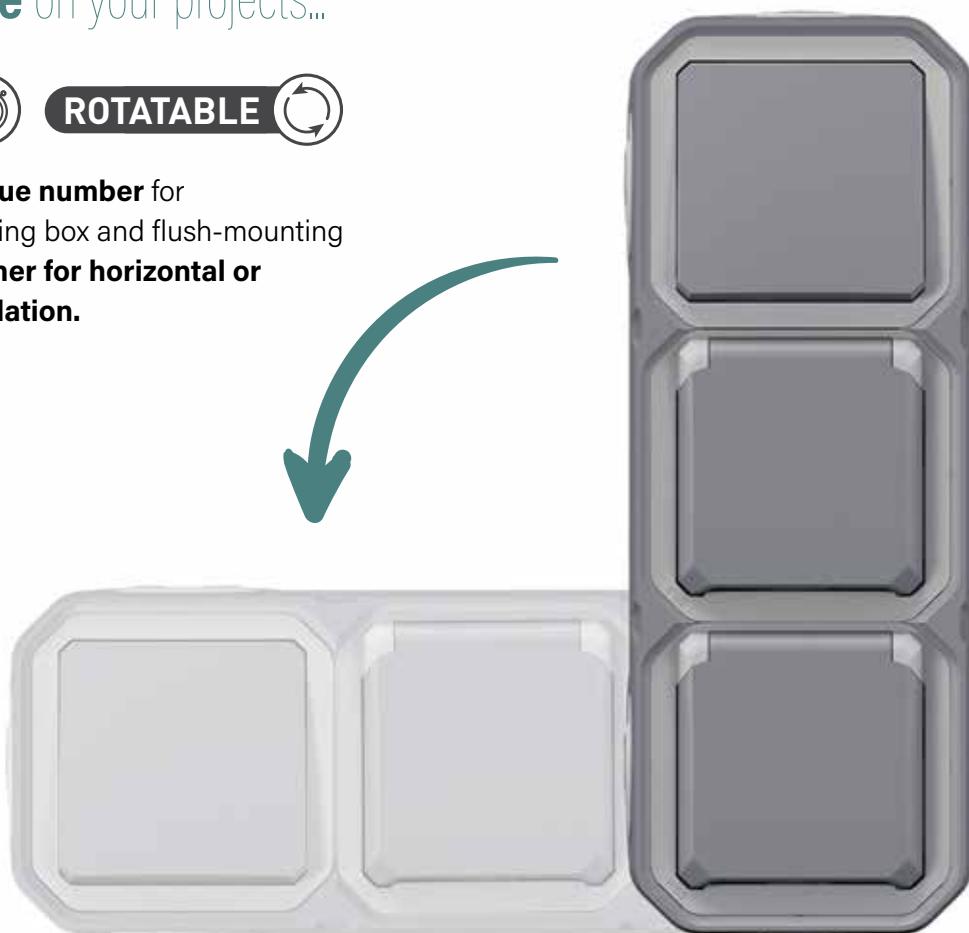



... and benefit from **more flexibility**

No need for tools, just clip and pivot the mechanism and the job's done!

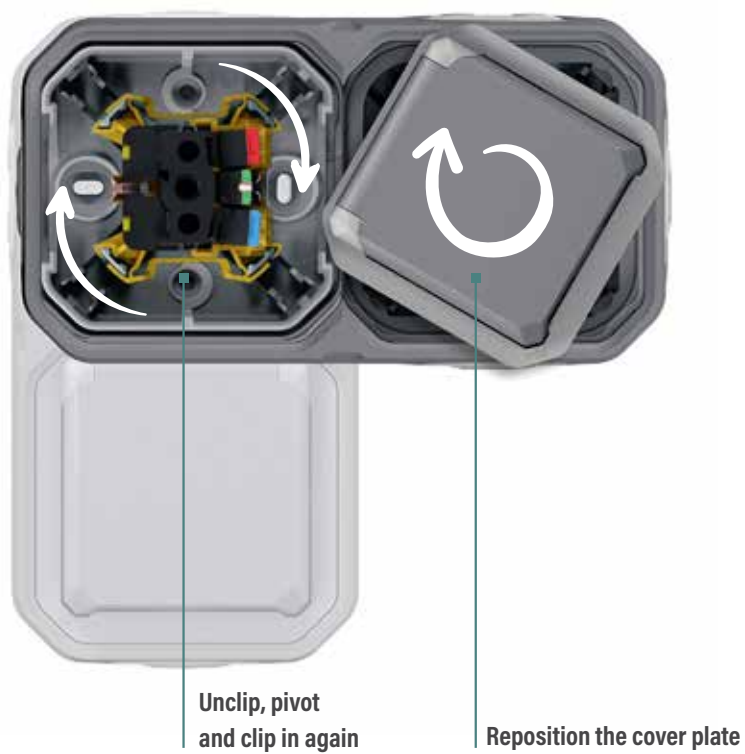

# Plexo™

rugged and suitable for  
any situation

The plate and frame give the product extra rigidity on an uneven surface.

**Redesigned seals and weatherproofing membranes** positioned at the main product assembly points.

An IP 55 range for safe use on any installation site and in any environment.



**WEATHERPROOF**




**RUGGED**



**LEGRAND  
PATENT**



Seal between cover plate and frame


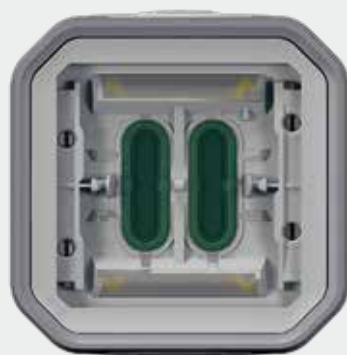


Switch inner membrane remains intact



Seal between plate and frame.  
Enhances weatherproofing once assembled



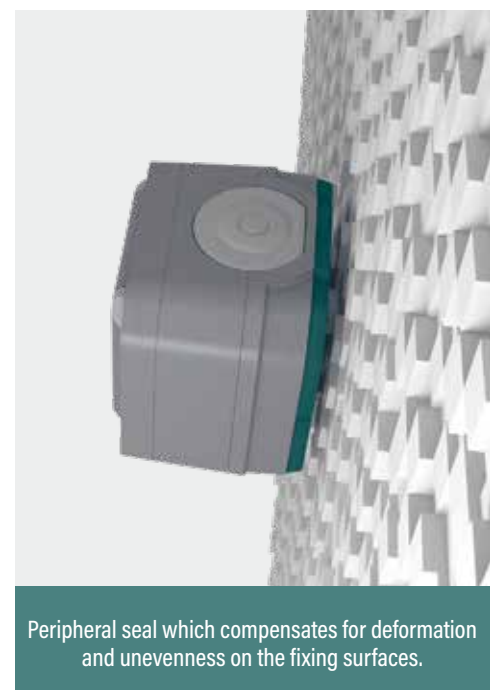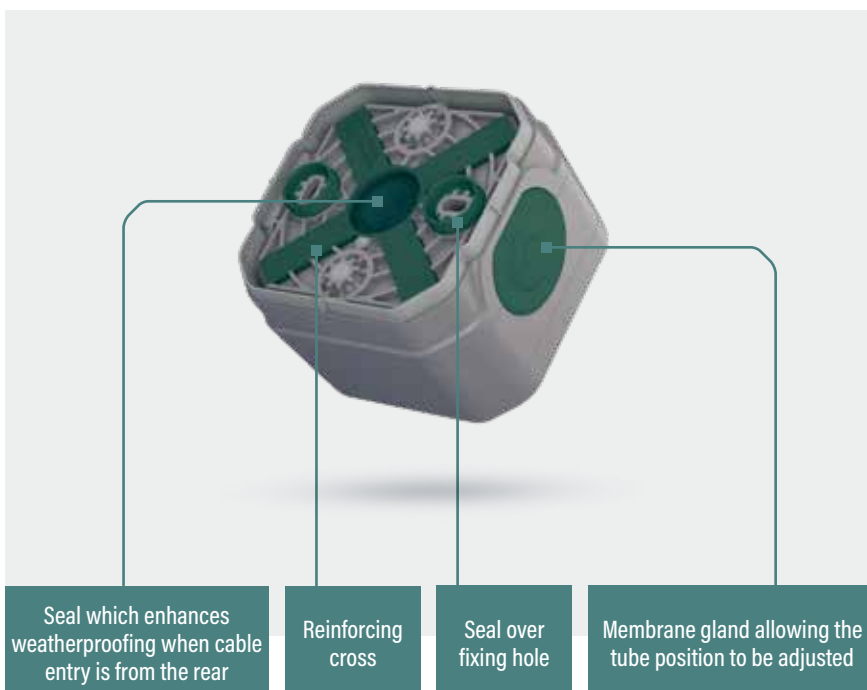

# Plexo™

more than 100 accessible functions

**With the most extensive offer on the market, Plexo is available in flush-mounting or surface-mounting, complete and modular versions, to suit:**

- **all requirements and all types of use:** single or double switches, with or without indicator, motion sensors, multi-gang sockets, etc.
- **all sites and activity sectors:** commercial, industrial, residential etc.

With the **Mosaic adaptor**, you have even greater choice with significantly more functions.





## Keyswitches

Keyswitches allow you to restrict control of the circuit to prevent untimely power cuts on logistics or industrial sites.



Ronis no. 455 keyswitch



"Secure access" keyswitch

# Plexo<sup>TM</sup>

## lighting control units

### Double switch and transformer

The double switch and transformer combine **several functions** in **a single catalogue number**.

A simple ¼ turn changes from one function to another.

These products are ideal for reducing your **stock on sites** and carrying out **maintenance** and repairs with greater **flexibility!**



INNOVATIVE



SMART



Double switch: a **3 in 1** product

The double switch contains 3 functions:

Push-button mode

Two-way switch mode



Mode changed with a 1/4 turn



Double push-button

OR

Double two-way switch

OR


Two-way switch + two-way push-button





## Transformer: a **5** in **1** product

5 lighting controls can be created:

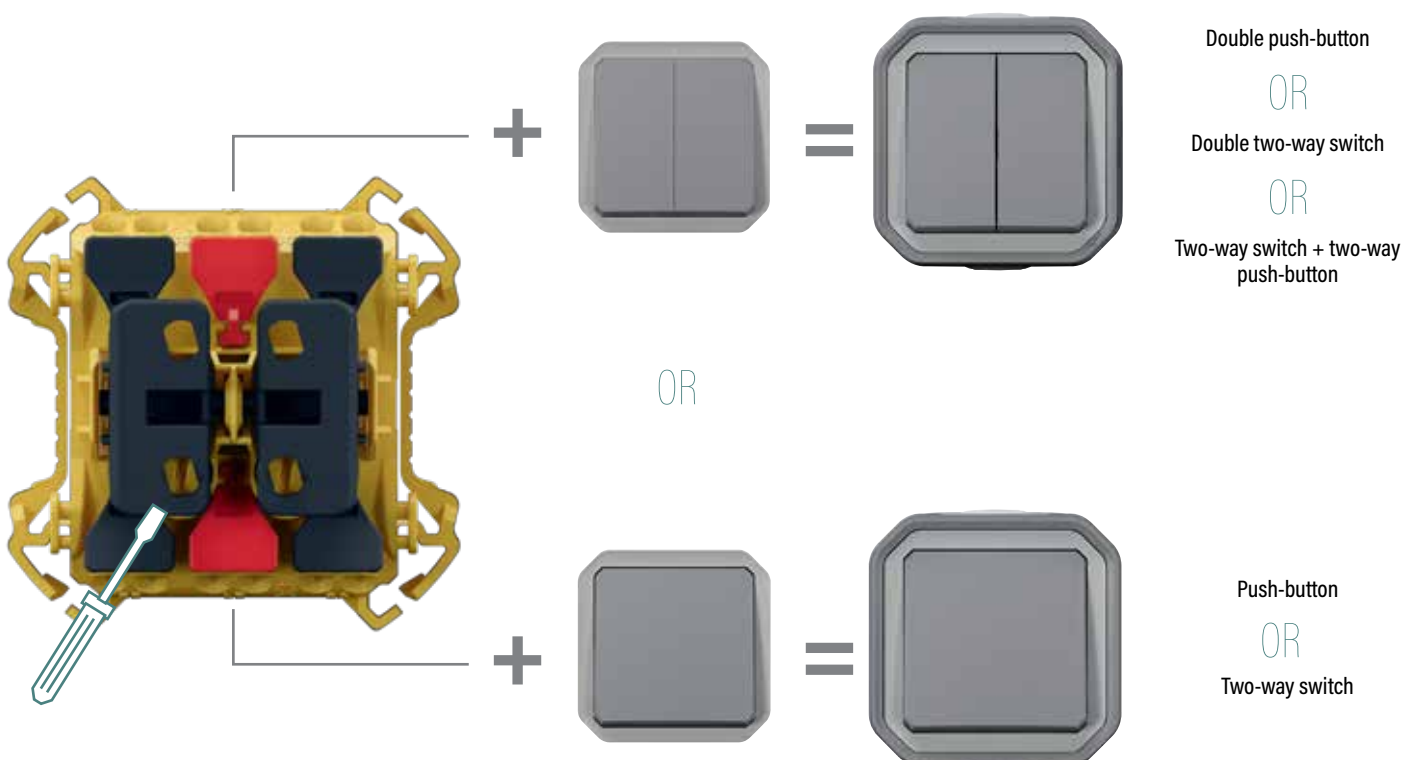

# Plexo™ functions:

## Power distribution

**Simple** and **modular**, the Plexo range extends the fields of **possibility** and can adapt to any **location**, **lifestyle** and **type of use**.



### 2P+E sockets

Thanks to its **easy installation**, you can wire up Plexo sockets **without tools** thanks to their **quick connection**.

Available with up to **3 gangs** for either **horizontal** or **vertical** installation, these power sockets allow electrical appliances to be plugged in in **damp places** or **outdoors**, and guarantee **weatherproofing** and **ruggedness**.

There is also a socket dedicated to **electric bikes**, which can easily be identified thanks to its pictogram.



### Prewired double and triple sockets

Complete, ready-to-install products



Horizontal triple 2P+E

Horizontal double 2P+E



## Green'Up Access

INNOVATIVE



SMART



Discover the Green'up Access socket with the new Plexo design!  
This **heavy-duty socket**, for use with electric and plug-in hybrid vehicles, features an **exclusive Legrand patented system\***. It can **release** the maximum power from the socket outlet on contact with the vehicle.  
It can charge an electric or plug-in hybrid vehicle twice as fast as a domestic socket!

*\*For the system to work properly, the vehicle must be compatible with GREEN'UP SYSTEM technology. Ask your Legrand agent for more information.*



Can be surface-mounted,  
flush-mounted or multi-gang

# Plexo™ functions:

For even more possibilities

## Mosaic™ adaptor with safety flap

The Mosaic™ adaptor with safety flap can incorporate a Mosaic™ mechanism without a support in a Plexo IP 55 design, making them weatherproof and shock-resistant regardless of which functions are included.



It extends the range of possibilities with, in particular, USB Type-C, RJ 45, TV sockets, etc.



## A harmonious design

Plexo™ and Mosaic™ in perfect harmony!

### Anthracite finishes



### Grey finishes




### White finishes



# Plexo™

## with Netatmo

**Plexo™ with Netatmo**, the Plexo™ connected version, can be used to control lighting, roller shutters and electrical appliances locally or remotely via the Home + Control app. First install a “with Netatmo” connected starter pack.

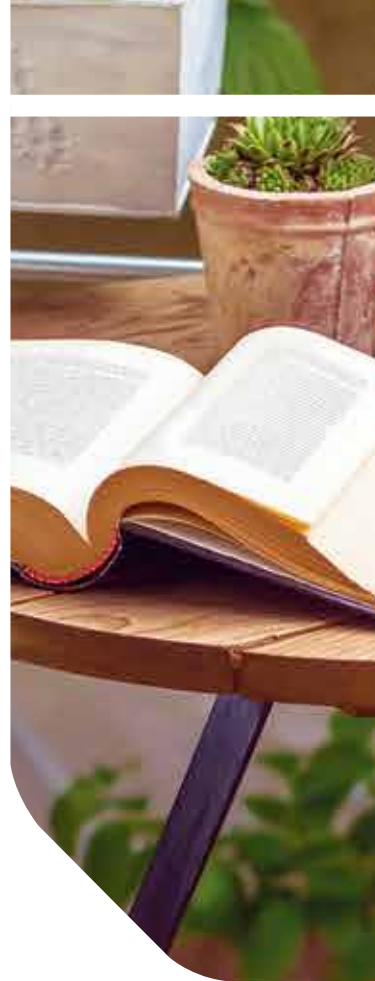

Complete the installation with wireless switches, which can be voice-controlled manually via voice assistants (Apple Siri, Amazon Alexa, Google Assistant), and also controlled remotely on a smartphone with the Home + Control app.



Home + Control





## CONNECTED



Dim the lights by simply pressing your switch, your smartphone or using your voice via a voice assistant.

Receive notifications of power failures on your smartphone and monitor your consumption.

Control your lights and connected power outlets with control points that need neither wires, nor batteries.



Connected switch with dimmer



2P+E power outlets - 16 A



Self-e lighting controls  
(no wires, no batteries)





Functions	COMPLETE VERSION for surface mounting				
	● Grey	● Anthracite	○ White	● Ivory	
TRANSFORMER					
Reversible transformer	0 697 19L	0 697 89L	-	-	
SWITCHES 10 AX - 250 V~					
1-gang 2-way switch	0 697 11L	0 697 61L	0 697 51L	-	
1-gang 2-way switch - with indicator	0 697 12L	0 697 21L	-	-	
Illuminated 1-gang 2-way switch	0 697 13L	0 697 36L	-	-	
1-gang 2-way switch 24 V - with indicator	1 002 77L	-	-	-	
2-gang 1-way switch	0 697 14L	-	-	-	
2-gang 2-way switch or 2-gang changeover push-button	0 697 15L	0 697 75L	0 697 55L	-	
Illuminated 2-gang 2-way switch or 2-gang changeover push-button	-	-	-	-	
Double pole switch	-	-	-	-	
Double pole switch - with indicator	0 697 26L	-	-	-	
SWITCHES 16 AX - 250 V~					
1-gang 2-way switch	-	-	-	-	
Double pole switch	-	-	-	-	
Double pole switch - with indicator	-	-	-	-	
SWITCH 4 AX					
1-gang 2-way switch without neutral - with indicator	-	-	-	-	
CONTACTLESS SWITCHES					
200 W LED for light	-	-	-	-	
1000 VA for door	-	-	-	-	
INTERMEDIATE SWITCH					
Intermediate switch	0 697 16L	-	-	-	
PUSH-BUTTONS 10 A					
NO contact push-button	0 697 20L	0 697 90L	0 697 60L	-	
NO contact push-button - with indicator	-	-	-	-	
Illuminated NO contact push-button	0 697 22L	0 697 82L	0 697 62L	-	
Changeover push-button	-	-	-	-	
Illuminated changeover push-button	-	-	-	-	
Illuminated changeover push-button with label-holder	-	-	-	-	
KEY-OPERATED SWITCHES					
Keyswitch - 2 positions - 2 NO contacts	-	-	-	-	
Keyswitch - 3 positions - 2 NO contacts	-	-	-	-	
Keyswitch - 2 positions - for European key barrel	-	-	-	-	
Key-operated push-button - 3 positions - for European key barrel	-	-	-	-	
European key barrel	-	-	-	-	
TIME LAG SWITCH					
Illuminated time lag switch	-	-	-	-	



	COMPLETE VERSION for flush-mounting				COMPLETE VERSION for flush-mounting with claws				MECHANISMS (to be equipped with a surface-mounting box or support frame and a plate)			
	● Grey	● Anthracite	○ White	● Ivory	● Grey	● Anthracite	○ White	● Ivory	● Grey	● Anthracite	○ White	● Ivory
	-	-	-	-	-	-	-	-	0 695 06L	0 698 00L	0 696 18L	0 698 09L
	0 698 11L	0 698 81L	0 698 51L	-	0 698 12L	-	0 698 52L	-	0 695 11L	0 698 01L	0 696 11L	0 698 08L
	-	-	-	-	-	-	-	-	0 695 12L	0 698 02L	0 696 12L	-
	-	-	-	-	-	-	-	-	0 695 13L	0 698 03L	0 696 13L	-
	-	-	-	-	-	-	-	-	-	-	-	-
	-	-	-	-	-	-	-	-	-	-	-	-
	0 698 15L	-	0 698 55L	-	-	-	-	-	0 695 25L	0 698 05L	0 696 25L	-
	-	-	-	-	-	-	-	-	0 695 26L	0 698 06L	0 696 26L	-
	-	-	-	-	-	-	-	-	0 695 30L	0 698 27L	0 696 27L	-
	-	-	-	-	-	-	-	-	-	-	-	-
	-	-	-	-	-	-	-	-	0 695 23L	-	-	-
	-	-	-	-	-	-	-	-	0 695 27L	-	-	-
	-	-	-	-	-	-	-	-	0 695 28L	-	-	-
	-	-	-	-	-	-	-	-	0 695 15L	-	-	-
	-	-	-	-	-	-	-	-	0 695 86L	-	-	-
	-	-	-	-	-	-	-	-	0 695 95L	-	-	-
	-	-	-	-	-	-	-	-	0 695 21L	-	0 696 20L	-
	0 698 20L	-	-	-	-	-	-	-	0 695 40L	0 698 10L	0 696 30L	-
	-	-	-	-	-	-	-	-	0 695 33L	-	-	-
	0 698 32L	-	0 698 23L	-	-	-	-	-	0 695 42L	0 698 13L	0 696 32L	-
	-	-	-	-	-	-	-	-	0 695 41L	0 698 41L	0 696 31L	-
	-	-	-	-	-	-	-	-	0 695 36L	0 698 16L	0 696 16L	0 698 26L
	0 698 24L	0 698 54L	0 698 64L	0 698 29L	-	-	-	-	0 695 44L	0 698 14L	0 696 34L	-
	-	-	-	-	-	-	-	-	0 695 34L	-	-	-
	-	-	-	-	-	-	-	-	0 695 35L	-	-	-
	-	-	-	-	-	-	-	-	0 697 06L	-	-	-
	-	-	-	-	-	-	-	-	0 697 05L	-	-	-
	-	-	-	-	-	-	-	-	0 697 95	-	-	-
	-	-	-	-	-	-	-	-	0 695 04L	0 698 04L	0 696 04L	-

Functions	COMPLETE VERSION for surface mounting				
	● Grey	● Anthracite	○ White	○ Ivory	
LIGHT SENSITIVE SWITCH					
Light sensitive switch	-	-	-	-	
AUTOMATIC SWITCHES AND MOTION SENSORS					
Automatic switch without neutral - 2-wire	-	-	-	-	
Automatic switch with neutral - 3-wire	-	-	-	-	
Motion sensors with neutral - 3-wire	0 697 40	-	0 488 98	-	
CONNECTED SWITCHES & DIMMERS					
1-gang ON/OFF switch, wireless and batteryless	0 698 74L	0 698 94L	0 698 84L	0 698 93L	
2-gang ON/OFF switch, wireless and batteryless	0 698 19L	0 698 36L	0 698 35L	0 698 57L	
Roller blind switch, wireless and batteryless	0 698 73L	0 698 83L	-	-	
Switch dimmer without neutral - 5-125 W - LED	-	-	-	-	
Switch dimmer - 3 wires	-	-	-	-	
ROLLER BLIND CONTROL					
Roller blind switch	-	-	-	-	
Roller blind push-button	-	-	-	-	
THERMOSTAT					
Electronic room thermostat	-	-	-	-	
EMERGENCY STOP FUNCTIONS - 3 A - 250 V					
Emergency stop button	-	-	-	-	
Emergency stop with key for reset	-	-	-	-	
Emergency stop with quarter-turn lock	-	-	-	-	
GERMAN STANDARD SOCKET OUTLETS - 16 A - 250 V					
2P+E - automatic terminals	0 697 30L	0 697 99L	0 697 70L	-	
2P+E - automatic terminals - key-operated	-	-	-	-	
2P+E - screw terminals	0 697 33L	0 697 83L	0 697 71L	-	
2P+E + 2-way switch - screw terminals	0 697 46L	-	-	-	
2 x 2P+E prewired - horizontal	0 697 42L	-	0 697 72L	-	
2 x 2P+E prewired - vertical	0 697 44L	-	-	-	
3 x 2P+E prewired - horizontal	0 697 43L	-	-	-	

	COMPLETE VERSION for flush-mounting				COMPLETE VERSION for flush-mounting with claws				MECHANISMS (to be equipped with a surface-mounting box or support frame and a plate)			
	● Grey	● Anthracite	○ White	● Ivory	● Grey	● Anthracite	○ White	● Ivory	● Grey	● Anthracite	○ White	● Ivory
	-	-	-	-	-	-	-	-	0 695 17L	-	-	-
	-	-	-	-	-	-	-	-	0 695 20L	-	-	-
	-	-	-	-	-	-	-	-	0 695 22L	-	-	-
	-	-	-	-	-	-	-	-	-	-	-	-
	-	-	-	-	-	-	-	-	-	-	-	-
	-	-	-	-	-	-	-	-	-	-	-	-
	-	-	-	-	-	-	-	-	-	-	-	-
	-	-	-	-	-	-	-	-	0 698 75L	0 698 95L	-	-
	-	-	-	-	-	-	-	-	0 698 76L	0 698 96L	-	-
	-	-	-	-	-	-	-	-	0 695 38L	0 698 98L	0 696 29L	-
	-	-	-	-	-	-	-	-	0 695 39L	-	0 696 38L	-
	-	-	-	-	-	-	-	-	0 695 08L	-	-	-
	-	-	-	-	-	-	-	-	0 695 47L	-	-	-
	-	-	-	-	-	-	-	-	0 695 48L	-	-	-
	-	-	-	-	-	-	-	-	0 695 49L	-	-	-
	-	-	-	-	-	-	-	-	0 695 70L	0 698 71L	0 696 40L	-
	-	-	-	-	-	-	-	-	0 695 74L	-	-	-
	0 698 33L	0 698 59L	0 698 69L	-	0 698 34L	-	0 698 68L	-	0 695 71L	0 698 39L	0 696 39L	-
	-	-	-	-	-	-	-	-	-	-	-	-
	-	-	-	-	-	-	-	-	0 695 76L	0 698 79L	0 696 75L	-
	-	-	-	-	-	-	-	-	0 695 77L	-	-	-
	-	-	-	-	-	-	-	-	0 695 78L	-	-	-

Functions	COMPLETE VERSION for surface mounting				
	 Grey	 Anthracite	 White	 Ivory	
SOCKET OUTLETS 20 A					
2P+E	0 916 55	-	-	-	
3P+E	0 916 56	-	-	-	
3P+N+E	0 916 57	-	-	-	
CONNECTED SOCKET OUTLETS - 16 A - 230 V~					
German standard socket outlet	-	-	-	-	
SOCKET OUTLETS FOR ELECTRIC VEHICLE CHARGING - 16 A - 230 V~					
German standard socket outlet for electric vehicle	-	0 697 08L	-	-	
Safety plate for electric car charging cord	-	-	-	-	
CABLE OUTLETS					
Cable outlet - 16 A - with cable grip	-	-	-	-	
Cable outlet - 20 A - with terminal block	-	-	-	-	
Cable outlet - 20-32 A	-	-	-	-	
RJ 45 SOCKETS					
RJ 45 socket Cat. 6A STP	-	-	-	-	
RJ 45 socket Cat. 6 FTP	-	-	-	-	
RJ 45 socket Cat. 6 UTP	-	-	-	-	
Arteor/Mosaic adaptor for RJ 45 socket	-	-	-	-	
TV SOCKETS					
TV-R-SAT socket	-	-	-	-	
ADAPTORS					
Osmoz adaptor	-	-	-	-	
Arteor/Mosaic adaptor with transparent flap	-	-	-	-	
Arteor/Mosaic adaptor with lockable transparent flap	-	-	-	-	
Arteor/Mosaic adaptor with opaque flap	-	-	-	-	
Arteor/Mosaic adaptor without flap	-	-	-	-	
Arteor/Mosaic adaptor with flexible membrane	-	-	-	-	
BLANKING PLATE					
Blanking plate	-	-	-	-	



	COMPLETE VERSION for flush-mounting				COMPLETE VERSION for flush-mounting with claws				MECHANISMS (to be equipped with a surface-mounting box or support frame and a plate)			
	● Grey	● Anthracite	○ White	● Ivory	● Grey	● Anthracite	○ White	● Ivory	● Grey	● Anthracite	○ White	● Ivory
	-	-	-	-	-	-	-	-	-	-	-	-
	-	-	-	-	-	-	-	-	-	-	-	-
	-	-	-	-	-	-	-	-	-	-	-	-
	-	-	-	-	-	-	-	-	0 698 77L	0 698 97L	0 698 87L	-
	-	-	-	-	-	-	-	-	-	0 698 18L	-	-
	-	-	-	-	-	-	-	-	-	0 694 94L	-	-
	0 698 48L	0 698 78L	0 698 88L	-	-	-	-	-	0 695 50L	-	-	-
	0 698 49L	0 698 99L	0 698 89L	-	-	-	-	-	-	-	-	-
	0 698 50L	-	-	-	-	-	-	-	-	-	-	-
	-	-	-	-	-	-	-	-	0 695 59L	-	-	-
	-	-	-	-	-	-	-	-	0 695 69L	-	-	-
	-	-	-	-	-	-	-	-	0 695 61L	-	-	-
	-	-	-	-	-	-	-	-	0 695 81L	-	-	-
	-	-	-	-	-	-	-	-	0 695 58L	-	-	-
	-	-	-	-	-	-	-	-	0 695 68L	-	-	-
	-	-	-	-	-	-	-	-	0 695 80L	0 698 80L	0 696 95L	0 698 38L
	-	-	-	-	-	-	-	-	0 695 79L	0 698 45L	-	-
	-	-	-	-	-	-	-	-	0 695 84L	0 698 30L	0 696 84L	-
	-	-	-	-	-	-	-	-	0 695 82L	-	-	-
	-	-	-	-	-	-	-	-	0 695 87L	-	-	-
	-	-	-	-	-	-	-	-	0 695 37L	0 698 37L	0 696 37L	0 698 47L

Functions	MECHANISMS (to be equipped with a surface-mounting box or support frame and a plate)			
	● Grey	● Anthracite	○ White	● Ivory
<b>PILOT LIGHT</b>				
Pilot light	0 695 83L	-	-	-
Diffuser for pilot light - colorless	0 695 88L	-	-	-
Diffuser for pilot light - green	0 695 89L	-	-	-
Diffuser for pilot light - orange	0 695 90L	-	-	-
Diffuser for pilot light - red	0 695 91L	-	-	-
<b>SURFACE MOUNTING BOXES</b>				
1-gang - with membrane glands	0 696 51L	0 696 01L	0 696 89L	0 698 63L
2-gang - with membrane glands - horizontal or vertical mounting	0 696 72L	0 696 02L	0 696 90L	0 698 67L
3-gang - with membrane glands - horizontal or vertical mounting	0 696 80L	0 696 03L	0 696 88L	-
1-gang - with cable gland PG16	0 696 52L	-	-	-
1-gang - with cable gland ISO 20	0 696 56L	0 696 28L	0 696 86L	-
1-gang - with cable gland ISO 20 - 2 entries	0 698 46L	-	-	-
2-gang - with cable gland ISO 20 - 2 entries - vertical mounting	0 696 68L	0 696 10L	0 698 66L	-
<b>SUPPORT FRAMES</b>				
1-gang	0 696 81L	0 696 06L	0 696 92L	0 698 90L
1-gang - with claws	0 696 82L	0 696 09L	0 696 93L	-
2-gang - horizontal or vertical mounting	0 696 83L	0 696 07L	0 696 94L	0 698 53L
3-gang - horizontal or vertical mounting	0 696 87L	0 696 08L	0 696 98L	-
<b>ACCESSORIES</b>				
Lamp - 12-24-48 V~	0 694 95L	-	-	-
Locator light - 230 V~	0 694 96L	-	-	-
Indicator light - 230 V~	0 694 98L	-	-	-
Membrane gland - 1 entry	0 695 96L	-	-	-
Membrane gland - 2 entries	0 695 99L	-	-	-
Pairing gland	0 696 65L	-	-	-
Cable gland - 1 entry - ISO 20	0 696 60L	0 696 63L	0 696 62L	-
Cable gland - 2 entries - ISO 20	0 696 70L	0 696 73L	0 696 71L	-
Cable gland - 1 entry - PG 16	0 696 48L	-	-	-
Cable gland - 2 entries - PG 16	0 696 50L	-	-	-
PG 16 gland - multidiameter - 7-14 mm	0 696 53L	-	-	-
Caps to protect screws from electrical contacts	0 695 98L	-	-	-
Security tool	0 919 45	-	-	-
Standard claw + spacer	0 697 96L	-	-	-
Long claw + spacer	0 697 97L	-	-	-
Inox accessory for sandwich panel - height 5 cm	0 694 92L	-	-	-
Fixing accessory for thin walls	0 695 97L	-	-	-

# Plexo™ complete surface mounting IP 55

## switches and push-buttons



0 697 19L



0 697 61L



0 697 55L



0 697 22L

Mechanisms supplied complete with non-clipped frame

Pack	Cat.Nos	Reversible transformer
1	0 697 19L	IP 55 - IK 08. Automatic terminals Allows to create 5 functions: - a two-way switch or changeover push-button - a 2-gang two-way switch or 2-gang changeover push-button - a two-way switch + changeover push-button (left or right) Supplied as a 2-gang changeover push-button with two mounted half cover plates Supplied with 1 cover plate and 2 half cover plates
1	0 697 89L	
		● Grey ● Anthracite
<b>Switches 10 AX - 250 V~</b>		
		IP 55 - IK 08. Automatic terminals
10	0 697 11L	<b>Two-way switch</b> ● Grey ● Anthracite ○ White
10	0 697 61L	
10	0 697 51L	
		<b>Two-way switch - with indicator</b>
		Supplied with 230 V~ lamp to be wired with a terminal block
10	0 697 12L	● Grey ● Anthracite
10	0 697 21L	
		<b>Illuminated two-way switch</b>
		Supplied with 230 V~ lamp to be wired
5	0 697 13L	● Grey ● Anthracite
5	0 697 36L	
		<b>2-gang one-way switch</b>
5	0 697 14L	● Grey
		<b>Double pole switch - with indicator</b>
5	0 697 26L	● Grey
		<b>Intermediate switch</b>
5	0 697 16L	● Grey

Pack	Cat.Nos	Two-way switch 10 AX - 24 V~ - with indicator
10	1 002 77L	Supplied with 24 V~ lamp to be wired with a terminal block ● Grey
		<b>2-gang switch/push-button - 10 AX - 250 V~</b>
		IP 55 - IK 08. Automatic terminals
		Supplied as a 2-gang push-button
		Allows to create 3 functions: - 2-gang two-way switch - 2-gang changeover push-button - two-way switch + changeover push-button
10	0 697 15L	● Grey ● Anthracite ○ White
10	0 697 75L	
10	0 697 55L	
		<b>Push-buttons 10 A</b>
		IP 55 - IK 08. Automatic terminals
		<b>NO contact push-button</b>
10	0 697 20L	● Grey ● Anthracite ○ White
10	0 697 90L	
10	0 697 60L	
		<b>Illuminated NO contact push-button</b>
		Supplied with 230 V~ lamp to be wired
10	0 697 22L	● Grey ● Anthracite ○ White
10	0 697 82L	
10	0 697 62L	

## Plexo™ complete surface mounting IP 55

### motion sensor



0 697 40

Mechanisms supplied complete with non-clipped frame

Pack	Cat.Nos	Motion sensor
		<p>IP 55 - IK 04 - 3-wire with neutral</p> <p>Automatic terminals</p> <p>Allows control of a lighting device as soon as the movement is detected</p> <p>Maximum load:</p> <ul style="list-style-type: none"> <li>- 2000 W for incandescent, halogen 230 V and halogen 12 V lamps,</li> <li>- 1000 VA for fluorescent tubes and compact fluorescent lamps</li> </ul> <p>Temporization between 12 s and 16 min.</p> <p>Detection angle: 360°</p> <p>Light level threshold : 5 à 1275 lux</p> <p>Detection range from 0 to 12 m with detector installed on wall at a height of 2.50 m. Minimum installation height: 1.70 m</p> <p>With directional head, can be removed without tools</p> <p>Dim. 90 x 91 mm (diameter: 91 mm)</p>
1	0 697 40	<ul style="list-style-type: none"> <li>● Grey</li> <li>○ White</li> <li>○ White - retail packaging</li> </ul>
1	0 697 80	
1	0 488 98	

### socket outlets



0 697 49L



0 919 14

IP 55 - IK 08. Mechanisms supplied complete with non-clipped frame

Pack	Cat.Nos	Yard stake
1	0 697 49L	<p>Automatic terminals</p> <p>Equipped with two prewired French standard 2P+E socket outlets</p> <p>Only one connection required</p> <ul style="list-style-type: none"> <li>● Anthracite</li> </ul>

### Membrane glands with marking of Ø for tubes and cables

Pack	Cat.Nos	
50	0 919 14	● Grey (RAL 7035)
50	0 919 15	Up to Ø20
		Up to Ø25

## Plexo™ complete surface mounting IP 55

### socket outlets



0 697 43L

IP 55 - IK 08. Mechanisms supplied complete with non-clipped frame

Pack	Cat.Nos	German standard socket outlets - 16 A - 250 V~
		<p>With shutters for child protection</p> <p>Supplied with 1 membrane gland - 2 outputs</p> <p><b>2P+E socket outlets - automatic terminals</b></p> <ul style="list-style-type: none"> <li>● Grey</li> <li>● Anthracite</li> <li>○ White</li> </ul> <p><b>2P+E socket outlets - screw terminals</b></p> <ul style="list-style-type: none"> <li>● Grey</li> <li>● Anthracite</li> <li>○ White</li> </ul>
10	0 697 30L	
10	0 697 99L	
10	0 697 70L	
10	0 697 33L	
10	0 697 83L	
10	0 697 71L	
		<p><b>Prewired German standard socket outlets - 16 A - 250 V~</b></p> <p>Only one connection required</p> <p><b>2 x 2P+E socket outlets - screw terminals</b></p> <ul style="list-style-type: none"> <li>● Grey - horizontal mounting</li> <li>○ White - horizontal mounting</li> </ul> <p>5 0 697 42L</p> <p>5 0 697 72L</p> <p>5 0 697 44L</p> <p> <ul style="list-style-type: none"> <li>● Grey - vertical mounting</li> </ul> </p> <p>5 0 697 43L</p> <p><b>3 x 2P+E socket outlets - screw terminals</b></p> <ul style="list-style-type: none"> <li>● Grey - horizontal mounting</li> </ul> <p>5 0 697 43L</p> <p> </p> <p>5 0 697 46L</p> <p><b>2P+E socket outlet + 2-way switch - screw terminals</b></p> <ul style="list-style-type: none"> <li>● Grey - horizontal or vertical mounting</li> </ul> <p> </p>
1	0 697 84L	<p><b>German standard socket outlet for recharging electric bikes and electric two-wheelers</b></p> <p>Automatic terminals</p> <p>With shutters for child protection</p> <p>Supplied with 1 membrane gland - 2 outputs</p> <p>Supplied without base</p> <p>With bike marking on the flap</p> <p>2P+E - 16 A - 250 V</p> <ul style="list-style-type: none"> <li>● Anthracite</li> </ul>



# Plexo™ complete flush-mounting IP 55

switches, push-buttons, socket outlets and cable outlets



0 698 81L



0 698 29L



0 698 33L



0 698 88L

IP 55 - IK 08. Mechanisms supplied complete

Can be installed with claws Cat.Nos 0 697 96L and 0 697 97L (p. 39), except for cable outlet Cat.No 0 698 50L

Pack	Cat.Nos	Switches 10 AX - 250 V~
10	0 698 11L	<b>Two-way switch - automatic terminals</b> ● Grey ● Anthracite ○ White
10	0 698 81L	
10	0 698 51L	
5	0 698 12L	<b>Two-way switch - with claws</b> ● Grey ○ White
5	0 698 52L	
10	0 698 15L	<b>2-gang switch/push-button - 10 AX - 250 V~</b> Automatic terminals Supplied as a 2-gang changeover push-button Allows to create 3 functions: - 2-gang two-way switch - 2-gang changeover push-button - two-way switch + changeover push-button ● Grey ○ White
10	0 698 55L	
5	0 698 24L	<b>Push-buttons 10 A</b> Automatic terminals <b>Illuminated changeover push-button with label-holder</b> NO + NC contact Supplied with 12 V~ to be wired Can be equipped with 230 V~ lamp Cat.No 0 694 96L ● Grey ● Anthracite ○ Ivory ○ White
5	0 698 54L	
5	0 698 29L	
5	0 698 64L	
10	0 698 20L	
10	0 698 32L	<b>Illuminated NO contact push-button</b> Supplied with 230 V~ lamp to be wired ● Grey ○ White
10	0 698 23L	

Pack	Cat.Nos	German standard socket outlets - 16 A - 250 V~
10	0 698 33L	<b>2P+E - screw terminals</b> ● Grey ● Anthracite ○ White
10	0 698 59L	
10	0 698 69L	
10	0 698 34L	<b>2P+E - with claws</b> ● Grey ○ White
10	0 698 68L	
10	0 903 59	<b>Surface mounting box</b> For 20 A sockets Cat.Nos 0 557 03/06/08 Dimensions: 79 x 86 x 40 mm
10	0 698 48L	<b>Cable outlets</b> <b>Cable outlet 16 A - 250 V~</b> Supplied with cable grip Ø 5 to 13 mm (3 x 2,5²) ● Grey ● Anthracite ○ White
10	0 698 78L	
10	0 698 88L	
1	0 698 49L	<b>Cable outlet 20 A with terminal block</b> Equipped with 3 entry terminals (2.5 mm²) and 3 front terminals for easy wiring ● Grey ● Anthracite ○ White
1	0 698 99L	
1	0 698 89L	
1	0 698 50L	<b>Cable outlet 20 - 32 A</b> ISO 32 : Ø12 to 25 mm ● Grey

# Plexo™ mechanisms IP 55

## switches



0 698 00L



0 695 11L



0 696 25L



0 695 26L

Mechanisms supplied with cover plate  
Installation with surface mounting boxes or flush-mounting support frames (p. 39)

Pack	Cat.Nos	Reversible transformer
		IP 55 - IK 08. Automatic terminals Allows to create 5 functions: - a two-way switch or changeover push-button - a 2-gang two-way switch or 2-gang changeover push-button - a two-way switch + changeover push-button (left or right) Supplied as a 2-gang changeover push-button with two mounted half cover plates Supplied with 1 cover plate and 2 half cover plates
1	0 695 06L	 ● Grey ● Anthracite ● Ivory ○ White
1	0 698 00L	
1	0 698 09L	
1	0 696 18L	

Pack	Cat.Nos	Switches 10 AX - 250 V
		IP 55 - IK 08. Automatic terminals
10	0 695 11L	<b>Two-way switch</b>  ● Grey ● Anthracite ● Ivory ○ White
10	0 698 01L	
10	0 698 08L	
10	0 696 11L	
		<b>Two-way switch - with indicator</b> Supplied with 230 V~ lamp to be wired with a terminal block
5	0 695 12L	 ● Grey ● Anthracite ○ White
5	0 698 02L	
5	0 696 12L	
		<b>Illuminated two-way switch</b> Supplied with 230 V~ lamp to be wired
5	0 695 13L	 ● Grey ● Anthracite ○ White
5	0 698 03L	
5	0 696 13L	
		<b>Double pole switch</b> Becomes illuminated with lamp Cat.No 0 694 96L (p. 40) Indicator version with lamp Cat.No 0 694 98L (p. 40) to be wired with terminal block
10	0 695 30L	 ● Grey ● Anthracite ○ White
10	0 698 27L	
10	0 696 27L	

Pack	Cat.Nos	Switches 16 A - 250 V~
		IP 55 - IK 08. Automatic terminals
5	0 695 23L	<b>Two-way switch</b>  ● Grey
5	0 695 27L	
		<b>Double pole switch</b> ● Grey
1	0 695 28L	<b>Double pole switch - with indicator</b>  ● Grey Supplied with 230 V~ lamp to be wired with a terminal block

Pack	Cat.Nos	Two-way switch without neutral - with indicator
1	0 695 15L	 IP 55 - IK 07 4 AX 60 W mini - 1500 W maxi Supplied with 230 V~ lamp ● Grey

### Contactless switches

Pack	Cat.Nos	200 W LED - for light
1	0 695 86L	 ● Grey
1	0 695 95L	<b>1000 VA - for door</b>  ● Grey

### 2-gang switches/push-buttons - 10 AX - 250 V~

Pack	Cat.Nos	2-gang switches/push-buttons - 10 AX - 250 V~
		IP 55 - IK 08. Automatic terminals Supplied as a 2-gang push-button Allows to create 3 functions: - 2-gang 2-way switch - 2-gang changeover push-button - two-way switch + changeover push-button
10	0 695 25L	<b>2-gang two-way switch or 2-gang changeover push-button</b>  ● Grey ● Anthracite ○ White
10	0 698 05L	
10	0 696 25L	
		<b>Illuminated 2-gang two-way switch or 2-gang changeover push-button</b> Supplied with 230 V~ lamp to be wired
5	0 695 26L	 ● Grey ● Anthracite ○ White
5	0 698 06L	
5	0 696 26L	

### Intermediate switch

Pack	Cat.Nos	Intermediate switch
5	0 695 21L	 IP 55 - IK 07 ● Grey ○ White
5	0 696 20L	

## Plexo™ mechanisms IP 55

### push-buttons



0 696 30L



0 698 26L



0 695 44L

Mechanisms supplied with cover plate  
Installation with surface mounting boxes or flush-mounting support frames (p. 39)

Pack	Cat.Nos	Push-buttons 10 A
		IP 55 - IK 08 Automatic terminals
		<b>NO contact push-button</b>
10	0 695 40L	● Grey
10	0 698 10L	● Anthracite
10	0 696 30L	○ White
		<b>NO contact push-button - with indicator</b>
5	0 695 33L	Supplied with 230 V~ lamp to be wired with a terminal block ● Grey
		<b>Illuminated NO contact push-button</b>
5	0 695 42L	Supplied with 230 V~ lamp to be wired ● Grey
5	0 698 13L	● Anthracite
5	0 696 32L	○ White
		<b>Changeover push-button</b>
		NO + NC contact
5	0 695 41L	● Grey
5	0 698 41L	● Anthracite
5	0 696 31L	○ White
		<b>Illuminated changeover push-button</b>
		NO + NC contact Supplied with 230 V~ lamp to be wired
5	0 695 36L	● Grey
5	0 698 16L	● Anthracite
5	0 698 26L	● Ivory
5	0 696 16L	○ White
		<b>Illuminated changeover push-button with label-holder</b>
		NO + NC contact Supplied with 12 V~ lamp to be wired Can be equipped with 230 V~ lamp Cat.No 0 694 96L (p. 40)
5	0 695 44L	● Grey
5	0 698 14L	● Anthracite
5	0 696 34L	○ White

## Plexo™ mechanisms IP 55

### keyswitches, time lag switch and light sensitive switch



0 695 34L



0 698 04L  
+ surface mounting box 0 696 01L



0 695 17L

Mechanisms supplied with cover plate  
Installation with surface mounting boxes or flush-mounting support frames (p. 39)

Pack	Cat.Nos	Keyswitches 3 A - 250 V - Ronis n° 455
		Supplied with a set of 2 RONIS keys n° 455 Keys removable in all positions 2 NO contacts
1	0 695 34L	2 positions marked "0 - I" ● Grey
1	0 695 35L	3 positions marked "I - 0 - II" ● Grey
		<b>Keyswitch and key-operated push-button "secure access"</b>
		IP 20 - IK 07 10 A - 250 V To be equipped with European key barrel Cat.No 0 697 95
		<b>2-position keyswitch</b>
1	0 697 06L	1 contact - 2 poles Key extracted in central position without changing the status of the contacts ● Grey
		<b>3-position key-operated push-button</b>
1	0 697 05L	Changeover switch with OFF position ● Grey
		<b>Accessory</b>
1	0 697 95	European standard key barrel Key extracted in 0 position Supplied with one set of 3 keys
		<b>Illuminated time lag switch 230 V~</b>
		IP 55 - IK 07 Without neutral - 2-wire - screw terminals Lighting or heating control with switch-off timer Possibility to install several time lag switches on the same circuit Supplied with lamp Temporization: 25 s to 15 min. Maximum loads: - 1000 W incandescent - 400 W halogen 130 V - 400 VA ELV halogen lamps - 400 VA fluorescent lamps - 1840 W resistive (heating)
1	0 695 04L	● Grey
1	0 698 04L	● Anthracite
1	0 696 04L	○ White
		<b>Light sensitive switch</b>
		IP 55 - IK 08 Screw terminals Can be used to switch a lighting circuit "ON" and "OFF" based on light conditions (nightfall, daybreak) Supplied in one piece, including photoelectric cell Maximum loads: - 1400 W incandescent - 500 VA fluorescent tubes - 200 VA LEDs Adjustable light level threshold: 2 to 1500 lux Can be combined with all finishes of surface mounting boxes and support frames (p. 39)
1	0 695 17L	

## Plexo™ mechanisms IP 55

### motion sensors



0 695 20L



0 401 49

Mechanisms supplied with cover plate  
Installation with surface mounting boxes or flush-mounting support frames (p. 39)

Pack	Cat.Nos	Motion sensors
1	0 695 20L	<p>Sensors without override Compatible with any type of lamp IR detection, detection field 170° Detection range 8 m Time delay setting from 5 s to 30 min Light level threshold setting from 5 to 1275 lux 4 levels of sensitivity setting Standby consumption : 0.01 W</p> <p><b>Motion sensor, 2 wires, without neutral</b> Accepted power by lamp type : - LEDs: 2 to 100 W - Compact fluorescent : 2 to 100 W - Halogens, incandescent: 2 to 150 W - LEDs, CFLs, Halogen, fluo tube with ferromagnetic or electronic transformer: 2 to 150 VA If several sensors are installed on the same circuit, the minimum load changes: refer to the technical sheet Possibility to install up to 3 sensors in parallel Additional remote manual control possible with push button, 10 max. Can be associated with a time-lag switch (p. 34) Accepted power by lamp type will be power of the time-lag switch used.</p>
1	0 695 22L	<p><b>Motion sensor, 3 wires, with neutral</b> Accepted power by lamp type : - LEDs: 0 to 500 W - Compact fluorescent: 0 to 500 W - Halogens, incandescent: 0 to 2000 W - LEDs, CFLs, Halogen, fluo tube with ferromagnetic or electronic transformer: 0 to 1000 VA Possibility to install up to 10 sensors in parallel Additional remote manual control possible with push button, 10 max. Master/Slave function available (10 slaves max. for 1 master)</p>
1	0 401 49	<p><b>Active power compensator</b> Ensures compatibility of 2-wire electronic lighting controls without neutral with all available types of loads (LEDs, compact fluorescent lamps, ELV halogen lamps with electronic or ferromagnetic ballast, 230 V halogen lamps, fluorescent tubes, incandescent lamps) Standby consumption: 1.2 W</p>

## Plexo™ mechanisms IP 55

### roller blind and ventilation controls



0 696 29L



0 695 08L

Mechanisms supplied with cover plate  
Installation with surface mounting boxes or flush-mounting support frames (p. 39)

Pack	Cat.Nos	Roller blind controls
1	0 695 38L	<p>IP 55 - IK 06</p> <p><b>Switch</b> For direct control of 6 AX - 250 V - 500 W max. blind, awning or canopy motor</p>
1	0 698 98L	<p>● Grey</p>
1	0 696 29L	<p>● Anthracite</p>
		○ White
1	0 695 39L	<p><b>Push-button</b> For controlling 6 A - 250 V - 500 W max. blind, awning or canopy motor by electronic box</p>
1	0 696 38L	<p>● Grey</p>
		○ White
1	0 695 08L	<p><b>Electronic room thermostat</b> IP 55 - IK 07 - 250 V~ Ensures the regulation of the temperature in wet premises or specific use (e.g. workshops, laboratories, greenhouses, etc.) Adjustable range from 10°C to 30°C Equipped with a push-button for summer/winter function</p>
		● Grey



## Plexo™ mechanisms IP 55

German standard and British standard socket outlets, cable outlet and blanking plate



0 695 70L



0 695 50L



0 696 37L

Mechanisms supplied with cover plate  
Installation with surface mounting boxes or flush-mounting support frames (p. 39)

### Pack Cat.Nos German standard socket outlets 16 A - 250 V~

		IP 55 - IK 08
		<b>2P+E - automatic terminals</b>
10	0 695 70L	● Grey
10	0 698 71L	● Anthracite
10	0 696 40L	○ White
		<b>2P+E - screw terminals</b>
10	0 695 71L	● Grey
10	0 698 39L	● Anthracite
10	0 696 39L	○ White
		<b>2P+E - key-operated - automatic terminals</b>
1	0 695 74L	● Grey

### Prewired German standard socket outlets 16 A - 250 V~

		Automatic terminals One-piece mechanism, only one connection required
		<b>2 x 2P+E - horizontal mounting</b>
5	0 695 76L	● Grey
5	0 698 79L	● Anthracite
5	0 696 75L	○ White
		<b>2 x 2P+E - vertical mounting</b>
5	0 695 77L	● Grey
		<b>3 x 2P+E - horizontal mounting</b>
5	0 695 78L	● Grey

### German standard socket outlet for recharging electric bikes and electric two-wheelers

		IP 55 - IK 08 Automatic terminals With shutters for child protection With bike marking on the flap 2P+E - 16 A - 250 V
1	0 698 86L	● Anthracite

### Pack Cat.Nos Cable outlet

		IP 55 - IK 08 16 A - 250 V Supplied with cable grip Ø5 to 13 mm (3 x 2,5²)
5	0 695 50L	● Grey

### Blanking plate

		Allows to conceal free space Compatible with surface mounting boxes and support frames
5	0 695 37L	● Grey
5	0 698 37L	● Anthracite
5	0 698 47L	● Ivory
5	0 696 37L	○ White



# Plexo™ mechanisms IP 55

## surface mounting boxes and flush-mounting support frames



To be equipped with modular Plexo mechanisms (p. 33 to 38)

Pack	Cat.Nos	1-gang surface mounting boxes with membrane glands
10	0 696 51L	Equipped with removable membrane glands
10	0 696 01L	2 membrane glands 1 entry
10	0 698 63L	● Grey
10	0 696 89L	● Anthracite
		● Ivory
		○ White
		<b>2-gang and 3-gang surface mounting boxes with membrane glands</b>
		No separation between compartments in order to facilitate the cabling operations and to allow the installation of prewired socket outlets
		<b>2-gang - horizontal or vertical mounting</b>
		3 membrane glands 1 entry
		1 membrane gland 2 entries
5	0 696 72L	● Grey
5	0 696 02L	● Anthracite
5	0 698 67L	● Ivory
5	0 696 90L	○ White
		<b>3-gang - horizontal or vertical mounting</b>
		4 membrane glands 1 entry
		1 membrane gland 2 entries
5	0 696 80L	● Grey
5	0 696 03L	● Anthracite
5	0 696 88L	○ White
		<b>Surface mounting boxes for cable glands</b>
		<b>1-gang, 1 entry - PG 16</b>
10	0 696 52L	● Grey
		<b>1-gang, 1 entry - ISO 20</b>
10	0 696 56L	● Grey
10	0 696 28L	● Anthracite
10	0 696 86L	○ White
		<b>1-gang, 2 entries - ISO 20</b>
10	0 698 46L	● Grey
		<b>2-gang, 2 entries - ISO 20</b>
		For horizontal or vertical mounting
		The 2-entry cable gland can be positioned at different locations
5	0 696 68L	● Grey
5	0 696 10L	● Anthracite
5	0 696 66L	○ White

Pack	Cat.Nos	Flush-mounting support frames
		Used for flush-mounting version for German and French standard boxes only
		<b>1-gang</b>
		Can be equipped with claws Cat.Nos 0 697 96L/97L
10	0 696 81L	● Grey
10	0 696 06L	● Anthracite
10	0 698 90L	● Ivory
10	0 696 92L	○ White
		<b>1-gang - with claws</b>
10	0 696 82L	● Grey
10	0 696 09L	● Anthracite
10	0 696 93L	○ White
		<b>2-gang - horizontal or vertical mounting</b>
		71 mm fixing centers
5	0 696 83L	● Grey
5	0 696 07L	● Anthracite
5	0 698 53L	● Ivory
5	0 696 94L	○ White
		<b>3-gang - horizontal or vertical mounting</b>
		71 mm fixing centers
5	0 696 87L	● Grey
5	0 696 08L	● Anthracite
5	0 696 98L	○ White
		<b>Claws</b>
		Sets of 2 claws + 1 spacer
50	0 697 96L	Standard claws
50	0 697 97L	Long claws

# Plexo™ mechanisms IP 55

## membrane glands and accessories



0 695 96L



0 695 99L



0 696 65L



0 696 60L



0 696 50L



0 694 96L



0 694 98L



0 694 95L



0 694 92L



0 695 97L

Pack	Cat.Nos	Membrane glands
10	0 695 96L	<b>1 entry - Ø up to 25 mm</b> Grey
10	0 695 99L	<b>2 entries - Ø up to 12.5 mm</b> Grey
10	0 696 65L	<b>For pairing</b> Allows to combine surface mounting boxes with one another for an IP 44 installation Grey

Pack	Cat.Nos	Cable glands
10	0 696 60L	<b>1 entry ISO 20</b> Grey Anthracite White
10	0 696 63L	
10	0 696 62L	
10	0 696 48L	<b>1 entry PG 16</b> Grey
10	0 696 70L	<b>2 entries ISO 20</b> Grey Anthracite White
10	0 696 73L	
10	0 696 71L	
10	0 696 50L	<b>2 entries PG 16</b> Grey
10	0 696 53L	<b>PG 16 gland - multidiameter</b> Ø7 to 14 mm

Pack	Cat.Nos	Lamps to be wired
5	0 694 96L	230 V~ - 0.2 mA - blue - locator 230 V~ - 2 mA - blue - indicator 12 to 48 V~ - 2.6 mA (48 V~) - blue
5	0 694 98L	
5	0 694 95L	
Pack	Cat.Nos	Fixing accessories
5	0 694 92L	<b>1-gang stainless steel height spacer for sandwich panel</b> Supplied with screw for fixing the product on the height spacer and double insulated caps (Class II) for the wiring accessory
10	0 695 97L	<b>For thin walls</b> Does not require a flush-mounting box
10	0 695 98L	<b>Set of 4 caps</b> For sealing fixing holes when installing a surface mounting box on a metal support Grey

## Green'up™ Access sockets

for electric vehicles





0 697 08L



0 698 18L

Used for safely charging rechargeable electric and hybrid vehicles which take Mode 2 cord (compatible with Mode 1)  
Suitable for residential and workplace use  
Connected to the consumer panel via one 3 x 2.5 mm<sup>2</sup> dedicated line (1 line per socket) protected by 30 mA - 20 A C curve, F type (Hpi) RCBOs Cat.No 4 107 54 or 4 108 56 (or 30 mA F type (Hpi) RCCB + 20 A C curve circuit breaker)  
The use of a surge protective device is recommended  
Recommended installation height: between 0.80 and 1.20 m from the floor

Pack	Cat.Nos	16 A EV sockets
		Heavy-duty mechanisms with silvered contacts Single-phase sockets - screw connection - 230 V For charging 1 vehicle Conform to NF C 61-314 and IEC 60-884-1 standards Suitable for installation in private houses, lock-up garages, parking lots, etc <b>IP 55 - IK 08 - 16 A - 230 V - Plexo</b> Automatic terminals, with shutters Can be used with base Cat.no 0 694 94L to hang up the vehicle charging cable control box ● Anthracite
1	0 697 08L	 Supplied complete, surface mounting, German standard
1	0 698 18L	 German standard mechanism, to be equipped with a Plexo IP 55 flush-mounting support frame or surface mounting box (p.39)
1	0 694 94L	<b>Base</b> For hanging up the vehicle charging cable control box


## Green'up™ Access sockets

for electric vehicles




The innovative Green'up system, a Legrand Group technology, activates "maximum power" mode, ensuring fast and safe charging.

### Installation principle for an individual Mode 2 socket

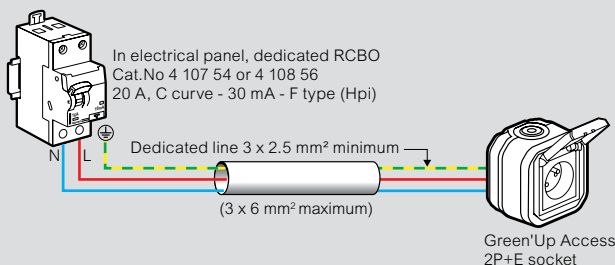

- Can be controlled by clock/switch type control units... (to be ordered separately)
- The use of a surge protective device is recommended

### Installation principle for several Mode 2 sockets

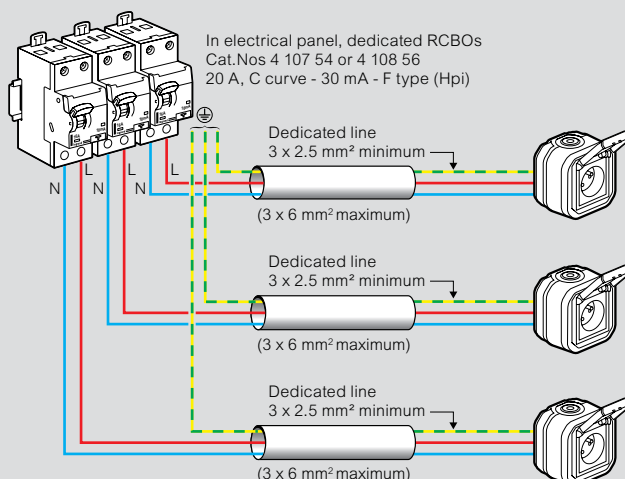

- Can be controlled by clock/switch type control units... (to be ordered separately)
- The use of a surge protective device is recommended










# Plexo with Netatmo - connected home

## switches and socket outlets



Used to complete your connected installation, require prior installation of a starter pack for connected installation  
Zigbee 3.0 compatible

Pack	Cat.Nos	Connected light switches	Pack	Cat.Nos	Wireless and batteryless roller shutter switch
		<p>For local or remote control of lighting Compatible with all loads (dimnable LEDs mandatory if dimmer mode is activated) Dimmer mode and locator/ indicator function can be activated from the Home + Control App Can be paired with one or more wireless controls or push-buttons Can be installed in place of an existing switch in a flush-mounting box 40 mm deep Screw fixing. Multi-gang installation possible To be equipped with a flush-mounting support frame or surface mounting box (p. 39)</p> <p><b>5-125 W LED without neutral - 230 V~ (with dimmer option)</b> Allows to control lights by voice (via a voice assistant) Supplied with a bleeder</p> <p>1 0 698 75L 1 0 698 95L</p> <p> ● Grey ● Anthracite</p> <p><b>150 W LED without neutral - 230 V~</b></p> <p>1 0 698 76L 1 0 698 96L</p> <p> ● Grey ● Anthracite</p>			<p>Used to control up to 20 wired roller shutter switches, or to centralise several roller shutters Pair by tapping on the selected roller shutter switch(es) or via the Home + Control App Supplied complete with removable stickers for fixing the control unit on any substrate Extra-flat switch Can be used as a weatherproof remote control</p> <p>1 0 698 73L 1 0 698 83L</p> <p> ● Grey ● Anthracite</p>
		<p><b>Wireless and batteryless light switch - 1-gang</b></p> <p>Used to add an extra lighting control Pair by tapping on the selected wired products (switches, micromodules, sockets and cable outlets) or via the Home + Control App Supplied complete with removable stickers for fixing the control unit on any substrate Extra-flat switch Can be used as a weatherproof remote control</p> <p>1 0 698 74L 1 0 698 94L 1 0 698 93L 1 0 698 84L</p> <p> ● Grey ● Anthracite ● Ivory ○ White</p>			<p><b>Connected socket outlets</b></p> <p>Used to control electrical appliances remotely by voice (via voice assistant) or via the Home + Control App Can be paired with one or more wireless light switch to create a controlled socket 16 A 3680 W maxi socket outlet (protected against overloads). Compatible with any electrical appliance or large household appliance Measures instantaneous power and monitors daily/ weekly/monthly/yearly consumption, plus sends configurable notifications (when a preset threshold has been reached) Compatible with load-shedding function Connection via automatic terminals LED indicator function can be activated via the Home + Control App</p> <p>1 0 698 72L 1 0 698 92L 1 0 698 82L</p> <p> ● Grey ● Anthracite ○ White</p> <p><b>French standard</b></p> <p>1 0 698 77L 1 0 698 97L 1 0 698 87L</p> <p> ● Grey ● Anthracite ○ White</p> <p><b>German standard</b></p>
		<p><b>Wireless and batteryless light switch - 2-gang</b></p> <p>Used to add 2 extra lighting controls Pair by tapping on the selected wired products (switches, micromodules, sockets and cable outlets) or via the Home + Control App Supplied complete with removable stickers for fixing the control unit on any substrate Extra-flat switch Can be used as a weatherproof remote control</p> <p>1 0 698 19L 1 0 698 36L 1 0 698 57L 1 0 698 35L</p> <p> ● Grey ● Anthracite ● Ivory ○ White</p>			





**Legrand SLV, d.o.o.**

Planjava 2

1236 Trzin

☎ : 01 562 01 70

email: [info.slovenia@legrand.si](mailto:info.slovenia@legrand.si)

[www.legrand.si](http://www.legrand.si)